


VNTC-18-24-BK-1 Cut Sheet

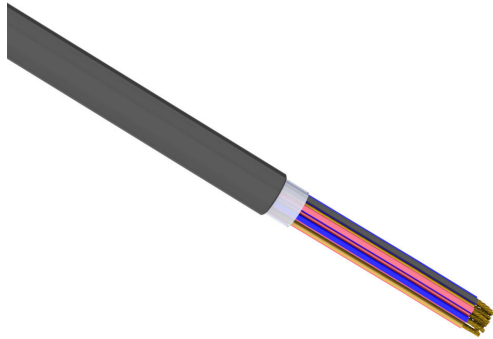

Southwire control cable, unshielded, 24 conductors, 18 AWG, bare copper, PVC/Nylon conductor insulation material, method 1 table 2 color code, PVC jacket, black, cut to length.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/VNTC-18-24-BK-1>

Technical Specifications

Brand	Southwire
Item	Cable
Wire/Cable Type	Control
UL Wire/Cable Type	TC-ER
Application	General purpose
Flexibility	Semi-flexible
Voltage Rating	600V
Conductors	24 conductors
Conductor Size	18 AWG
Conductor Stranding	7-stranded
Conductor Material	Bare copper
Conductor Insulation Material	PVC/Nylon
Conductor Insulation Color	Method 1 table 2 color code

Shielding	Unshielded
Jacket Material	PVC
Jacket Color	Black
Nominal Overall Cable Diameter	0.826in
Bulk Length	Cut to length
Package Type	<ul style="list-style-type: none">• 25 to 30ft = Coil• 31 to 55ft = 14 x 7in Reel• 56 to 80ft = 14 x 10in Reel• 81 to 125ft = 16 x 10in Reel• 126 to 175ft = 18 x 10in Reel• 176 to 225ft = 18 x 13in Reel• 226 to 510ft = 24 x 17in Wooden Reel• 511 to 815ft = 30 x 17in Wooden Reel• 816 to 5000ft = Large Wooden Reel

Agency Approvals

UL Listed File #	E75755
UL Recognized File #	None
UL Hazardous File #	None
CE	None
CSA File #	None
RoHS Status	Meets RoHS Chemical Restrictions - No CE (See RoHS Statement Below)
EU REACH	View EU REACH document
Other	RoHS Statement