


VNTC-18-8-BK-1 Cut Sheet

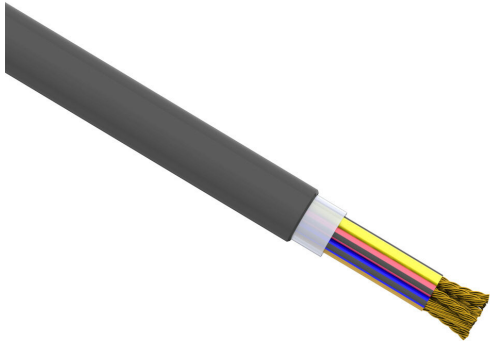

Southwire control cable, unshielded, 8 conductors, 18 AWG, bare copper, PVC/Nylon conductor insulation material, method 1 table 2 color code, PVC jacket, black, cut to length.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/VNTC-18-8-BK-1>

Technical Specifications

Brand	Southwire
Item	Cable
Wire/Cable Type	Control
UL Wire/Cable Type	TC-ER
Application	General purpose
Flexibility	Semi-flexible
Voltage Rating	600V
Conductors	8 conductors
Conductor Size	18 AWG
Conductor Stranding	7-stranded
Conductor Material	Bare copper
Conductor Insulation Material	PVC/Nylon
Conductor Insulation Color	Method 1 table 2 color code

Shielding	Unshielded
Jacket Material	PVC
Jacket Color	Black
Nominal Overall Cable Diameter	0.49in
Bulk Length	Cut to length
Package Type	<ul style="list-style-type: none">• 25 to 50ft = Coil• 51 to 160ft = 14 x 7in Reel• 161 to 230ft = 14 x 10in Reel• 231 to 355ft = 16 x 10in Reel• 356 to 495ft = 18 x 10in Reel• 496 to 645ft = 18 x 13in Reel• 646 to 1445ft = 24 x 17in Wooden Reel• 1446 to 2315ft = 30 x 17in Wooden Reel• 2316 to 5000ft = Large Wooden Reel

Agency Approvals

UL Listed File #	E75755
UL Recognized File #	None
UL Hazardous File #	None
CE	None
CSA File #	None
RoHS Status	Meets RoHS Chemical Restrictions - No CE (See RoHS Statement Below)
EU REACH	View EU REACH document
Other	RoHS Statement