


W-8-4BK-1 Cut Sheet

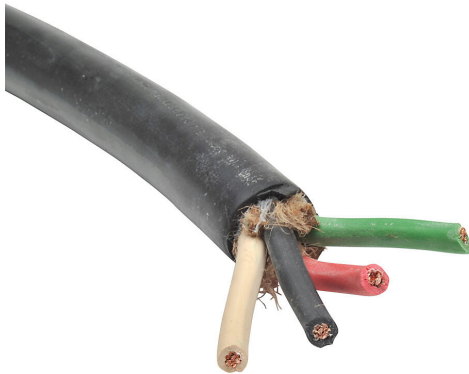

Southwire portable cord, unshielded, W, 2000V, 4 conductors (includes ground), 8 AWG, EPDM thermoset rubber conductor insulation material, black, white, red and green, CPE thermoset rubber jacket, black, cut to length.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/W-8-4BK-1>

Technical Specifications

Brand	Southwire
Item	Cord
Wire/Cable Type	Portable
UL Wire/Cable Type	W
Applicable Standards	UL 1650
Application	Power
Flexibility	Flexible
Voltage Rating	2000V
Conductors	4 conductors (includes ground)
Conductor Size	8 AWG
Conductor Stranding	71-stranded
Conductor Material	Bare copper
Conductor Insulation Material	EPDM thermoset rubber

Conductor Insulation Color	Black, white, red and green
Shielding	Unshielded
Jacket Material	CPE thermoset rubber
Jacket Color	Black
Nominal Overall Cable Diameter	1.01in
Bulk Length	Cut to length
Package Type	<ul style="list-style-type: none">• 20 to 20ft = Coil• 21 to 40ft = 14 x 7in Reel• 41 to 55ft = 14 x 10in Reel• 56 to 85ft = 16 x 10in Reel• 86 to 115ft = 18 x 10in Reel• 116 to 150ft = 18 x 13in Reel• 151 to 250ft = 24 x 17in Wooden Reel

Agency Approvals

UL Listed File #	E172226
UL Recognized File #	None
UL Hazardous File #	None
CE	None
CSA File #	236844
RoHS Status	Meets RoHS Chemical Restrictions - No CE (See RoHS Statement Below)
EU REACH	View EU REACH document
Other	RoHS Statement