


# WG-262-040-R Cut Sheet

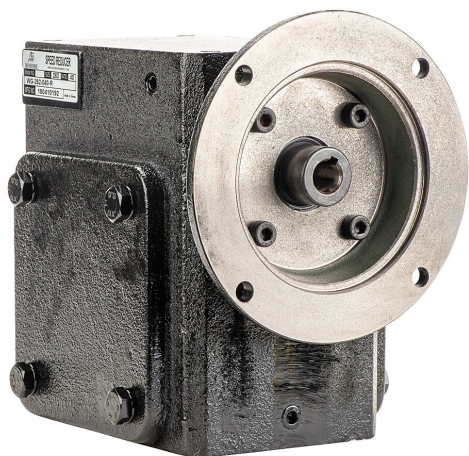

IronHorse heavy-duty worm gearbox, 40:1 ratio, 56C-Face input, right hand, 1.125in diameter output shaft, nominal 0.75hp at 1.0 SF, 1919 lb-in mechanical output torque, 2-5/8in center distance, cast iron housing, tapped-base mount.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/WG-262-040-R>

## Technical Specifications

|                      |                              |
|----------------------|------------------------------|
| Brand                | IronHorse                    |
| Item                 | Gearbox                      |
| Application          | General purpose              |
| Duty Rating          | Heavy-duty                   |
| Gearbox Type         | Worm                         |
| Gear Ratio           | 40:1                         |
| Speed Rating         | 1750rpm input / 44rpm output |
| Input Configuration  | 56C-Face                     |
| Input Power Rating   | Nominal 0.75hp at 1.0 SF     |
| Output Configuration | Right hand                   |

|                               |                                 |
|-------------------------------|---------------------------------|
| Gearbox Output Shaft Diameter | 1.125in                         |
| Mechanical Output Torque      | 1919 lb-in                      |
| Thermal Output Torque         | 1153 lb-in                      |
| Center Distance               | 2-5/8in                         |
| Housing Material              | Cast iron                       |
| Mounting                      | Tapped-base                     |
| Finish                        | Anti-corrosion primer and paint |
| Lubrication Type              | Pre-filled with synthetic lube  |
| Oil Seal Type                 | Double-lip                      |

## Agency Approvals

|                      |                        |
|----------------------|------------------------|
| UL Listed File #     | None                   |
| UL Recognized File # | None                   |
| UL Hazardous File #  | None                   |
| CE                   | None                   |
| CSA File #           | None                   |
| RoHS Status          | No                     |
| EU REACH             | View EU REACH document |

## Dimensional Drawings



2D Drawing PDF Link:  
<https://cdn.automationdirect.com/static/drawings/WG-262-040-R.pdf>  
See store item page for other formats.