


WPG-A-M-0100-N Cut Sheet

Gefran magnetostrictive linear position sensor, rodless slide, 100mm stroke, 0-10 VDC output, 33 x 16.3 x 254mm, channel mount, 18mm DIN 43650 Form A.

For complete product information, please see this item on our store at the following link:

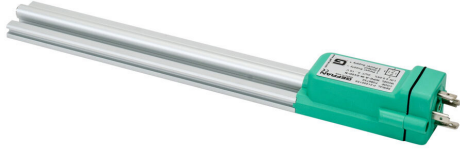

<https://www.automationdirect.com/pn/WPG-A-M-0100-N>

Technical Specifications

Brand	Gefran	Operating Voltage	19.2-28.8 VDC
Item	Linear position sensor	Sensor Resolution	Infinite
Transducer Type	Magnetostrictive	Linearity	+/- 0.15%
Action	Rodless slide	Mounting	Channel
Stroke	100mm	IP Rating	IP67
Output	0-10 VDC	Connection	18mm DIN 43650 Form A
Housing Material	Anodized aluminum	Number of Wires	4
Housing Size	33 x 16.3 x 254mm	Additional Information	Purchase cursor and mounting brackets separately

Agency Approvals

UL Listed File #	None
UL Recognized File #	None
UL Hazardous File #	None
CE	View CE declarations
CSA File #	None
RoHS Status	Yes (See CE Doc)
EU REACH	View EU REACH document

Dimensional Drawings



2D Drawing PDF Link:
<https://cdn.automationdirect.com/static/drawings/WPG-A-M-0100-N.pdf>
See store item page for other formats.