


# WT41104 Cut Sheet

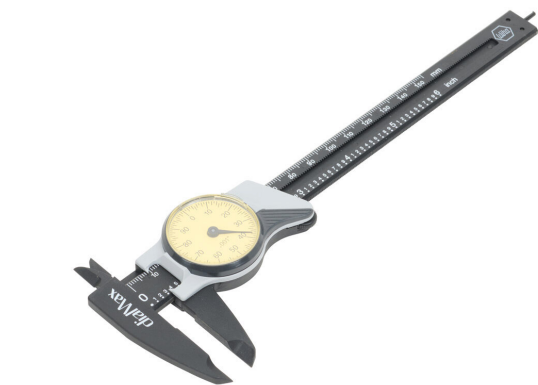

Wiha DialMax series dial caliper, 0–6in (152mm) range, 0.001in accuracy.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/WT41104>

## Technical Specifications

Brand	Wiha
Item	Caliper
Series	DialMax
Display Type	Dial
Measuring Range (PF)	0–6in (152mm)
Accuracy	0.001in
Measurement Type	Imperial
Jaw Material	Steel
Jaw Depth	1.6in

Range Per Revolution	0.1in
Caliper Measurements	Depth, inside, outside and step
Caliper Material	Non metallic, non magnetic plastic
Includes	Printed instruction insert
Application	Measurement
Additional Information	Bi-directional thumb roller with friction stop, bezel rotation allows for quick realignment to zero

## Agency Approvals

UL Listed File #	None
UL Recognized File #	None
UL Hazardous File #	None
CE	None
CSA File #	None
RoHS Status	No
EU REACH	<a href="#">View EU REACH document</a>