


XBF-AD08A Cut Sheet

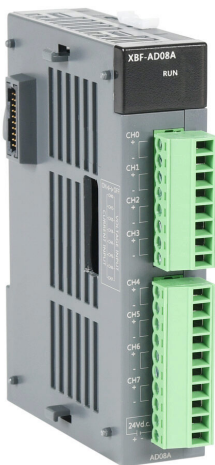

LS Electric XGB analog input module, 8-channel, current/voltage, 12-bit, input current signal range(s) of 0-20 mA, 4-20 mA, input voltage signal range(s) of 0-5 VDC, 1-5 VDC, 0-10 VDC, external 24 VDC required.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/XBF-AD08A>

Technical Specifications

Brand	LS Electric XGB
Item	Input module
I/O Module Type	Analog
Number Of Input Channels	8
Input Signal Type(s)	Current/voltage
Isolated Channels	No
Input Resolution	12-bit
Input Current Signal Range	0-20 mA, 4-20 mA
Input Voltage Signal Range	0-5 VDC, 1-5 VDC, 0-10 VDC
External Power Requirement	24 VDC
Includes	Removable terminal block
Programming Software	XG5000 programming software v4.7 or later

Agency Approvals

UL Listed File #	E124950
UL Recognized File #	None
UL Hazardous File #	None
CE	View CE declarations
CSA File #	None
RoHS Status	Yes (See CE Doc)
EU REACH	View EU REACH document

Dimensional Drawings



2D Drawing PDF Link:
<https://cdn.automationdirect.com/static/drawings/2d/XBF-AD08A.pdf>
See store item page for other formats.