


# XGC220390-091 Cut Sheet

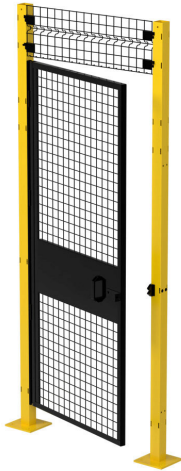

Velox machine guarding door, left hinged, swing out, 36 x 96in, 2 x 2in grid, carbon steel, yellow and black. 2 door posts XG5508D and mounting hardware included.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/XGC220390-091>

## Technical Specifications

<b>Brand</b>	Velox
<b>Item</b>	Machine guarding door
<b>Door Type</b>	Left hinged
<b>Open Direction</b>	Swing out
<b>Door Size</b>	36 x 96in
<b>Overall Width</b>	39.25in
<b>Grid Size</b>	2 x 2in
<b>Wire Thickness</b>	8 gauge

<b>Material</b>	Carbon steel
<b>Finish</b>	Powder coat
<b>Color</b>	Yellow and black
<b>Number of Hinges Per Door</b>	4
<b>Hinge Type</b>	Drop pin
<b>Number Of Latches</b>	1
<b>Latch Type</b>	Snap
<b>Includes</b>	2 door posts XG5508D and mounting hardware

## Agency Approvals

<b>UL Listed File #</b>	None
<b>UL Recognized File #</b>	None
<b>UL Hazardous File #</b>	None
<b>CSA File #</b>	None
<b>RoHS Status</b>	No
<b>EU REACH</b>	<a href="#">View EU REACH document</a>

## Dimensional Drawings



2D Drawing PDF Link:  
<https://cdn.automationdirect.com/static/drawings/2d/XGC220390-091.pdf>  
See store item page for other formats.