


# XTD-N40140F-PT1 Cut Sheet

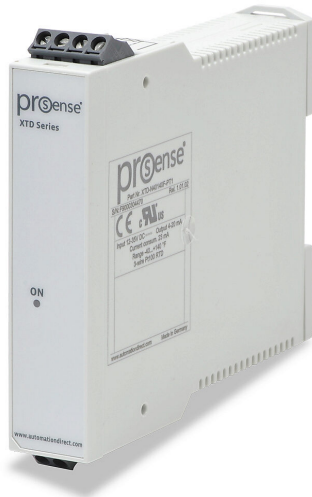

ProSense temperature transmitter, isolated, Pt100 RTD input, -40 to 140 deg F fixed, 4-20 mA output, 12 to 35 VDC operating voltage, 35mm DIN rail mount, removable screw terminal plugs.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/XTD-N40140F-PT1>

## Technical Specifications

<b>Brand</b>	ProSense
<b>Item</b>	Temperature transmitter
<b>Isolation</b>	Isolated
<b>Field Configurable</b>	No
<b>Input RTD Signal Types</b>	Pt100 RTD
<b>Factory Calibrated Temperature Range</b>	-40 to 140 deg F fixed
<b>Output Current Signal Range</b>	4-20 mA
<b>Operating Voltage</b>	12 to 35 VDC
<b>Housing Material</b>	Plastic
<b>Mounting</b>	35mm DIN rail
<b>Electrical Connection</b>	Removable screw terminal plugs

## Agency Approvals

<b>UL Listed File #</b>	None
<b>UL Recognized File #</b>	E311366
<b>UL Hazardous File #</b>	None
<b>CE</b>	<a href="#">View CE declarations</a>
<b>CSA File #</b>	None
<b>RoHS Status</b>	Yes (See CE Doc)
<b>EU REACH</b>	<a href="#">View EU REACH document</a>