


# XTOE1P6CGSS Cut Sheet

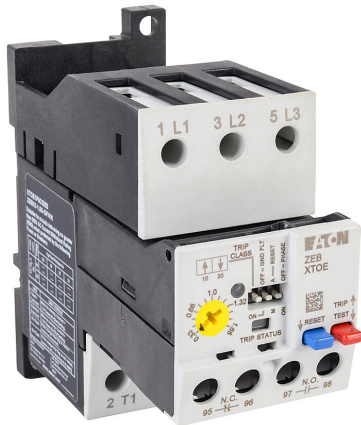

Eaton XT series electronic overload relay, 0.33-1.65A adjustable, solid state, ground fault protection, stand-alone power connection(s), DIN rail or panel mount. For use with any contactor.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/XTOE1P6CGSS>

## Technical Specifications

|                                 |   |
|---------------------------------|---|
| <b>Brand</b>                    | Eaton   |
| <b>Item</b>                     | Relay   |
| <b>Series</b>                   | XT  |
| <b>Relay Type</b>               | Electronic overload   |
| <b>Full Load Amperage Range</b> | 0.33-1.65A adjustable   |
| <b>Operation Type</b>           | Solid state   |
| <b>Auxiliary Contacts</b>       | (1) N.O. / (1) N.C.   |
| <b>Trip Class</b>               | Selectable 10/20  |
| <b>Phase Loss Sensitive</b>     | Yes   |
| <b>Ground Fault Protection</b>  | Yes   |
| <b>Connection</b>               | Stand-alone power   |
| <b>Mounting</b>                 | DIN rail or panel   |
| <b>For Use With</b>             | Any contactor   |
| <b>Additional Information</b>   | Self powered, selectable phase imbalance and ground fault protection, optional communications available |

## Agency Approvals

|                             |  |
|-----------------------------|--|
| <b>UL Listed File #</b>     | E1230                                  |
| <b>UL Recognized File #</b> | None                                   |
| <b>UL Hazardous File #</b>  | None                                   |
| <b>CE</b>                   | <a href="#">View CE declarations</a>   |
| <b>CSA File #</b>           | 156828, 000353_0_000                   |
| <b>RoHS Status</b>          | No                                     |
| <b>EU REACH</b>             | <a href="#">View EU REACH document</a> |