


ZL-RRL16F-24-2 Cut Sheet

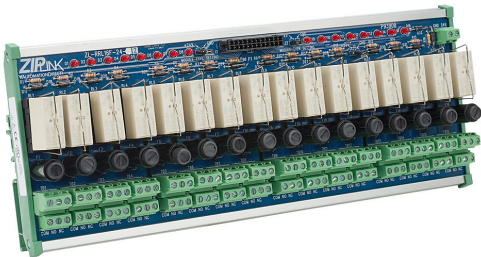

ZIPLink fused relay output module, 16-point, sourcing, (16) Form C (SPDT) relays, LED indication, 24 VDC (coil), 8A at 250 VAC, 8A at 30 VDC, DIN rail mount. For replacement relays, use ZL-RELAY-F24X4. Fuses sold separately.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/ZL-RRL16F-24-2>

Technical Specifications

Brand	ZIPLink
Item	Output module
I/O Module Type	Fused relay
Replacement	No
Number of Points	16
Discrete Output Type	Sourcing
Relay Configuration	(16) Form C (SPDT) relays
Indicating Type	LED indication
Nominal Voltage	24 VDC (coil)
Load Current	8A at 250 VAC, 8A at 30 VDC
Fuse Type	5mm x 20mm fuses
Mounting	DIN rail
Additional Information	For replacement relays, use ZL-RELAY-F24X4. Fuses sold separately

Agency Approvals

UL Listed File #	E139594
UL Recognized File #	None
UL Hazardous File #	None
CE	View CE declarations
CSA File #	None
RoHS Status	Yes (See CE Doc)
EU REACH	View EU REACH document

Dimensional Drawings



2D Drawing PDF Link:
<https://cdn.automationdirect.com/static/drawings/ZL-RRL16F-24-2.pdf>
See store item page for other formats.