

Enclosure Accessories - Universal Deep-Hinged Window Door



Applications

The Wiegmann Universal Deep Hinged Door is styled after their Ultimate Series Enclosures. Doors are compatible with any NEMA 3R, 4, 4X, and 12 rated enclosures.

Deep-hinged window doors provide a degree of protection for HMI's or other operator interface devices that are installed on electrical enclosures. This allows for easy access to the devices with a hinged door and 1/4-turn latches. Viewing windows allow the operator to monitor the devices while the door is latched shut, keeping them protected during operation.



Construction

- Quarter-turn style latching for easy access.
- Latch type can be changed using [N41214 series latches](#) (sold separately).
- Concealed hinges with removable pins.
- Fabricated from 1/4 gauge carbon steel or 1/4 gauge 304 stainless steel.
- Carbon steel models have an ANSI 61 gray light-textured polyester powder finish. Stainless steel models have a No. 3 intermediate polished finish.
- Polycarbonate viewing window for clear visibility.
- Drill template and mounting hardware provided.
- Door and mounting surface are sealed with poured-in-place polyurethane gasket.

Listing


- UL Recognized type 3R, 4, 12, and 4X (SS only) [UL File E64791]
- IP66
- CSA Type 3R, 4, 12 and 4x (SS only) [CSA File 222873]



Enclosure Accessories - Universal Deep-Hinged Window Door

ANSI 61 Gray Steel	Price	304 Stainless Steel	Price	Height	Width	Depth	Window Height	Window Width	Weight (lb)
WADW131602	\$376.00	WADW131602SS	\$593.00	12.75 [324]	15.88 [403]	2.75 [70]	8.68 [220]	9.83 [250]	11.0
WADW150902	\$358.00	WADW150902SS	\$570.00	14.75 [375]	9.5 [241]		10.68 [271]	3.41 [87]	8.0
WADW191302	\$385.00	WADW191302SS	\$629.00	18.75 [476]	13.5 [343]		14.68 [373]	7.41 [188]	14.0
WADW231302	\$429.00	WADW231302SS	\$673.00	22.75 [578]	13.5 [343]		18.68 [474]	7.41 [188]	17.0
WADW231702	\$500.00	WADW231702SS	\$724.00	22.75 [578]	17.5 [445]		18.68 [474]	11.41 [290]	21.0
WADW232602	\$568.00	WADW232602SS	\$832.00	22.75 [578]	26.25 [667]		18.68 [474]	20.22 [514]	32.0
WADW292002	\$575.00	WADW292002SS	\$830.00	28.75 [731]	20.25 [514]		24.68 [627]	14.22 [361]	31.0

Notes: Dimensions in inches [millimeters].
Cutout dimension: Height - 3.00 [76], Width - 3.00 [76]

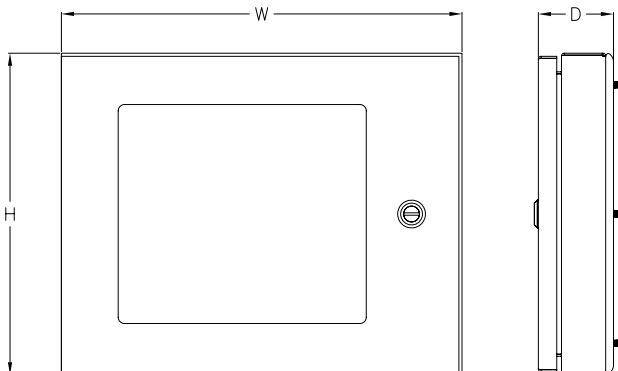

Enclosure Shipping Schedule	
1 -10 days	1-15 days
Color indicates shipping lead time in business days.	