




Disconnect Terminal Blocks




Both the DN-DIS10 (MN) and the DN-KBD12 (MN) allow fast circuit disconnection without rewiring and are 35mm DIN-rail mountable. The DN-DIS10 (MN) is supplied with a copper disconnect bar installed in the fuse holder. The DN-KBD12 (MN) offers circuit disconnection capability by means of a pivoting, insulated "knife blade".

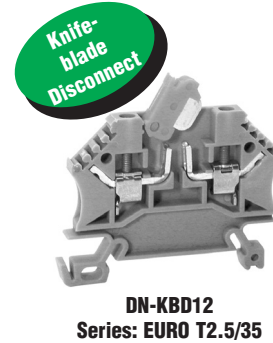


Ordering Information							
	Part Number	Pcs/Pkg	Price	Part Number	Pcs/Pkg	Price	
Gray Disconnect Block	DN-DIS10	50	\$188.00	DN-KBD12	50	\$104.00	
	DN-DIS10MN	10	\$30.00	DN-KBD12MN	10	\$17.50	
Technical Specifications							
Stripping Length	10mm [0.39 in]			10mm [0.39 in]			
Tightening Torque	0.6 N-m [5.3 lb-in]			0.5 N-m [4.4 lb-in]			
Density	125/m [30 pcs/ft]			200/m [60 pcs/ft]			
UL Approval*	300V	30A	24-10 AWG	600V	20A	22-12 AWG	
CSA Approval	300V	25A	18-12 AWG	600V	16A	18-12 AWG	
VDE Approval	500V	25A	4mm ²	600V	16A	2.5 mm ²	
Disconnect Type	Copper bar			Copper blade			
Operating Temperature	Ambient air temperature: -20°C to 85°C [-4°F to 185°F] Relative humidity: 50% max at 40°C [104°F]; 90% max at 20°C [68°F]						
SCCR Rating	10kA per Table SB4.1, 2009, UL 508A, Maximum short circuit current rating for unmarked components						
CE Conformity	CE (EN 60947-1 / EN 60947-7-3)			CE (EN 60947-1 / EN 60947-7-1)			
Agency File #	UL E179129 / LR84816						
<i>Note: To obtain the most current agency approval information, see the Agency Approval Checklist section on the specific part number's web page.</i>							
Accessories							
End Cover		Included			DN-ECKBD	100	\$29.50
					DN-ECKBDMN	10	\$4.00
35mm DIN Rail	7.5 mm high	DN-R35S1	10	\$32.50	DN-R35S1	10	\$32.50
		DN-R35S1-2	2	\$10.00	DN-R35S1-2	2	\$10.00
	15mm high	DN-R35HS1	10	\$57.00	DN-R35HS1	10	\$57.00
		DN-R35HS1-2	2	\$15.00	DN-R35HS1-2	2	\$15.00
End Bracket	DN-EB35		50	\$46.00	DN-EB35	50	\$46.00
	DN-EB35MN		20	\$21.50	DN-EB35MN	20	\$21.50
	DN-EB35-A		50	\$33.00	DN-EB35-A	50	\$33.00
	DN-EB35-A-10		10	\$9.00	DN-EB35-A-10	10	\$9.00
	DN-QEB35		50	\$29.00	DN-QEB35	50	\$29.00
	DN-QEB35-10		10	\$9.00	DN-QEB35-10	10	\$9.00
Angled Support Bracket		DN-ASB1	50	\$57.00	DN-ASB1	50	\$57.00
Marking Tags		DN-L or DN-LT series	500/100	various	DN-LA or DN-LT series	500/100	various
<i>*For copper wire only</i>							
<i>Note: For more information on accessories, see the DINnectors Accessories section of this chapter.</i>							

DN-DIS10 / DN-DIS10MN

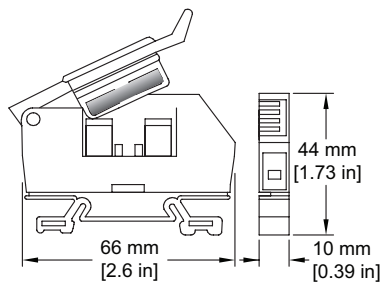

DN-KBD12 / DN-KBD12MN

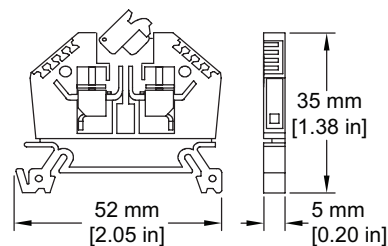


DINnectors Accessories

Marking Tags Cross Reference Charts - Screw-type


DINector Marking Tags Cross Reference - Screw-type					
<i>Block Type</i>	<i>DN-L</i>	<i>DN-LA</i>	<i>DN-LT</i>	<i>DN-LAT</i>	<i>DN-EMLBL</i>
<i>DN-T12</i>		X	X		
<i>DN-T10</i>	X		X		
<i>DN-T8</i>	X		X		
<i>DN-T6</i>	X		X		
<i>DN-T4</i>	X		X		
<i>DN-T1/0</i>	X		X		
<i>DN-T3/0</i>	X		X		
<i>DN-D10</i>	X		X		
<i>DN-D10X</i>	X		X		
<i>DN-D10LED</i>	X		X		
<i>DN-D10DR</i>	X		X		
<i>DN-TL14</i>				X	
<i>DN-THERM</i>	X		X		
<i>DN-EMXM1</i>		X	X		X
<i>DN-EMXDV</i>		X	X		X
<i>DN-M10</i>			X		
<i>DN-MG10</i>			X		
<i>DN-G10</i>	X		X		
<i>DN-G8</i>	X		X		
<i>DN-G6</i>	X		X		
<i>DN-G4</i>	X		X		
<i>DN-G1/0</i>	X		X		
<i>DN-F6</i>	X		X		
<i>DN-F10</i>	X		X		
<i>DN-DIS2</i>		X	X		
<i>DN-DIS4</i>	X		X		
<i>DN-FE2</i>		X	X		
<i>DN-FE4</i>	X		X		
<i>DN-DIS10</i>	X		X		
<i>DN-KBD12</i>		X	X		

Continued on next page

DINnectors® Accessories


Marking Tags

Marking Tags DN-L Series			
Part#	Marking Sequence	Pcs/Pkg	Price
DN-L50	1-50	500	\$38.00
DN-L100	51-100	500	\$38.00
DN-L150	101-150	500	\$38.00
DN-L200	151-200	500	\$38.00
DN-L250	201-250	500	\$38.00
DN-L300	251-300	500	\$38.00
DN-L350	301-350	500	\$38.00
DN-L400	351-400	500	\$38.00
DN-L450	401-450	500	\$38.00
DN-LB	Blank	500	\$26.00
DN-LS	L1, L2, L3, L, N, GND, +, -, COM,COM*	500	\$38.00

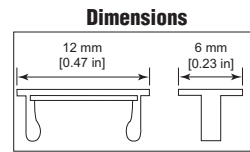


- Notes:
1. The marking sequence of 50 tags (i.e. 101-150) is printed 10 times in each package of 500.
 2. The DN-L tags fit all DINnectors 6mm wide and wider. There will be a gap between tags on blocks wider than 6mm.
 3. Material: Thermoplastic with heat embossed black print.

Marking Tags DN-LA Series			
Part#	Marking Sequence	Pcs/Pkg	Price
DN-LA100	1-100	500	\$38.00
DN-LA200	101-200	500	\$38.00
DN-LA300	201-300	500	\$38.00
DN-LA400	301-400	500	\$38.00
DN-LAB	Blank Tags	500	\$38.00
DN-LAS	L1, L2, L3, L, N, GND, +, -, COM,COM*	500	\$38.00

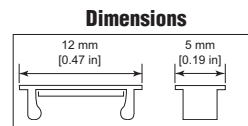


- Notes:
1. The marking sequence of 100 tags (i.e. 1-100) is printed five times in each package of 500.
 2. The DN-LA tags fit all DINnectors 5mm wide and wider. There will be a gap between tags on blocks wider than 5mm.
 3. Material: Thermoplastic with heat embossed black print.

Marking Tags DN-LAT Series			
Part#	Marking Sequence	Pcs/Pkg	Price
DN-LAT100-A	1-100	500	\$33.50
DN-LAT200-A	101-200	500	\$33.50
DN-LAT300-A	201-300	500	\$33.50
DN-LAT400-A	301-400	500	\$33.50
DN-LAT500-A	401-500	500	\$33.50
DN-LAT600-A	501-600	500	\$33.50
DN-LATB-A	Blank Tags	500	\$24.50
DN-LATS-A	L1, L2, L3, L, N, +, -, COM,COM*	500	\$33.50

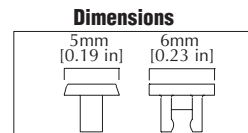

- Notes:
1. The marking sequence of 500 tags (i.e. 1-100) is printed five times in each package of 500.
 2. Material: Thermoplastic with heat embossed black print.

Marking Tags DN-QL Series			
Part#	Marking Sequence	Pcs/Pkg	Price
DN-QL100	1-100	500	\$29.00
DN-QL200	101-200	500	\$29.00
DN-QL300	201-300	500	\$29.00
DN-QL400	301-400	500	\$29.00
DN-QL500	401-500	500	\$29.00
DN-QLB	Blank Tags	500	\$25.00
DN-QLS	L1, L2, L3, L, N, +, -, COM,COM*	500	\$33.50

 


- Notes:
1. The marking sequence of 500 (i.e. 1-100) is printed five times in each package of 500.
 2. Material: Thermoplastic with heat embossed black print.

DINnectors® Accessories

Marking Tags continued


Marking Tags DN-LT Series			
Part#	Marking Sequence	Pcs/Pkg	Price
DN-LT15	1-5	100	\$7.00
DN-LT60	6-0	100	\$7.00
DN-LT1	1	100	\$7.00
DN-LT2	2	100	\$7.00
DN-LT3	3	100	\$7.00
DN-LT4	4	100	\$7.00
DN-LT5	5	100	\$7.00
DN-LT6	6	100	\$7.00
DN-LT7	7	100	\$7.00
DN-LT8	8	100	\$7.00
DN-LT9	9	100	\$7.00
DN-LT0	0	100	\$7.00
DN-LTBLNK	Unprinted	100	\$7.00
DN-LTA	A	100	\$7.00
DN-LTB	B	100	\$7.00
DN-LTC	C	100	\$7.00
DN-LTD	D	100	\$7.00
DN-LTE	E	100	\$7.00
DN-LTF	F	100	\$7.00
DN-LTG	G	100	\$7.00
DN-LTH	H	100	\$7.00
DN-LTI	I	100	\$7.00
DN-LTJ	J	100	\$7.00
DN-LTK	K	100	\$7.00
DN-LTL	L	100	\$7.00
DN-LTM	M	100	\$7.00
DN-LTN	N	100	\$7.00
-	-	-	-
DN-LTP	P	100	\$7.00
DN-LTQ	Q	100	\$7.00
DN-LTR	R	100	\$7.00
DN-LTS	S	100	\$7.00
DN-LTT	T	100	\$7.00
DN-LTU	U	100	\$7.00
DN-LTV	V	100	\$7.00
DN-LTW	W	100	\$7.00
DN-LTX	X	100	\$7.00
DN-LTY	Y	100	\$7.00
DN-LTZ	Z	100	\$7.00
DN-LTGND	⊕	100	\$7.00
DN-LTPOS	+	100	\$7.00
DN-LTNEG	-	100	\$7.00
DN-LTAC	~	100	\$7.00
DN-LTDC	=	100	\$7.00

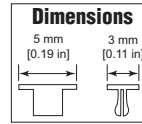


Note:

1. These marking tags allow the flexibility of creating custom marking sequences on site.
2. The DN-M series supports a maximum of three digits (tags), while other DINnectors support up to four digits (tags).
3. Material: Thermoplastic with heat embossed black print.

DN-MTA marking tag adapter

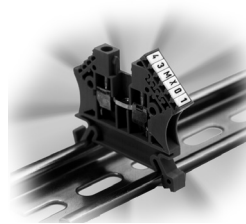

DN-MTA dimensions

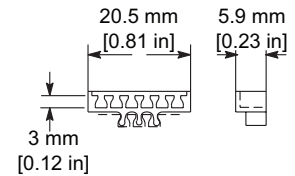

Part#	Description	Pcs/Pkg	Price
DN-MTA	Marking tag adapter holds up to six DN-LT tags	50	\$9.50

Note: DN-MTA adapter does not fit DN-T12-A terminal blocks.

DINnectors® Accessories

Terminal Marking Accessories



DN-EMLBL1



DN-EMLBL2



DN-EMLBL3

Part #	Description	For Use With	Pcs/Pkg	Price Each
DN-EMLBL1	Blank labels	DN-EMPEG1 pin protectors for DN-xEMxxx plug-in terminal blocks	100	\$6.25
DN-EMLBL2	Labels printed 1 – 12		100	\$8.75
DN-EMLBL3	Labels printed 13 – 24		100	\$8.75

Marking Pen – for terminal and wire marking tags

- Permanent
- Smudge-proof
- Waterproof
- Weatherproof
- Lightfast (won't fade)
- Dries in seconds (excellent for left-handed users)
- Dry-safe (pen can be left uncapped for days without drying out)
- Low odor ink

Part#	Description	Pcs/Pkg	Price Each
DN-MP	Indelible black ink marking pen	1	\$3.75



Marking pen

Wire Marking Accessories



DN-WMTAG1 wire tags & DN-WM-x wire tag holders

Part #	Description	For Use With	Pcs/Pkg	Price Each
DN-WMTAG1	Wire tag – blank	all DN-WM-x wire tag holders	525	\$40.50
DN-WM-1	Wire tag holder, clear, 12mm length, 0.051–0.118 in diameter; for 22–16 AWG wire	DN-WMTAG1	200	\$8.50
DN-WM-2	Wire tag holder, clear, 12mm length, 0.098–0.196 in diameter; for 16–11 AWG wire		200	\$8.50
DN-WM-3	Wire tag holder, clear, 12mm length, 0.157–0.393 in diameter; for 13–5 AWG wire		100	\$5.50
DN-WM-4	Wire tag holder, clear, 12mm length, 0.314–0.629 in diameter; for 5AWG wire		100	\$4.75