


DINnectors[®] Accessories

Terminal Plugs



DN-xxPLUG / DN-xxPLUGMN

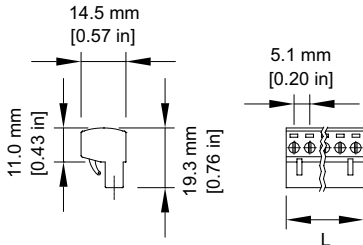

Accessories – Terminal Plugs							
Plugs* Part Number	Pcs/Pkg	Price/Pkg	Plugs* Part Number	Pcs/Pkg	Price/Pkg	Number of Poles	Length mm [in]
DN-2PLUG	200	\$67.00	DN-2PLUGMN	10	\$4.25	2	10.2 [0.40]
DN-3PLUG	200	\$104.00	DN-3PLUGMN	10	\$6.25	3	15.2 [0.60]
DN-4PLUG	100	\$69.00	DN-4PLUGMN	10	\$8.25	4	20.3 [0.80]
DN-5PLUG	100	\$70.00	DN-5PLUGMN	10	\$10.25	5	25.4 [1.00]
DN-6PLUG	100	\$81.00	DN-6PLUGMN	10	\$10.25	6	30.5 [1.20]
DN-7PLUG	50	\$49.50	DN-7PLUGMN	5	\$8.25	7	35.6 [1.40]
DN-8PLUG	50	\$68.00	DN-8PLUGMN	5	\$8.25	8	40.6 [1.60]
DN-9PLUG	50	\$63.25	DN-9PLUGMN	5	\$9.00	9	45.7 [1.80]
DN-10PLUG	50	\$80.00	DN-10PLUGMN	5	\$10.00	10	50.8 [2.00]
DN-11PLUG	50	\$77.00	DN-11PLUGMN	5	\$11.00	11	55.9 [2.20]
DN-12PLUG	50	\$103.00	DN-12PLUGMN	5	\$11.75	12	61.0 [2.40]

Terminal Plugs Ratings	
Voltage/Current	300V, 12A
Wire Gauge	14–22 AWG, CU only
Torque	Tightening Torque: 0.51 N·m [4.5 lb·in]
Usage Temperature	Ambient air temperature: -20°C to 105°C [-4°F to 221°F] Relative humidity: 50% max at 40°C [104°F]; 90% max at 20°C [68°F]
Agency Approvals	UL file #: E179129


Note: To obtain the most current agency approval information, see the Agency Approval Checklist section on the specific part number's web page.

* DN-xxPLUGs fit all DN-EMXxx & DN-QEMXxx plug-in terminal blocks

Disconnect Blade



**DN-DIS-BLADE
DN-DIS-BMN**




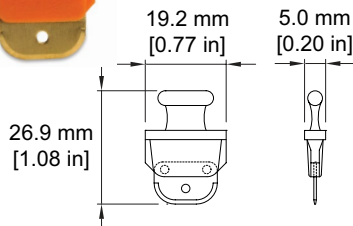


Disconnect Blade			
Part Number	Description	Pcs/Pkg	Price
DN-DIS-BLADE	Terminal block disconnect blade for DN-FE2, DN-FE4, DN-DIS2 and DN-DIS4	50	\$21.50
DN-DIS-BMN		10	\$5.50

End Brackets



End Brackets			
Part Number	Description	Pcs/Pkg	Price/Pkg
DN-EB15	Terminal block end stop 7mm width screw clamping. Gray	100	\$64.00
DN-EB15MN		20	\$14.00
DN-EB35	Terminal block end stop 9mm width screw clamping. Gray	50	\$39.50
DN-EB35MN		20	\$18.00
DN-EB35-A	Terminal block end stop 6mm width screw clamping. Black	50	\$28.50
DN-EB35-A-10		10	\$7.50
DN-QEB35	Terminal block end stop 6mm width screwless clamping. Black	50	\$25.50
DN-QEB35-10		10	\$7.50

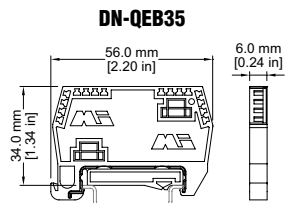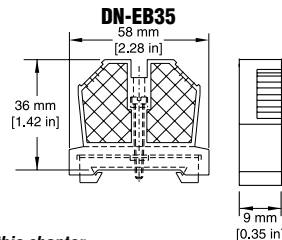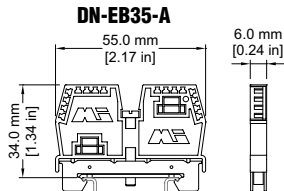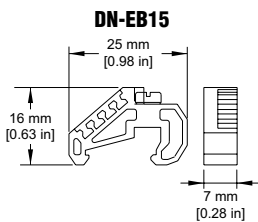

For more information on accessories, see the "DINnectors Accessories" section of this chapter.


DINnectors Accessories

End Covers

Certain end covers can be used with multiple terminal block parts to cover and insulate the open side, or to put more space between adjacent blocks.

DINnectors End Covers				
Part Number	Description	For Use With	Pcs/Pkg	Price
DN-EC1210	Covers open side of DN-T12-A and DN-T10-A series terminal blocks	DN-T10-A, DN-T12-A	100	\$26.00
DN-EC1210MN			25	\$8.00
DN-EC86	Covers open side of DN-T8 and DN-T6 series terminal blocks	DN-T8, DN-T6	100	\$28.00
DN-EC86MN			25	\$8.00
DN-EC4	Covers open side of DN-T4 series terminal blocks	DN-T4	50	\$17.00
DN-EC4MN			10	\$3.50
DN-EC1/0	Covers open side of DN-T1/0 series terminal blocks	DN-T1/0	50	\$19.50
DN-EC1/0MN			10	\$4.00
DN-DEC10	Covers open side of DN-D10 series double-level terminal blocks	DN-D10	100	\$18.00
DN-DEC10MN			10	\$3.75
DN-EC14	Covers open side of DN-TL14-A series terminal blocks	DN-TL14-A	25	\$10.00
DN-EC14S	Covers open side of DN-TL14S-A series terminal blocks	DN-TL14S-A	25	\$9.00
DN-ECM10	Covers open side of DN-M10-A series terminal blocks	DN-M10-A DN-M10B-A	100	\$26.00
DN-ECM10MN			25	\$8.00
DN-ECKBD	Covers open side of DN-KBD12 (MN) series disconnect blocks	DN-KBD12 (MN)	100	\$26.00
DN-ECKBDMN			10	\$3.75
DN-EMXM1EC1	Covers open side of DN-EMXM1 and DN-QEMXM1 terminal blocks	DN-EMXM1	25	\$8.50
DN-EMXM1EC2	Covers closed side of DN-EMXM1 and DN-QEMXM1 terminal blocks	DN-QEMXM1	25	\$8.50
DN-EMXDVEC1	Covers open side of DN-EMXDV and DN-QEMXDV terminal blocks	DN-EMXDV	25	\$8.50
DN-EMXDVEC2	Covers closed side of DN-EMXDV and DN-QEMXDV terminal blocks	DN-QEMXDV	25	\$8.50
DN-FESEP	Covers closed side of DN-FE sockets and DN-DIS disconnects	DN-FE, DN-DIS	50	\$15.00
DN-FESEP-10			10	\$3.00
DN-QEC12	Covers open side of DN-Q12-A or DN-QG12 series screwless terminal blocks	DN-Q12-A DN-QG12	50	\$12.00
DN-QEC12MN			10	\$3.25
DN-QEC10	Covers open side of DN-Q10-A or DN-QG10 series screwless terminal blocks	DN-Q10-A DN-QG10	50	\$12.00
DN-QEC10MN			10	\$3.25
DN-QEC8	Covers open side of DN-Q8-A or DN-QG8 series screwless terminal blocks	DN-Q8-A DN-QG8	50	\$14.00
DN-QEC8MN			10	\$3.50
DN-QEC12-1-2	Covers open side of DN-Q12-1-2-A and DN-QKBD12-A series screwless terminal blocks	DN-Q12-1-2-A, DN-QKBD12	25	\$8.75
DN-QEC12-2-2	Covers open side of DN-Q12-2-2-A series screwless terminal blocks	DN-Q12-2-2-A	25	\$9.75
DN-QDEC12	Covers open side of DN-QD12-A series screwless terminal blocks	DN-QD12-A	25	\$9.75

Spacers

Spacers are used to put more space between adjacent blocks.

DINnectors Spacers				
Part Number	Description	For Use with	Pcs/Pkg	Price
DN-S1210	Spacer for DN-T12-A and DN-T10-A series terminal blocks	DN-T10-A DN-T12-A	100	\$30.50
DN-S1210MN			25	\$9.25
DN-S86	Spacer for DN-T8 and DN-T6 series terminal blocks	DN-T8 DN-T6	100	\$36.50
DN-S86MN			25	\$7.75
DN-EMXM1SPA1	Spacer for single-level plug-in terminal blocks	DN-EMXM1 DN-QEMXM1	25	\$7.25
DN-EMXDVSPA1	Spacer for double-level plug-in terminal blocks	DN-EMXDV DN-QEMXDV	25	\$8.25
DN-FESPA	Spacer for DN-FE sockets and DN-DIS disconnects	DN-FE DN-DIS	50	\$15.00
DN-FESPA-10			10	\$3.00

Top Covers








DINnectors Top Covers				
Part Number	Description	For Use with	Pcs/Pkg	Price
DN-C12	Top cover, clear, printed electrical symbol.	DN-T12-A	100	\$36.50
DN-C12MN			25	\$7.75
DN-C10	Top cover, clear, printed electrical symbol.	DN-T10-A	100	\$36.50
DN-C10MN			25	\$7.75
DN-C86	Top cover, clear, printed electrical symbol.	DN-T8 DN-T6	100	\$36.50
DN-C86MN			25	\$7.75
DN-DC10	Top cover, clear, printed electrical symbol.	DN-D10	100	\$34.50
DN-DC10MN			25	\$7.75
DN-MC10	Top cover, clear, printed electrical symbol.	DN-M10	100	\$37.50
DN-MC10MN			25	\$7.75

DINnectors[®] Accessories

DINnector End Covers and Spacers Dimensions

Part Number		Length	Height	Thickness
DN-EC1210	DN-EC1210MN	44mm [1.73 in]	35mm [1.38 in]	1.5 mm [0.06 in]
DN-S1210	DN-S1210MN	55mm [2.17 in]	44mm [1.73 in]	
DN-EC86	DN-EC86MN	50mm [1.97 in]	43mm [1.69 in]	
DN-S86	DN-S86MN	55mm [2.17 in]	49mm [1.93 in]	
DN-EC4	DN-EC4MN	56mm [2.21 in]	48mm [1.89 in]	
DN-EC1/O	DN-EC1/OMN	62mm [2.44 in]	60mm [2.36 in]	
DN-DEC10	DN-DEC10MN	72mm [2.80 in]	55mm [2.17 in]	
DN-EC14	–	78mm [3.08 in]	55mm [2.17 in]	
DN-EC14S	–	55mm [2.17 in]	50mm [1.97 in]	
DN-ECM10	DN-ECM10MN	32mm [1.26 in]	27mm [1.06 in]	
DN-ECKBD	DN-ECKBDMN	52mm [2.05 in]	34.5 mm [1.36 in]	
DN-EMXM1EC1	DN-EMXM1EC2	as shown on next page		
DN-EMXDVEC1	DN-EMXDVEC2			
DN-EMXDVSPA1	DN-EMXM1SPA1			
DN-FESPA	DN-FESPA-10			
DN-FESEP	DN-FESEP-10			
DN-QEC12	DN-QEC12MN	50mm [1.97 in]	23mm [0.9 in]	1.5 mm [0.06 in]
DN-QEC10	DN-QEC10MN	57.4 mm [2.26 in]	33.6 mm [1.32 in]	
DN-QEC8	DN-QEC8MN	63mm [2.48 in]	38.5 mm [1.52 in]	
DN-QEC12-1-2	–	68.5 mm [2.70 in]	28.5 mm [1.12 in]	
DN-QEC12-2-2	–	87.5 mm [3.44 in]	28.5 mm [1.12 in]	
DN-QDEC12	–	98mm [3.86 in]	37mm [1.46 in]	


DN-EC1210, DN-EC1210MN DN-EC86, DN-EC86MN DN-EC4 (MN), DN-EC1/O (MN), DN-ECKBD (MN), DN-S1210, DN-S1210MN, DN-S86 (MN)

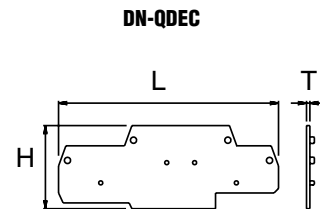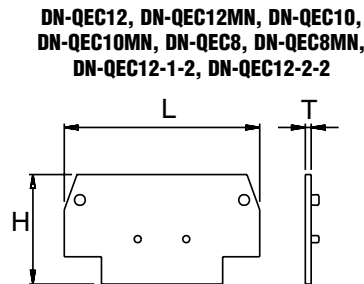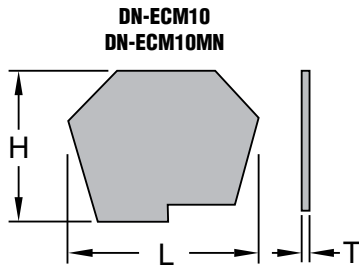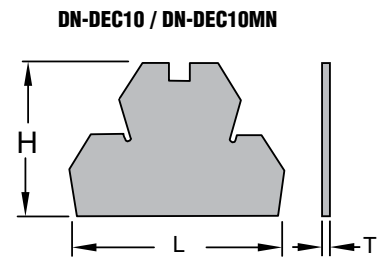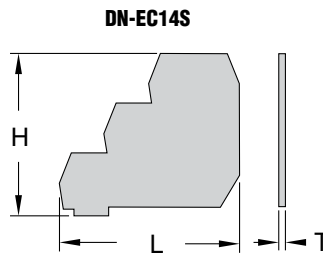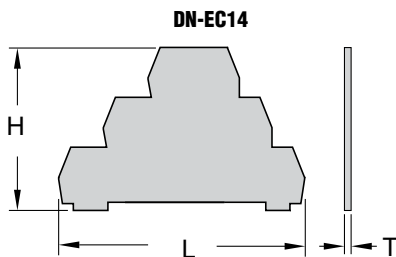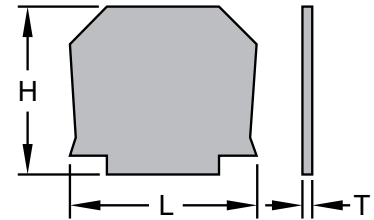


DINnectors Accessories

Dimensional Drawings


DN-EMXM1EC1

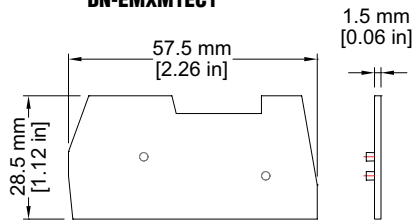


DN-EMXM1EC2

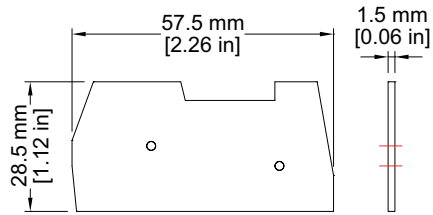


DN-EMXDVSPA1

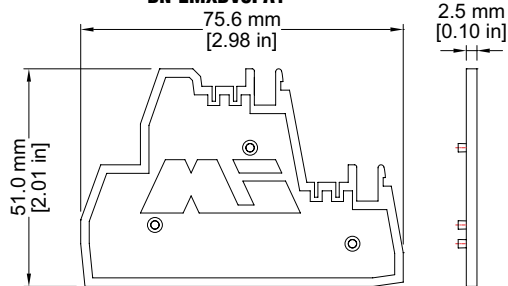


DN-EMXM1SPA1

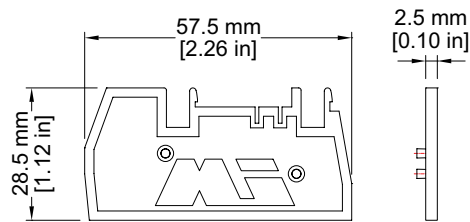


DN-EMXDVEC1

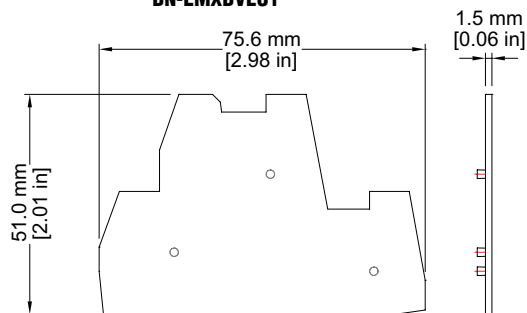

DN-EMXDVEC2

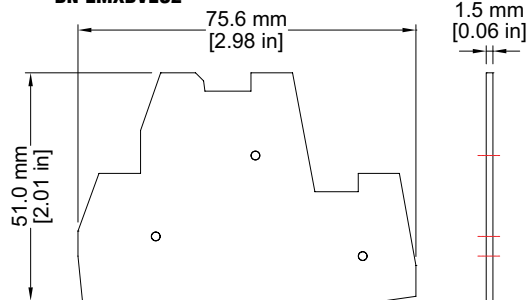

**DN-FESEP,
DN-FESEP-10**

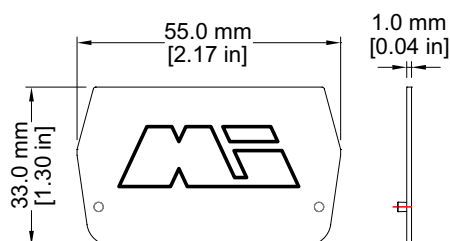

DN-FESPA, DN-FESPA-10

