 




Fuse Terminal Blocks

Fuse terminal blocks are available for 1 1/4" x 1/4" and 5x20mm-5x25mm fuses and they are 35mm DIN-rail mountable. These blocks are available with or without a blown fuse LED. Fuse terminal blocks with blown fuse LED are polarity sensitive. The hinge side is positive.



DN-F6 Series:
EURO S 10H/35



DN-F6L Series:
EURO S 10H/35



DN-F10 Series:
EURO S 4LH/35







DN-F10L Series:
EURO S 4LH/35

Ordering Information												
	Part Number	Qty	Price	Part Number	Qty	Price	Part Number	Qty	Price	Part Number	Qty	Price
Gray Terminal Block	DN-F6	25	\$131.00	-			DN-F10	50	\$210.00	-		
	DN-F6MN	7	\$28.50				DN-F10MN	10	\$33.00			
12-24 VAC/DC*				DN-F6L24	10	\$74.00				DN-F10L24	10	\$73.00
110 VAC/DC*				DN-F6L110	10	\$74.00				DN-F10L110	10	\$73.00
220 VAC/DC*				DN-F6L220	10	\$74.00				DN-F10L220	10	\$73.00

Technical Specifications												
Stripping Length	12mm [0.47 in]			12mm [0.47 in]			10mm [0.39 in]			10mm [0.39 in]		
Tightening Torque	0.8 N·m [10 lb·in]			0.8 N·m [10 lb·in]			0.6 N·m [5.3 lb·in]			0.6 N·m [5.3 lb·in]		
Density	100/m [30 pcs/ft]			100/m [30 pcs/ft]			100/m [30 pcs/ft]			100/m [30 pcs/ft]		
UL Approval**	600V	30A	20-6 AWG	600V	30A	20-6 AWG	300V	15A	24-10 AWG	300V	15A	24-10 AWG
CSA Approval	600V	30A	18-6 AWG	600V	30A	18-6 AWG	300V	8A	18-12 AWG	300V	8A	18-12 AWG
VDE Approval	750V	8A	-	750V	8A	-	500V	8A	4mm ²	500V	8A	4mm ²
Fuse Size (not supplied)	1 1/4" x 1/4"			1 1/4" x 1/4"			5x20mm-5x25mm			5x20mm-5x25mm		
Indicator Type	Non-indicating			LED blown fuse indicator			Non-indicating			LED blown fuse indicator		
Operating Temperature	Ambient air temperature: -20 to 85°C [-4 to 185°F] / Relative humidity: 50% max at 40°C [104°F]; 90% max at 20°C [68°F]											
SCCR Rating	10kA per Table SB4.1, 2009, UL 508A, Maximum short circuit current rating for unmarked components											
CE Conformity	CE (EN 60947-1 / 60947-7-3)											
Agency File #	UL E179129 / LR84816											

Accessories													
End Covers	Included			Included			Included			Included			
35mm DIN Rail	7.5 mm high	DN-R35S1	10	\$54.00	DN-R35S1	10	\$54.00	DN-R35S1	10	\$54.00	DN-R35S1	10	\$54.00
		DN-R35S1-2	2	\$12.50	DN-R35S1-2	2	\$12.50	DN-R35S1-2	2	\$12.50	DN-R35S1-2	2	\$12.50
	15mm high	DN-R35HS1	10	\$89.00	DN-R35HS1	10	\$89.00	DN-R35HS1	10	\$89.00	DN-R35HS1	10	\$89.00
		DN-R35HS1-2	2	\$21.00	DN-R35HS1-2	2	\$21.00	DN-R35HS1-2	2	\$21.00	DN-R35HS1-2	2	\$21.00
End Brackets	DN-EB35	50	\$56.00	DN-EB35	50	\$56.00	DN-EB35	50	\$56.00	DN-EB35	50	\$56.00	
	DN-EB35MN	20	\$26.50	DN-EB35MN	20	\$26.50	DN-EB35MN	20	\$26.50	DN-EB35MN	20	\$26.50	
	DN-EB35-A	50	\$40.00	DN-EB35-A	50	\$40.00	DN-EB35-A	50	\$40.00	DN-EB35-A	50	\$40.00	
	DN-EB35-A-10	10	\$10.50	DN-EB35-A-10	10	\$10.50	DN-EB35-A-10	10	\$10.50	DN-EB35-A-10	10	\$10.50	
	DN-QEB35	50	\$35.50	DN-QEB35	50	\$35.50	DN-QEB35	50	\$35.50	DN-QEB35	50	\$35.50	
	DN-QEB35-10	10	\$10.00	DN-QEB35-10	10	\$10.00	DN-QEB35-10	10	\$10.00	DN-QEB35-10	10	\$10.00	
Angled Support Bracket	DN-ASB1	50	\$89.00	DN-ASB1	50	\$89.00	DN-ASB1	50	\$89.00	DN-ASB1	50	\$89.00	
Marking Tags	DN-L*** or DN-LT****	500/ 100	various	DN-L*** or DN-LT****	500/ 100	various	DN-L*** or DN-LT****	500/ 100	various	DN-L*** or DN-LT****	500/ 100	various	

*Working voltage **For copper wire only ***On lever arm ****On terminal body
 Note: DN-F6 series fuse holders will accommodate the following AutomationDirect fuses: ABC, AGC, MDA and MDL Series.
 DN-F10 series fuse holders will accommodate the following AutomationDirect fuses: GMA, GMC, S500, and S506 Series.
 For more information on accessories, see the DINnectors Accessories section of this chapter.

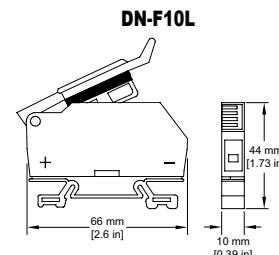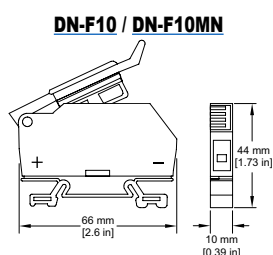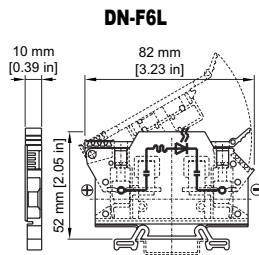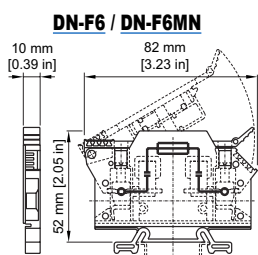


DINnectors® Accessories

Marking Tags Cross Reference Charts - Screw-type


DINector Marking Tags Cross Reference - Screw-type					
<i>Block Type</i>	<i>DN-L</i>	<i>DN-LA</i>	<i>DN-LT</i>	<i>DN-LAT</i>	<i>DN-EMLBL</i>
<i>DN-T12</i>	-	X	X	-	-
<i>DN-T10</i>	X	-	X	-	-
<i>DN-T8</i>	X	-	X	-	-
<i>DN-T6</i>	X	-	X	-	-
<i>DN-T4</i>	X	-	X	-	-
<i>DN-T1/0</i>	X	-	X	-	-
<i>DN-T3/0</i>	X	-	X	-	-
<i>DN-D10</i>	X	-	X	-	-
<i>DN-D10X</i>	X	-	X	-	-
<i>DN-D10LED</i>	X	-	X	-	-
<i>DN-D10DR</i>	X	-	X	-	-
<i>DN-TL14</i>	-	-	-	X	-
<i>DN-THERM</i>	X	-	X	-	-
<i>DN-EMXM1</i>	-	X	X	-	X
<i>DN-EMXDV</i>	-	X	X	-	X
<i>DN-M10</i>	-	-	X	-	-
<i>DN-MG10</i>	-	-	X	-	-
<i>DN-G10</i>	X	-	X	-	-
<i>DN-G8</i>	X	-	X	-	-
<i>DN-G6</i>	X	-	X	-	-
<i>DN-G4</i>	X	-	X	-	-
<i>DN-G1/0</i>	X	-	X	-	-
<i>DN-F6</i>	X	-	X	-	-
<i>DN-F10</i>	X	-	X	-	-
<i>DN-DIS2</i>	-	X	X	-	-
<i>DN-DIS4</i>	X	-	X	-	-
<i>DN-FE2</i>	-	X	X	-	-
<i>DN-FE4</i>	X	-	X	-	-
<i>DN-DIS10</i>	X	-	X	-	-
<i>DN-KBD12</i>	-	X	X	-	-

Continued on next page

Marking Tags

Marking Tags DN-L Series			
Part Number	Marking Sequence	Qty	Price
DN-L50	1-50	500	\$46.50
DN-L100	51-100	500	\$46.50
DN-L150	101-150	500	\$46.50
DN-L200	151-200	500	\$46.50
DN-L250	201-250	500	\$46.50
DN-L300	251-300	500	\$46.50
DN-L350	301-350	500	\$46.50
DN-L400	351-400	500	\$46.50
DN-L450	401-450	500	\$46.50
DN-LB	Blank	500	\$31.50
DN-LS	L1, L2, L3, L, N, GND, +, -, COM,COM*	500	\$46.50


Dimensions

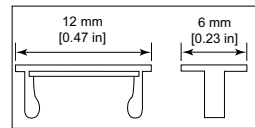

- The marking sequence of 50 tags (i.e. 101-150) is printed 10 times in each package of 500.
- The DN-L tags fit all DINnectors 6mm wide and wider.
- There will be a gap between tags on blocks wider than 6mm.
- Material: Thermoplastic with heat embossed black print.

Marking Tags DN-LA Series			
Part Number	Marking Sequence	Qty	Price
DN-LA100	1-100	500	\$46.50
DN-LA200	101-200	500	\$46.50
DN-LA300	201-300	500	\$46.50
DN-LA400	301-400	500	\$46.50
DN-LAB	Blank Tags	500	\$46.50
DN-LAS	L1, L2, L3, L, N, GND, +, -, COM,COM*	500	\$46.50

 
Dimensions



- The marking sequence of 100 tags (i.e. 1-100) is printed five times in each package of 500.
- The DN-LA tags fit all DINnectors 5mm wide and wider. There will be a gap between tags on blocks wider than 5mm.
- Material: Thermoplastic with heat embossed black print.

Marking Tags DN-LAT Series			
Part Number	Marking Sequence	Qty	Price
DN-LAT100-A	1-100	500	\$41.00
DN-LAT200-A	101-200	500	\$41.00
DN-LAT300-A	201-300	500	\$41.00
DN-LAT400-A	301-400	500	\$41.00
DN-LAT500-A	401-500	500	\$41.00
DN-LAT600-A	501-600	500	\$41.00
DN-LATB-A	Blank Tags	500	\$30.00
DN-LATS-A	L1, L2, L3, L, N, +, -, COM,COM*	500	\$41.00

 
Dimensions



- The marking sequence of 500 tags (i.e. 1-100) is printed five times in each package of 500.
- Material: Thermoplastic with heat embossed black print.

Marking Tags DN-QL Series			
Part Number	Marking Sequence	Qty	Price
DN-QL100	1-100	500	\$35.50
DN-QL200	101-200	500	\$35.50
DN-QL300	201-300	500	\$35.50
DN-QL400	301-400	500	\$35.50
DN-QL500	401-500	500	\$35.50
DN-QLB	Blank Tags	500	\$30.50
DN-QLS	L1, L2, L3, L, N, +, -, COM,COM*	500	\$41.00

 Dimensions




- The marking sequence of 500 (i.e. 1-100) is printed five times in each package of 500.
- Material: Thermoplastic with heat embossed black print.

DINnectors® Accessories

Marking Tags continued

Marking Tags DN-LT Series			
Part Number	Marking Sequence	Qty	Price
DN-LT15	1-5	100	\$8.50
DN-LT60	6-0	100	\$8.50
DN-LT1	1	100	\$8.50
DN-LT2	2	100	\$8.50
DN-LT3	3	100	\$8.50
DN-LT4	4	100	\$8.50
DN-LT5	5	100	\$8.50
DN-LT6	6	100	\$8.50
DN-LT7	7	100	\$8.50
DN-LT8	8	100	\$8.50
DN-LT9	9	100	\$8.50
DN-LT0	0	100	\$8.50
DN-LTBLNK	Unprinted	100	\$8.50
DN-LTA	A	100	\$8.50
DN-LTB	B	100	\$8.50
DN-LTC	C	100	\$8.50
DN-LTD	D	100	\$8.50
DN-LTE	E	100	\$8.50
DN-LTF	F	100	\$8.50
DN-LTG	G	100	\$8.50
DN-LTH	H	100	\$8.50
DN-LTI	I	100	\$8.50
DN-LTJ	J	100	\$8.50
DN-LTK	K	100	\$8.50
DN-LTL	L	100	\$8.50
DN-LTM	M	100	\$8.50
DN-LTN	N	100	\$8.50
-	-	-	-
DN-LTP	P	100	\$8.50
DN-LTQ	Q	100	\$8.50
DN-LTR	R	100	\$8.50
DN-LTS	S	100	\$8.50
DN-LTT	T	100	\$8.50
DN-LTU	U	100	\$8.50
DN-LTV	V	100	\$8.50
DN-LTW	W	100	\$8.50
DN-LTX	X	100	\$8.50
DN-LTY	Y	100	\$8.50
DN-LTZ	Z	100	\$8.50
DN-LTGND	⊕	100	\$8.50
DN-LTPOS	+	100	\$8.50
DN-LTNEG	-	100	\$8.50
DN-LTAC	~	100	\$8.50
DN-LTDC	=	100	\$8.50

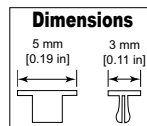


- These marking tags allow the flexibility of creating custom marking sequences on site.
- The DN-M series supports a maximum of three digits (tags), while other DINnectors support up to four digits (tags).
- Material: Thermoplastic with heat embossed black print.

DN-MTA marking tag adapter



DN-MTA dimensions

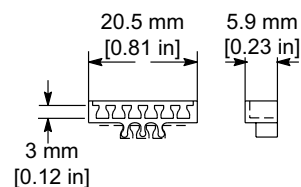

Part Number	Description	Qty	Price
DN-MTA	Marking tag adapter holds up to six DN-LT tags	50	\$12.00

Note: [DN-MTA](#) adapter does not fit [DN-T12-A](#) terminal blocks.

DINnectors® Accessories

Terminal Marking Accessories



DN-EMLBL1



DN-EMLBL2



DN-EMLBL3

Part Number	Description	For Use With	Qty	Price
DN-EMLBL1	Blank labels	DN-EMPEG1 pin protectors for DN-xEMxx plug-in terminal blocks	100	\$7.75
DN-EMLBL2	Labels printed 1 – 12		100	\$11.00
DN-EMLBL3	Labels printed 13 – 24		100	\$11.00

Marking Pen – for terminal and wire marking tags

- Permanent
- Smudge-proof
- Waterproof
- Weatherproof
- Lightfast (won't fade)
- Dries in seconds (excellent for left-handed users)
- Dry-safe (pen can be left uncapped for days without drying out)
- Low odor ink

Part Number	Description	Qty	Price
DN-MP	Staedtler-Mars marking pen, for use with blank marking tags. Permanent Ink, fine tip.	1	\$4.25



Marking pen

Wire Marking Accessories



DN-WMTAG1 wire tags & DN-WM-x wire tag holders

Part Number	Description	For Use With	Qty	Price
DN-WMTAG1	Wire tag – blank	all DN-WM-x wire tag holders	525	\$50.00
DN-WM-1	Wire tag holder, clear, 12mm length, 0.051–0.118 in diameter; for 22–16 AWG wire	DN-WMTAG1	200	\$10.50
DN-WM-2	Wire tag holder, clear, 12mm length, 0.098–0.196 in diameter; for 16–11 AWG wire		200	\$10.50
DN-WM-3	Wire tag holder, clear, 12mm length, 0.157–0.393 in diameter; for 13–5 AWG wire		100	\$7.00
DN-WM-4	Wire tag holder, clear, 12mm length, 0.314–0.629 in diameter; for 5AWG wire		100	\$6.50