




Mini Terminal Blocks

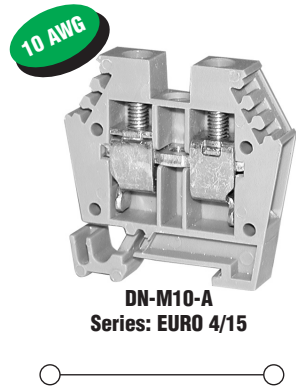

DN-M10-A
Series: EURO 4/15



DN-MG10
Series: EURO E4/15

Mini terminal blocks are used in areas with extremely limited space requirements, and mount on the smaller DIN rail type DN-R15S1.



Ordering Information						
	Part Number	Pcs/Pkg	Price	Part Number	Pcs/Pkg	Price
Gray Block	DN-M10-A	100	\$67.00	-	-	-
Blue Block	DN-M10B-A	100	\$91.00	-	-	-
Green/Yellow Block	-	-	-	DN-MG10	20	\$55.00

Technical Specifications						
Stripping Length	10mm [0.39 in]			10mm [0.39 in]		
Tightening Torque	0.6 N-m [5.3 lb-in]			0.6 N-m [5.3 lb-in]		
Density	142/m [43 pcs/ft]			166/m [50 pcs/ft]		
CE Conformity	LVD 2006/95/EC			LVD 2006/95/EC		
UL Approval*	300V	30A	24-10 AWG	-	-	18-10 AWG
CSA Approval	300V	30A	24-10 AWG	-	-	18-10 AWG
VDE Approval	400V	32A	4mm ²	-	-	4mm ²
Operating Temperature	Ambient air temperature: -20°C to 105°C [-4°F to 221°F] Relative humidity: 50% max at 40°C [104°F]; 90% max at 20°C [68°F]					
SCCR Rating	10kA per Table SB4.1, 2009, UL 508A, Maximum short circuit current rating for unmarked components					
CE Conformity	CE (EN 60947-1 / EN 60947-7-1)					
Agency File #	UL E179129					

Note: To obtain the most current agency approval information, see the Agency Approval Checklist section on the specific part number's web page.

Accessories								
End Covers	DN-ECM10		100	\$29.50				
	DN-ECM10MN		25	\$9.50				
Jumpers	2-pole	DN-2J4Y		100	\$31.50	-		
		DN-2J4YMN		25	\$9.50			
	3-pole	DN-3J4Y		100	\$51.00			
		DN-3J4YMN		25	\$15.00			
	24-pole	DN-24J4Y		5	\$20.00			
	Jumper Cutting Tool**	DN-J4CUT		1	\$54.00			
Top Cover	DN-MC10		100	\$44.00				
	DN-MC10MN		25	\$9.25				
Test Plug/Red	DN-TPR		10	\$28.50				
Test Plug/Black	DN-TPB		10	\$28.50				
15mm DIN Rail	5.5 mm high	DN-R15S1		10	\$29.50	DN-R15S1	10	\$29.50
		DN-R15S1-2		2	\$9.50	DN-R15S1-2	2	\$9.50
End Brackets	DN-EB15		100	\$74.00				
	DN-EB15MN		20	\$17.00				
Angled Support Bracket	DN-ASB1		50	\$57.00	DN-ASB1	50	\$57.00	
Marking Tags	DN-LT series		100	various	DN-LT series	100	various	

* For copper wire only
** Jumper cutting tool DN-J4CUT cuts DN-xJ4Y Series multi-pole jumpers and MAINTAINS THE JUMPER INSULATIONS.
Note: For more information on accessories, see the DINnectors Accessories section of this chapter.

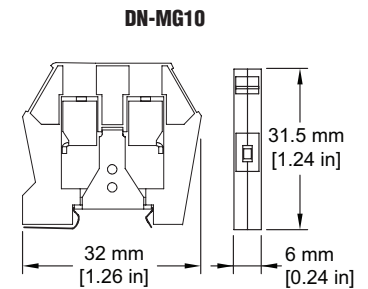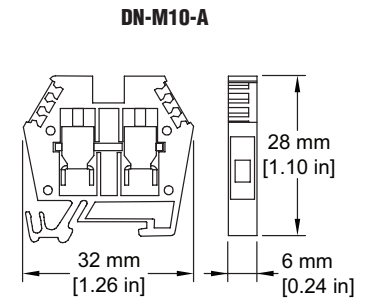


DINnectors Accessories

Marking Tags Cross Reference Charts - Screw-type


DINnector Marking Tags Cross Reference - Screw-type					
Block Type	DN-L	DN-LA	DN-LT	DN-LAT	DN-EMLBL
DN-T12		X	X		
DN-T10	X		X		
DN-T8	X		X		
DN-T6	X		X		
DN-T4	X		X		
DN-T1/0	X		X		
DN-T3/0	X		X		
DN-D10	X		X		
DN-D10X	X		X		
DN-D10LED	X		X		
DN-D10DR	X		X		
DN-TL14				X	
DN-THERM	X		X		
DN-EMXM1		X	X		X
DN-EMXDV		X	X		X
DN-M10			X		
DN-MG10			X		
DN-G10	X		X		
DN-G8	X		X		
DN-G6	X		X		
DN-G4	X		X		
DN-G1/0	X		X		
DN-F6	X		X		
DN-F10	X		X		
DN-DIS2		X	X		
DN-DIS4	X		X		
DN-FE2		X	X		
DN-FE4	X		X		
DN-DIS10	X		X		
DN-KBD12		X	X		

Continued on next page

DINnectors® Accessories

Marking Tags continued


Marking Tags DN-LT Series			
Part#	Marking Sequence	Pcs/Pkg	Price
DN-LT15	1-5	100	\$7.00
DN-LT60	6-0	100	\$7.00
DN-LT1	1	100	\$7.00
DN-LT2	2	100	\$7.00
DN-LT3	3	100	\$7.00
DN-LT4	4	100	\$7.00
DN-LT5	5	100	\$7.00
DN-LT6	6	100	\$7.00
DN-LT7	7	100	\$7.00
DN-LT8	8	100	\$7.00
DN-LT9	9	100	\$7.00
DN-LT0	0	100	\$7.00
DN-LTBLNK	Unprinted	100	\$7.00
DN-LTA	A	100	\$7.00
DN-LTB	B	100	\$7.00
DN-LTC	C	100	\$7.00
DN-LTD	D	100	\$7.00
DN-LTE	E	100	\$7.00
DN-LTF	F	100	\$7.00
DN-LTG	G	100	\$7.00
DN-LTH	H	100	\$7.00
DN-LTI	I	100	\$7.00
DN-LTJ	J	100	\$7.00
DN-LTK	K	100	\$7.00
DN-LTL	L	100	\$7.00
DN-LTM	M	100	\$7.00
DN-LTN	N	100	\$7.00
-	-	-	-
DN-LTP	P	100	\$7.00
DN-LTQ	Q	100	\$7.00
DN-LTR	R	100	\$7.00
DN-LTS	S	100	\$7.00
DN-LTT	T	100	\$7.00
DN-LTU	U	100	\$7.00
DN-LTV	V	100	\$7.00
DN-LTW	W	100	\$7.00
DN-LTX	X	100	\$7.00
DN-LTY	Y	100	\$7.00
DN-LTZ	Z	100	\$7.00
DN-LTGND	⊕	100	\$7.00
DN-LTPOS	+	100	\$7.00
DN-LTNEG	-	100	\$7.00
DN-LTAC	~	100	\$7.00
DN-LTDC	=	100	\$7.00

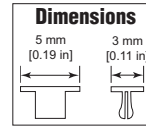


Note:

1. These marking tags allow the flexibility of creating custom marking sequences on site.
2. The DN-M series supports a maximum of three digits (tags), while other DINnectors support up to four digits (tags).
3. Material: Thermoplastic with heat embossed black print.

DN-MTA marking tag adapter

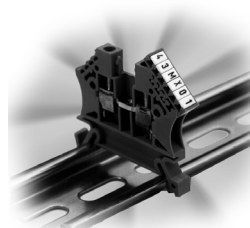

DN-MTA dimensions

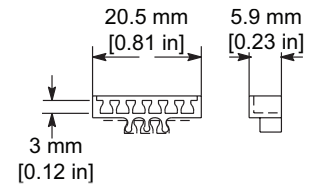

Part#	Description	Pcs/Pkg	Price
DN-MTA	Marking tag adapter holds up to six DN-LT tags	50	\$9.50

Note: DN-MTA adapter does not fit DN-T12-A terminal blocks.

DINnectors® Accessories

Terminal Marking Accessories



DN-EMLBL1



DN-EMLBL2



DN-EMLBL3

Part #	Description	For Use With	Pcs/Pkg	Price Each
DN-EMLBL1	Blank labels	DN-EMPEG1 pin protectors for DN-xEMXxx plug-in terminal blocks	100	\$6.25
DN-EMLBL2	Labels printed 1 – 12		100	\$8.75
DN-EMLBL3	Labels printed 13 – 24		100	\$8.75

Marking Pen – for terminal and wire marking tags

- Permanent
- Smudge-proof
- Waterproof
- Weatherproof
- Lightfast (won't fade)
- Dries in seconds (excellent for left-handed users)
- Dry-safe (pen can be left uncapped for days without drying out)
- Low odor ink

Part#	Description	Pcs/Pkg	Price Each
DN-MP	Indelible black ink marking pen	1	\$3.75



Marking pen

Wire Marking Accessories



DN-WMTAG1 wire tags & DN-WM-x wire tag holders

Part #	Description	For Use With	Pcs/Pkg	Price Each
DN-WMTAG1	Wire tag – blank	all DN-WM-x wire tag holders	525	\$40.50
DN-WM-1	Wire tag holder, clear, 12mm length, 0.051–0.118 in diameter; for 22–16 AWG wire	DN-WMTAG1	200	\$8.50
DN-WM-2	Wire tag holder, clear, 12mm length, 0.098–0.196 in diameter; for 16–11 AWG wire		200	\$8.50
DN-WM-3	Wire tag holder, clear, 12mm length, 0.157–0.393 in diameter; for 13–5 AWG wire		100	\$5.50
DN-WM-4	Wire tag holder, clear, 12mm length, 0.314–0.629 in diameter; for 5AWG wire		100	\$4.75