


WA-F1/F2 Panels for Single-Door Freestanding Enclosures

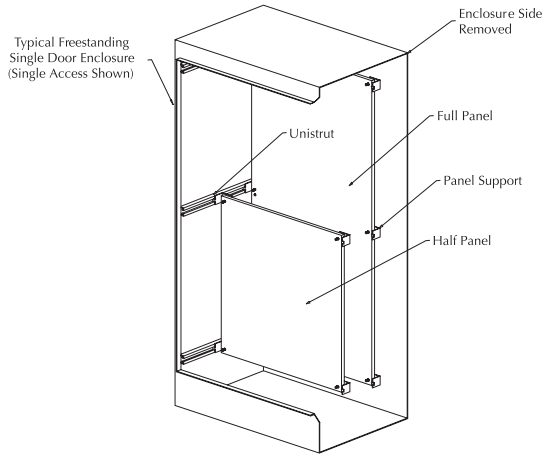

Description

- Panels for single-door single-access and single-door dual-access, freestanding NEMA 12, and freestanding NEMA 4 enclosures
- Can be positioned anywhere along horizontal depth-wise mounting channels
- Half-height panels can be located in the upper or lower portion of the enclosure
- Mounting hardware is furnished with each panel
- Painted steel subpanels are painted white polyester powder over phosphatized surfaces
- Galvanized subpanels have a conductive finish (no paint)
- May be used in two-door enclosures along with other freestanding accessories

Shipping Schedule

Same day 1 - 5 days 1 - 7 days 1 - 15 days 1 - 20 days

Color indicates shipping lead time in business days.

Painted Steel	Price	Galvanized	Price	Steel Gauge	Panel Size HxW	Subpanel Type
WA60P24F1	\$300.00	WA60P24F1G	\$300.00	12	48.00 x 20.00 [1219 x 508]	Full
WA60P24F2	\$216.00	WA60P24F2G	\$200.00	10	24.88 x 20.00 [632 x 508]	Half
WA60P36F1	\$388.00	WA60P36F1G	\$388.00	12	48.00 x 32.00 [1219 x 813]	Full
WA60P36F2	\$244.00	WA60P36F2G	\$244.00	12	24.88 x 32.00 [632 x 813]	Half
WA72P24F1	\$337.00	WA72P24F1G	\$337.00	12	60.00 x 20.00 [1524 x 508]	Full
WA72P24F2	\$234.00	WA72P24F2G	\$234.00	12	30.88 x 20.00 [784 x 508]	Half
WA72P30F1	\$391.00	WA72P30F1G	\$423.00	12	60.00 x 26.00 [1524 x 660]	Full
WA72P30F2	\$264.00	WA72P30F2G	\$264.00	10	30.88 x 26.00 [784 x 660]	Half
WA72P36F1	\$446.00	WA72P36F1G	\$446.00	12	60.00 x 32.00 [1524 x 813]	Full
WA72P36F2	\$273.00	WA72P36F2G	\$273.00	12	30.88 x 32.00 [784 x 813]	Half
WA90P24F1	\$391.00	WA90P24F1G	\$391.00	12	78.00 x 20.00 [1981 x 508]	Full
WA90P24F2	\$264.00	WA90P24F2G	\$264.00	10	39.88 x 20.00 [1013 x 508]	Half
WA90P36F1	\$533.00	WA90P36F1G	\$533.00	12	78.00 x 32.00 [1981 x 813]	Full
WA90P36F2	\$342.00	WA90P36F2G	\$342.00	10	39.88 x 32.00 [1013 x 813]	Half


Notes: Dimensions in inches [millimeters].

Letters in table correspond to letters on dimensional drawing.


If used in a two-door enclosure, a center panel support must be ordered.

Suffix F1= full panel, F2 = half panel

Dimensions

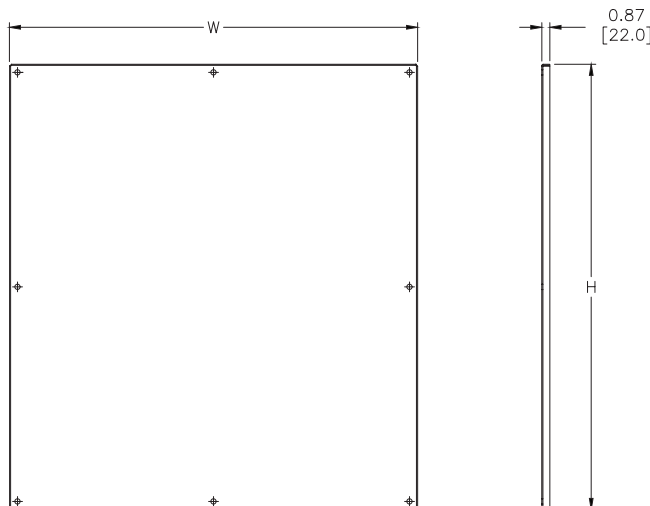

WA-F1/F2 Panels for Two Door Freestanding Enclosures

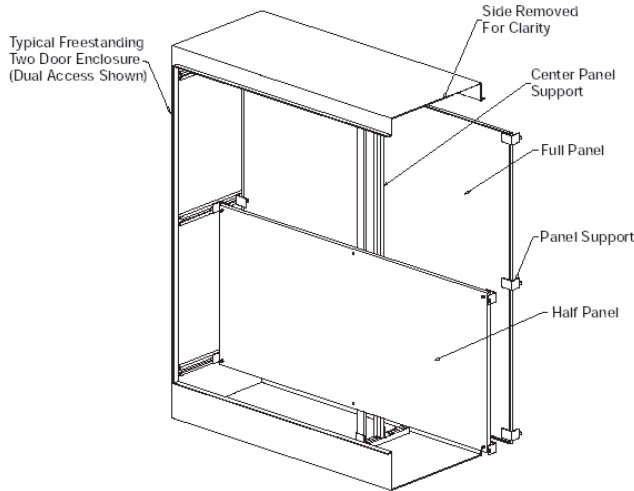

Description

- Panels for two-door single-access and two-door dual-access, freestanding NEMA 12 enclosures
- Manufactured of 10 gauge steel and can be positioned anywhere along horizontal depth-wise mounting channels
- Half-height panels can be located in the upper or lower portion of the enclosure
- Mounting hardware is furnished with each panel
- Painted steel subpanels are painted white polyester powder over phosphatized surfaces
- Galvanized subpanels have a conductive finish (no paint)

Shipping Schedule


Same day 1 - 5 days 1 - 7 days 1 - 15 days 1 - 20 days

Color indicates shipping lead time in business days.

Painted Steel	Price	Galvanized	Price	Panel Size AxB	Subpanel Type
WA60P48F1	\$622.00	WA60P48F1G	\$622.00	48.00 x 44.00 [1219 x 1118]	Full
WA60P48F2	\$367.00	WA60P48F2G	\$367.00	24.88 x 44.00 [632 x 1118]	Half
WA72P48F1	\$703.00	WA72P48F1G	\$703.00	60.00 x 44.00 [1524 x 1118]	Full
WA72P48F2	\$487.00	WA72P48F2G	\$487.00	30.88 x 44.00 [784 x 1118]	Half
WA72P60F1	\$815.00	WA72P60F1G	\$815.00	60.00 x 56.00 [1524 x 1422]	Full
WA72P60F2	\$549.00	WA72P60F2G	\$549.00	30.88 x 56.00 [784 x 1422]	Half
WA72P72F1	\$927.00	—	—	68.00 x 68.00 [1727 x 1727]	Full
WA72P72F2	\$611.00	WA72P72F2G	\$611.00	30.88 x 68.88 [784 x 1727]	Half
WA90P48F1	\$828.00	WA90P48F1G	\$896.00	78.00 x 44.00 [1981 x 1118]	Full
WA90P48F2	\$555.00	WA90P48F2G	\$555.00	39.88 x 44.00 [1013 x 1118]	Half
WA90P72F1	\$1,117.00	—	—	78.00 x 68.00 [1981 x 1727]	Full
WA90P72F2	\$714.00	WA90P72F2G	\$660.00	39.88 x 68.00 [1013 x 1727]	Half


Notes: Dimensions in inches [millimeters].
 Letters in table correspond to letters on dimensional drawing.
 Suffix F1 = full panel, F2 = half panel

Dimensions

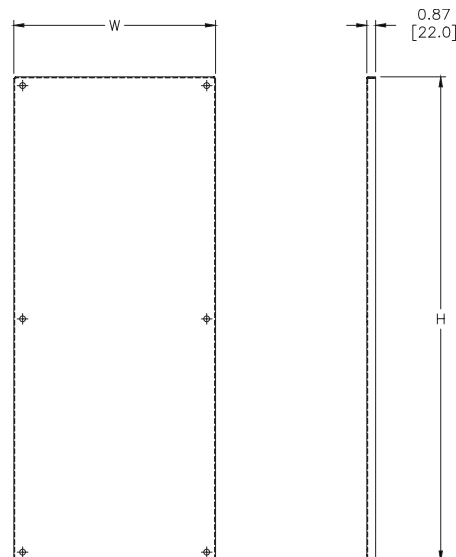

Note: Center panel support is supplied with a regular two-door enclosure panel. This support is used only as a brace. It is not intended to be used as a support for single-door subpanels, relay racks, etc. Use WA_FSCPS panel supports for this purpose.

WA-SMP Series Side-Mount Panels for Freestanding Enclosures

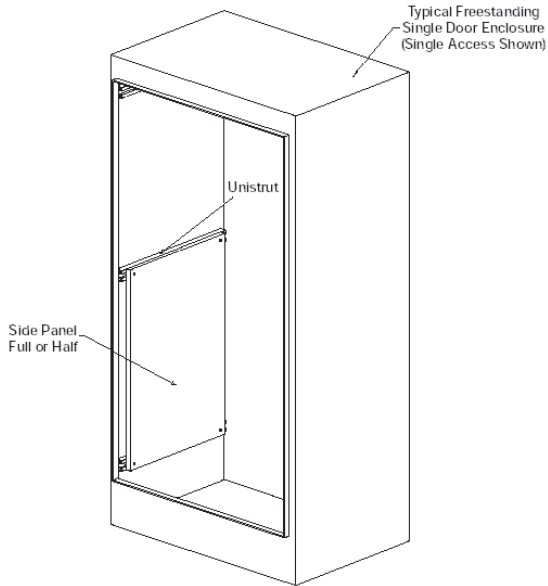

Description

- Panels for freestanding NEMA 4 and freestanding NEMA 12 enclosures
- Panels are fabricated from 12 gauge steel
- They provide extra mounting space on the sides of the enclosure
- Mounting hardware is furnished with each panel
- Painted steel subpanels are painted white polyester powder over phosphatized surfaces
- Galvanized subpanels have a conductive finish (no paint)
- Panels attach securely to mounting channels

Shipping Schedule


Same day 1 - 5 days 1 - 7 days 1 - 15 days 1 - 20 days

Color indicates shipping lead time in business days.


Painted Steel	Price	Galvanized	Price	Panel Size AxB
WA60SMP14	\$182.00	WA60SMP14G	\$197.00	48.00 x 14.00 [1219 x 356]
WA72SMP14	\$207.00	WA72SMP14G	\$207.00	60.00 x 14.00 [1524 x 356]
WA72SMP20	\$253.00	WA72SMP20G	\$274.00	60.00 x 20.00 [1524 x 508]
WA90SMP14	\$322.00	WA90SMP14G	\$322.00	78.00 x 14.00 [1981 x 356]
WA90SMP20	\$336.00	WA90SMP20G	\$336.00	78.00 x 20.00 [1981 x 508]

Note: Dimensions in inches [millimeters].

Dimensions

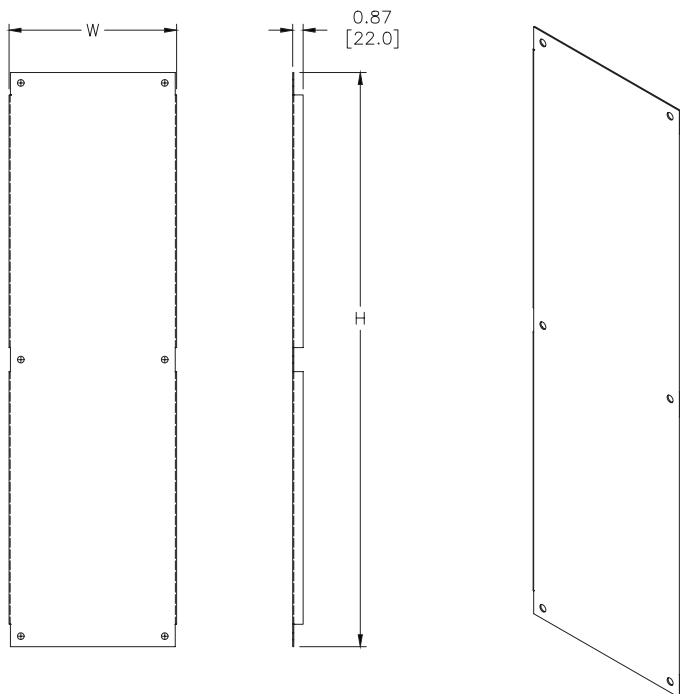

WASP-F3/F4 Series Accessory Swing-Out Panels For Freestanding Enclosures

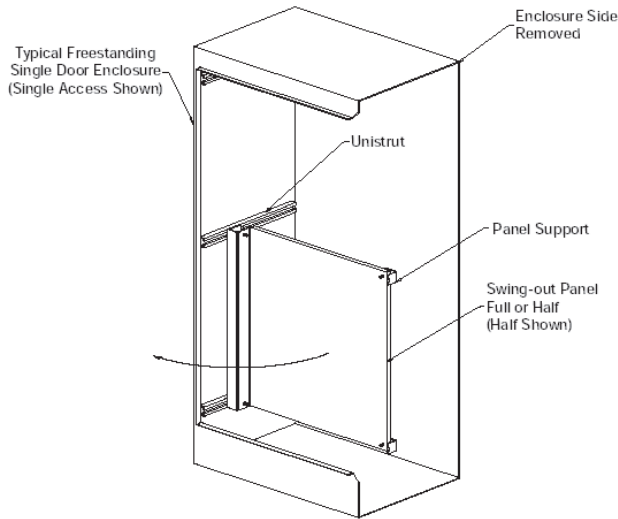

Description

- Panels for freestanding NEMA 12 enclosures and freestanding NEMA 4 enclosures
- Full-height and half-height swing-out panels are available
- Half-height panels can be located in the upper or lower portion of the enclosure
- Mounting can be on either side of the enclosure
- Painted steel subpanels are painted white polyester powder over phosphatized surfaces
- Galvanized subpanels have a conductive finish (no paint)
- May be used in two-door enclosures along with other freestanding accessories
- Fabricated from 12 gauge steel
- Mounting hardware is furnished with each panel

Shipping Schedule

Same day 1 - 5 days 1 - 7 days 1 - 15 days 1 - 20 days

Color indicates shipping lead time in business days.

Painted Steel	Price	Galvanized	Price	Panel Size AxB	Subpanel Type
WA60SP24F3	\$475.00	WA60SP24F3G	\$514.00	48.00 x 19.00 [1219 x 483]	Full
WA60SP24F4	\$362.00	WA60SP24F4G	\$362.00	24.88 x 19.00 [632 x 483]	Half
WA60SP36F3	\$585.00	WA60SP36F3G	\$634.00	48.00 x 31.00 [1219 x 787]	Full
WA60SP36F4	\$388.00	WA60SP36F4G	\$420.00	24.88 x 31.00 [632 x 787]	Half
WA72SP24F3	\$637.00	WA72SP24F3G	\$637.00	60.00 x 19.00 [1524 x 483]	Full
WA72SP24F4	\$432.00	WA72SP24F4G	\$432.00	30.88 x 19.00 [784 x 483]	Half
WA72SP30F3	\$738.00	WA72SP30F3G	\$738.00	60.00 x 25.00 [1524 x 635]	Full
WA72SP30F4	\$488.00	WA72SP30F4G	\$488.00	30.88 x 25.00 [784 x 635]	Half
WA72SP36F3	\$775.00	WA72SP36F3G	\$839.00	60.00 x 31.00 [1524 x 787]	Full
WA72SP36F4	\$544.00	WA72SP36F4G	\$544.00	30.88 x 31.00 [784 x 787]	Half
WA90SP36F3	\$996.00	WA90SP36F3G	\$996.00	78.00 x 31.00 [1981 x 787]	Full
WA90SP36F4	\$628.00	WA90SP36F4G	\$628.00	39.88 x 31.00 [1013 x 787]	Half

Notes: Dimensions in inches [millimeters].

If used in a two-door enclosure, a center panel support must be ordered.

Suffix F3 =full panel, F4 =half panel

Dimensions

