



# Exhaust Grilles With Filters

**118000-00**


## Features


- No-screw installation
- Mounting depth 0.6 in. (16mm)

## Accessories

- Come with gaskets attached (adhesive-sided to stick on panel)

Part Number	Price	Filter Density (g/m <sup>2</sup> )	Mass Filter Level %
<b>Exhaust Grilles</b>			
<b>118000-00</b>	<--->	350	94%
<b>118010-00</b>	<--->		
<b>118020-00</b>	<--->		
<b>118030-00</b>	<--->		
<b>Outdoor Exhaust Grilles</b>			
<b>118210-00</b>	<--->	360	98%
Dimensions in inches (millimeters)			

## Dimensions [in mm]

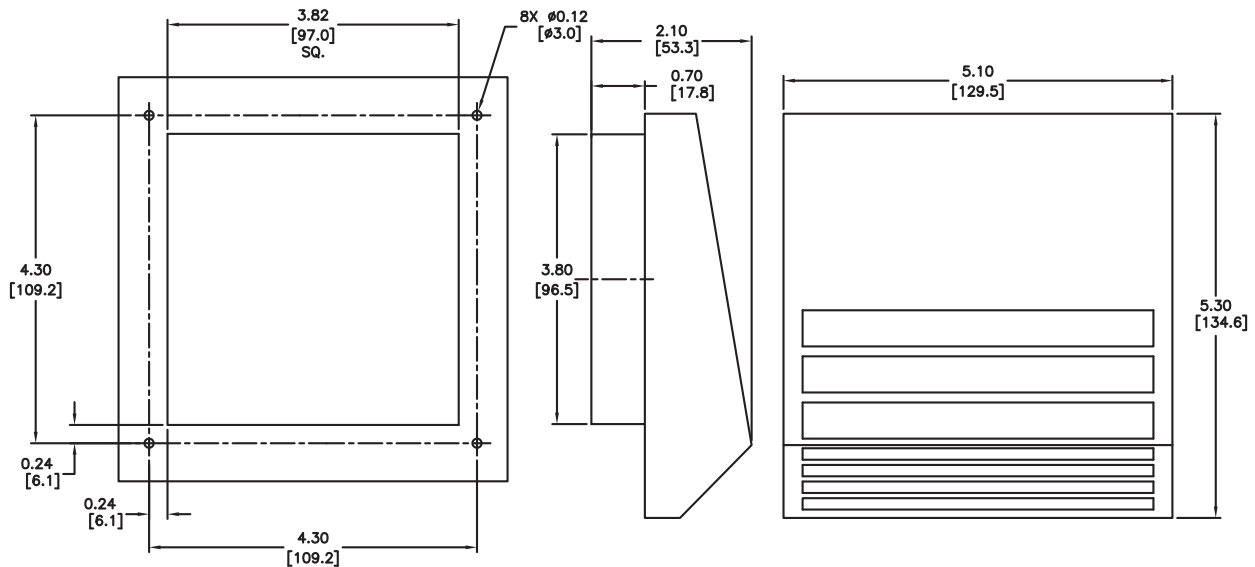
**118000-00**


CUTOUT DIMENSIONS




# Exhaust Grille and Filter Accessories

118010-00

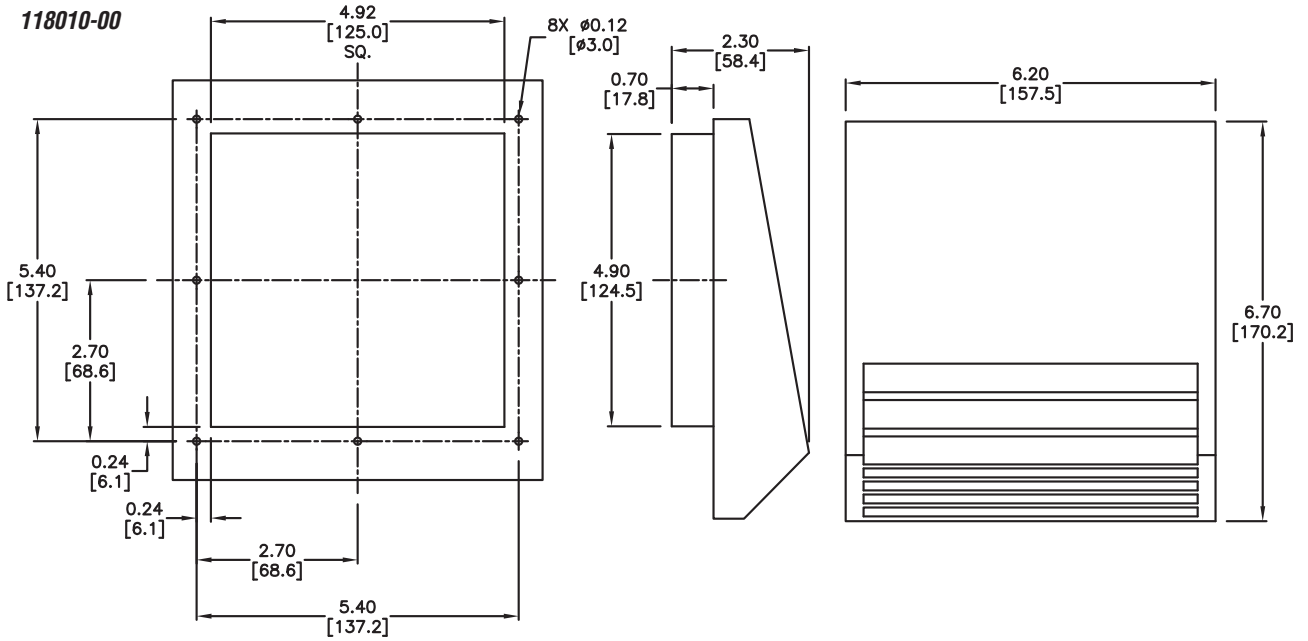

CUTOUT DIMENSIONS

118020-00

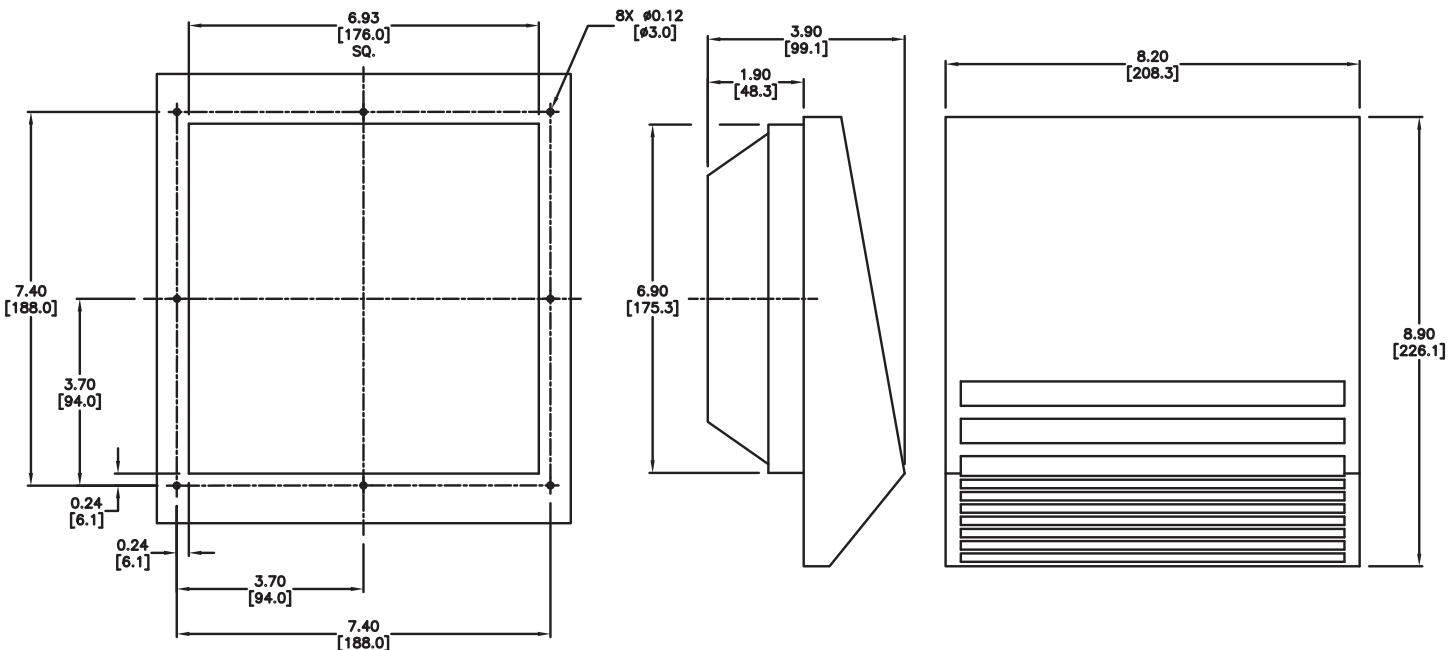


CUTOUT DIMENSIONS




# Exhaust Grille and Filter Accessories

**118030-00**

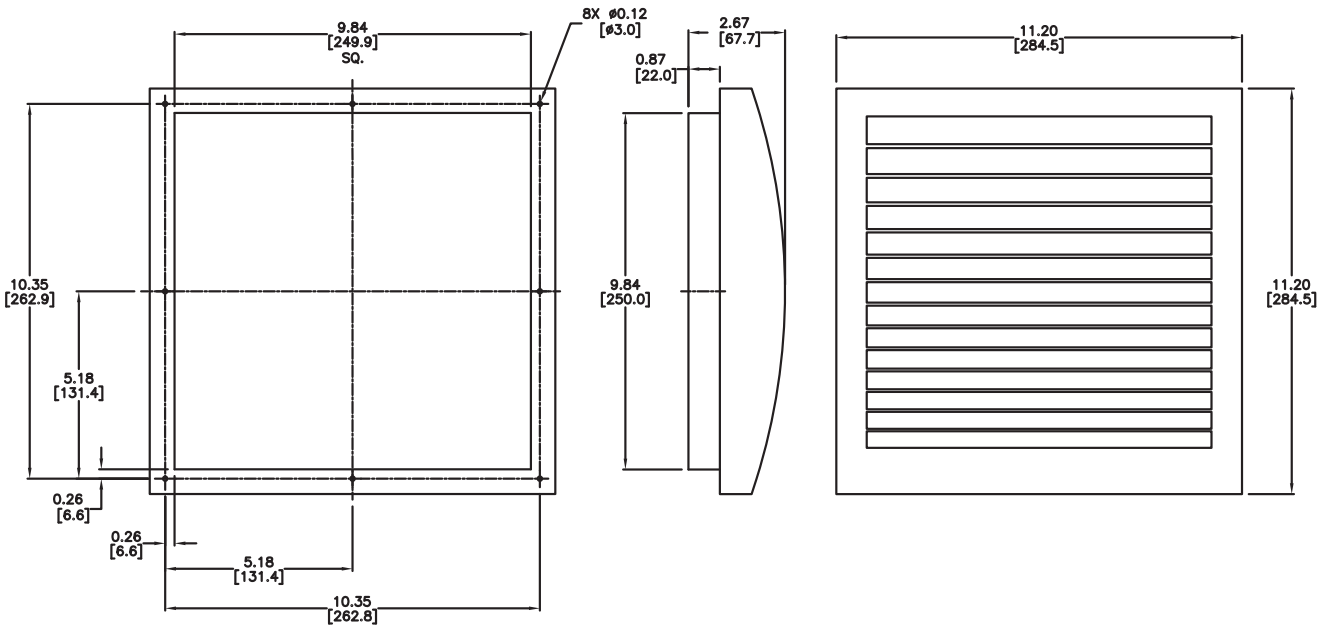


CUTOUT DIMENSIONS

**118210-00**

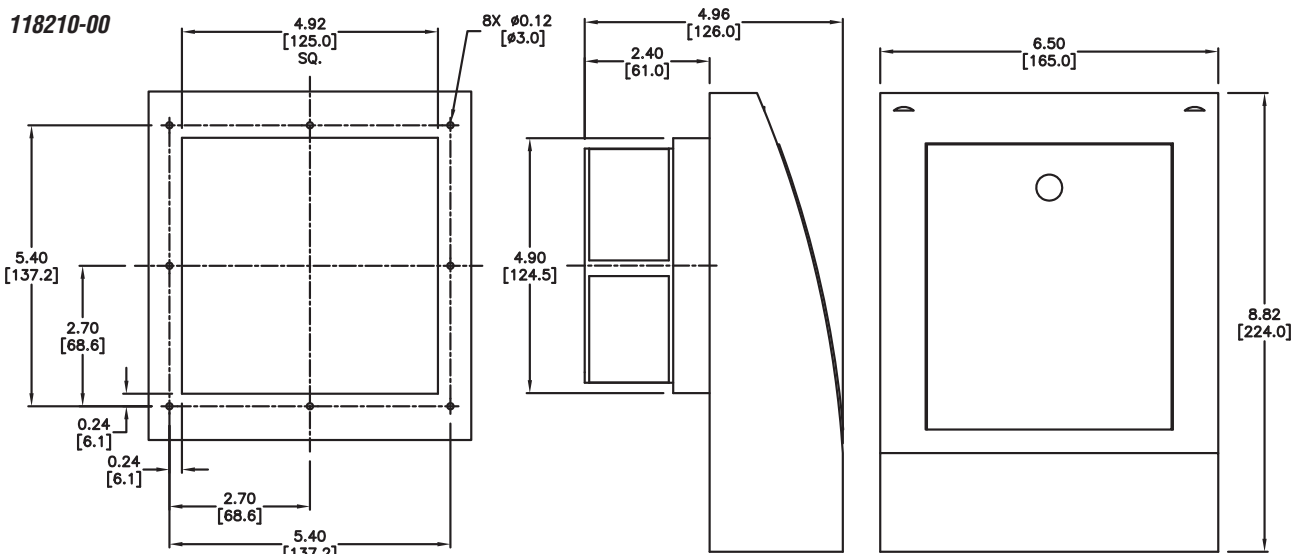

CUTOUT DIMENSIONS

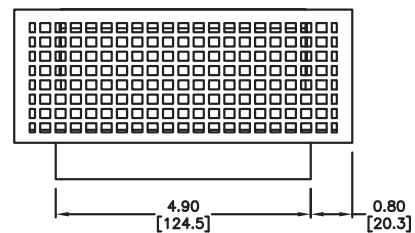

# Replacement Filter Elements

086000-00



## Applications

- Replacement filter mats for Stego series filter fans and Stego series exhaust grilles

## Features

- Filter media for enclosure fans
- Fine or medium density
- Fits 3.82 x 3.82, 4.92 x 4.92, 6.93 x 6.93, or 9.84 x 9.84 inch filter fans
- Package of 3

Replacement Filter Elements							
Part Number	Pieces per Package	Use With Filter Fan Kit Part Number	Use With Exhaust Grille and Filter Part Number	Filter Rating	Filter Density g/m <sup>2</sup>	Mass Filter Level %	Dimensions HxW in (mm)
086000-00	3	018000-01 018000-02	118000-00	G4 (Med.)	350	94	3.5 x 3.5 (88.90x88.90)
086010-00		018010-01 018010-02	118010-00				4.6 x 4.6 (116.84x116.84)
086020-00		018020-01 018020-02 018040-01	118020-00				6.6 x 6.6 (167.64x167.64)
086080-00		018030-01 018030-03 018050-01	118030-00				9.7 x 9.7 (246.38x246.38)
086030-00		018000-01 018000-02	118000-00	F5 (Fine)	360	98	3.5 x 3.5 (88.90x88.90)
086040-00		018010-01 018010-02 018210-02 018210-04	118010-00				4.6 x 4.6 (116.84x116.84)
086050-00		018020-01 018020-02 018040-01	118020-00				6.6 x 6.6 (167.64x167.64)
086090-00		018030-01 018030-03 018050-01	118030-00				9.7x9.7 (246.38x246.38mm)

Air Volume and Pressure Data						
Part Number	Filter Mat Air Volume (cfm)				Filter Mat Static Pressure (Pa)	
	G4 filter free flow*	G4 filter with exhaust filter**	F5 filter free flow*	F5 filter with exhaust filter**	G4 filter free flow*	F5 filter free flow*
018000-02	12	9	4	3	19	37
018000-01	14	11	5	4	18	35
018010-02	32	25	16	13	32	53
018010-01	37	28	19	15	30	50
018020-02	60	40	31	21	23	30
018020-01	69	46	36	24	27	35
018040-01	136	84	58	36	60	100
018030-03	176	135	47	36	23	46
018030-01	202	156	54	42	27	54
018050-01	373	203	145	83	85	140
018210-04	30	n/a	12	n/a	48	74
018210-02	35	n/a	14	n/a	35	54

\*Fan with filter and louver

\*\*Fan with filter, louver, exhaust filter, and grille.