

EZTouch 6" STN COLOR PANELS

6" color panels (5.7" STN)

The 6" color EZTouch panels have a 5.7" diagonal screen, with a 320x240 pixel resolution. They also feature an STN LCD (liquid crystal display). There are two standard color models of 6" panels to choose from: one for Koyo PLCs/Think & Do only, and one for multiple PLC brands including Koyo PLCs/Think & Do.

6" color panel for Koyo PLCs/Think & Do only

- 5.7" diagonal color STN LCD
- 128 colors
- NEMA 4, 4X (indoor)
- 320x240 pixel resolution
- 512K RAM expandable to 1.5MB
- 512K, 1MB or 2MB option flash card for memory backup
- No Ethernet card support
- 25,000 hour expected bulb half-life
- 48 touch cells (8x6)
- 1/4" O-ring gasket and eight mounting studs for NEMA 4/4X (indoor)
- 2.3" (59.0mm) installed depth

6" color panel for multiple PLC brands

- 5.7" diagonal color STN LCD
- 128 colors
- NEMA 4, 4X (indoor)
- 320x240 pixel resolution
- 512K RAM expandable to 1.5MB
- 512K, 1MB or 2MB option flash card for memory backup
- Ethernet card optional (EZ-ETHERNET)
- Modbus TCP/IP card optional (EZ-ETHERPLUS)
- 25,000 hour expected bulb half-life
- 48 touch cells (8x6)
- 1/4" O-ring gasket and eight mounting studs for NEMA 4/4X (indoor)
- 2.3" (59.0mm) installed depth




NEMA 4, 4X (indoor)

- **Part No. EZ-S6C-F \$845.00**
 - includes all serial drivers and accepts optional Ethernet cards
- **Part No. EZ-S6C-FH \$1,469.00**
 - includes Data Highway Plus interface

NEMA 4, 4X (indoor)

- **Part No. EZ-S6C-K \$745.00**
 - includes Koyo PLCs / Think & Do drivers (no Ethernet card support)

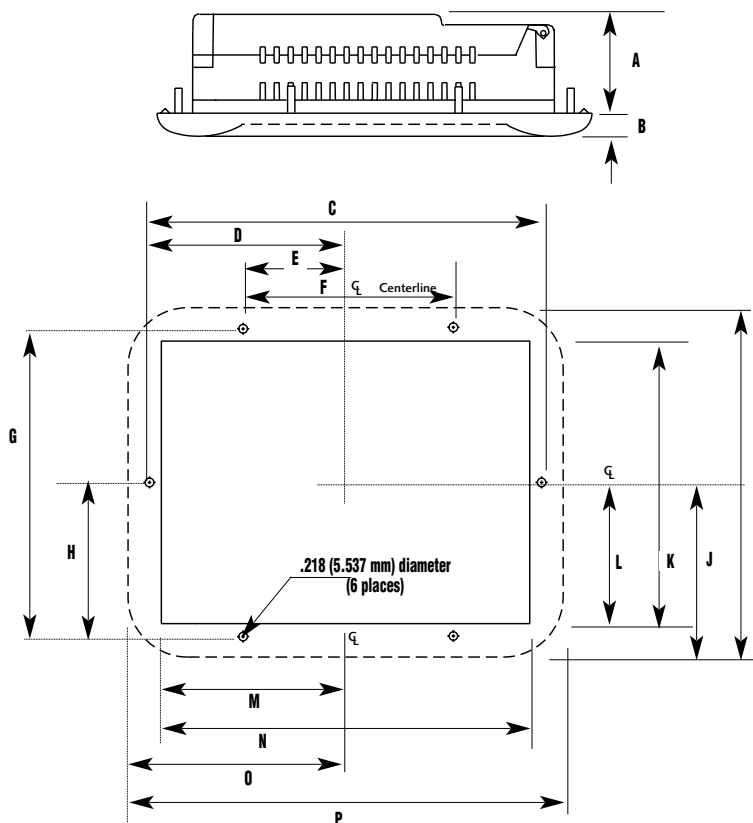

Dimensions (inch, mm)	
Legend	EZ-S6M-R/F EZ-S6C-K/F
A	2.325 (59.055)
B	.618 (15.697)
C	8.076 (205.135)
D	4.038 (102.565)
E	2.125 (53.978)
F	4.250 (107.950)
G	6.223 (158.057)
H	3.111 (79.029)
I	7.297 (185.343)
J	3.649 (92.672)
K	5.625 (142.878)
L	2.812 (71.427)
M	3.761 (95.532)
N	7.522 (191.064)
O	4.466 (113.436)
P	8.932 (226.873)