


Eclipse Series NEMA 12 Hinged Double-Door Wall Mount with Handle

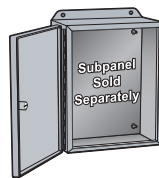

Applications

- Designed to enclose electrical and/or electronic equipment and protect against harsh, industrial environments for Wall Mount applications.
- Impressive styling features like hidden hinges and an attractive latching system make the Eclipse a suitable addition to any high-tech equipment installation.
- A wide range of sizes and practical accessories make this product line a complete package.

- Doors are secured with a 3-point key-lockable handle.
- Hinges are constructed from 304 stainless steel.
- Key-lockable handle is zinc diecast with black epoxy finish.
- Hinge pins are stainless steel.
- Door alignment guides provided on all doors.

Construction

- Formed 14 gauge steel.
- Continuously welded seams ground smooth.
- Door stiffeners are provided for increased strength and rigidity - designed to also permit additional mounting options.
- Formed lip on enclosure to exclude flowing liquids and contaminants.
- Oil-resistant gaskets are permanently secured.
- Collar studs provided for mounting subpanel.
- Includes hardware kit with panel mounting nuts and sealing washers for wall mounting holes.
- Bonding stud provided on door, and grounding stud installed in enclosure.

Finish

- Cover and enclosure are phosphatized and finished with a recoatable powder inside and out with choice of ANSI 61 smooth Gray (GY) or RAL7035 textured light gray (LG)..

Listings

- UL 508A Type 3R, 4, and 12 [UL File E65324]
- CSA Type 3R, 4, and 12 [CSA File LR21001]
- Complies with
 - NEMA Type 3R, 4, and 12
 - IEC 60529, IP66



Shipping Schedule	
Same day	1 - 15 days
Color indicates shipping lead time in business days.	


Eclipse Series NEMA 12 Hinged Double-Door Wall Mount with Handle					
ANSI 61 Gray	Price	RAL7035 Light Gray	Price	Enclosure Size HxWxD	Optional Painted Subpanel
EN4TD24428GY	\$557.00	EN4TD24428LG	\$557.00	24.00 x 42.00 x 8.82 [610 x 1067 x 224]	EP2442
EN4TD24488GY	\$605.00	EN4TD24488LG	\$605.00	24.00 x 48.00 x 8.82 [610 x 1219 x 224]	EP2448
EN4TD30488GY	\$684.00	EN4TD30488LG	\$684.00	30.00 x 48.00 x 8.82 [762 x 1219 x 224]	EP3048
EN4TD244210GY	\$585.00	EN4TD244210LG	\$585.00	24.00 x 42.00 x 10.82 [610 x 1067 x 275]	EP2442
EN4TD304210GY	\$663.00	EN4TD304210LG	\$663.00	30.00 x 42.00 x 10.82 [762 x 1067 x 275]	EP3042
EN4TD304810GY	\$691.00	EN4TD304810LG	\$691.00	30.00 x 48.00 x 10.82 [762 x 1219 x 275]	EP3048
EN4TD306010GY	\$822.00	EN4TD306010LG	\$822.00	30.00 x 60.00 x 10.82 [762 x 1524 x 275]	EP3060
EN4TD306012GY	\$883.00	EN4TD306012LG	\$883.00	30.00 x 60.00 x 12.82 [762 x 1524 x 326]	EP3060
EN4TD364212GY	\$789.00	EN4TD364212LG	\$789.00	36.00 x 42.00 x 12.82 [914 x 1067 x 326]	EP3642
EN4TD364812GY	\$846.00	EN4TD364812LG	\$846.00	36.00 x 48.00 x 12.82 [914 x 1219 x 326]	EP3648
EN4TD366012GY	\$987.00	EN4TD366012LG	\$987.00	36.00 x 60.00 x 12.82 [914 x 1524 x 326]	EP3660
EN4TD484812GY	\$1,030.00	EN4TD484812LG	\$1,030.00	48.00 x 48.00 x 12.82 [1219 x 1219 x 326]	EP3648

Note: Dimensions in inches [millimeters].

Eclipse Series NEMA 12 Hinged Double-Door Wall Mount with Handle



Dimensions

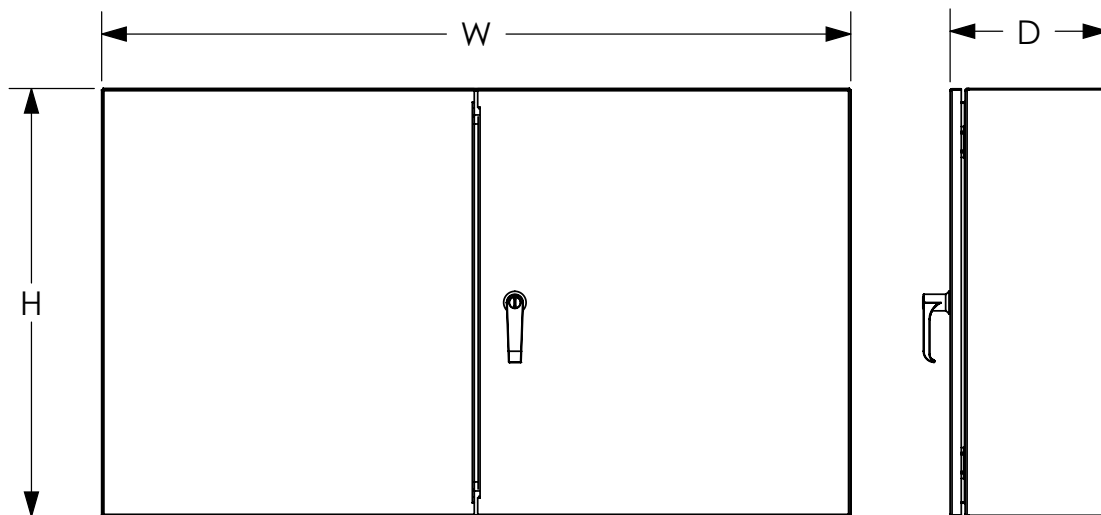

See our website: www.AutomationDirect.com for complete engineering drawings.