


Eclipse Series NEMA 3R, 4 and 12 Single-Door Wall Mount

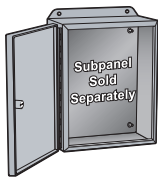

Shipping Schedule	
Same day	1 - 15 days
Color indicates shipping lead time in business days.	

Applications

- Designed to enclose electrical and/or electronic equipment and protect against harsh, industrial environments for Wall Mount applications.
- Impressive styling features like hidden hinges, attractive latching systems make the Eclipse a suitable addition to any high-tech equipment installation.
- A wide range of sizes and practical accessories make this product line a complete package.

Construction

- Formed 14 (24x24in and larger) or 16 gauge (24x20in and smaller) steel.
- Smooth, continuously welded seams ground smooth.
- Door stiffeners are provided where required for increased strength and rigidity - designed to also permit additional mounting options.
- Formed lip on enclosure to exclude flowing liquids and contaminants.
- Door latching: Type A has slotted 1/4-turns, Type B has handle with 3-point latching; Type C has handle with 3-point latching plus additional 1/4 turns top and bottom.
- Doors may be easily removed for modifications and are interchangeable.
- Seamless poured-in-place gasket.

- Collar studs provided for mounting subpanel.
- Includes hardware kit with panel mounting nuts, and sealing washers for wall mounting holes.
- Bonding stud provided on door, and grounding stud installed in enclosure.
- Hinges are constructed from 304 stainless steel.
- Hinge pins are 316 stainless steel.
- 1/4-turn latch and multi-point handle (key-lockable) are zinc diecast with black epoxy finish.
- Door alignment guide provided on 36in wide enclosures.

Finish

- Cover and enclosure are phosphatized and finished with a recoatable powder inside and out with choice of ANSI 61 smooth Gray (GY) or RAL7035 textured light gray (LG).

Listings

- UL 508A Type 3R, 4, and 12 [UL File E63524]
- CSA Type 3R, 4, and 12 [CSA File LR21001]
- Complies with
 - NEMA Type 3R, 4, and 12
 - IEC 60529, IP66



Eclipse Series NEMA 3R, 4 and 12 Single-Door Wall Mount							
ANSI 61 Gray	Price	RAL 7035 Light Gray	Price	Enclosure Size HxWxD	Latch Type	Optional Subpanels	
						Painted	Galvanized
EN4SD12106GY	\$176.00	EN4SD12106LG	\$176.00	12.00 x 10.00 x 6.82 [109 x 254 x 173]	A	EP1210	EPG1210
EN4SD12126GY	\$180.00	EN4SD12126LG	\$180.00	12.00 x 12.00 x 6.82 [109 x 305 x 173]		EP1212	EPG1212
EN4SD12246GY	\$184.00	EN4SD12246LG	\$184.00	12.00 x 24.00 x 6.82 [109 x 610 x 173]		EP1224	EPG1224
EN4SD12248GY	\$191.00	EN4SD12248LG	\$191.00	12.00 x 24.00 x 8.82 [109 x 610 x 224]		EP1224	EPG1224
EN4SD16126GY	\$192.00	EN4SD16126LG	\$192.00	16.00 x 12.00 x 6.82 [109 x 305 x 173]		EP1612	EPG1612
EN4SD16128GY	\$202.00	EN4SD16128LG	\$202.00	16.00 x 12.00 x 8.82 [109 x 305 x 224]		EP1612	EPG1612
EN4SD161210GY	\$208.00	EN4SD161210LG	\$208.00	16.00 x 12.00 x 10.82 [109 x 305 x 275]		EP1612	EPG1612
EN4SD16166GY	\$207.00	EN4SD16166LG	\$207.00	16.00 x 16.00 x 6.82 [109 x 406 x 173]		EP1616	EPG1616
EN4SD16168GY	\$218.00	EN4SD16168LG	\$218.00	16.00 x 16.00 x 8.82 [109 x 406 x 224]		EP1616	EPG1616
EN4SD161610GY	\$223.00	EN4SD161610LG	\$223.00	16.00 x 16.00 x 10.82 [109 x 406 x 275]		EP1616	EPG1616
EN4SD16206GY	\$222.00	EN4SD16206LG	\$222.00	16.00 x 20.00 x 6.82 [109 x 508 x 173]		EP1620	EPG1620

Note: Dimensions in inches [millimeters].

Continued on next page

Eclipse Series NEMA 3R, 4 and 12 Single-Door Wall Mount



Continued from previous page

Eclipse Series NEMA 3R, 4 and 12 Single-Door Wall Mount							
ANSI 61 Gray	Price	RAL 7035 Light Gray	Price	Enclosure Size HxWxD	Latch Type	Optional Subpanels	
						Painted	Galvanized
EN4SD16208GY	\$241.00	EN4SD16208LG	\$241.00	16.00 x 20.00 x 8.82 [109 x 508 x 224]	A	EP1620	EPG1620
EN4SD162010GY	\$240.00	EN4SD162010LG	\$240.00	16.00 x 20.00 x 10.82 [109 x 508 x 275]		EP1620	EPG1620
EN4SD20126GY	\$220.00	EN4SD20126LG	\$220.00	20.00 x 12.00 x 6.82 [109 x 305 x 173]		EP2012	EPG2012
EN4SD20128GY	\$225.00	EN4SD20128LG	\$225.00	20.00 x 12.00 x 8.82 [109 x 305 x 224]		EP2012	EPG2012
EN4SD20166GY	\$222.00	EN4SD20166LG	\$222.00	20.00 x 16.00 x 6.82 [109 x 406 x 173]		EP2016	EPG2016
EN4SD20168GY	\$234.00	EN4SD20168LG	\$234.00	20.00 x 16.00 x 8.82 [109 x 406 x 224]		EP2016	EPG2016
EN4SD201610GY	\$240.00	EN4SD201610LG	\$240.00	20.00 x 16.00 x 10.82 [109 x 406 x 275]		EP2016	EPG2016
EN4SD201612GY	\$292.00	EN4SD201612LG	\$292.00	20.00 x 16.00 x 12.82 [109 x 406 x 326]		EP2016	EPG2016
EN4SD20206GY	\$240.00	EN4SD20206LG	\$240.00	20.00 x 20.00 x 6.82 [109 x 508 x 173]		EP2020	EPG2020
EN4SD20208GY	\$253.00	EN4SD20208LG	\$253.00	20.00 x 20.00 x 8.82 [109 x 508 x 224]		EP2020	EPG2020
EN4SD202010GY	\$260.00	EN4SD202010LG	\$260.00	20.00 x 20.00 x 10.82 [109 x 508 x 275]		EP2020	EPG2020
EN4SD202012GY	\$288.00	EN4SD202012LG	\$288.00	20.00 x 20.00 x 12.82 [109 x 508 x 326]		EP2020	EPG2020
EN4SD20246GY	\$270.00	EN4SD20246LG	\$270.00	20.00 x 24.00 x 6.82 [109 x 610 x 173]		EP2024	EPG2024
EN4SD20248GY	\$280.00	EN4SD20248LG	\$280.00	20.00 x 24.00 x 8.82 [508 x 610 x 224]		EP2024	EPG2024
EN4SD202410GY	\$278.00	EN4SD202410LG	\$278.00	20.00 x 24.00 x 10.82 [109 x 610 x 275]		EP2024	EPG2024
EN4SD24126GY	\$223.00	EN4SD24126LG	\$223.00	24.00 x 12.00 x 6.82 [109 x 305 x 173]		EP2412	EPG2412
EN4SD24128GY	\$241.00	EN4SD24128LG	\$241.00	24.00 x 12.00 x 8.82 [109 x 305 x 224]		EP2412	EPG2412
EN4SD241210GY	\$256.00	EN4SD241210LG	\$256.00	24.00 x 12.00 x 10.82 [109 x 305 x 275]		EP2412	EPG2412
EN4SD24166GY	\$243.00	EN4SD24166LG	\$243.00	24.00 x 16.00 x 6.82 [109 x 406 x 173]		EP2416	EPG2416
EN4SD24168GY	\$250.00	EN4SD24168LG	\$250.00	24.00 x 16.00 x 8.82 [109 x 406 x 224]		EP2416	EPG2416
EN4SD241610GY	\$256.00	EN4SD241610LG	\$256.00	24.00 x 16.00 x 10.82 [109 x 406 x 275]		EP2416	EPG2416
EN4SD24206GY	\$264.00	EN4SD24206LG	\$264.00	24.00 x 20.00 x 6.82 [109 x 508 x 173]		EP2420	EPG2420
EN4SD24208GY	\$272.00	EN4SD24208LG	\$272.00	24.00 x 20.00 x 8.82 [109 x 508 x 224]		EP2420	EPG2420
EN4SD242010GY	\$279.00	EN4SD242010LG	\$279.00	24.00 x 20.00 x 10.82 [109 x 508 x 275]		EP2420	EPG2420
EN4SD242012GY	\$310.00	EN4SD242012LG	\$310.00	24.00 x 20.00 x 12.82 [109 x 508 x 326]		EP2420	EPG2420
EN4SD242016GY	\$338.00	EN4SD242016LG	\$338.00	24.00 x 20.00 x 16.82 [109 x 508 x 427]		EP2420	EPG2420
EN4SD24246GY	\$285.00	EN4SD24246LG	\$285.00	24.00 x 24.00 x 6.82 [109 x 610 x 173]		EP2424	EPG2424
EN4SD24248GY	\$293.00	EN4SD24248LG	\$293.00	24.00 x 24.00 x 8.82 [109 x 610 x 224]		EP2424	EPG2424
EN4SD242410GY	\$301.00	EN4SD242410LG	\$301.00	24.00 x 24.00 x 10.82 [109 x 610 x 275]		EP2424	EPG2424
EN4SD242412GY	\$326.00	EN4SD242412LG	\$326.00	24.00 x 24.00 x 12.82 [109 x 610 x 326]		EP2424	EPG2424
EN4SD242416GY	\$368.00	EN4SD242416LG	\$368.00	24.00 x 24.00 x 16.82 [109 x 610 x 427]		EP2424	EPG2424
EN4SD242420GY	\$401.00	EN4SD242420LG	\$401.00	24.00 x 24.00 x 20.82 [610 x 610 x 529]		EP2424	EPG2424
EN4SD24308GY	\$326.00	EN4SD24308LG	\$326.00	24.00 x 30.00 x 8.82 [610 x 762 x 224]		EP2430	EPG2430
EN4SD243010GY	\$334.00	EN4SD243010LG	\$334.00	24.00 x 30.00 x 10.82 [109 x 762 x 275]		EP2430	EPG2430
EN4SD243012GY	\$356.00	EN4SD243012LG	\$356.00	24.00 x 30.00 x 12.82 [610 x 762 x 326]	EP2430	EPG2430	
EN4SD30128GY	\$292.00	EN4SD30128LG	\$292.00	30.00 x 12.00 x 8.82 [762 x 305 x 224]	EP3012	EPG3012	
EN4SD30166GY	\$290.00	EN4SD30166LG	\$290.00	30.00 x 16.00 x 6.82 [762 x 406 x 173]	EP3016	EPG3016	
EN4SD30168GY	\$295.00	EN4SD30168LG	\$295.00	30.00 x 16.00 x 8.82 [762 x 406 x 224]	EP3016	EPG3016	
EN4SD30206GY	\$296.00	EN4SD30206LG	\$296.00	30.00 x 20.00 x 6.82 [762 x 508 x 173]	EP3020	EPG3020	
EN4SD30208GY	\$309.00	EN4SD30208LG	\$309.00	30.00 x 20.00 x 8.82 [762 x 508 x 224]	EP3020	EPG3020	

Note: Dimensions in inches [millimeters].

Continued on next page

Eclipse Series NEMA 3R, 4 and 12 Single-Door Wall Mount



Shipping Schedule	
Same day	1 - 15 days
Color indicates shipping lead time in business days.	

Continued from previous page

Eclipse Series NEMA 3R, 4 and 12 Single-Door Wall Mount							
ANSI 61 Gray	Price	RAL 7035 Light Gray	Price	Enclosure Size HxWxD	Latch Type	Optional Subpanels	
						Painted	Galvanized
EN4SD302010GY	\$308.00	EN4SD302010LG	\$308.00	30.00 x 20.00 x 10.82 [762 x 508 x 275]	A	EP3020	EPG3020
EN4SD30246GY	\$309.00	EN4SD30246LG	\$309.00	30.00 x 24.00 x 6.82 [762 x 610 x 173]		EP3024	EPG3024
EN4SD30248GY	\$326.00	EN4SD30248LG	\$326.00	30.00 x 24.00 x 8.82 [762 x 610 x 224]		EP3024	EPG3024
EN4SD302410GY	\$334.00	EN4SD302410LG	\$334.00	30.00 x 24.00 x 10.82 [762 x 610 x 275]		EP3024	EPG3024
EN4SD302412GY	\$362.00	EN4SD302412LG	\$362.00	30.00 x 24.00 x 12.82 [762 x 610 x 326]		EP3024	EPG3024
EN4SD302416GY	\$401.00	EN4SD302416LG	\$401.00	30.00 x 24.00 x 16.82 [762 x 610 x 427]		EP3024	EPG3024
EN4SD302420GY	\$447.00	EN4SD302420LG	\$447.00	30.00 x 24.00 x 20.82 [762 x 610 x 529]		EP3024	EPG3024
EN4SD302424GY	\$487.00	EN4SD302424LG	\$486.00	30.00 x 24.00 x 24.82 [762 x 610 x 630]		EP3024	EPG3024
EN4SD30308GY	\$364.00	EN4SD30308LG	\$364.00	30.00 x 30.00 x 8.82 [762 x 762 x 224]		EP3030	EPG3030
EN4SD303010GY	\$374.00	EN4SD303010LG	\$374.00	30.00 x 30.00 x 10.82 [762 x 762 x 275]		EP3030	EPG3030
EN4SD303012GY	\$404.00	EN4SD303012LG	\$404.00	30.00 x 30.00 x 12.82 [762 x 762 x 326]		EP3030	EPG3030
EN4SD30368GY	\$400.00	EN4SD30368LG	\$400.00	30.00 x 36.00 x 8.82 [762 x 914 x 224]		EP3036	EPG3036
EN4SD36246GY	\$358.00	EN4SD36246LG	\$358.00	36.00 x 24.00 x 6.82 [914 x 610 x 173]		EP3624	EPG3624
EN4SD36248GY	\$358.00	EN4SD36248LG	\$358.00	36.00 x 24.00 x 8.82 [914 x 610 x 224]		EP3624	EPG3624
EN4SD362410GY	\$368.00	EN4SD362410LG	\$368.00	36.00 x 24.00 x 10.82 [914 x 610 x 275]		EP3624	EPG3624
EN4SD362412GY	\$408.00	EN4SD362412LG	\$408.00	36.00 x 24.00 x 12.82 [914 x 610 x 326]		EP3624	EPG3624
EN4SD362416GY	\$453.00	EN4SD362416LG	\$453.00	36.00 x 24.00 x 16.82 [914 x 610 x 427]		EP3624	EPG3624
EN4SD36306GY	\$395.00	EN4SD36306LG	\$395.00	36.00 x 30.00 x 6.82 [914 x 762 x 173]		EP3630	EPG3630
EN4SD36308GY	\$401.00	EN4SD36308LG	\$401.00	36.00 x 30.00 x 8.82 [914 x 762 x 224]		EP3630	EPG3630
EN4SD363010GY	\$414.00	EN4SD363010LG	\$414.00	36.00 x 30.00 x 10.82 [914 x 762 x 275]		EP3630	EPG3630
EN4SD363012GY	\$445.00	EN4SD363012LG	\$445.00	36.00 x 30.00 x 12.82 [914 x 762 x 326]	EP3630	EPG3630	
EN4SD363016GY	\$505.00	EN4SD363016LG	\$505.00	36.00 x 30.00 x 16.82 [914 x 762 x 427]	EP3630	EPG3630	
EN4SD363020GY	\$551.00	EN4SD363020LG	\$551.00	36.00 x 30.00 x 20.82 [914 x 762 x 529]	EP3630	EPG3630	
EN4SD36368GY	\$445.00	EN4SD36368LG	\$445.00	36.00 x 36.00 x 8.82 [914 x 914 x 224]	EP3636	EPG3636	
EN4SD363610GY	\$458.00	EN4SD363610LG	\$458.00	36.00 x 36.00 x 10.82 [914 x 914 x 275]	EP3636	EPG3636	
EN4SD363612GY	\$509.00	EN4SD363612LG	\$509.00	36.00 x 36.00 x 12.82 [914 x 914 x 326]	EP3636	EPG3636	
EN4SD363616GY	\$549.00	EN4SD363616LG	\$549.00	36.00 x 36.00 x 16.82 [914 x 914 x 427]	EP3636	EPG3636	
EN4SD42248GY	\$455.00	EN4SD42248LG	\$455.00	42.00 x 24.00 x 8.82 [1067 x 610 x 224]	B	EP4224	EPG4224
EN4SD422410GY	\$487.00	EN4SD422410LG	\$487.00	42.00 x 24.00 x 10.82 [1067 x 610 x 275]		EP4224	EPG4224
EN4SD42308GY	\$496.00	EN4SD42308LG	\$496.00	42.00 x 30.00 x 8.82 [1067 x 762 x 224]		EP4230	EPG4230
EN4SD423010GY	\$510.00	EN4SD423010LG	\$510.00	42.00 x 30.00 x 10.82 [1067 x 762 x 275]		EP4230	EPG4230
EN4SD423012GY	\$594.00	EN4SD423012LG	\$594.00	42.00 x 30.00 x 12.82 [1067 x 762 x 326]		EP4230	EPG4230
EN4SD423016GY	\$633.00	EN4SD423016LG	\$633.00	42.00 x 30.00 x 16.82 [1067 x 762 x 427]		EP4230	EPG4230
EN4SD42368GY	\$508.00	EN4SD42368LG	\$508.00	42.00 x 36.00 x 8.82 [1067 x 914 x 224]		EP4236	EPG4236
EN4SD423610GY	\$521.00	EN4SD423610LG	\$521.00	42.00 x 36.00 x 10.82 [1067 x 914 x 275]		EP4236	EPG4236
EN4SD423612GY	\$543.00	EN4SD423612LG	\$543.00	42.00 x 36.00 x 12.82 [1067 x 914 x 326]		EP4236	EPG4236
EN4SD423616GY	\$628.00	EN4SD423616LG	\$628.00	42.00 x 36.00 x 16.82 [1067 x 914 x 427]		EP4236	EPG4236

Note: Dimensions in inches [millimeters].

Continued on next page

Eclipse Series NEMA 3R, 4 and 12 Single-Door Wall Mount



Continued from previous page


Eclipse Series NEMA 3R, 4 and 12 Single-Door Wall Mount							
ANSI 61 Gray	Price	RAL 7035 Light Gray	Price	Enclosure Size HxWxD	Latch Type	Optional Subpanels	
						Painted	Galvanized
EN4SD48248GY	\$545.00	EN4SD48248LG	\$545.00	48.00 x 24.00 x 8.82 [1219 x 610 x 224]	B	EP4824	EPG4824
EN4SD482410GY	\$553.00	EN4SD482410LG	\$553.00	48.00 x 24.00 x 10.82 [1219 x 610 x 275]		EP4824	EPG4824
EN4SD482412GY	\$547.00	EN4SD482412LG	\$547.00	48.00 x 24.00 x 12.82 [1219 x 610 x 326]		EP4824	EPG4824
EN4SD48308GY	\$552.00	EN4SD48308LG	\$552.00	48.00 x 30.00 x 8.82 [1219 x 762 x 224]		EP4830	EPG4830
EN4SD483010GY	\$559.00	EN4SD483010LG	\$559.00	48.00 x 30.00 x 10.82 [1219 x 762 x 275]		EP4830	EPG4830
EN4SD483016GY	\$652.00	EN4SD483016LG	\$652.00	48.00 x 30.00 x 16.82 [1219 x 762 x 427]		EP4830	EPG4830
EN4SD48368GY	\$560.00	EN4SD48368LG	\$560.00	48.00 x 36.00 x 8.82 [1219 x 914 x 224]		EP4836	EPG4836
EN4SD483610GY	\$568.00	EN4SD483610LG	\$568.00	48.00 x 36.00 x 10.82 [1219 x 914 x 275]		EP4836	EPG4836
EN4SD483612GY	\$593.00	EN4SD483612LG	\$593.00	48.00 x 36.00 x 12.82 [1219 x 914 x 326]		EP4836	EPG4836
EN4SD483616GY	\$649.00	EN4SD483616LG	\$649.00	48.00 x 36.00 x 16.82 [1219 x 914 x 427]		EP4836	EPG4836
EN4SD483620GY	\$701.00	EN4SD483620LG	\$701.00	48.00 x 36.00 x 20.82 [1219 x 914 x 529]		EP4836	EPG4836
EN4SD60368GY	\$633.00	EN4SD60368LG	\$633.00	60.00 x 36.00 x 8.82 [1524 x 914 x 224]		EP6036	EPG6036
EN4SD603610GY	\$662.00	EN4SD603610LG	\$662.00	60.00 x 36.00 x 10.82 [1524 x 914 x 275]		EP6036	EPG6036
EN4SD603612GY	\$690.00	EN4SD603612LG	\$690.00	60.00 x 36.00 x 12.82 [1524 x 914 x 326]		EP6036	EPG6036
EN4SD603616GY	\$751.00	EN4SD603616LG	\$751.00	60.00 x 36.00 x 16.82 [1524 x 914 x 427]	EP6036	EPG6036	
EN4SD603620GY	\$841.00	EN4SD603620LG	\$841.00	60.00 x 36.00 x 20.82 [1524 x 914 x 529]	EP6036	EPG6036	
EN4SD723012GY	\$714.00	EN4SD723012LG	\$714.00	72.00 x 30.00 x 12.82 [1829 x 762 x 326]	C	EP7230	EPG7230
EN4SD723016GY	\$784.00	EN4SD723016LG	\$784.00	72.00 x 30.00 x 16.82 [1829 x 762 x 427]		EP7230	EPG7230
EN4SD723020GY	\$865.00	EN4SD723020LG	\$864.00	72.00 x 30.00 x 20.82 [1829 x 762 x 529]		EP7230	EPG7230
EN4SD723024GY	\$923.00	EN4SD723024LG	\$923.00	72.00 x 30.00 x 24.82 [1829 x 762 x 630]		EP7230	EPG7230
EN4SD723612GY	\$788.00	EN4SD723612LG	\$788.00	72.00 x 36.00 x 12.82 [1829 x 914 x 326]		EP7236	EPG7236
EN4SD723616GY	\$847.00	EN4SD723616LG	\$847.00	72.00 x 36.00 x 16.82 [1829 x 914 x 427]		EP7236	EPG7236

Note: Dimensions in inches [millimeters].

Eclipse Series NEMA 3R, 4 and 12 Single-Door Wall Mount



Dimensions

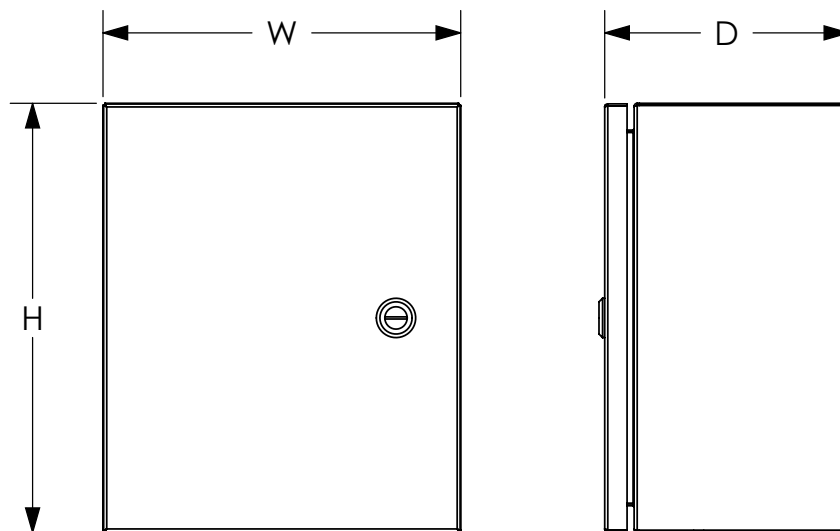

See our website: www.AutomationDirect.com for complete engineering drawings.