


Eclipse Series NEMA 3R, 4 and 12 Single-Door Wall Mount Slope Top

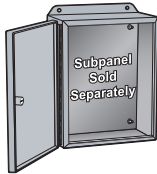

Shipping Schedule	
Same day	1 - 15 days
Color indicates shipping lead time in business days.	

Applications

- Designed to enclose electrical and/or electronic equipment and protect against harsh, industrial environments for Wall Mount applications.
- Sloped top prevents water from resting on top as well as providing potential for controls mounting.
- Impressive styling features like hidden hinges and attractive latching systems make the Eclipse a suitable addition to any high-tech equipment installation.
- A wide range of sizes and practical accessories make this product line a complete package.

Construction

- Formed 14 gauge (24x24in and larger) or 16 gauge (24x20in and smaller) steel.
- Continuously welded seams ground smooth.
- Door stiffeners are provided where required for increased strength and rigidity - designed to also permit additional mounting options.
- Formed lip on enclosure to exclude flowing liquids and contaminants.
- Door latching: Type A has slotted 1/4 turns, Type B has handle with 3-point latching

- Doors may be easily removed for modifications and are interchangeable.
- Seamless poured-in-place gasket.
- Collar studs provided for mounting subpanel.
- Includes hardware kit with panel mounting nuts and sealing washers for wall mounting holes.
- Bonding stud provided on door and grounding stud installed in enclosure.
- Hinges are mild steel.
- Stainless steel hinge pins and 1/4- turn latches.

Finish

- Cover and enclosure are finished in recoatable RAL7035 light gray textured powder coating.

Listings

- UL 508A Type 3R, 4, and 12 [UL File 65324]
- CSA Type 3R, 4, and 12 [CSA File LR21001]
- Complies with
 - NEMA Type 3R, 4, and 12
 - IEC 60529, IP66

Eclipse Series NEMA 3R, 4 and 12 Single-Door Wall Mount Slope Top						
Part Number	Price	Enclosure Size HxWxD	Latch Type	Optional Subpanels		
				Painted	Galvanized	Dimensions
ST12126LG	\$223.00	14.18 x 12.00 x 6.82 [360 x 305 x 173]	A	EP1212	EPG1212	10.17 x 10.17in
ST16126LG	\$239.00	18.18 x 12.00 x 6.82 [462 x 305 x 173]		EP1612	EPG1612	14.17 x 10.17in
ST16168LG	\$270.00	18.91 x 16.00 x 8.82 [480 x 406 x 224]		EP1616	EPG1616	14.17 x 14.17in
ST20166LG	\$275.00	22.18 x 16.00 x 6.82 [563 x 406 x 173]		EP2016	EPG2016	18.17 x 14.17in
ST20168LG	\$290.00	22.91 x 16.00 x 8.82 [582 x 406 x 224]		EP2016	EPG2016	18.17 x 14.17in
ST20206LG	\$298.00	22.16 x 20.00 x 6.82 [563 x 508 x 173]		EP2020	EPG2020	18.17 x 18.17in
ST20208LG	\$314.00	22.91 x 20.00 x 8.82 [582 x 508 x 224]		EP2020	EPG2020	18.17 x 18.17in
ST24208LG	\$337.00	26.91 x 20.00 x 8.82 [684 x 508 x 224]		EP2420	EPG2420	22.17 x 18.17in
ST24248LG	\$364.00	26.93 x 24.00 x 8.84 [684 x 610 x 225]		EP2424	EPG2424	22.17 x 22.17in
ST242410LG	\$374.00	27.63 x 24.00 x 10.84 [702 x 610 x 275]		EP2424	EPG2424	22.17 x 22.17in
ST242412LG	\$405.00	28.38 x 24.00 x 12.84 [721 x 610 x 326]		EP2424	EPG2424	22.17 x 22.17in
ST30248LG	\$405.00	32.92 x 24.00 x 8.84 [836 x 610 x 225]		EP3024	EPG3024	28.17 x 22.17in
ST302410LG	\$416.00	33.65 x 24.00 x 10.84 [855 x 610 x 275]		EP3024	EPG3024	28.17 x 22.17in
ST302412LG	\$448.00	34.36 x 24.00 x 12.84 [873 x 610 x 326]		EP3024	EPG3024	28.17 x 22.17in
ST302420LG	\$556.00	37.29 x 24.00 x 20.84 [947 x 610 x 529]		EP3024	EPG3024	28.17 x 22.17in
ST30308LG	\$453.00	32.92 x 30.00 x 8.84 [836 x 762 x 225]		EP3030	EPG3030	28.17 x 28.17in
ST36308LG	\$501.00	38.92 x 30.00 x 8.84 [989 x 762 x 225]		EP3630	EPG3630	34.17 x 28.17in
ST363010LG	\$514.00	39.65 x 30.00 x 10.84 [1007 x 762 x 275]		EP3630	EPG3630	34.17 x 28.17in
ST363012LG	\$554.00	40.37 x 30.00 x 12.84 [1025 x 762 x 326]		EP3630	EPG3630	34.17 x 28.17in
ST363016LG	\$629.00	41.83 x 30.00 x 16.84 [1062 x 762 x 428]		EP3630	EPG3630	34.17 x 28.17in
ST363612LG	\$615.00	40.37 x 36.00 x 12.84 [1025 x 914 x 326]	EP3636	EPG3636	34.17 x 34.17in	
ST483610LG	\$707.00	51.65 x 36.00 x 10.84 [1312 x 914 x 275]	EP4836	EPG4836	46.17 x 34.17in	
ST483612LG	\$738.00	52.38 x 36.00 x 12.84 [1330 x 914 x 326]	EP4836	EPG4836	46.17 x 34.17in	
ST483616LG	\$810.00	53.84 x 36.00 x 16.84 [1368 x 914 x 428]	EP4836	EPG4836	46.17 x 34.17in	
ST603612LG	\$861.00	64.35 x 36.00 x 12.84 [1634 x 914 x 326]	EP6036	EPG6036	58.17 x 34.17in	


Note: Dimensions in inches [millimeters].



Eclipse Series NEMA 3R, 4 and 12 Single-Door Wall Mount Sloped Top



Dimensions

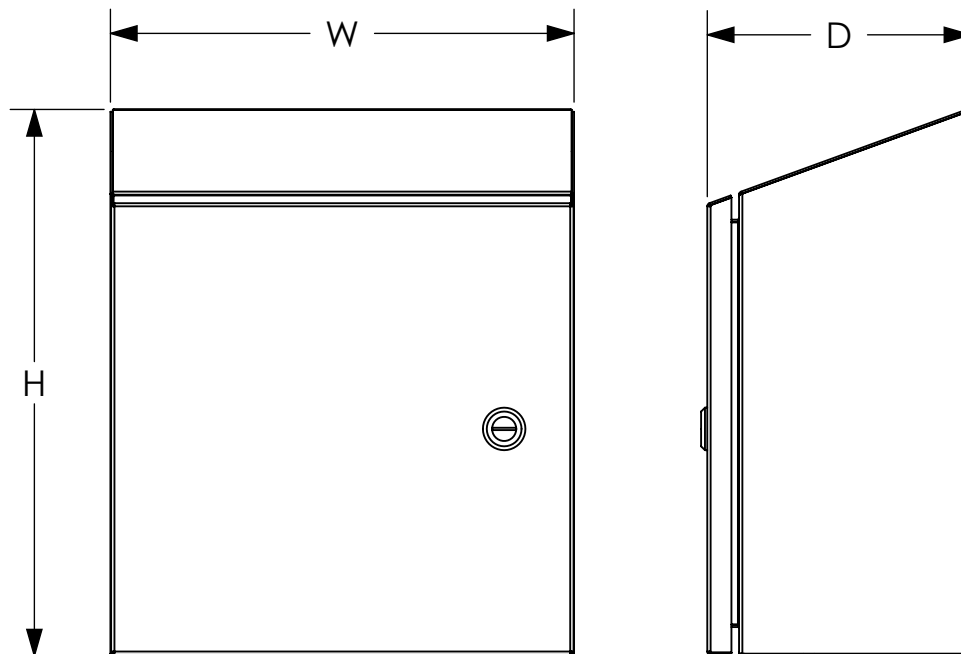

See our website: www.AutomationDirect.com for complete engineering drawings.