


# Eclipse Series NEMA 3R, 4 and 12 Single-Door Wall Mount with Window

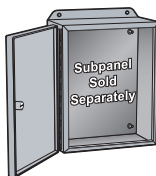

## Applications

- Designed to enclose electrical and/or electronic equipment in Wall Mount applications where viewing of component operation is necessary while maintaining protection ratings.
- Impressive styling features like hidden hinges and an attractive latching system make the Eclipse a suitable addition to any high-tech equipment installation.
- A wide range of sizes and practical accessories make this product line a complete package.

- Seamless poured-in-place gasket.
- Collar studs provided for mounting subpanel.
- Includes hardware kit with panel mounting nuts and sealing washers for wall mounting holes.
- Bonding stud provided on door, and grounding stud installed in enclosure.
- Hinges are constructed from 304 stainless steel.
- Hinge pins are 316 stainless steel.
- 1/4-turn latches are zinc diecast with black epoxy finish.

## Construction

- Formed 14 gauge (24x24in and larger) or 16 gauge (24x20in and smaller) steel.
- Full view UV-resistant polycarbonate window allow maximum viewing area of interior.
- Continuously welded seams ground smooth.
- Door stiffeners are provided where required for increased strength and rigidity - designed to also permit additional mounting options.
- Formed lip on enclosure to exclude flowing liquids and contaminants.
- Door latches feature the added safety of 1/4-turn slot requiring use of tool for opening.
- Doors may be easily removed for modifications and are interchangeable.

## Finish

- Cover and enclosure are phosphatized and finished with a recoatable powder inside and out with choice of ANSI 61 smooth Gray (GY) or RAL7035 textured light gray (LG)..

## Listings

- UL 508A Type 3R, 4, and 12 [UL File E65324]
- CSA Type 3R, 4, and 12 [CSA File LR21001]
- Complies with
  - NEMA Type 3R, 4, and 12
  - IEC 60529, IP66

Shipping Schedule	
Same day	1 - 15 days
Color indicates shipping lead time in business days.	




Eclipse Series NEMA 3R, 4 and 12 Single-Door Wall Mount with Window						
ANSI 61 Gray	Price	RAL7035 Light Gray	Price	Enclosure Size HxWxD	Optional Subpanels	
					Painted	Galvanized
EN4SD16126WGY	\$291.00	EN4SD16126WLG	\$291.00	16.00 x 12.00 x 6.82 [406 x 305 x 173]	EP1612	EPG1612
EN4SD16128WGY	\$305.00	EN4SD16128WLG	\$305.00	16.00 x 12.00 x 8.82 [406 x 305 x 224]	EP1612	EPG1612
EN4SD20166WGY	\$335.00	EN4SD20166WLG	\$335.00	20.00 x 16.00 x 6.82 [508 x 406 x 173]	EP2016	EPG2016
EN4SD20168WGY	\$354.00	EN4SD20168WLG	\$354.00	20.00 x 16.00 x 8.82 [508 x 406 x 224]	EP2016	EPG2016
EN4SD20206WGY	\$362.00	EN4SD20206WLG	\$362.00	20.00 x 20.00 x 6.82 [508 x 508 x 173]	EP2020	EPG2020
EN4SD20208WGY	\$382.00	EN4SD20208WLG	\$382.00	20.00 x 20.00 x 8.82 [508 x 508 x 224]	EP2020	EPG2020
EN4SD202012WGY	\$423.00	EN4SD202012WLG	\$423.00	20.00 x 20.00 x 12.82 [508 x 508 x 326]	EP2020	EPG2020
EN4SD24206WGY	\$389.00	EN4SD24206WLG	\$389.00	24.00 x 20.00 x 6.82 [610 x 508 x 173]	EP2420	EPG2420
EN4SD24208WGY	\$410.00	EN4SD24208WLG	\$410.00	24.00 x 20.00 x 8.82 [610 x 508 x 224]	EP2420	EPG2420
EN4SD242012WGY	\$456.00	EN4SD242012WLG	\$456.00	24.00 x 20.00 x 12.82 [610 x 508 x 326]	EP2420	EPG2420
EN4SD24246WGY	\$419.00	EN4SD24246WLG	\$419.00	24.00 x 24.00 x 6.82 [610 x 610 x 173]	EP2424	EPG2424
EN4SD24248WGY	\$444.00	EN4SD24248WLG	\$444.00	24.00 x 24.00 x 8.82 [610 x 610 x 224]	EP2424	EPG2424
EN4SD242412WGY	\$492.00	EN4SD242412WLG	\$492.00	24.00 x 24.00 x 12.82 [610 x 610 x 326]	EP2424	EPG2424
EN4SD242416WGY	\$541.00	EN4SD242416WLG	\$541.00	24.00 x 24.00 x 16.82 [610 x 610 x 427]	EP2424	EPG2424
EN4SD242420WGY	\$591.00	EN4SD242420WLG	\$591.00	24.00 x 24.00 x 20.82 [610 x 610 x 529]	EP2424	EPG2424
EN4SD30248WGY	\$492.00	EN4SD30248WLG	\$492.00	30.00 x 24.00 x 8.82 [762 x 610 x 224]	EP3024	EPG3024
EN4SD302412WGY	\$548.00	EN4SD302412WLG	\$548.00	30.00 x 24.00 x 12.82 [762 x 610 x 326]	EP3024	EPG3024
EN4SD302420WGY	\$660.00	EN4SD302420WLG	\$660.00	30.00 x 24.00 x 20.82 [762 x 610 x 529]	EP3024	EPG3024

Note: Dimensions in inches [millimeters].

# Eclipse Series NEMA 3R, 4 and 12 Single-Door Wall Mount with Window



## Dimensions

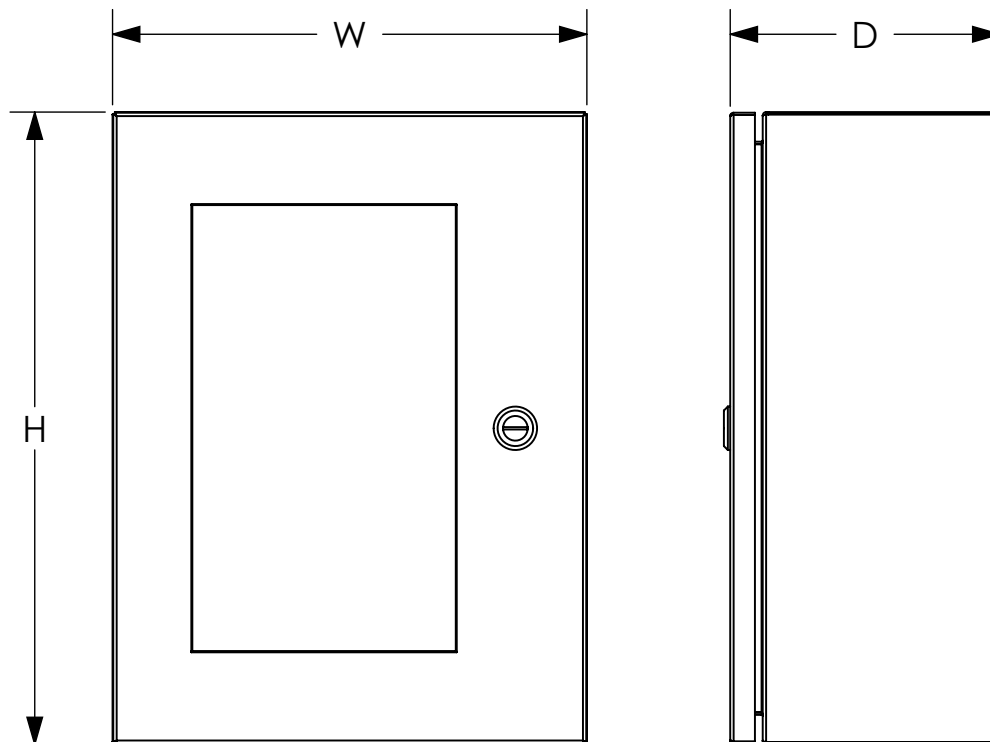

*See our website: [www.AutomationDirect.com](http://www.AutomationDirect.com) for complete engineering drawings.*