


Eclipse Junior Series NEMA 3R, 4, 4X, 12 and 13 Stainless Steel Single-Door Wall Mount with 1/4-Turn Latch

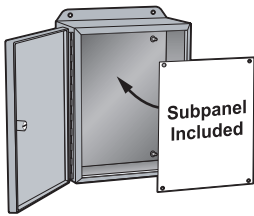

Shipping Schedule	
Same day	1 - 15 days
Color indicates shipping lead time in business days.	

Applications

- Designed for use as instrument enclosures, electric, hydraulic or pneumatic control housings, electrical junction boxes or terminal wiring enclosures.
- Provides protection where equipment may be hosed down or otherwise be very wet, or in specific applications where corrosion may be a problem.
- For high temperature applications, a gasket retainer may be required, please refer to factory.

Construction

- Body and cover are formed from 16 gauge steel.
- Smooth, continuously welded seams without knockouts, cutouts, or holes.
- Formed lip on enclosure to exclude flowing liquids and contaminants.
- 1/4 gauge welded brackets provide for enclosure mounting.
- Continuously hinged cover has stainless steel hinges and provides 180° opening.
- Door latches feature the added safety of 1/4-turn slot requiring use of tool for opening.
- 1/4-turn latches formed from 316 stainless steel.

- Seamless poured-in-place gasket.
- Models larger than 4x4in include a removable 14 gauge galvanized subpanel.
- Tapped studs are provided for mounting subpanels.
- A bonding stud is provided on the door, and a grounding stud is provided on the enclosure.
- Grounding and subpanel mounting hardware provided.

Finish

- Cover and enclosure are natural stainless steel with a #4 smooth brushed finish.
- Removable subpanel is unpainted galvanized steel.

Listings

- UL 508A Type 3R, 4, 4X, 12 and 13 [UL File E65324]
- CSA Type 3R, 4, 14X, 2 and 13 [CSA File LR21001]
- Complies with
 - NEMA Type 3R, 4, 4X, 12 and 13
 - IEC 60529, IP66



Eclipse Junior Series NEMA 3R, 4, 4X, 12 and 13 Stainless Steel Single-Door Wall Mount with 1/4-Turn Latch										
		Enclosures				Included Subpanel	Subpanel HxW	Optional Subpanels		
304 Stainless	Price	316 Stainless	Price	Enclosure Size HxWxD	Steel			Aluminum	Stainless	
EJ443SS	\$149.00	EJ443S16	\$187.00	4.00 x 4.16 x 3.59 [102 x 106 x 91]	-	-	-	-	-	
EJ444SS	\$149.00	EJ444S16	\$188.00	4.00 x 4.16 x 4.59 [102 x 106 x 117]	-	-	-	-	-	
EJ643SS	\$150.00	EJ643S16	\$189.00	6.00 x 4.16 x 3.59 [152 x 106 x 91]	14G0503	4.88 x 2.88in	14R0503	14A0503	14R0503SS	
EJ644SS	\$150.00	EJ644S16	\$189.00	6.00 x 4.16 x 4.59 [152 x 106 x 117]	14G0503	4.88 x 2.88in	14R0503	14A0503	14R0503SS	
EJ664SS	\$168.00	EJ664S16	\$211.00	6.00 x 6.16 x 4.59 [152 x 156 x 117]	14G0505	4.88 x 4.88in	14R0505	14A0505	14R0505SS	
EJ863SS	\$182.00	EJ863S16	\$230.00	8.00 x 6.16 x 4.09 [203 x 156 x 104]	14G0705	6.75 x 4.88in	14R0705	14A0705	14R0705SS	
EJ866SS	\$221.00	EJ866S16	\$278.00	8.00 x 6.16 x 6.59 [203 x 156 x 167]	14G0705	6.75 x 4.88in	14R0705	14A0705	14R0705SS	
EJ884SS	\$211.00	EJ884S16	\$266.00	8.00 x 8.16 x 4.59 [203 x 207 x 117]	14G0707	6.75 x 6.88in	14R0707	14A0707	14R0707SS	
EJ1084SS	\$227.00	EJ1084S16	\$286.00	10.00 x 8.16 x 4.59 [254 x 207 x 117]	14G0907	8.75 x 6.88in	14R0907	14A0907	14R0907SS	
EJ1086SS	\$260.00	EJ1086S16	\$338.00	10.00 x 8.16 x 6.59 [254 x 207 x 167]	14G0907	8.75 x 6.88in	14R0907	14A0907	14R0907SS	
EJ10106SS	\$304.00	EJ10106S16	\$383.00	10.00 x 10.16 x 6.59 [254 x 258 x 167]	14G0909	8.75 x 8.88in	14R0909	14A0909	14R0909SS	
EJ1264SS	\$247.00	EJ1264S16	\$311.00	12.00 x 6.16 x 4.59 [305 x 156 x 117]	14G1105	10.75 x 4.88in	14R1105	14A1105	-	
EJ12105SS	\$298.00	EJ12105S16	\$376.00	12.00 x 10.16 x 5.59 [305 x 258 x 142]	14G1109	10.75 x 8.88in	14R1109	14A1109	14R1109SS	
EJ12106SS	\$310.00	EJ12106S16	\$391.00	12.00 x 10.16 x 6.59 [305 x 258 x 167]	14G1109	10.75 x 8.88in	14R1109	14A1109	14R1109SS	
EJ12108SS	\$341.00	EJ12108S16	\$430.00	12.00 x 10.16 x 8.59 [305 x 258 x 218]	14G1109	10.75 x 8.88in	14R1109	14A1109	14R1109SS	
EJ12124SS	\$314.00	EJ12124S16	\$387.00	12.00 x 12.16 x 4.59 [305 x 309 x 117]	14G1111	10.75 x 10.88in	14R1111	14A1111	14R1111SS	
EJ12126SS	\$338.00	EJ12126S16	\$426.00	12.00 x 12.16 x 6.59 [305 x 309 x 167]	14G1111	10.75 x 10.88in	14R1111	14A1111	14R1111SS	

Note: Dimensions in inches [millimeters].

Continued on next page

Eclipse Junior Series NEMA 3R, 4, 4X, 12 and 13 Stainless Steel Single-Door Wall Mount with 1/4-Turn Latch




Continued from previous page

Eclipse Junior Series NEMA 3R, 4, 4X, 12 and 13 Stainless Steel Single-Door Wall Mount with 1/4-Turn Latch									
Enclosures					Included Subpanel	Subpanel HxW	Optional Subpanels		
304 Stainless	Price	316 Stainless	Price	Enclosure Size HxWxD			Steel	Aluminum	Stainless
EJ14126SS	\$370.00	EJ14126S16	\$466.00	14.00 x 12.16 x 6.59 [356 x 309 x 167]	14G1311	12.75 x 10.88in	14R1311	14A1311	14R1311SS
EJ14128SS	\$401.00	EJ14128S16	\$505.00	14.00 x 12.16 x 8.59 [356 x 309 x 218]	14G1311	12.75 x 10.88in	14R1311	14A1311	14R1311SS
EJ16146SS	\$441.00	EJ16146S16	\$536.00	16.00 x 14.16 x 6.59 [406 x 360 x 167]	14G1513	14.75 x 12.88in	14R1513	14A1513	14R1513SS
EJ16148SS	\$479.00	EJ16148S16	\$603.00	16.00 x 14.16 x 8.59 [406 x 360 x 218]	14G1513	14.75 x 12.88in	14R1513	14A1513	14R1513SS
EJ161410SS	\$498.00	EJ161410S16	\$622.00	16.00 x 14.16 x 10.59 [406 x 360 x 269]	14G1513	14.75 x 12.88in	14R1513	14A1513	14R1513SS

Note: Dimensions in inches [millimeters].

Dimensions

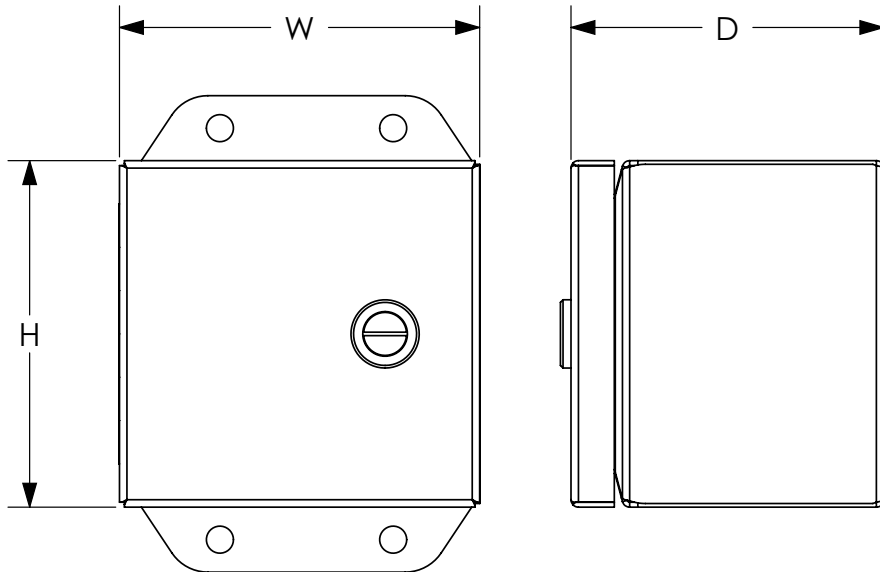

See our website: www.AutomationDirect.com for complete engineering drawings.