

Aluminum Panels for 19-Inch Racks



Application

Install in unused 19 in [483 mm] wide rack space to improve both cooling efficiency and prevent air recirculation.

Features


- Fits standard EIA compliant rails.

Construction

- Constructed of 8-gauge (0.125 in [3mm]) 5052-H32 aluminum.
- Finished in smooth powder coat paint or unfinished.

Listings

- TAA compliant for GSA Schedule purchases.
- RoHS

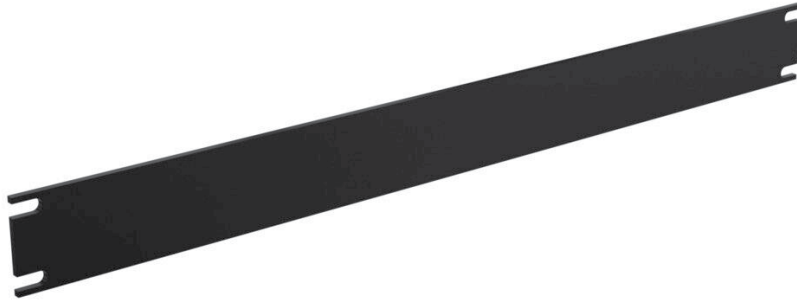

Aluminum Panels for 19-Inch Racks

<i>Gloss Black</i>	<i>Matte Black</i>	<i>RAL7035 Gray</i>	<i>ANSI 61 Gray</i>	<i>Unfinished</i>	<i>Price</i>	<i>Rack Units</i>	<i>Panel Height</i>	<i>Drawing Link</i>
PBPA19001BK2	PBPA19001BK	PBPA19001LG2	PBPA19001GY2	PBPA19001UNF	\$12.50	1U	1.75 [44]	PDF
PBPA19003BK2	PBPA19003BK	PBPA19003LG2	PBPA19003GY2	PBPA19003UNF	\$18.25	2U	3.50 [89]	PDF
PBPA19005BK2	PBPA19005BK	PBPA19005LG2	PBPA19005GY2	PBPA19005UNF	\$27.50	3U	5.25 [133]	PDF
PBPA19007BK2	PBPA19007BK	PBPA19007LG2	PBPA19007GY2	PBPA19007UNF	\$32.50	4U	7.00 [178]	PDF
PBPA19008BK2	—	PBPA19008LG2	PBPA19008GY2	PBPA19008UNF	\$38.50	5U	8.75 [222]	PDF
PBPA19010BK2	—	PBPA19010LG2	PBPA19010GY2	PBPA19010UNF	\$45.00	6U	10.50 [267]	PDF
PBPA19012BK2	—	PBPA19012LG2	PBPA19012GY2	PBPA19012UNF	\$54.00	7U	12.25 [311]	PDF
PBPA19014BK2	—	PBPA19014LG2	PBPA19014GY2	PBPA19014UNF	\$61.00	8U	14.00 [356]	PDF
PBPA19015BK2	—	PBPA19015LG2	PBPA19015GY2	PBPA19015UNF	\$66.00	9U	15.75 [400]	PDF
PBPA19017BK2	—	PBPA19017LG2	PBPA19017GY2	PBPA19017UNF	\$73.00	10U	17.50 [445]	PDF

Note: Dimensions in inches [millimeters].