


# Eclipse Series NEMA 3R, 4, 4X, 12 and 13 Stainless Steel Single-Door Wall Mount

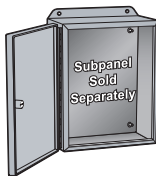

## Applications

- Designed to enclose electrical and/or electronic equipment and protect against harsh, industrial environments for Wall Mount applications.
- Impressive styling features like hidden hinges and attractive latching systems make the Eclipse a suitable addition to any high-tech equipment installation.
- A wide range of sizes and practical accessories make this product line a complete package.

- Includes hardware kit with panel mounting nuts and sealing washers for wall mounting holes.
- Bonding stud provided on door and grounding stud installed in enclosure.
- 316S stainless steel hinge pins and 1/4-turns.
- Door alignment guide provided on 36in wide enclosures.

## Construction

- Formed 14 gauge (24x24in and larger) or 16 gauge (24x20in and smaller) stainless steel.
- Continuously welded seams ground smooth.
- Door stiffeners are provided where required for increased strength and rigidity - designed to also permit additional mounting options.
- Formed lip on enclosure to exclude flowing liquids and contaminants.
- Door latching: Type A has stainless steel slotted 1/4-turns, Type B has stainless steel handle with 3-point latching.
- Doors may be easily removed for modifications and are interchangeable.
- Seamless poured-in-place gasket.
- Collar studs provided for mounting subpanel.

## Finish

- Cover and enclosure are natural stainless steel with a #4 smooth brushed finish.

## Listings

- UL 508A Type 3R, 4, 4X and 12 [UL File 65324]
- CSA Type 3R, 4, 4X and 12 [CSA File LR21001]
- Complies with
  - NEMA Type 3R, 4, 4X, 12, and 13
  - IEC 60529, IP66



Shipping Schedule	
Same day	1 - 15 days
Color indicates shipping lead time in business days.	

Eclipse Series NEMA 3R, 4, 4X, 12 and 13 Stainless Steel Single-Door Wall Mount							
304 Stainless Steel	Price	316 Stainless Steel	Price	Enclosure Size HxWxD	Latch Type	Optional Subpanels	
						Painted	Galvanized
EN4SD12126SS	\$439.00	EN4SD12126S16	\$650.00	12.00 x 12.00 x 6.82 [305 x 305 x 173]	A	EP1212	EPG1212
EN4SD16126SS	\$482.00	EN4SD16126S16	\$687.00	16.00 x 12.00 x 6.82 [406 x 305 x 173]		EP1612	EPG1612
EN4SD16128SS	\$508.00	EN4SD16128S16	\$809.00	16.00 x 12.00 x 8.82 [406 x 305 x 224]		EP1612	EPG1612
EN4SD161210SS	\$603.00	EN4SD161210S16	\$898.00	16.00 x 12.00 x 10.82 [406 x 305 x 275]		EP1612	EPG1612
EN4SD16166SS	\$535.00	EN4SD16166S16	\$838.00	16.00 x 16.00 x 6.82 [406 x 406 x 173]		EP1616	EPG1616
EN4SD16168SS	\$580.00	EN4SD16168S16	\$876.00	16.00 x 16.00 x 8.82 [406 x 406 x 224]		EP1616	EPG1616
EN4SD161610SS	\$647.00	EN4SD161610S16	\$960.00	16.00 x 16.00 x 10.82 [406 x 406 x 275]		EP1616	EPG1616
EN4SD16206SS	\$603.00	-	-	16.00 x 20.00 x 6.82 [406 x 508 x 173]		EP1620	EPG1620
EN4SD16208SS	\$647.00	EN4SD16208S16	\$898.00	16.00 x 20.00 x 8.82 [406 x 508 x 224]		EP1620	EPG1620
EN4SD162010SS	\$696.00	EN4SD162010S16	\$1,033.00	16.00 x 20.00 x 10.82 [406 x 508 x 275]		EP1620	EPG1620
EN4SD20166SS	\$603.00	EN4SD20166S16	\$782.00	20.00 x 16.00 x 6.82 [508 x 406 x 173]		EP2016	EPG2016
EN4SD20168SS	\$630.00	EN4SD20168S16	\$898.00	20.00 x 16.00 x 8.82 [508 x 406 x 224]		EP2016	EPG2016
EN4SD20206SS	\$668.00	EN4SD20206S16	\$836.00	20.00 x 20.00 x 6.82 [508 x 508 x 173]		EP2020	EPG2020
EN4SD20208SS	\$696.00	EN4SD20208S16	\$1,045.00	20.00 x 20.00 x 8.82 [508 x 508 x 224]		EP2020	EPG2020

Note: Dimensions in inches [millimeters].

Continued on next page

# Eclipse Series NEMA 3R, 4, 4X, 12 and 13 Stainless Steel Single-Door Wall Mount



Shipping Schedule	
Same day	1 - 15 days
Color indicates shipping lead time in business days.	

Continued from previous page


Eclipse Series NEMA 3R, 4, 4X, 12 and 13 Stainless Steel Single-Door Wall Mount							
304 Stainless Steel	Price	316 Stainless Steel	Price	Enclosure Size HxWxD	Latch Type	Optional Subpanels	
						Painted	Galvanized
EN4SD201610SS	\$696.00	EN4SD201610S16	\$1,033.00	20.00 x 16.00 x 10.82 [508 x 406 x 275]	A	EP2016	EPG2016
EN4SD202010SS	\$754.00	EN4SD202010S16	\$1,119.00	20.00 x 20.00 x 10.82 [508 x 508 x 275]		EP2020	EPG2020
EN4SD202012SS	\$794.00	EN4SD202012S16	\$1,236.00	20.00 x 20.00 x 12.82 [508 x 508 x 326]		EP2020	EPG2020
EN4SD20248SS	\$761.00	-	-	20.00 x 24.00 x 8.82 [508 x 610 x 224]		EP2024	EPG2024
EN4SD202410SS	\$810.00	EN4SD202410S16	\$1,196.00	20.00 x 24.00 x 10.82 [508 x 610 x 275]		EP2024	EPG2024
EN4SD24168SS	\$687.00	EN4SD24168S16	\$1,013.00	24.00 x 16.00 x 8.82 [610 x 406 x 224]		EP2416	EPG2416
EN4SD241610SS	\$745.00	EN4SD241610S16	\$1,103.00	24.00 x 16.00 x 10.82 [610 x 406 x 275]		EP2416	EPG2416
EN4SD24206SS	\$709.00	-	-	24.00 x 20.00 x 6.82 [610 x 508 x 173]		EP2420	EPG2420
EN4SD24208SS	\$761.00	EN4SD24208S16	\$1,086.00	24.00 x 20.00 x 8.82 [610 x 508 x 224]		EP3024	EPG3024
EN4SD242010SS	\$813.00	EN4SD242010S16	\$1,203.00	24.00 x 20.00 x 10.82 [610 x 508 x 275]		EP2420	EPG2420
EN4SD24248SS	\$838.00	EN4SD24248S16	\$1,194.00	24.00 x 24.00 x 8.82 [610 x 610 x 224]		EP2424	EPG2424
EN4SD242410SS	\$877.00	EN4SD242410S16	\$1,298.00	24.00 x 24.00 x 10.82 [610 x 610 x 275]		EP2424	EPG2424
EN4SD242412SS	\$998.00	EN4SD242412S16	\$1,439.00	24.00 x 24.00 x 12.82 [610 x 610 x 326]		EP2424	EPG2424
EN4SD24308SS	\$952.00	-	-	24.00 x 30.00 x 8.82 [610 x 762 x 224]		EP2430	EPG2430
EN4SD243010SS	\$973.00	EN4SD243010S16	\$1,438.00	24.00 x 30.00 x 10.82 [610 x 762 x 275]		EP2430	EPG2430
EN4SD30208SS	\$861.00	-	-	30.00 x 20.00 x 8.82 [762 x 508 x 224]		EP3020	EPG3020
EN4SD302010SS	\$895.00	EN4SD302010S16	\$1,325.00	30.00 x 20.00 x 10.82 [762 x 508 x 275]		EP3020	EPG3020
EN4SD30248SS	\$953.00	EN4SD30248S16	\$1,355.00	30.00 x 24.00 x 8.82 [762 x 610 x 224]		EP3024	EPG3024
EN4SD302410SS	\$974.00	EN4SD302410S16	\$1,442.00	30.00 x 24.00 x 10.82 [762 x 610 x 275]		EP3024	EPG3024
EN4SD302412SS	\$1,089.00	EN4SD302412S16	\$1,535.00	30.00 x 24.00 x 12.82 [762 x 610 x 326]		EP3024	EPG3024
EN4SD302416SS	\$1,194.00	-	-	30.00 x 24.00 x 16.82 [762 x 610 x 427]		EP3024	EPG3024
EN4SD30308SS	\$1,086.00	EN4SD30308S16	\$1,612.00	30.00 x 30.00 x 8.82 [762 x 762 x 224]		EP3030	EPG3030
EN4SD303010SS	\$1,119.00	EN4SD303010S16	\$1,644.00	30.00 x 30.00 x 10.82 [762 x 762 x 275]		EP3030	EPG3030
EN4SD303012SS	\$1,186.00	-	-	30.00 x 30.00 x 12.82 [762 x 762 x 326]		EP3030	EPG3030
EN4SD36248SS	\$1,097.00	EN4SD36248S16	\$1,598.00	36.00 x 24.00 x 8.82 [914 x 610 x 224]		EP3624	EPG3624
EN4SD362410SS	\$1,070.00	EN4SD362410S16	\$1,584.00	36.00 x 24.00 x 10.82 [914 x 610 x 275]		EP3624	EPG3624
EN4SD362412SS	\$1,193.00	EN4SD362412S16	\$1,644.00	36.00 x 24.00 x 12.82 [914 x 610 x 326]		EP3624	EPG3624
EN4SD36308SS	\$1,257.00	EN4SD36308S16	\$1,736.00	36.00 x 30.00 x 8.82 [914 x 762 x 224]		EP3630	EPG3630
EN4SD363010SS	\$1,283.00	EN4SD363010S16	\$1,865.00	36.00 x 30.00 x 10.82 [914 x 762 x 275]	EP3630	EPG3630	
EN4SD363012SS	\$1,425.00	EN4SD363012S16	\$1,956.00	36.00 x 30.00 x 12.82 [914 x 762 x 326]	EP3630	EPG3630	
EN4SD363016SS	\$1,534.00	-	-	36.00 x 30.00 x 16.82 [914 x 762 x 427]	EP3630	EPG3630	
EN4SD363610SSR	\$1,356.00	EN4SD363610S16R	\$2,012.00	36.00 x 36.00 x 10.82 [914 x 914 x 275]	EP3636	EPG3636	
EN4SD363612SSR	\$1,577.00	EN4SD363612S16R	\$2,384.00	36.00 x 36.00 x 12.82 [914 x 914 x 326]	EP3636	EPG3636	
EN4SD423010SSR	\$1,424.00	-	-	42.00 x 30.00 x 10.82 [1067 x 762 x 275]	EP4230	EPG4230	
EN4SD42368SSR	\$1,563.00	-	-	42.00 x 36.00 x 8.82 [1067 x 914 x 224]	EP4236	EPG4236	
EN4SD423610SSR	\$1,540.00	EN4SD423610S16R	\$2,283.00	42.00 x 36.00 x 10.82 [1067 x 914 x 275]	EP4236	EPG4236	
EN4SD423612SSR	\$1,749.00	EN4SD423612S16R	\$2,639.00	42.00 x 36.00 x 12.82 [1067 x 914 x 326]	EP4236	EPG4236	
EN4SD482410SS	\$1,604.00	EN4SD482410S16	\$2,377.00	48.00 x 24.00 x 10.82 [1219 x 610 x 275]	B	EP4824	EPG4824
EN4SD48368SSR	\$1,725.00	-	-	48.00 x 36.00 x 8.82 [1219 x 914 x 224]		EP4836	EPG4836
EN4SD483610SSR	\$1,760.00	EN4SD483610S16R	\$2,574.00	48.00 x 36.00 x 10.82 [1219 x 914 x 275]	A	EP4836	EPG4836
EN4SD483612SSR	\$1,923.00	EN4SD483612S16R	\$2,906.00	48.00 x 36.00 x 12.82 [1219 x 914 x 326]		EP4836	EPG4836
EN4SD483616SSR	\$1,950.00	EN4SD483616S16R	\$2,829.00	48.00 x 36.00 x 16.82 [1219 x 914 x 427]		EP4836	EPG4836
EN4SD603610SSR	\$1,950.00	EN4SD603610S16R	\$2,893.00	60.00 x 36.00 x 10.82 [1524 x 914 x 275]		EP6036	EPG6036
EN4SD603612SSR	\$2,174.00	EN4SD603612S16R	\$3,429.00	60.00 x 36.00 x 12.82 [1524 x 914 x 326]		EP6036	EPG6036
EN4SD723612SSR	\$2,804.00	EN4SD723612S16R	\$3,477.00	72.00 x 36.00 x 12.82 [1829 x 914 x 326]		EP7236	EPG7236

Note: Dimensions in inches [millimeters].

# Eclipse Series NEMA 3R, 4, 4X, 12 and 13 Stainless Steel Single-Door Wall Mount



## Dimensions

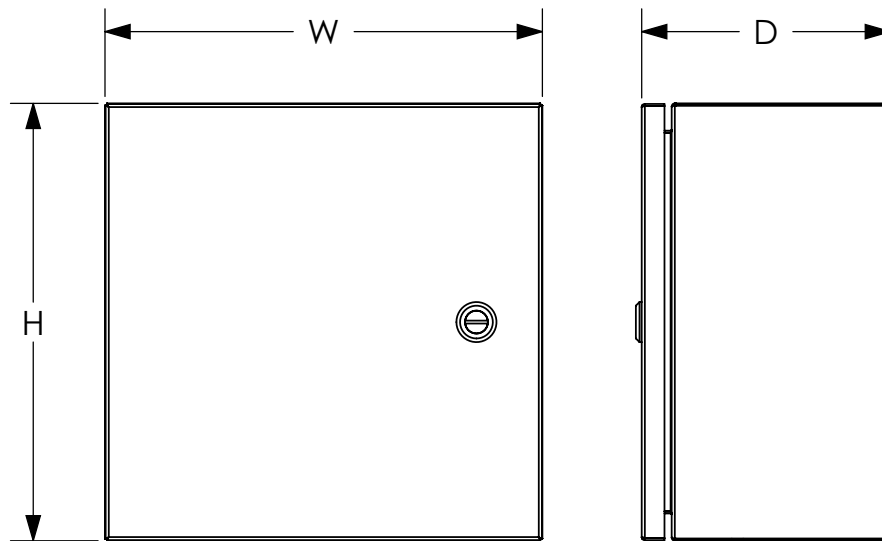

*See our website: [www.AutomationDirect.com](http://www.AutomationDirect.com) for complete engineering drawings.*