


# Eclipse Series NEMA 3R, 4, 4X, 12, and 13 Stainless Steel Single-Door Wall-Mount with Slope Top

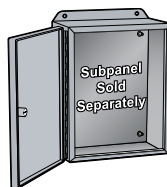

## Applications

- Designed to enclose electrical and/or electronic equipment and protect against harsh, industrial environments for wall-mount applications.
- Sloped top prevents water from resting on top as well as providing potential for controls mounting.
- Impressive styling features like hidden hinges and attractive latching systems make the Eclipse a suitable addition to any high-tech equipment installation.
- A wide range of sizes and practical accessories make this product line a complete package.
- Doors may be easily removed for modifications and are interchangeable.
- Seamless poured-in-place gasket.
- Collar studs provided for mounting subpanel.
- Includes hardware kit with subpanel mounting nuts and sealing washers for wall-mounting holes.
- Bonding stud provided on door and grounding stud installed in enclosure.
- Hinges are 304 stainless steel.
- 316 stainless steel hinge pins and 1/4-turns.
- Door alignment guide provided on 36 in [914 mm] wide enclosures.

## Construction

- Formed 14-gauge 304 stainless steel.
- Continuously welded seams ground smooth.
- Door stiffeners are provided where required for increased strength and rigidity—designed to also permit additional mounting options.
- Formed lip on enclosure to exclude flowing liquids and contaminants.
- Door latches feature the added safety of 1/4-turn slot requiring use of tool for opening.
- Uses Eclipse 1/4 turn latches or handles.

## Finish

- Cover and enclosure are natural stainless steel with a #4 smooth brushed finish.

## Listings

- UL 508A Type 3R, 4, 4X, and 12 [UL File E65324]
- CSA Type 3R, 4, 4X, and 12 [CSA File LR21001]
- Complies with
  - NEMA Type 3R, 4, 4X, and 12
  - IEC 60529, IP66

Eclipse Series NEMA 3R, 4, 4X, 12, and 13 Stainless Steel Single-Door Wall-Mount with Slope Top					
Part Number	Price	Enclosure Size HxWxD	Optional Subpanels		Drawing Link
			Painted	Galvanized	
<a href="#">ST161208SS</a>	\$850.00	18.91 x 12.00 x 8.84 [480 x 305 x 225]	<a href="#">EP1612</a>	<a href="#">EPG1612</a>	<a href="#">PDF</a>
<a href="#">ST161608SS</a>	\$934.00	18.91 x 16.00 x 8.84 [480 x 406 x 225]	<a href="#">EP1616</a>	<a href="#">EPG1616</a>	<a href="#">PDF</a>
<a href="#">ST201608SS</a>	\$1,034.00	22.91 x 16.00 x 8.84 [582 x 406 x 225]	<a href="#">EP2016</a>	<a href="#">EPG2016</a>	<a href="#">PDF</a>
<a href="#">ST201612SS</a>	\$1,159.00	24.37 x 16.00 x 12.84 [619 x 406 x 326]	<a href="#">EP2016</a>	<a href="#">EPG2016</a>	<a href="#">PDF</a>
<a href="#">ST202008SS</a>	\$1,180.00	22.93 x 20.00 x 8.84 [582 x 508 x 225]	<a href="#">EP2020</a>	<a href="#">EPG2020</a>	<a href="#">PDF</a>
<a href="#">ST202012SS</a>	\$1,356.00	24.35 x 20.00 x 12.84 [618 x 508 x 326]	<a href="#">EP2020</a>	<a href="#">EPG2020</a>	<a href="#">PDF</a>
<a href="#">ST242008SS</a>	\$1,256.00	26.93 x 20.00 x 8.84 [684 x 508 x 225]	<a href="#">EP2420</a>	<a href="#">EPG2420</a>	<a href="#">PDF</a>
<a href="#">ST242408SS</a>	\$1,378.00	26.93 x 24.00 x 8.84 [684 x 610 x 225]	<a href="#">EP2424</a>	<a href="#">EPG2424</a>	<a href="#">PDF</a>
<a href="#">ST242412SS</a>	\$1,568.00	28.37 x 24.00 x 12.84 [721 x 610 x 326]	<a href="#">EP2424</a>	<a href="#">EPG2424</a>	<a href="#">PDF</a>
<a href="#">ST302408SS</a>	\$1,422.00	32.93 x 24.00 x 8.84 [836 x 610 x 225]	<a href="#">EP3024</a>	<a href="#">EPG3024</a>	<a href="#">PDF</a>
<a href="#">ST302412SS</a>	\$1,777.00	34.37 x 24.00 x 12.84 [873 x 610 x 326]	<a href="#">EP3024</a>	<a href="#">EPG3024</a>	<a href="#">PDF</a>
<a href="#">ST303008SS</a>	\$1,786.00	32.93 x 30.00 x 8.84 [836 x 762 x 225]	<a href="#">EP3030</a>	<a href="#">EPG3030</a>	<a href="#">PDF</a>
<a href="#">ST363008SS</a>	\$2,011.00	38.93 x 30.00 x 8.84 [989 x 762 x 225]	<a href="#">EP3630</a>	<a href="#">EPG3630</a>	<a href="#">PDF</a>
<a href="#">ST363012SS</a>	\$2,264.00	40.37 x 30.00 x 12.84 [1025 x 762 x 326]	<a href="#">EP3630</a>	<a href="#">EPG3630</a>	<a href="#">PDF</a>
<a href="#">ST363016SS</a>	\$2,521.00	41.83 x 30.00 x 16.84 [1062 x 762 x 428]	<a href="#">EP3630</a>	<a href="#">EPG3630</a>	<a href="#">PDF</a>
<a href="#">ST363612SS</a>	\$2,546.00	40.37 x 36.00 x 12.84 [1025 x 914 x 326]	<a href="#">EP3636</a>	<a href="#">EPG3636</a>	<a href="#">PDF</a>
<a href="#">ST483616SS</a>	\$3,429.00	53.84 x 36.00 x 16.84 [1368 x 914 x 428]	<a href="#">EP4836</a>	<a href="#">EPG4836</a>	<a href="#">PDF</a>
<a href="#">ST603616SS</a>	\$4,225.00	65.84 x 36.00 x 16.84 [1672 x 914 x 428]	<a href="#">EP6036</a>	<a href="#">EPG6036</a>	<a href="#">PDF</a>
<a href="#">ST603612SS</a>	\$3,794.00	64.38 x 36.00 x 12.84 [1635 x 914 x 326]	<a href="#">EP6036</a>	<a href="#">EPG6036</a>	<a href="#">PDF</a>
<a href="#">ST603616SS</a>	\$4,225.00	65.84 x 36.00 x 16.84 [1672 x 914 x 428]	<a href="#">EP6036</a>	<a href="#">EPG6036</a>	<a href="#">PDF</a>


Note: Dimensions in inches [millimeters].



# Eclipse Series NEMA 3R, 4, 4X, 12, and 13 Stainless Steel Single-Door Wall-Mount with Slope Top



## Dimensions

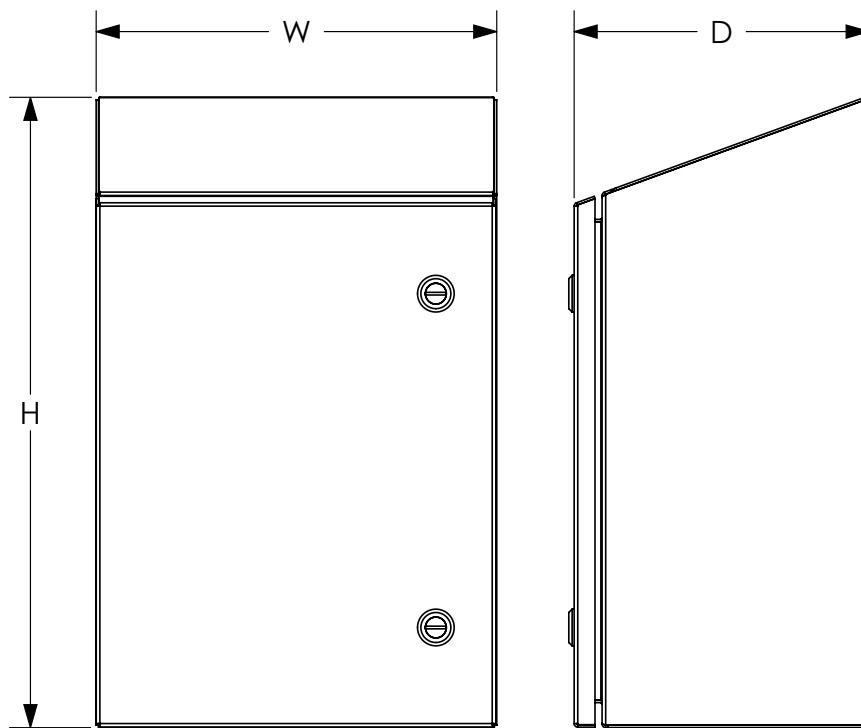

# Enclosure Accessories

## Locks and Latches



### 1/4-Turn Inserts and Keys

#### Features

- For Eclipse Series enclosures.
- Field installable inserts replace standard 1/4-turn slot.
- Available in square and triangle formats, as well as slotted.
- Maintains NEMA, UL and CSA 12, 4, and 4X ratings.
- Non-slot inserts provide extra security since standard screw drivers cannot open.
- Keys constructed from die-cast zinc.
- Keys sold separately from inserts.

[2SQI7](#)[2DBI3](#)

1/4-Turn Inserts and Keys								
Latch Insert	Price	Type	Material	Finish	Drawing Link	Key	Price	Finish
<a href="#">2SQI7</a>	\$18.00	square key	die-cast zinc	black matte	<a href="#">PDF</a>	<a href="#">2SQK7</a>	\$16.75	black matte
<a href="#">2TRI7</a>	\$18.00	triangular key	die-cast zinc	black matte	<a href="#">PDF</a>	<a href="#">2TRK7</a>	\$16.75	natural
<a href="#">2SLI</a>	\$18.00	slotted	die-cast zinc	black matte	<a href="#">PDF</a>	—	—	—
<a href="#">2DBI3</a>	\$18.00	3mm double-bit	die-cast zinc	black matte	<a href="#">PDF</a>	<a href="#">PMKEY</a>	\$16.50	black matte
<a href="#">2DBI3SS</a>	\$45.00	3mm double-bit	stainless steel	natural	<a href="#">PDF</a>	<a href="#">PMKEY</a>	\$16.50	natural

[2DBI3SS](#)[PMKEY](#)

### 1/4-Turn Latch Assemblies

#### Features

- Field installable.
- Interchangeable with standard 1/4-turn latches on Eclipse or Eclipse Jr series.
- Maintains NEMA, UL, and CSA ratings of enclosures.
- Keylocking latch assemblies include two keys.

[2WKL](#)  
1/4-turn wing handle[EQTRL](#)  
1/4-turn semi-flush[2QPL](#)  
1/4-turn knob[EJQTR](#)  
1/4-turn semi-flush[EJWKL](#)  
1/4-turn wing handle

1/4-Turn Latch Assemblies							
Part Number	Price	Style	Security	Material	Finish	For Use With	Drawing Link
<a href="#">EQTRL</a>	\$24.50	1/4-turn semi-flush	keylocking	die-cast zinc	chrome	Eclipse series swing-out panels	<a href="#">PDF</a>
<a href="#">2QTR</a>	\$18.25	1/4-turn semi-flush	slotted	die-cast zinc	black matte	Eclipse series	<a href="#">PDF</a>
<a href="#">2SSQTR</a>	\$68.00	1/4-turn semi-flush	slotted	316 stainless steel	—	Eclipse series	<a href="#">PDF</a>
<a href="#">2WKL</a>	\$99.00	1/4-turn wing handle	keylocking	die-cast zinc	black matte	Eclipse series	<a href="#">PDF</a>
<a href="#">2QPL</a>	\$84.00	1/4-turn knob	padlocking	die-cast zinc	black matte	Eclipse series	<a href="#">PDF</a>
<a href="#">EJQTR</a>	\$15.00	1/4-turn semi-flush	slotted	die-cast zinc	black matte	Eclipse Junior series	<a href="#">PDF</a>
<a href="#">EJSSQTR</a>	\$47.00	1/4-turn semi-flush	slotted	316 stainless steel	—	Eclipse Junior series	<a href="#">PDF</a>
<a href="#">EJWKL</a>	\$46.00	1/4-turn wing handle	keylocking	die-cast zinc	black matte	Eclipse Junior series	<a href="#">PDF</a>
<a href="#">EJWKNL</a>	\$46.00	1/4-turn wing handle	—	die-cast zinc	black matte	Eclipse Junior series	<a href="#">PDF</a>

# Enclosure Accessories

## Locks and Latches



### Eclipse Series 1-Point 1/4-Turn Handles



T-Handle



L-Handle

#### Features

- Field installable.
- Interchangeable with standard 1/4-turn latches on all Eclipse series enclosures.
- Keylocking latch assemblies include two keys.
- Maintain NEMA, UL and CSA ratings of enclosure.

Eclipse Series 1-Point 1/4-Turn Handles						
Part Number	Price	Style	Security	Material	Finish	Drawing Link
<a href="#">EHTL</a>	\$68.00	1/4-turn tee handle	keylocking	die-cast zinc	black matte	<a href="#">PDF</a>
<a href="#">EHLL</a>	\$69.00	1/4-turn L-handle	keylocking	die-cast zinc	black matte	<a href="#">PDF</a>
<a href="#">EHLNL</a>	\$69.00	1/4-turn L-handle	—	die-cast zinc	black matte	<a href="#">PDF</a>
<a href="#">EHLPL</a>	\$127.00	1/4-turn L-handle	padlocking	zinc plated steel	—	<a href="#">PDF</a>
<a href="#">EHLSS</a>	\$310.00	1/4-turn L-handle	keylocking	316 stainless steel	—	<a href="#">PDF</a>
<a href="#">EHLNLSS</a>	\$310.00	1/4-turn L-handle	—	316 stainless steel	—	<a href="#">PDF</a>
<a href="#">EHLPLSS</a>	\$310.00	1/4-turn L-handle	padlocking	316 stainless steel	—	<a href="#">PDF</a>