


Eclipse Series NEMA 3R, 4, 4X, 12 and 13 Stainless Steel Single-Door Wall Mount with Slope Top

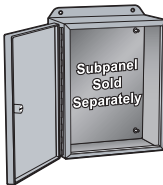

Shipping Schedule	
Same day	1 - 15 days
Color indicates shipping lead time in business days.	

Applications

- Designed to enclose electrical and/or electronic equipment and protect against harsh, industrial environments for Wall Mount applications.
- Sloped top prevents water from resting on top as well as providing potential for controls mounting.
- Impressive styling features like hidden hinges and attractive latching systems make the Eclipse a suitable addition to any high-tech equipment installation.
- A wide range of sizes and practical accessories make this product line a complete package.

Construction

- Formed 14 gauge 304 stainless steel.
- Continuously welded seams ground smooth.
- Door stiffeners are provided where required for increased strength and rigidity - designed to also permit additional mounting options.
- Formed lip on enclosure to exclude flowing liquids and contaminants.
- Door latches feature the added safety of 1/4-turn slot requiring use of tool for opening.
- Doors may be easily removed for modifications and are interchangeable.

- Seamless poured-in-place gasket.
- Collar studs provided for mounting subpanel.
- Includes hardware kit with subpanel mounting nuts and sealing washers for wall mounting holes.
- Bonding stud provided on door and grounding stud installed in enclosure.
- Hinges are 304 stainless steel.
- 316 stainless steel hinge pins and 1/4-turns.
- Door alignment guide provided on 36" wide enclosures.

Finish

- Cover and enclosure are natural stainless steel with a #4 smooth brushed finish.

Listings

- UL 508A Type 3R, 4, 4X, and 12 [UL File E65324]
- CSA Type 3R, 4, 4X, and 12 [CSA File LR21001]
- Complies with
 - NEMA Type 3R, 4, 4X, and 12
 - IEC 60529, IP66




Eclipse Series NEMA 3R, 4, 4X, 12 and 13 Stainless Steel Single-Door Wall Mount with Slope Top						
Part Number	Price	Enclosure Size HxWxD	Drawing Link	Optional Subpanels		
				Painted	Galvanized	
ST161208SS	\$602.00	18.91 x 12.00 x 8.84 [480 x 305 x 225]	PDF	EP1612	EPG1612	
ST161608SS	\$662.00	18.91 x 16.00 x 8.84 [480 x 406 x 225]	PDF	EP1616	EPG1616	
ST201608SS	\$732.00	22.91 x 16.00 x 8.84 [582 x 406 x 225]	PDF	EP2016	EPG2016	
ST201612SS	\$820.00	24.37 x 16.00 x 12.84 [619 x 406 x 326]	PDF	EP2016	EPG2016	
ST202008SS	\$835.00	22.93 x 20.00 x 8.84 [582 x 508 x 225]	PDF	EP2020	EPG2020	
ST202012SS	\$960.00	24.35 x 20.00 x 12.84 [618 x 508 x 326]	PDF	EP2020	EPG2020	
ST242008SS	\$889.00	26.93 x 20.00 x 8.84 [684 x 508 x 225]	PDF	EP2420	EPG2420	
ST242408SS	\$975.00	26.93 x 24.00 x 8.84 [684 x 610 x 225]	PDF	EP2424	EPG2424	
ST242412SS	\$1,110.00	28.37 x 24.00 x 12.84 [721 x 610 x 326]	PDF	EP2424	EPG2424	
ST302408SS	\$1,007.00	32.93 x 24.00 x 8.84 [836 x 610 x 225]	PDF	EP3024	EPG3024	
ST302412SS	\$1,258.00	34.37 x 24.00 x 12.84 [873 x 610 x 326]	PDF	EP3024	EPG3024	
ST303008SS	\$1,264.00	32.93 x 30.00 x 8.84 [836 x 762 x 225]	PDF	EP3030	EPG3030	
ST363008SS	\$1,423.00	38.93 x 30.00 x 8.84 [989 x 762 x 225]	PDF	EP3630	EPG3630	
ST363012SS	\$1,603.00	40.37 x 30.00 x 12.84 [1025 x 762 x 326]	PDF	EP3630	EPG3630	
ST363016SS	\$1,785.00	41.83 x 30.00 x 16.84 [1062 x 762 x 428]	PDF	EP3630	EPG3630	
ST363612SS	\$1,802.00	40.37 x 36.00 x 12.84 [1025 x 914 x 326]	PDF	EP3636	EPG3636	
ST483612SS	\$2,180.00	52.38 x 36.00 x 12.84 [1330 x 914 x 326]	PDF	EP4836	EPG4836	
ST483616SS	\$2,428.00	53.84 x 36.00 x 16.84 [1368 x 914 x 428]	PDF	EP4836	EPG4836	
ST603612SS	\$2,686.00	64.38 x 36.00 x 12.84 [1635 x 914 x 326]	PDF	EP6036	EPG6036	
ST603616SS	\$2,991.00	65.84 x 36.00 x 16.84 [1672 x 914 x 428]	PDF	EP6036	EPG6036	

Note: Dimensions in inches [millimeters].

Eclipse Series NEMA 3R, 4, 4X, 12 and 13 Stainless Steel Single-Door Wall Mount with Sloped Top



Dimensions

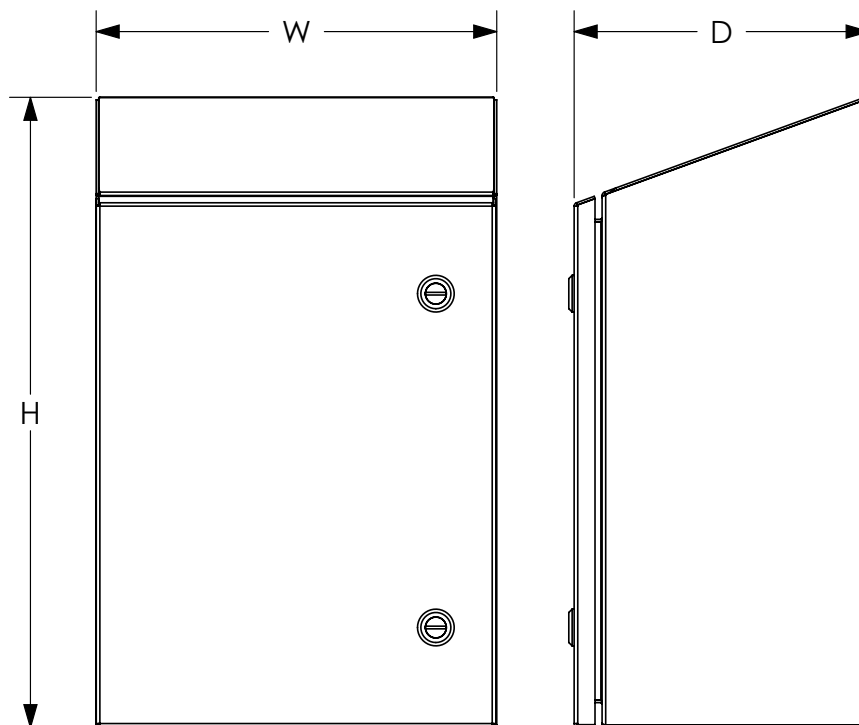

See our website: www.AutomationDirect.com for complete engineering drawings.