


# Eclipse Series NEMA 3R, 4, 4X, 12, and 13 Stainless Steel Single-Door Wall-Mount with Slope Top

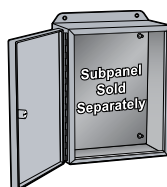

## Applications

- Designed to enclose electrical and/or electronic equipment and protect against harsh, industrial environments for wall-mount applications.
- Sloped top prevents water from resting on top as well as providing potential for controls mounting.
- Impressive styling features like hidden hinges and attractive latching systems make the Eclipse a suitable addition to any high-tech equipment installation.
- A wide range of sizes and practical accessories make this product line a complete package.
- Seamless poured-in-place gasket.
- Collar studs provided for mounting subpanel.
- Includes hardware kit with subpanel mounting nuts and sealing washers for wall-mounting holes.
- Bonding stud provided on door and grounding stud installed in enclosure.
- Hinges are 304 stainless steel.
- 316 stainless steel hinge pins and 1/4-turns.
- Door alignment guide provided on 36 in [914 mm] wide enclosures.

## Construction

- Formed 14-gauge 304 stainless steel.
- Continuously welded seams ground smooth.
- Door stiffeners are provided where required for increased strength and rigidity—designed to also permit additional mounting options.
- Formed lip on enclosure to exclude flowing liquids and contaminants.
- Door latches feature the added safety of 1/4-turn slot requiring use of tool for opening.
- Doors may be easily removed for modifications and are interchangeable.

## Finish

- Cover and enclosure are natural stainless steel with a #4 smooth brushed finish.

## Listings

- UL 508A Type 3R, 4, 4X, and 12  
UL File E65324]
- CSA Type 3R, 4, 4X, and 12  
[CSA File LR21001
- Complies with
  - NEMA Type 3R, 4, 4X, and 12
  - IEC 60529, IP66



Eclipse Series NEMA 3R, 4, 4X, 12, and 13 Stainless Steel Single-Door Wall-Mount with Slope Top					
Part Number	Price	Enclosure Size HxWxD	Optional Subpanels		Drawing Link
			Painted	Galvanized	
<a href="#">ST161208SS</a>	\$850.00	18.91 x 12.00 x 8.84 [480 x 305 x 225]	<a href="#">EP1612</a>	<a href="#">EPG1612</a>	<a href="#">PDF</a>
<a href="#">ST161608SS</a>	\$934.00	18.91 x 16.00 x 8.84 [480 x 406 x 225]	<a href="#">EP1616</a>	<a href="#">EPG1616</a>	<a href="#">PDF</a>
<a href="#">ST201608SS</a>	\$1,034.00	22.91 x 16.00 x 8.84 [582 x 406 x 225]	<a href="#">EP2016</a>	<a href="#">EPG2016</a>	<a href="#">PDF</a>
<a href="#">ST201612SS</a>	\$1,159.00	24.37 x 16.00 x 12.84 [619 x 406 x 326]	<a href="#">EP2016</a>	<a href="#">EPG2016</a>	<a href="#">PDF</a>
<a href="#">ST202008SS</a>	\$1,180.00	22.93 x 20.00 x 8.84 [582 x 508 x 225]	<a href="#">EP2020</a>	<a href="#">EPG2020</a>	<a href="#">PDF</a>
<a href="#">ST202012SS</a>	\$1,356.00	24.35 x 20.00 x 12.84 [618 x 508 x 326]	<a href="#">EP2020</a>	<a href="#">EPG2020</a>	<a href="#">PDF</a>
<a href="#">ST242008SS</a>	\$1,256.00	26.93 x 20.00 x 8.84 [684 x 508 x 225]	<a href="#">EP2420</a>	<a href="#">EPG2420</a>	<a href="#">PDF</a>
<a href="#">ST242408SS</a>	\$1,378.00	26.93 x 24.00 x 8.84 [684 x 610 x 225]	<a href="#">EP2424</a>	<a href="#">EPG2424</a>	<a href="#">PDF</a>
<a href="#">ST242412SS</a>	\$1,568.00	28.37 x 24.00 x 12.84 [721 x 610 x 326]	<a href="#">EP2424</a>	<a href="#">EPG2424</a>	<a href="#">PDF</a>
<a href="#">ST302408SS</a>	\$1,422.00	32.93 x 24.00 x 8.84 [836 x 610 x 225]	<a href="#">EP3024</a>	<a href="#">EPG3024</a>	<a href="#">PDF</a>
<a href="#">ST302412SS</a>	\$1,777.00	34.37 x 24.00 x 12.84 [873 x 610 x 326]	<a href="#">EP3024</a>	<a href="#">EPG3024</a>	<a href="#">PDF</a>
<a href="#">ST303008SS</a>	\$1,786.00	32.93 x 30.00 x 8.84 [836 x 762 x 225]	<a href="#">EP3030</a>	<a href="#">EPG3030</a>	<a href="#">PDF</a>
<a href="#">ST363008SS</a>	\$2,011.00	38.93 x 30.00 x 8.84 [989 x 762 x 225]	<a href="#">EP3630</a>	<a href="#">EPG3630</a>	<a href="#">PDF</a>
<a href="#">ST363012SS</a>	\$2,264.00	40.37 x 30.00 x 12.84 [1025 x 762 x 326]	<a href="#">EP3630</a>	<a href="#">EPG3630</a>	<a href="#">PDF</a>
<a href="#">ST363016SS</a>	\$2,521.00	41.83 x 30.00 x 16.84 [1062 x 762 x 428]	<a href="#">EP3630</a>	<a href="#">EPG3630</a>	<a href="#">PDF</a>
<a href="#">ST363612SS</a>	\$2,546.00	40.37 x 36.00 x 12.84 [1025 x 914 x 326]	<a href="#">EP3636</a>	<a href="#">EPG3636</a>	<a href="#">PDF</a>
<a href="#">ST483616SS</a>	\$3,429.00	53.84 x 36.00 x 16.84 [1368 x 914 x 428]	<a href="#">EP4836</a>	<a href="#">EPG4836</a>	<a href="#">PDF</a>
<a href="#">ST603616SS</a>	\$4,225.00	65.84 x 36.00 x 16.84 [1672 x 914 x 428]	<a href="#">EP6036</a>	<a href="#">EPG6036</a>	<a href="#">PDF</a>
<a href="#">ST603612SS</a>	\$3,794.00	64.38 x 36.00 x 12.84 [1635 x 914 x 326]	<a href="#">EP6036</a>	<a href="#">EPG6036</a>	<a href="#">PDF</a>
<a href="#">ST603616SS</a>	\$4,225.00	65.84 x 36.00 x 16.84 [1672 x 914 x 428]	<a href="#">EP6036</a>	<a href="#">EPG6036</a>	<a href="#">PDF</a>

Note: Dimensions in inches [millimeters].

# Eclipse Series NEMA 3R, 4, 4X, 12, and 13 Stainless Steel Single-Door Wall-Mount with Slope Top



## Dimensions

