


Eclipse Series NEMA 3R, 4, 4X, 12 and 13 Stainless Steel Single-Door Wall Mount with Window

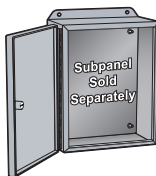

Applications

- Designed to enclose electrical and/or electronic equipment in Wall Mount applications where viewing of component operation is necessary while maintaining protection ratings.
- Impressive styling features like hidden hinges and attractive latching systems make the Eclipse a suitable addition to any high-tech equipment installation.
- A wide range of sizes and practical accessories make this product line a complete package.

Construction

- Formed 14 gauge (24x24in and larger) or 16 gauge (24x20in and smaller) stainless steel.
- Full view UV-resistant polycarbonate window allows maximum viewing area of subpanel.
- Continuously welded seams ground smooth.
- Door stiffeners are provided where required for increased strength and rigidity - designed to also permit additional mounting options.
- Formed lip on enclosure to exclude flowing liquids and contaminants.
- Door latches feature the added safety of 1/4-turn slot requiring use of tool for opening.
- Doors may be easily removed for modifications and are interchangeable.

- Seamless poured-in-place gasket.
- Collar studs provided for mounting subpanel.
- Includes hardware kit with subpanel mounting nuts and sealing washers for wall mounting holes.
- Bonding stud provided on door, and grounding stud installed in enclosure.
- Hinges are constructed from stainless steel.
- 316 stainless steel hinge pins and 1/4-turns.

Finish

- Cover and enclosure are natural stainless steel with a #4 smooth brushed finish.

Listings

- UL 508A Type 3R, 4, 4X and 12 [UL File E65324]
- CSA Type 3R, 4, 4X, and 12 [CSA File LR21001]
- Complies with
 - NEMA Type 3R, 4, 4X, 12 and 13
 - IEC 60529, IP66



Shipping Schedule	
Same day	1 - 15 days
Color indicates shipping lead time in business days.	


Eclipse Series NEMA 3R, 4, 4X, 12 and 13 Stainless Steel Single-Door Wall Mount with Window				
Part Number	Price	Enclosure Size HxWxD	Optional Subpanels	
			Painted	Galvanized
EN4SD12126WSS	\$656.00	12.00 x 12.00 x 6.82 [305 x 305 x 173]	EP1212	EPG1212
EN4SD16126WSS	\$728.00	16.00 x 12.00 x 6.82 [406 x 305 x 173]	EP1612	EPG1612
EN4SD161210WSS	\$883.00	16.00 x 12.00 x 10.82 [406 x 305 x 275]	EP1612	EPG1612
EN4SD20166WSS	\$884.00	20.00 x 16.00 x 6.82 [508 x 406 x 173]	EP2016	EPG2016
EN4SD20168WSS	\$943.00	20.00 x 16.00 x 8.82 [508 x 406 x 224]	EP2016	EPG2016
EN4SD201610WSS	\$1,026.00	20.00 x 16.00 x 10.82 [508 x 406 x 275]	EP2016	EPG2016
EN4SD20206WSS	\$967.00	20.00 x 20.00 x 6.82 [508 x 508 x 173]	EP2020	EPG2020
EN4SD20208WSS	\$1,041.00	20.00 x 20.00 x 8.82 [508 x 508 x 224]	EP2020	EPG2020
EN4SD202010WSS	\$1,111.00	20.00 x 20.00 x 10.82 [508 x 508 x 275]	EP2020	EPG2020
EN4SD202012WSS	\$1,226.00	20.00 x 20.00 x 12.82 [508 x 508 x 326]	EP2020	EPG2020
EN4SD24208WSS	\$1,146.00	24.00 x 20.00 x 8.82 [610 x 508 x 224]	EP2420	EPG2420
EN4SD242010WSS	\$1,194.00	24.00 x 20.00 x 10.82 [610 x 508 x 275]	EP2420	EPG2420
EN4SD24248WSS	\$1,252.00	24.00 x 24.00 x 8.82 [610 x 610 x 224]	EP2424	EPG2424
EN4SD242410WSS	\$1,288.00	24.00 x 24.00 x 10.82 [610 x 610 x 275]	EP2424	EPG2424
EN4SD30248WSS	\$1,430.00	30.00 x 24.00 x 8.82 [762 x 610 x 224]	EP3024	EPG3024
EN4SD302410WSS	\$1,432.00	30.00 x 24.00 x 10.82 [762 x 610 x 275]	EP3024	EPG3024
EN4SD302412WSS	\$1,583.00	30.00 x 24.00 x 12.82 [762 x 610 x 326]	EP3024	EPG3024

Note: Dimensions in inches [millimeters].

Eclipse Series NEMA 3R, 4, 4X, 12 and 13 Stainless Steel Single-Door Wall Mount with Window



Dimensions

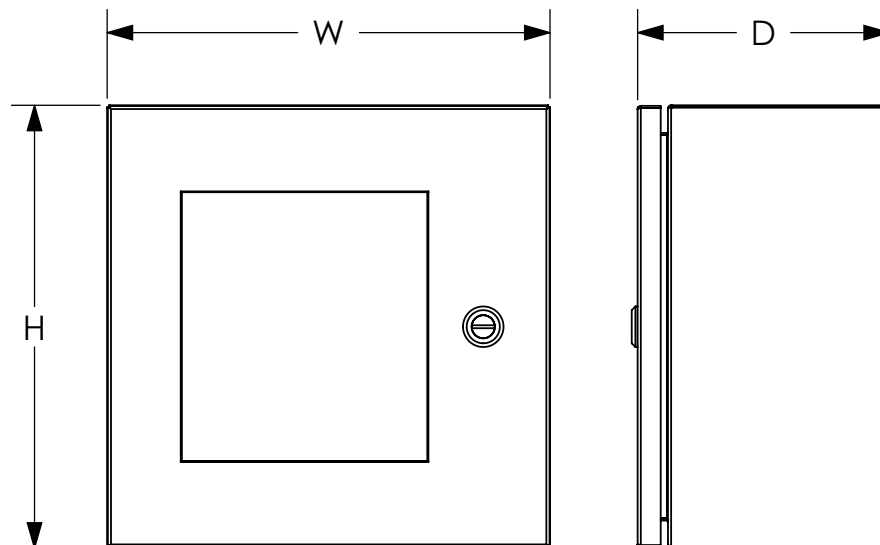

See our website: www.AutomationDirect.com for complete engineering drawings.