

# NEMA 12 and 13 Operator Consolets



## Applications

- Designed for use as electric, hydraulic or pneumatic control and instrument enclosures.
- Ideal for flat surface mounting or pedestal mounting to provide the necessary 30° or 60° control slope.
- Provides protection from dirt, dust, oil, and water.

## Construction

- Formed 14-gauge steel.
- Smooth, continuously welded seams.
- Construction provides either 30° or 60° slope on front cover depending on mounting position.
- Continuously hinged cover may be removed by pulling the hinge pin.
- Captive cover screws thread into sealed wells.
- Oil-resistant gasket and adhesive.
- A bonding stud is provided on the door and a ground stud is provided on the enclosure.

## Finish

- Cover and enclosure are phosphatized and finished in ANSI 61 gray powder coating.

## Listings

- UL 508A Type 12 and 13 [UL File E65324]
- CSA Type 12 and 13 [CSA File LR21001]
- Complies with
  - NEMA Type 12 and 13
  - IEC 60529, IP54



### Shipping Schedule

Same day      1 - 15 days

Color indicates shipping lead time in business days.

## NEMA 12 and 13 Operator Consolets


Part Number	Price	Console Size HxWxD	Drawing Link
<a href="#">1488EE7</a>	\$169.00	8.05 x 8.34 x 7.41 [204 x 212 x 188]	<a href="#">PDF</a>
<a href="#">1488EH7</a>	\$187.00	8.05 x 12.34 x 7.41 [204 x 313 x 188]	<a href="#">PDF</a>
<a href="#">1488EJ7</a>	\$205.00	8.05 x 16.34 x 7.41 [204 x 415 x 188]	<a href="#">PDF</a>
<a href="#">1488EL7</a>	\$227.00	8.05 x 20.34 x 7.41 [204 x 517 x 188]	<a href="#">PDF</a>
<a href="#">1488HH9</a>	\$218.00	11.51 x 12.34 x 9.37 [292 x 313 x 238]	<a href="#">PDF</a>
<a href="#">1488HJ9</a>	\$241.00	11.51 x 16.34 x 9.37 [292 x 415 x 238]	<a href="#">PDF</a>
<a href="#">1488HL9</a>	\$274.00	11.51 x 20.34 x 9.37 [292 x 517 x 238]	<a href="#">PDF</a>
<a href="#">1488HN9</a>	\$298.00	11.51 x 24.34 x 9.37 [292 x 618 x 238]	<a href="#">PDF</a>
<a href="#">1488JJ11</a>	\$279.00	14.98 x 16.34 x 11.37 [380 x 415 x 289]	<a href="#">PDF</a>
<a href="#">1488JL11</a>	\$311.00	14.97 x 20.34 x 11.37 [380 x 517 x 289]	<a href="#">PDF</a>
<a href="#">1488JN11</a>	\$342.00	14.97 x 24.34 x 11.37 [380 x 618 x 289]	<a href="#">PDF</a>
<a href="#">1488JQ11</a>	\$400.00	14.97 x 30.34 x 11.37 [380 x 771 x 289]	<a href="#">PDF</a>
<a href="#">1488JS11</a>	\$450.00	14.97 x 36.34 x 11.37 [380 x 923 x 289]	<a href="#">PDF</a>
<a href="#">1488LL13</a>	\$367.00	18.44 x 20.34 x 13.37 [468 x 517 x 340]	<a href="#">PDF</a>
<a href="#">1488LN13</a>	\$409.00	18.44 x 24.34 x 13.37 [468 x 618 x 340]	<a href="#">PDF</a>
<a href="#">1488LQ13</a>	\$454.00	18.44 x 30.34 x 13.37 [468 x 771 x 340]	<a href="#">PDF</a>

Dimensions in inches [millimeters].

# NEMA 12 and 13 Operator Consolets



## Dimensions

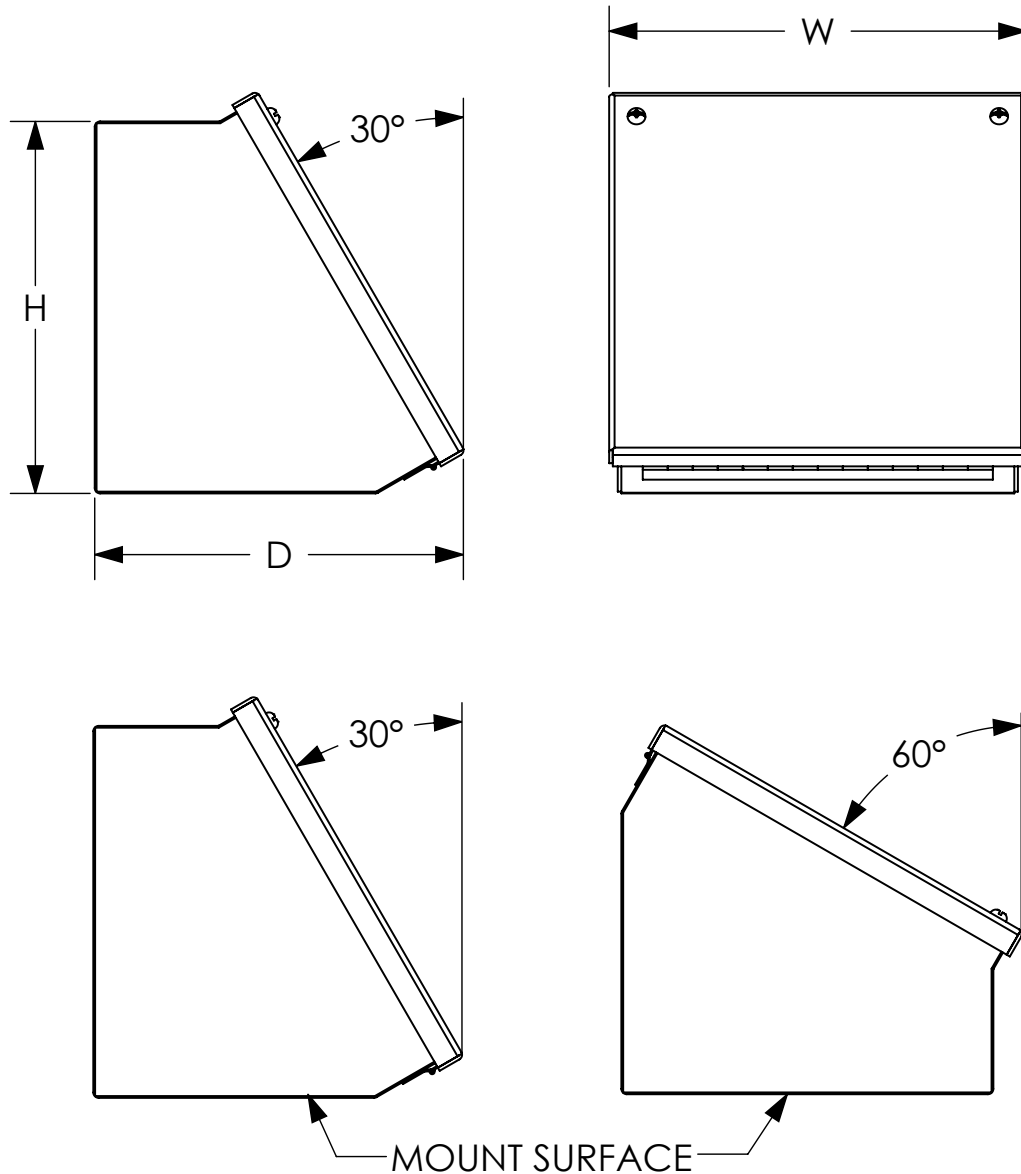

CONSOLE CAN BE POSITIONED AT 30° OR 60° ANGLE