

NEMA 12 and 13 Operator Consolets



Applications

- Designed for use as electric, hydraulic or pneumatic control and instrument enclosures.
- Ideal for flat surface mounting or pedestal mounting to provide the necessary 30° or 60° control slope.
- Provides protection from dirt, dust, oil and water.

Construction

- Formed 14 gauge steel.
- Smooth, continuously welded seams.
- Construction provides either 30° or 60° slope on front cover depending on mounting position.
- Continuously hinged cover may be removed by pulling the hinge pin.
- Captive cover screws thread into sealed wells.
- Oil-resistant gasket and adhesive.
- A bonding stud is provided on the door and a ground stud is provided on the enclosure.

Finish

- Cover and enclosure are phosphatized and finished in ANSI 61 gray powder coating.

Listings

- UL 508A Type 12 and 13 [UL File E65324]
- CSA Type 12 and 13 [CSA File LR21001]
- Complies with
 - NEMA Type 12 and 13
 - IEC 60529, IP54



Shipping Schedule

Same day 1 - 15 days

Color indicates shipping lead time in business days.


| NEMA 12 and 13 Operator Consolets | | |
|-----------------------------------|----------|---|
| Part Number | Price | Console Size HxWxD |
| 1488EE7 | \$120.00 | 8.05 x 8.34 x 7.41 [204 x 212 x 188] |
| 1488EH7 | \$133.00 | 8.05 x 12.34 x 7.41 [204 x 313 x 188] |
| 1488EJ7 | \$145.00 | 8.05 x 16.34 x 7.41 [204 x 415 x 188] |
| 1488EL7 | \$162.00 | 8.05 x 20.34 x 7.41 [204 x 517 x 188] |
| 1488HH9 | \$154.00 | 11.51 x 12.34 x 9.37 [292 x 313 x 238] |
| 1488HJ9 | \$172.00 | 11.51 x 16.34 x 9.37 [292 x 415 x 238] |
| 1488HL9 | \$195.00 | 11.51 x 20.34 x 9.37 [292 x 517 x 238] |
| 1488HN9 | \$212.00 | 11.51 x 24.34 x 9.37 [292 x 618 x 238] |
| 1488JL11 | \$221.00 | 14.97 x 20.34 x 11.37 [380 x 517 x 289] |
| 1488JN11 | \$243.00 | 14.97 x 24.34 x 11.37 [380 x 618 x 289] |
| 1488JQ11 | \$285.00 | 14.97 x 30.34 x 11.37 [380 x 771 x 289] |
| 1488JS11 | \$321.00 | 14.97 x 36.34 x 11.37 [380 x 923 x 289] |
| 1488JJ11 | \$199.00 | 14.98 x 16.34 x 11.37 [380 x 415 x 289] |
| 1488LL13 | \$262.00 | 18.44 x 20.34 x 13.37 [468 x 517 x 340] |
| 1488LN13 | \$291.00 | 18.44 x 24.34 x 13.37 [468 x 618 x 340] |
| 1488LQ13 | \$324.00 | 18.44 x 30.34 x 13.37 [468 x 771 x 340] |

Dimensions in inches [millimeters]

NEMA 12 and 13 Operator Consolets



Dimensions

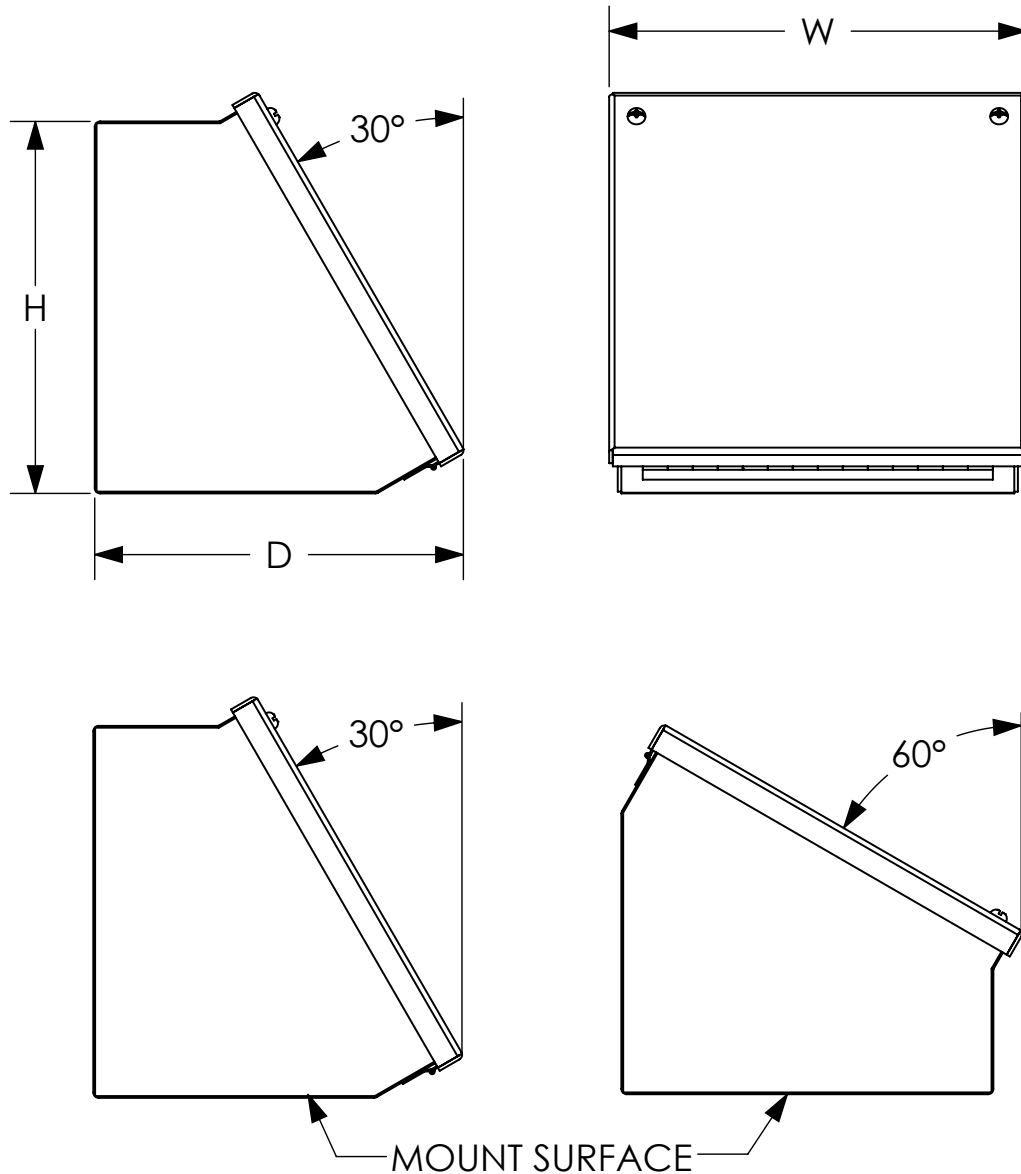

CONSOLE CAN BE POSITIONED AT 30° OR 60° ANGLE

See our website: www.AutomationDirect.com for complete engineering drawings.