

# NEMA 12 and 13 Pushbutton Operator Consolelet



## Applications

- Designed to accept standard heavy duty oil-tight pushbuttons, switches and pilot lights.
- Ideal for wall or surface mounting to provide the necessary control slope.
- Provides protection from dirt, dust, oil and water.

## Construction

- Formed 14 gauge steel.
- Smooth continuously welded seams.
- Construction provides either a 30° or 60° slope on front cover depending on mounting position.
- Welded brackets provide for enclosure mounting.
- Captive cover screws thread into sealed wells.
- Larger enclosures provide internally hinged removable covers designed to hold the cover open during wiring (as noted in table).
- Oil-resistant gasket and adhesive.
- A bonding stud is provided on the door and a grounding stud is provided on the enclosure.

## Finish

- Cover and enclosure are phosphatized and finished in ANSI 61 gray powder coating.

## Listings

- UL 508A Type 12 and 13 [UL File E65324]
- CSA Type 12 and 13 [CSA File LR21001]
- Complies with
  - NEMA Type 12 and 13
  - IEC 60529, IP54
- All appropriate components are required to maintain these standards.



Shipping Schedule	
Same day	1 - 15 days
Color indicates shipping lead time in business days.	



NEMA 12 and 13 Pushbutton Operator Consolelet						
22mm	Price	30mm	Price	Console Size HxWxD	# Holes	Hinged
<b>1490MD1</b>	\$64.00	<b>1490D1</b>	\$66.00	3.53 x 3.56 x 5.06 [90 x 90 x 129]	1	No
<b>1490MD2</b>	\$75.00	<b>1490D2</b>	\$78.00	3.53 x 5.81 x 5.06 [90 x 148 x 129]	2	
<b>1490MD3</b>	\$86.00	<b>1490D3</b>	\$88.00	3.53 x 8.06 x 5.06 [90 x 205 x 129]	3	
<b>1490MD4</b>	\$97.00	<b>1490D4</b>	\$99.00	3.53 x 10.31 x 5.06 [90 x 262 x 129]	4	
<b>1490MG4</b>	\$108.00	<b>1490G4</b>	\$112.00	6.78 x 6.56 x 6.94 [172 x 167 x 176]	4	Yes
<b>1490MG6</b>	\$125.00	<b>1490G6</b>	\$129.00	6.78 x 8.81 x 6.94 [172 x 224 x 176]	6	
<b>1490MG8</b>	\$142.00	<b>1490G8</b>	\$146.00	6.78 x 11.06 x 6.94 [172 x 281 x 176]	8	
<b>1490MH9</b>	\$148.00	<b>1490H9</b>	\$153.00	8.75 x 8.81 x 8.06 [222 x 224 x 205]	9	
<b>1490MG10</b>	\$157.00	<b>1490G10</b>	\$162.00	6.78 x 13.31 x 6.94 [172 x 338 x 176]	10	
<b>1490MG12</b>	\$172.00	<b>1490G12</b>	\$177.00	6.78 x 15.56 x 6.94 [172 x 395 x 176]	12	
<b>1490MJ12</b>	\$165.00	<b>1490J12</b>	\$170.00	10.69 x 8.81 x 9.19 [272 x 224 x 233]	12	
<b>1490MG16</b>	\$200.00	<b>1490G16</b>	\$206.00	6.78 x 20.06 x 6.94 [172 x 510 x 176]	16	
<b>1490MJ16</b>	\$184.00	<b>1490J16</b>	\$189.00	10.69 x 11.06 x 9.19 [272 x 281 x 233]	16	
<b>1490MJ20</b>	\$212.00	<b>1490J20</b>	\$218.00	10.69 x 13.31 x 9.19 [272 x 338 x 233]	20	
<b>1490MK25</b>	\$240.00	<b>1490K25</b>	\$248.00	12.63 x 13.31 x 10.31 [321 x 338 x 262]	25	
<b>1490MK30</b>	\$262.00	<b>1490K30</b>	\$270.00	12.63 x 15.56 x 10.31 [321 x 395 x 262]	30	

Note: Dimensions in inches (millimeters)

# NEMA 12 and 13 Pushbutton Operator Consolelet



## Dimensions

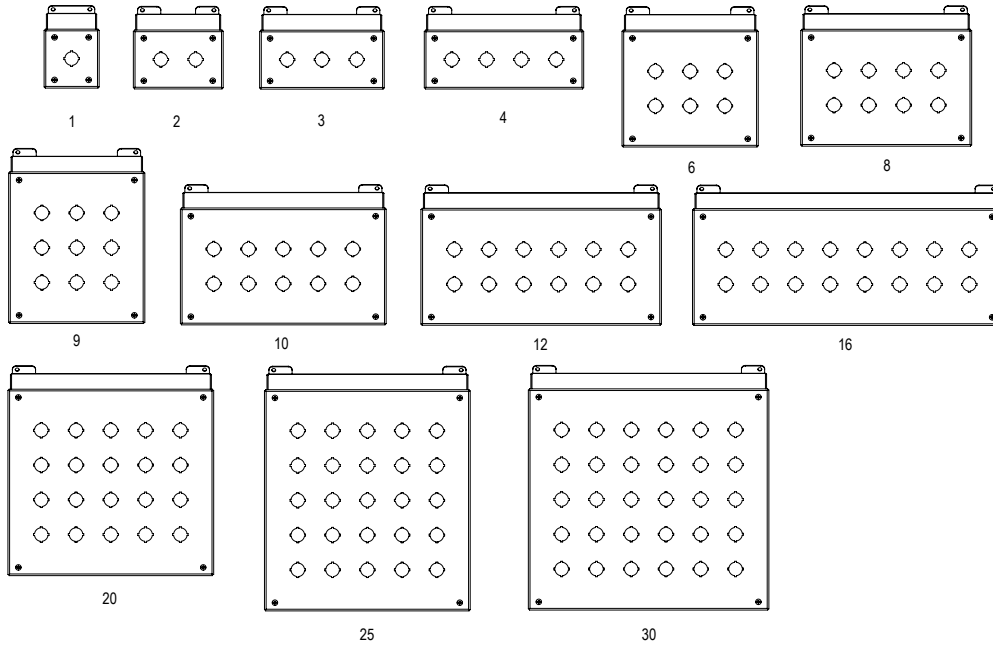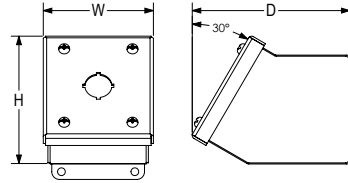

See our website: [www.AutomationDirect.com](http://www.AutomationDirect.com) for complete engineering drawings.