


NEMA 12 and 13 Single-Door Wall Mount

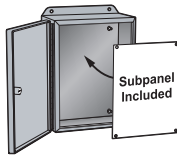

Applications

- Designed to house electrical, electronic, hydraulic or pneumatic controls and instruments.
- Provides a degree of protection from falling dirt, dust, oil and water.

Construction

- Formed 14 gauge steel bodies and doors.
- Smooth, continuously welded seams without knockouts, cutouts or holes.
- Door and body stiffeners are provided in the larger enclosures for extra rigidity.
- 14 gauge welded mounting brackets
- Formed lip on door and enclosure exclude flowing liquids and contaminants.
- Continuously hinged door may be removed by pulling the hinge pin.
- Door is secured with easily operated stainless steel clamps.
- Provision for padlocking.
- Oil-resistant gaskets are permanently secured.
- A removable 12 gauge subpanel is included.

- Collar studs are provided for mounting subpanels.
- A bonding stud is provided on the door, and a grounding stud is provided in the enclosure.
- A literature pocket is provided for the inside of the door.

Finish

- Cover and enclosure are finished in recoatable smooth ANSI 61 gray powder coating on the inside and outside.
- Removable subpanel is finished in white RAL 9003 powder coating.

Listings

- UL 508A Type 12 and 13 [UL File E65324]
- CSA Type 12 and 13 [CSA File LR21001]
- Complies with
 - NEMA Type 12 and 13
 - IEC 60529, IP54



Shipping Schedule

Same day	1 - 15 days
----------	-------------

Color indicates shipping lead time in business days.

NEMA 12 and 13 Single-Door Wall Mount

Part Number	Price	Enclosure Size HxWxD	Subpanels					
			Painted (included)	Perforated	Aluminum	Galvanized	Stainless	Dimensions
1418A6	\$303.00	12.00 x 24.00 x 7.20 [305 x 610 x 183]	18P2109	-	-	18G2109	-	21.00 x 9.00in
1418A8	\$318.00	12.00 x 24.00 x 9.20 [305 x 610 x 234]	18P2109	-	-	18G2109	-	21.00 x 9.00in
1418B6	\$257.00	16.00 x 12.00 x 7.20 [406 x 305 x 183]	18P1309	18P1309PP	18A1309	18G1309	18P1309S16	13.00 x 9.00in
1418B8	\$269.00	16.00 x 12.00 x 9.20 [406 x 305 x 234]	18P1309	18P1309PP	18A1309	18G1309	18P1309S16	13.00 x 9.00in
1418B10	\$287.00	16.00 x 12.00 x 11.20 [406 x 305 x 284]	18P1309	18P1309PP	18A1309	18G1309	18P1309S16	13.00 x 9.00in
1418G6	\$280.00	16.00 x 16.00 x 7.20 [406 x 406 x 183]	18P1313	18P1313PP	18A1313	18G1313	18P1313S16	13.00 x 13.00in
1418G8	\$293.00	16.00 x 16.00 x 9.20 [406 x 406 x 234]	18P1313	18P1313PP	18A1313	18G1313	18P1313S16	13.00 x 13.00in
1418CR6	\$311.00	16.00 x 20.00 x 7.20 [406 x 508 x 183]	18P1713	18P1713PP	-	18G1713	18P1713S16	17.00 x 13.00in
1418CR8	\$326.00	16.00 x 20.00 x 9.20 [406 x 508 x 234]	18P1713	18P1713PP	-	18G1713	18P1713S16	17.00 x 13.00in
1418CA6	\$283.00	20.00 x 12.00 x 7.20 [508 x 305 x 183]	18P1709	-	-	18G1709	-	17.00 x 9.00in
1418CA8	\$296.00	20.00 x 12.00 x 9.20 [508 x 305 x 234]	18P1709	-	-	18G1709	-	17.00 x 9.00in
1418C6	\$303.00	20.00 x 16.00 x 7.20 [508 x 406 x 183]	18P1713	18P1713PP	-	18G1713	18P1713S16	17.00 x 13.00in
1418C8	\$318.00	20.00 x 16.00 x 9.20 [508 x 406 x 234]	18P1713	18P1713PP	-	18G1713	18P1713S16	17.00 x 13.00in
1418C10	\$332.00	20.00 x 16.00 x 11.20 [508 x 406 x 284]	18P1713	18P1713PP	-	18G1713	18P1713S16	17.00 x 13.00in
1418C12	\$356.00	20.00 x 16.00 x 13.20 [508 x 406 x 335]	18P1713	18P1713PP	-	18G1713	18P1713S16	17.00 x 13.00in
1418D6	\$332.00	20.00 x 20.00 x 7.20 [508 x 508 x 183]	18P1717	18P1717PP	18A1717	18G1717	18P1717S16	17.00 x 17.00in
1418D8	\$348.00	20.00 x 20.00 x 9.20 [508 x 508 x 234]	18P1717	18P1717PP	18A1717	18G1717	18P1717S16	17.00 x 17.00in

Note: Dimensions in inches [millimeters].

Continued on next page

NEMA 12 and 13 Single-Door Wall Mount



Continued from previous page

NEMA 12 and 13 Single-Door Wall Mount								
Part Number	Price	Enclosure Size HxWxD	Subpanels					Dimensions
			Painted (included)	Perforated	Aluminum	Galvanized	Stainless	
1418D10	\$364.00	20.00 x 20.00 x 11.20 [508 x 508 x 284]	18P1717	18P1717PP	18A1717	18G1717	18P1717S16	17.00 x 17.00in
1418ER6	\$373.00	20.00 x 24.00 x 7.20 [508 x 610 x 183]	18P2117	18P2117PP	18A2117	18G2117	18P2117S16	21.00 x 17.00in
1418ER8	\$382.00	20.00 x 24.00 x 9.20 [508 x 610 x 234]	18P2117	18P2117PP	18A2117	18G2117	18P2117S16	21.00 x 17.00in
1418AR6	\$303.00	24.00 x 12.00 x 7.20 [610 x 305 x 183]	18P2109	-	-	18G2109	-	21.00 x 9.00in
1418AR8	\$318.00	24.00 x 12.00 x 9.20 [610 x 305 x 234]	18P2109	-	-	18G2109	-	21.00 x 9.00in
1418AR10	\$333.00	24.00 x 12.00 x 11.20 [610 x 305 x 284]	18P2109	-	-	18G2109	-	21.00 x 9.00in
1418H6	\$335.00	24.00 x 16.00 x 7.20 [610 x 406 x 183]	18P2113	-	-	18G2113	18P2113S16	21.00 x 13.00in
1418H8	\$343.00	24.00 x 16.00 x 9.20 [610 x 406 x 234]	18P2113	-	-	18G2113	18P2113S16	21.00 x 13.00in
1418E6	\$364.00	24.00 x 20.00 x 7.20 [610 x 508 x 183]	18P2117	18P2117PP	18A2117	18G2117	18P2117S16	21.00 x 17.00in
1418E8	\$382.00	24.00 x 20.00 x 9.20 [610 x 508 x 234]	18P2117	18P2117PP	18A2117	18G2117	18P2117S16	21.00 x 17.00in
1418E10	\$400.00	24.00 x 20.00 x 11.20 [610 x 508 x 284]	18P2117	18P2117PP	18A2117	18G2117	18P2117S16	21.00 x 17.00in
1418E12	\$429.00	24.00 x 20.00 x 13.20 [610 x 508 x 335]	18P2117	18P2117PP	18A2117	18G2117	18P2117S16	21.00 x 17.00in
1418E16	\$466.00	24.00 x 20.00 x 17.20 [610 x 508 x 437]	18P2117	18P2117PP	18A2117	18G2117	18P2117S16	21.00 x 17.00in
1418J6	\$397.00	24.00 x 24.00 x 7.20 [610 x 610 x 183]	18P2121	18P2121PP	18A2121	18G2121	18P2121S16	21.00 x 21.00in
1418J8	\$416.00	24.00 x 24.00 x 9.20 [610 x 610 x 234]	18P2121	18P2121PP	18A2121	18G2121	18P2121S16	21.00 x 21.00in
1418J10	\$436.00	24.00 x 24.00 x 11.20 [610 x 610 x 284]	18P2121	18P2121PP	18A2121	18G2121	18P2121S16	21.00 x 21.00in
1418J12	\$455.00	24.00 x 24.00 x 13.20 [610 x 610 x 335]	18P2121	18P2121PP	18A2121	18G2121	18P2121S16	21.00 x 21.00in
1418J16	\$507.00	24.00 x 24.00 x 17.20 [610 x 610 x 437]	18P2121	18P2121PP	18A2121	18G2121	18P2121S16	21.00 x 21.00in
1418KR8	\$468.00	24.00 x 30.00 x 9.20 [610 x 762 x 234]	18P2721	18P2721PP	18A2721	18G2721	18P2721S16	27.00 x 21.00in
1418KA8	\$404.00	30.00 x 12.00 x 9.20 [762 x 305 x 234]	18P2709	-	-	18G2709	-	27.00 x 9.00in
1418FG6	\$375.00	30.00 x 16.00 x 7.20 [762 x 406 x 183]	18P2713	-	-	18G2713	-	27.00 x 13.00in
1418KG8	\$425.00	30.00 x 16.00 x 9.20 [762 x 406 x 234]	18P2713	-	-	18G2713	-	27.00 x 13.00in
1418F6	\$416.00	30.00 x 20.00 x 7.20 [762 x 508 x 183]	18P2717	-	-	18G2717	18P2717S16	27.00 x 17.00in
1418F8	\$438.00	30.00 x 20.00 x 9.20 [762 x 508 x 234]	18P2717	-	-	18G2717	18P2717S16	27.00 x 17.00in
1418F10	\$459.00	30.00 x 20.00 x 11.20 [762 x 508 x 284]	18P2717	-	-	18G2717	18P2717S16	27.00 x 17.00in
1418K6	\$457.00	30.00 x 24.00 x 7.20 [762 x 610 x 183]	18P2721	18P2721PP	18A2721	18G2721	18P2721S16	27.00 x 21.00in
1418K8	\$468.00	30.00 x 24.00 x 9.20 [762 x 610 x 234]	18P2721	18P2721PP	18A2721	18G2721	18P2721S16	27.00 x 21.00in
1418K10	\$490.00	30.00 x 24.00 x 11.20 [762 x 610 x 284]	18P2721	18P2721PP	18A2721	18G2721	18P2721S16	27.00 x 21.00in
1418K12	\$512.00	30.00 x 24.00 x 13.20 [762 x 610 x 335]	18P2721	18P2721PP	18A2721	18G2721	18P2721S16	27.00 x 21.00in
1418K16	\$570.00	30.00 x 24.00 x 17.20 [762 x 610 x 437]	18P2721	18P2721PP	18A2721	18G2721	18P2721S16	27.00 x 21.00in
1418K20	\$617.00	30.00 x 24.00 x 21.20 [762 x 610 x 538]	18P2721	18P2721PP	18A2721	18G2721	18P2721S16	27.00 x 21.00in
1418K24	\$663.00	30.00 x 24.00 x 25.20 [762 x 610 x 640]	18P2721	18P2721PP	18A2721	18G2721	18P2721S16	27.00 x 21.00in
1418KK8	\$544.00	30.00 x 30.00 x 9.20 [762 x 762 x 234]	18P2727	18P2727PP	-	18G2727	18P2727S16	27.00 x 21.00in
1418KK12	\$593.00	30.00 x 30.00 x 13.20 [762 x 762 x 335]	18P2727	18P2727PP	-	18G2727	18P2727S16	27.00 x 21.00in
1418MR8	\$618.00	30.00 x 36.00 x 9.20 [762 x 914 x 234]	18P3327	18P3327PP	18A3327	18G3327	18P3327S16	33.00 x 27.00in
1418L6	\$508.00	36.00 x 24.00 x 7.20 [914 x 610 x 183]	18P3321	18P3327PP	18A3321	18G3321	18P3321S16	33.00 x 27.00in
1418L8	\$521.00	36.00 x 24.00 x 9.20 [914 x 610 x 234]	18P3321	18P3321PP	18A3321	18G3321	18P3321S16	33.00 x 21.00in
1418L10	\$546.00	36.00 x 24.00 x 11.20 [914 x 610 x 284]	18P3321	18P3321PP	18A3321	18G3321	18P3321S16	33.00 x 21.00in
1418L12	\$570.00	36.00 x 24.00 x 13.20 [914 x 610 x 335]	18P3321	18P3321PP	18A3321	18G3321	18P3321S16	33.00 x 21.00in
1418M6	\$590.00	36.00 x 30.00 x 7.20 [914 x 762 x 183]	18P3327	18P3327PP	18A3327	18G3327	18P3327S16	33.00 x 27.00in
1418M8	\$604.00	36.00 x 30.00 x 9.20 [914 x 762 x 234]	18P3327	18P3327PP	18A3327	18G3327	18P3327S16	33.00 x 27.00in
1418M10	\$631.00	36.00 x 30.00 x 11.20 [914 x 762 x 284]	18P3327	18P3327PP	18A3327	18G3327	18P3327S16	33.00 x 27.00in
1418M12	\$658.00	36.00 x 30.00 x 13.20 [914 x 762 x 335]	18P3327	18P3327PP	18A3327	18G3327	18P3327S16	33.00 x 27.00in
1418M16	\$731.00	36.00 x 30.00 x 17.20 [914 x 762 x 437]	18P3327	18P3327PP	18A3327	18G3327	18P3327S16	33.00 x 27.00in

Note: Dimensions in inches [millimeters].

Continued on next page

NEMA 12 and 13 Single-Door Wall Mount



Continued from previous page


NEMA 12 and 13 Single-Door Wall Mount								
Part Number	Price	Enclosure Size HxWxD	Subpanels					Dimensions
			Painted (included)	Perforated	Aluminum	Galvanized	Stainless	
1418M20	\$786.00	36.00 x 30.00 x 21.20 [914 x 762 x 538]	18P3327	18P3327PP	18A3327	18G3327	18P3327S16	33.00 x 27.00in
1418LL8	\$679.00	36.00 x 36.00 x 9.20 [914 x 914 x 234]	18P3333	18P3333PP	-	18G3333	18P3333S16	33.00 x 33.00in
1418LL12	\$738.00	36.00 x 36.00 x 13.20 [914 x 914 x 335]	18P3333	18P3333PP	-	18G3333	18P3333S16	33.00 x 33.00in
1418N8	\$592.00	42.00 x 24.00 x 9.20 [1067 x 610 x 234]	18P3921	-	-	18G3921	-	39.00 x 21.00in
1418O8	\$684.00	42.00 x 30.00 x 9.20 [1067 x 762 x 234]	18P3927	-	-	18G3927	18P3927S16	39.00 x 27.00in
1418O10	\$714.00	42.00 x 30.00 x 11.20 [1067 x 762 x 284]	18P3927	-	-	18G3927	18P3927S16	39.00 x 27.00in
1418O12	\$745.00	42.00 x 30.00 x 13.20 [1067 x 762 x 335]	18P3927	-	-	18G3927	18P3927S16	39.00 x 27.00in
1418P8	\$770.00	42.00 x 36.00 x 9.20 [1067 x 914 x 234]	18P3933	-	-	18G3933	-	39.00 x 33.00in
1418P10	\$803.00	42.00 x 36.00 x 11.20 [1067 x 914 x 284]	18P3933	-	-	18G3933	-	39.00 x 33.00in
1418P12	\$817.00	42.00 x 36.00 x 13.20 [1067 x 914 x 335]	18P3933	-	-	18G3933	-	39.00 x 33.00in
1418P16	\$904.00	42.00 x 36.00 x 17.20 [1067 x 914 x 437]	18P3933	-	-	18G3933	-	39.00 x 33.00in
1418Q8	\$649.00	48.00 x 24.00 x 9.20 [1219 x 610 x 234]	18P4521	-	-	18G4521	-	45.00 x 21.00in
1418R8	\$747.00	48.00 x 30.00 x 9.20 [1219 x 762 x 234]	18P4527	-	-	18G4527	-	45.00 x 27.00in
1418R10	\$782.00	48.00 x 30.00 x 11.20 [1219 x 762 x 284]	18P4527	-	-	18G4527	-	45.00 x 27.00in
1418S8	\$827.00	48.00 x 36.00 x 9.20 [1219 x 914 x 234]	18P4533	-	18A4533	18G4533	18P4533S16	45.00 x 33.00in
1418S10	\$862.00	48.00 x 36.00 x 11.20 [1219 x 914 x 284]	18P4533	-	18A4533	18G4533	18P4533S16	45.00 x 33.00in
1418S12	\$897.00	48.00 x 36.00 x 13.20 [1219 x 914 x 335]	18P4533	-	18A4533	18G4533	18P4533S16	45.00 x 33.00in
1418S16	\$968.00	48.00 x 36.00 x 17.20 [1219 x 914 x 437]	18P4533	-	18A4533	18G4533	18P4533S16	45.00 x 33.00in
1418S20	\$1,062.00	48.00 x 36.00 x 21.20 [1219 x 914 x 538]	18P4533	-	18A4533	18G4533	18P4533S16	45.00 x 33.00in
1418T8	\$1,000.00	60.00 x 36.00 x 9.20 [1524 x 914 x 234]	18P4533	-	18A5733	18G5733	18P4533S16	45.00 x 33.00in
1418T10	\$1,017.00	60.00 x 36.00 x 11.20 [1524 x 914 x 284]	18P5733	-	18A5733	18G5733	18P5733S16	57.00 x 33.00in
1418T12	\$1,056.00	60.00 x 36.00 x 13.20 [1524 x 914 x 335]	18P5733	-	18A5733	18G5733	18P5733S16	57.00 x 33.00in
1418T16	\$1,164.00	60.00 x 36.00 x 17.20 [1524 x 914 x 437]	18P5733	-	18A5733	18G5733	18P5733S16	57.00 x 33.00in
1418T20	\$1,244.00	60.00 x 36.00 x 21.20 [1524 x 914 x 538]	18P5733	-	18A5733	18G5733	18P5733S16	57.00 x 33.00in
1418U12	\$1,079.00	72.00 x 30.00 x 13.20 [1829 x 762 x 335]	18P6927	-	-	18G6927	-	69.00 x 27.00in
1418U16	\$1,164.00	72.00 x 30.00 x 17.20 [1829 x 762 x 437]	18P6927	-	-	18G6927	-	69.00 x 27.00in
1418U20	\$1,263.00	72.00 x 30.00 x 21.20 [1829 x 762 x 538]	18P6927	-	-	18G6927	-	69.00 x 27.00in
1418U24	\$1,334.00	72.00 x 30.00 x 25.20 [1829 x 762 x 640]	18P6927	-	-	18G6927	-	69.00 x 27.00in
1418V12	\$1,214.00	72.00 x 36.00 x 13.20 [1829 x 914 x 335]	18P6933	-	-	18G6933	-	69.00 x 33.00in

Note: Dimensions in inches [millimeters].

NEMA 12 and 13 Single-Door Wall Mount



Dimensions

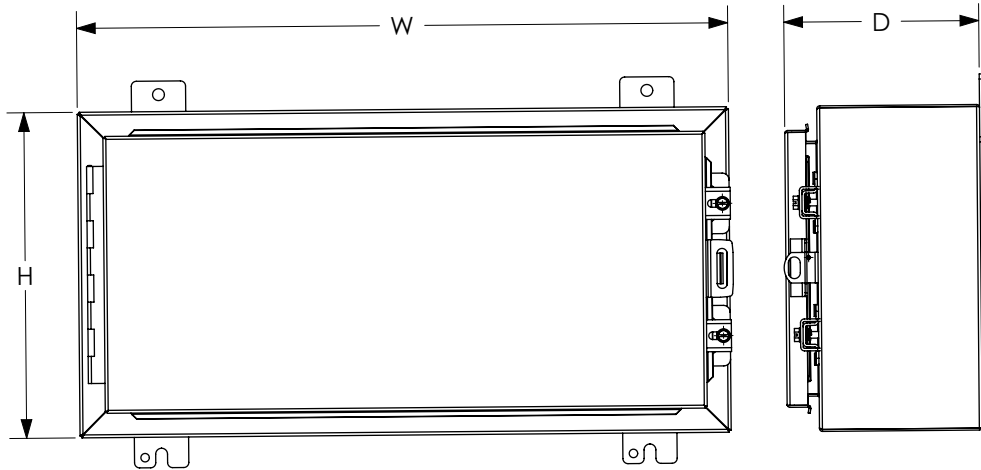

See our website: www.AutomationDirect.com for complete engineering drawings.