

NEMA 12 Double-Door Wall Mount



Applications

- Designed to house electrical, electronic, hydraulic or pneumatic controls and instruments.
- Provides a degree of protection from falling dirt, dust, oil and water.


- Collar studs are provided for mounting subpanels.
- A grounding stud is provided in the enclosure, and a bonding stud is provided on the door.
- A literature pocket is provided for the inside of the door.

Construction

- Enclosures are formed 14 gauge steel with 12 gauge steel subpanels. Exceptions are 42 x 60in and 48 x 48in which are formed 12 gauge steel with 10 gauge steel subpanels.
- Smooth, continuously welded seams without knockouts, cutouts or holes.
- Body stiffeners are provided in enclosures 30in high or more for extra rigidity.
- 14 gauge welded mounting brackets
- Gasketed overlapping doors eliminate the need for a center post.
- Continuously hinged doors may be removed by pulling the hinge pin.
- Doors are secured with a 3-point latch and operated with a key locking automotive type handle.
- Latch rods are equipped with rollers for easier door closing.
- Oil-resistant gaskets are permanently secured.

Finish

- Cover and enclosure are finished in recoatable smooth ANSI 61 gray powder coating on the inside and outside.
- Removable subpanel is finished in RAL 9003 white powder coating.

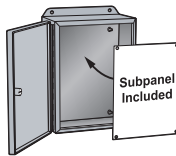

Shipping Schedule	
Same day	1 - 15 days
Color indicates shipping lead time in business days.	

Listings

- UL 508A Type 12 [UL File E65324]
- CSA Type 12 [CSA File LR21001]
- Complies with
 - NEMA Type 12
 - IEC 60529, IP54




NEMA 12 Double-Door Wall Mount							
Part Number	Price	Enclosure Size HxWxD	Optional Subpanels				
			Painted (included)	Aluminum	Galvanized	Stainless	Dimensions
1422P8	\$730.00	24.00 x 42.00 x 9.21 [610 x 1067 x 234]	18P3921	-	18G3921	-	39.00 x 21.00in
1422P10	\$876.00	24.00 x 42.00 x 11.21 [610 x 1067 x 285]	18P3921	-	18G3921	-	39.00 x 21.00in
1422PW8	\$799.00	24.00 x 48.00 x 9.21 [610 x 1219 x 234]	18P4521	-	18G4521	-	45.00 x 21.00in
1422R10	\$880.00	30.00 x 42.00 x 11.21 [762 x 1067 x 285]	18P3927	-	18G3927	18P3927S16	39.00 x 27.00in
1422RW10	\$962.00	30.00 x 48.00 x 11.21 [762 x 1219 x 285]	18P4527	-	18G4527	-	45.00 x 27.00in
1422RX10	\$1,154.00	30.00 x 60.00 x 11.21 [762 x 1524 x 285]	-	-	-	-	57.00 x 27.00in
1422UV12	\$1,056.00	36.00 x 42.00 x 13.21 [914 x 1067 x 336]	18P3933	-	18G3933	18P3933S16	39.00 x 33.00in
1422UW12	\$1,130.00	36.00 x 48.00 x 13.21 [914 x 1219 x 336]	18P4533	18A4533	18G4533	18P4533S16	45.00 x 33.00in
1422UX12	\$1,326.00	36.00 x 60.00 x 13.21 [914 x 1524 x 336]	18P5733	18A5733	18G5733	18P5733S16	57.00 x 33.00in
1422VV12	\$1,169.00	42.00 x 42.00 x 13.21 [1067 x 1067 x 336]	-	-	-	-	39.00 x 39.00in
1422VW12	\$1,284.00	42.00 x 48.00 x 13.21 [1067 x 1219 x 336]	-	-	-	-	45.00 x 39.00in
1422VX12	\$1,491.00	42.13 x 60.06 x 13.85 [1070 x 1526 x 352]	-	-	-	-	57.00 x 39.00in
1422WW12	\$1,396.00	48.13 x 48.06 x 13.85 [1223 x 1221 x 1221]	-	-	-	-	45.00 x 45.00in

Note: Dimensions in inches [millimeters].

NEMA 12 Double-Door Wall Mount



Dimensions

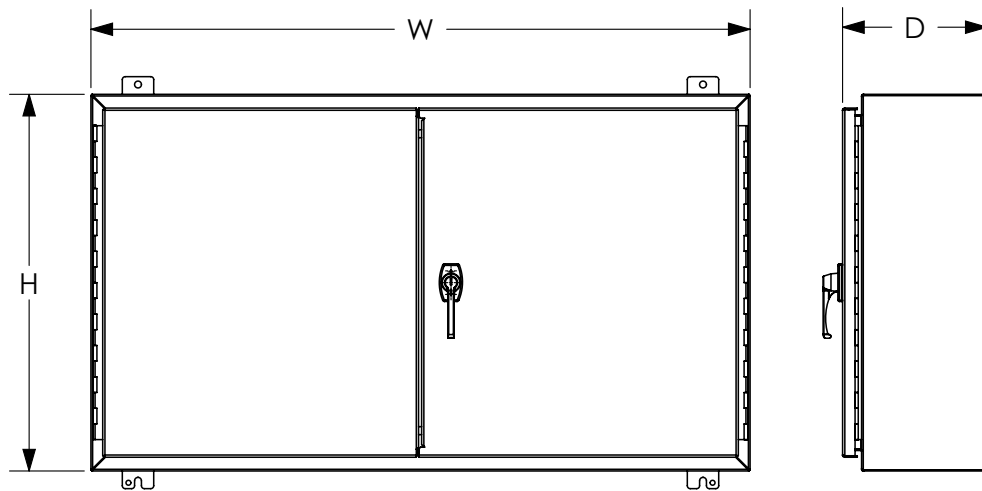

See our website: www.AutomationDirect.com for complete engineering drawings.