

# NEMA 12 Hinged Screw Cover Wall Mount



## Applications

- Designed to house electrical, electronic, hydraulic or pneumatic controls and instruments.
- Provides a degree of protection from falling dirt, dust, oil and water.

## Construction

- Formed from 14 gauge steel.
- Smooth, continuously welded seams without knockouts, cutouts or holes.
- Door and body stiffeners are provided in the larger enclosures for extra rigidity.
- 14 gauge welded mounting brackets
- Continuously hinged cover is secured with plated screws, threaded into sealed wells.
- Oil-resistant gaskets are permanently secured.
- A removable 12 gauge subpanel is included.
- Collar studs are provided for mounting subpanels.


- A bonding stud is provided on the door, and a grounding stud is provided on the enclosure.
- A literature pocket is provided for the inside of the door.

## Finish

- Cover and enclosure are phosphatized and finished in ANSI 61 gray recoatable powder coating.
- Removable subpanel is finished in RAL9003 white powder coating.

## Listings

- UL 508A Type 12 [UL File E65324]
- Complies with
  - NEMA Type 12
  - IEC 60529, IP54

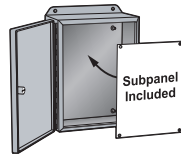

Shipping Schedule	
Same day	1 - 15 days
Color indicates shipping lead time in business days.	




NEMA 12 Hinged Screw Cover Wall Mount								
Part Number	Price	Enclosure Size HxWxD	Subpanels					Dimensions
			Painted (included)	Perforated	Aluminum	Galvanized	Stainless	
1418JB7	\$302.00	16.31 x 12.38 x 7.17 [414 x 314 x 182]	18P1309	18P1309PP	18A1309	18G1309	18P1309S16	13.00 x 9.00in
1418JC7	\$316.00	20.31 x 16.38 x 7.17 [516 x 416 x 182]	18P1713	18P1713PP	-	18G1713	18P1713S16	17.00 x 13.00in
1418JC9	\$336.00	20.31 x 16.38 x 9.17 [516 x 416 x 233]	18P1713	18P1713PP	-	18G1713	18P1713S16	17.00 x 13.00in
1418JD7	\$353.00	20.31 x 20.38 x 7.17 [516 x 518 x 182]	18P1717	18P1717PP	18A1717	18G1717	18P1717S16	17.00 x 17.00in
1418JD9	\$376.00	20.31 x 20.38 x 9.17 [516 x 518 x 233]	18P1717	18P1717PP	18A1717	18G1717	18P1717S16	17.00 x 17.00in
1418JE7	\$396.00	24.31 x 20.38 x 7.17 [617 x 518 x 182]	18P2117	18P2117PP	18A2117	18G2117	18P2117S16	21.00 x 17.00in
1418JE9	\$420.00	24.31 x 20.38 x 9.17 [617 x 518 x 233]	18P2117	18P2117PP	18A2117	18G2117	18P2117S16	21.00 x 17.00in
1418JF7	\$452.00	30.31 x 20.38 x 7.17 [770 x 518 x 182]	18P2717	-	-	18G2717	18P2717S16	27.00 x 17.00in
1418JF9	\$480.00	30.31 x 20.38 x 9.17 [770 x 518 x 233]	18P2717	-	-	18G2717	18P2717S16	27.00 x 17.00in
1418JJ11	\$516.00	24.31 x 24.38 x 11.17 [617 x 619 x 284]	18P2121	18P2121PP	18A2121	18G2121	18P2121S16	21.00 x 21.00in
1418JJ7	\$438.00	24.31 x 24.38 x 7.17 [617 x 619 x 182]	18P2121	18P2121PP	18A2121	18G2121	18P2121S16	21.00 x 21.00in
1418JJ9	\$466.00	24.31 x 24.38 x 9.17 [617 x 619 x 233]	18P2121	18P2121PP	18A2121	18G2121	18P2121S16	21.00 x 21.00in
1418JK13	\$594.00	30.31 x 24.38 x 13.17 [770 x 619 x 335]	18P2721	18P2721PP	18A2721	18G2721	18P2721S16	27.00 x 21.00in
1418JK7	\$504.00	30.31 x 24.38 x 7.17 [770 x 619 x 182]	18P2721	18P2721PP	18A2721	18G2721	18P2721S16	27.00 x 21.00in
1418JK9	\$534.00	30.31 x 24.38 x 9.17 [770 x 619 x 233]	18P2721	18P2721PP	18A2721	18G2721	18P2721S16	27.00 x 21.00in
1418JL7	\$570.00	36.31 x 24.38 x 7.17 [922 x 619 x 182]	18P3321	18P3321PP	18A3321	18G3321	18P3321S16	33.00 x 21.00in
1418JL9	\$604.00	36.31 x 24.38 x 9.17 [922 x 619 x 233]	18P3321	18P3321PP	18A3321	18G3321	18P3321S16	33.00 x 21.00in
1418JL11	\$638.00	36.31 x 24.38 x 11.17 [922 x 619 x 284]	18P3321	18P3321PP	18A3321	18G3321	18P3321S16	33.00 x 21.00in
1418JM13	\$783.00	36.31 x 30.38 x 13.17 [922 x 772 x 335]	18P3327	18P3327PP	18A3327	18G3327	-	33.00 x 27.00in
1418JM9	\$709.00	36.31 x 30.38 x 9.17 [922 x 772 x 233]	18P3327	18P3327PP	18A3327	18G3327	-	33.00 x 27.00in
1418JO9	\$812.00	42.31 x 30.38 x 9.17 [1075 x 772 x 233]	18P3927	-	-	18G3927	18P3927S16	39.00 x 27.00in
1418JP9	\$927.00	42.31 x 36.38 x 9.17 [1075 x 924 x 233]	18P3933	-	-	18G3933	-	39.00 x 33.00in
1418JS11	\$1,018.00	48.31 x 36.38 x 11.17 [1227 x 924 x 284]	18P4533	-	18A4533	18G4533	-	45.00 x 33.00in

Note: Dimensions in inches [millimeters].

# NEMA 12 Hinged Screw Cover Wall Mount



## Dimensions

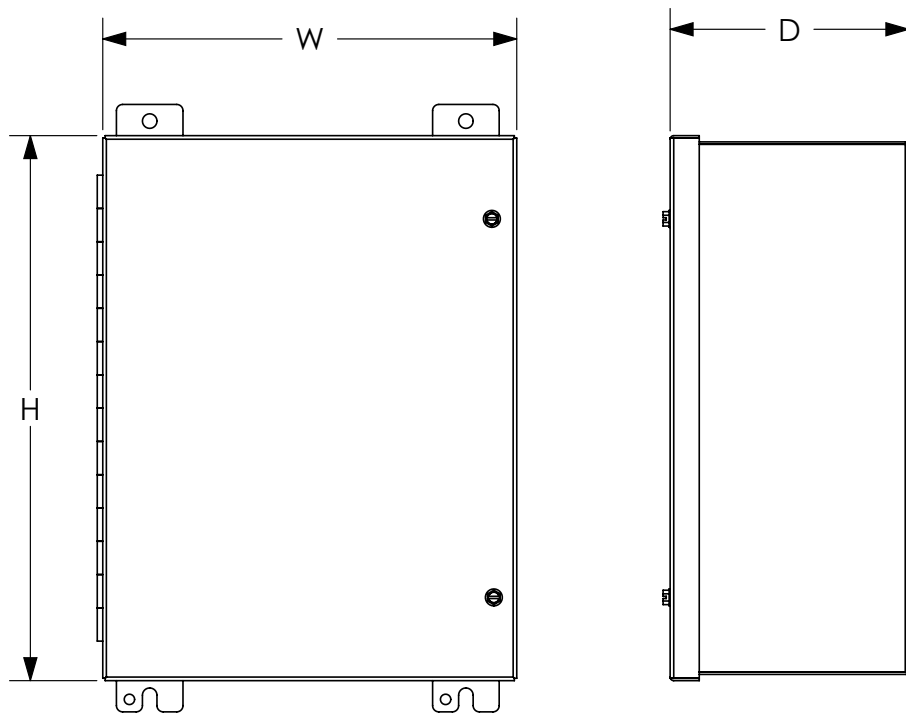

*See our website: [www.AutomationDirect.com](http://www.AutomationDirect.com) for complete engineering drawings.*