

# NEMA 1 Galvanized Steel Screw Cover Wall-Mount with Knockouts



## Applications

- Designed for general purpose indoor commercial use as a junction, pull or switch box.

## Construction

- Formed and spot welded from 16- or 14-gauge steel depending on size.
- Flat steel covers fastened with plated steel screws.
- Keyhole slots permit cover to be lifted off without removing screws entirely.
- Easily removed knockouts on all four sides (see drawings for sizes and locations).
- Through holes in back for wall-mounting.
- Grounding location embossed in body.

## Finish

- Enclosure and cover are unpainted galvanized steel.

## Listings

- UL-50 Type 1 [UL File E63524]
- CSA Type 1 [CSA File LR21001]
- Complies with
  - NEMA Type 1
  - IEC 60529, IP20




| NEMA 1 Galvanized Steel Screw Cover Wall-Mount with Knockouts |         |                                        |                     |                   |                        |
|---------------------------------------------------------------|---------|----------------------------------------|---------------------|-------------------|------------------------|
| Part Number                                                   | Price   | Enclosure Size HxWxD                   | Drawing Link        | Side Pattern      | Top and Bottom Pattern |
| <a href="#">CSKOG664</a>                                      | \$11.75 | 6.00 x 6.00 x 4.06 [152 x 152 x 103]   | <a href="#">PDF</a> | Z-X-Z             | Z-X-Z                  |
| <a href="#">CSKOG666</a>                                      | \$15.25 | 6.00 x 6.00 x 6.06 [152 x 152 x 154]   | <a href="#">PDF</a> | Z-X-Z             | Z-X-Z                  |
| <a href="#">CSKOG884</a>                                      | \$16.75 | 8.00 x 8.00 x 4.06 [203 x 203 x 103]   | <a href="#">PDF</a> | X-Z-X-Z           | X-Z-X-Z                |
| <a href="#">CSKOG886</a>                                      | \$21.00 | 8.00 x 8.00 x 6.06 [203 x 203 x 154]   | <a href="#">PDF</a> | X-Z-X-Z           | X-Z-X-Z                |
| <a href="#">CSKOG10104</a>                                    | \$23.00 | 10.00 x 10.00 x 4.06 [254 x 254 x 103] | <a href="#">PDF</a> | X-Z-X-Z           | X-Z-Y-Z-X              |
| <a href="#">CSKOG10106</a>                                    | \$27.00 | 10.00 x 10.00 x 6.06 [254 x 254 x 154] | <a href="#">PDF</a> | X-Z-X-Z           | X-Z-Y-Z-X              |
| <a href="#">CSKOG12124</a>                                    | \$28.00 | 12.00 x 12.00 x 4.06 [305 x 305 x 103] | <a href="#">PDF</a> | X-Z-Y-Z-X         | X-Z-Y-Z-X              |
| <a href="#">CSKOG12126</a>                                    | \$34.50 | 12.00 x 12.00 x 6.06 [305 x 305 x 154] | <a href="#">PDF</a> | X-Z-Y-Z-X         | X-Z-Y-Z-X              |
| <a href="#">CSKOG12128</a>                                    | \$43.00 | 12.00 x 12.00 x 8.06 [305 x 305 x 205] | <a href="#">PDF</a> | X-Z-Y-Z-X         | X-Z-Y-Z-X              |
| <a href="#">CSKOG16166</a>                                    | \$60.00 | 16.00 x 16.00 x 6.06 [406 x 406 x 154] | <a href="#">PDF</a> | Z-X-Z-Y-Z-X-Z     | Z-X-Z-Y-Z-X-Z          |
| <a href="#">CSKOG16168</a>                                    | \$75.00 | 16.00 x 16.00 x 8.06 [406 x 406 x 205] | <a href="#">PDF</a> | Z-X-Z-Y-Z-X-Z     | Z-X-Z-Y-Z-X-Z          |
| <a href="#">CSKOG18124</a>                                    | \$44.50 | 18.00 x 12.00 x 4.06 [457 x 305 x 103] | <a href="#">PDF</a> | X-Z-X-Z-Y-Z-X-Z-X | X-Z-Y-Z-X              |

Note: Dimensions in inches [millimeters].





# NEMA 1 Galvanized Steel Screw Cover Wall-Mount with Knockouts




## Dimensions

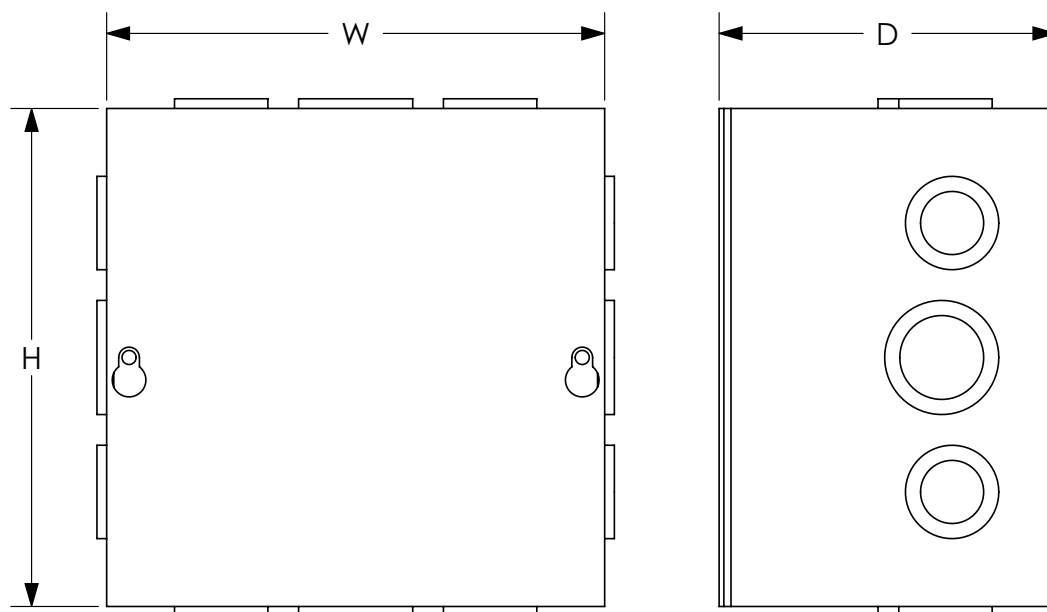

TYPICAL SIZES AND SPACING

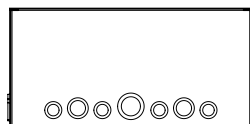   

Z X Z Y Z X Z

 

X Z X Z Y Z X Z X

| SIZE & DISTANCE INFORMATION |                 |                 |                 |
|-----------------------------|-----------------|-----------------|-----------------|
| ID                          | INNER KNOCK-OUT | OUTER KNOCK-OUT | ☒ DISTANCE      |
| X                           | 1.00 $\phi$     | 1.38 $\phi$     | 1.62<br>TYPICAL |
| Y                           | 1.23 $\phi$     | 1.75 $\phi$     |                 |
| Z                           | 0.73 $\phi$     | 1.13 $\phi$     |                 |

# Enclosure Accessories

## Flush Covers for CS and CSKO Enclosures



### Application

- Oversized covers for CS/CSKO screw cover enclosures
- Designed for flush mount installation requirements
- 1.5 in [38mm] taller and wider than standard covers
- Constructed of 16- or 14-gauge steel
- Painted ANSI 61 gray
- Note: Enclosures sold separately

### Flush Covers

| Part Number              | Price   | Actual Size HxW           | For Use with Screw Cover Enclosures HxW | Cover Thickness | Drawing Link        |
|--------------------------|---------|---------------------------|-----------------------------------------|-----------------|---------------------|
| <a href="#">CSFC66</a>   | \$3.00  | 7.50 x 7.50 [191 x 191]   | 6.00 x 6.00 [152 x 152]                 | 16 gauge        | <a href="#">PDF</a> |
| <a href="#">CSFC86</a>   | \$3.75  | 9.50 x 7.50 [241 x 191]   | 8.00 x 6.00 [203 x 152]                 |                 | <a href="#">PDF</a> |
| <a href="#">CSFC88</a>   | \$4.50  | 9.50 x 9.50 [241 x 241]   | 8.00 x 8.00 [203 x 203]                 |                 | <a href="#">PDF</a> |
| <a href="#">CSFC108</a>  | \$5.50  | 11.50 x 9.50 [292 x 241]  | 10.00 x 8.00 [254 x 203]                |                 | <a href="#">PDF</a> |
| <a href="#">CSFC1010</a> | \$6.25  | 11.50 x 11.50 [292 x 292] | 10.00 x 10.00 [254 x 254]               |                 | <a href="#">PDF</a> |
| <a href="#">CSFC128</a>  | \$6.00  | 13.50 x 9.50 [343 x 241]  | 12.00 x 8.00 [305 x 203]                |                 | <a href="#">PDF</a> |
| <a href="#">CSFC1212</a> | \$8.50  | 13.50 x 13.50 [343 x 343] | 12.00 x 12.00 [305 x 305]               |                 | <a href="#">PDF</a> |
| <a href="#">CSFC1616</a> | \$10.25 | 17.50 x 17.50 [445 x 445] | 16.00 x 16.00 [406 x 406]               |                 | <a href="#">PDF</a> |
| <a href="#">CSFC1812</a> | \$11.00 | 19.50 x 13.50 [495 x 343] | 18.00 x 12.00 [457 x 305]               |                 | <a href="#">PDF</a> |
| <a href="#">CSFC1818</a> | \$15.25 | 19.50 x 19.50 [495 x 495] | 18.00 x 18.00 [457 x 457]               |                 | <a href="#">PDF</a> |
| <a href="#">CSFC2418</a> | \$19.75 | 25.50 x 19.50 [648 x 495] | 24.00 x 18.00 [610 x 457]               | 14 gauge        | <a href="#">PDF</a> |
| <a href="#">CSFC2424</a> | \$25.00 | 25.50 x 25.50 [648 x 648] | 24.00 x 24.00 [610 x 610]               |                 | <a href="#">PDF</a> |

Note: Dimensions in inches [millimeters].