


NEMA 1 Large Single-Door Wall Mount with 1/4-Turn Latch

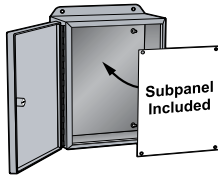

Applications

- Designed for indoor use to house controls, instruments and components not requiring oil-tight or dust-tight protection.

Construction

- Enclosure is formed and spot welded from 12 or 14 gauge steel.
- Removable 12 or 14 gauge subpanel is mounted in the rear of the enclosure on collar studs.
- Door is fastened with a slotted 1/4-turn latch.
- A bonding stud is provided on the door, and a grounding stud is provided in the box.
- Mounting holes are provided in the rear of the enclosure.

Finish

- Enclosure and door are finished in ANSI 61 gray powder coating.
- Subpanel is finished in RAL9003 white powder coating

Listings

- 50 Type 1 [UL File E65324]
- CSA Type 1 [CSA File LR21001]
- Complies with
 - NEMA Type 1
 - IEC 60529, IP20



Shipping Schedule

Same day 1 - 15 days

Color indicates shipping lead time in business days.

NEMA 1 Large Single-Door Wall Mount with 1/4-Turn Latch						
Part Number	Price	Enclosure Size HxWxD	Included Subpanel	Subpanel Dimensions	Optional Perforated Subpanel	Hinge Type
N1A16127	\$136.00	16.38 x 12.38 x 7.18 [416 x 314 x 182]	AP1612	13.00 x 10.50in [330x 267]	AP1612PP	slip hinges
N1A16129	\$147.00	16.38 x 12.38 x 9.18 [416 x 314 x 233]	AP1612	13.00 x 10.50in [330x 267]	AP1612PP	
N1A16167	\$154.00	16.38 x 16.38 x 7.18 [416 x 416 x 182]	AP1616	13.00 x 14.50in [330 x 368]	AP1616PP	
N1A16207	\$172.00	16.38 x 20.38 x 7.18 [416 x 518 x 182]	AP1620	13.00 x 18.50in [330 x 470]	AP1620PP	
N1A20167	\$172.00	20.38 x 16.38 x 7.18 [518 x 416 x 182]	AP2016	17.00 x 14.50in [432 x 368]	AP2016PP	
N1A20169	\$186.00	20.38 x 16.38 x 9.18 [518 x 416 x 233]	AP2016	17.00 x 14.50in [432 x 368]	AP2016PP	
N1A20207	\$193.00	20.38 x 20.38 x 7.18 [518 x 518 x 182]	AP2020	17.00 x 18.50in [432 x 470]	AP2020PP	
N1A20209	\$209.00	20.38 x 20.38 x 9.18 [518 x 518 x 233]	AP2020	17.00 x 18.50in [432 x 470]	AP2020PP	
N1A20249	\$232.00	20.38 x 24.38 x 9.18 [518 x 619 x 233]	AP2024	17.00 x 22.50in [432 x 572]	AP2024PP	
N1A24167	\$190.00	24.38 x 16.38 x 7.18 [619 x 416 x 182]	AP2416	21.00 x 14.50in [533 x 368]	AP2416PP	
N1A24207	\$214.00	24.38 x 20.38 x 7.18 [619 x 518 x 182]	AP2420	21.00 x 18.50in [533 x 470]	AP2420PP	
N1A24209	\$232.00	24.38 x 20.38 x 9.18 [619 x 518 x 233]	AP2420	21.00 x 18.50in [533 x 470]	AP2420PP	
N1A242012	\$249.00	24.38 x 20.38 x 12.18 [619 x 518 x 309]	AP2420	21.00 x 18.50in [533 x 470]	AP2420PP	
N1A24247	\$241.00	24.38 x 24.38 x 7.18 [619 x 619 x 182]	AP2424	21.00 x 22.50in [533 x 572]	AP2424PP	
N1A24249	\$259.00	24.38 x 24.38 x 9.18 [619 x 619 x 233]	AP2424	21.00 x 22.50in [533 x 572]	AP2424PP	
N1A242412	\$298.00	24.38 x 24.38 x 12.18 [619 x 619 x 309]	AP2424	21.00 x 22.50in [533 x 572]	AP2424PP	
N1A30207	\$246.00	30.38 x 20.38 x 7.18 [772 x 518 x 182]	AP3020	26.00 x 18.50in [660 x 470]	AP3020PP	
N1A30209	\$278.00	30.38 x 20.38 x 9.18 [772 x 518 x 233]	AP3020	26.00 x 18.50in [660 x 470]	AP3020PP	
N1A30247	\$278.00	30.38 x 24.38 x 7.18 [772 x 619 x 182]	AP3024	26.00 x 22.50in [660 x 572]	AP3024PP	
N1A30249	\$299.00	30.38 x 24.38 x 9.18 [772 x 619 x 233]	AP3024	26.00 x 22.50in [660 x 572]	AP3024PP	
N1A302412	\$343.00	30.38 x 24.38 x 12.18 [772 x 619 x 309]	AP3024	26.00 x 22.50in [660 x 572]	AP3024PP	

Notes: Dimensions in inches [millimeters]
*12 gauge construction

Continued on next page


NEMA 1 Large Single-Door Wall Mount with 1/4-Turn Latch



Continued from previous page

NEMA 1 Large Single-Door Wall Mount with 1/4-Turn Latch						
Part Number	Price	Enclosure Size HxWxD	Included Subpanel	Subpanel Dimensions	Optional Perforated Subpanel	Hinge Type
N1A30309	\$346.00	30.38 x 30.38 x 9.18 [772 x 772 x 233]	AP3030	26.00 x 28.50in [660 x 724]	AP3030PP	slip hinges
N1A36247	\$314.00	36.38 x 24.38 x 7.18 [924 x 619 x 182]	AP3624	32.00 x 22.50in [813 x 572]	AP3624PP	
N1A36249	\$338.00	36.38 x 24.38 x 9.18 [924 x 619 x 233]	AP3624	32.00 x 22.50in [813 x 572]	AP3624PP	
N1A36307	\$368.00	36.38 x 30.38 x 7.18 [924 x 772 x 182]	AP3630	32.00 x 28.50in [813 x 724]	AP3630PP	
N1A36309	\$394.00	36.38 x 30.38 x 9.18 [924 x 772 x 233]	AP3630	32.00 x 28.50in [813 x 724]	AP3630PP	
N1A363012	\$446.00	36.43 x 30.51 x 12.22 [925 x 775 x 310]	AP3630	32.00 x 28.50in [813 x 724]	AP3630PP	
N1A42249	\$375.00	42.38 x 24.38 x 9.18 [1076 x 619 x 233]	AP4224	38.00 x 22.50in [965 x 572]	AP4224PP	continuous hinge
N1A423012*	\$704.00	42.43 x 30.51 x 12.22 [1078 x 775 x 310]	AP4230	38.00 x 28.50in [965 x 724]	-	
N1A423612*	\$802.00	42.43 x 36.51 x 12.22 [1078 x 927 x 310]	AP4236	38.00 x 34.50in [965 x 876]	-	
N1A483612*	\$851.00	48.43 x 36.51 x 12.22 [1230 x 927 x 310]	AP4836	44.00 x 34.50in [1118 x 876]	-	

Notes: Dimensions in inches [millimeters]
*12 gauge construction

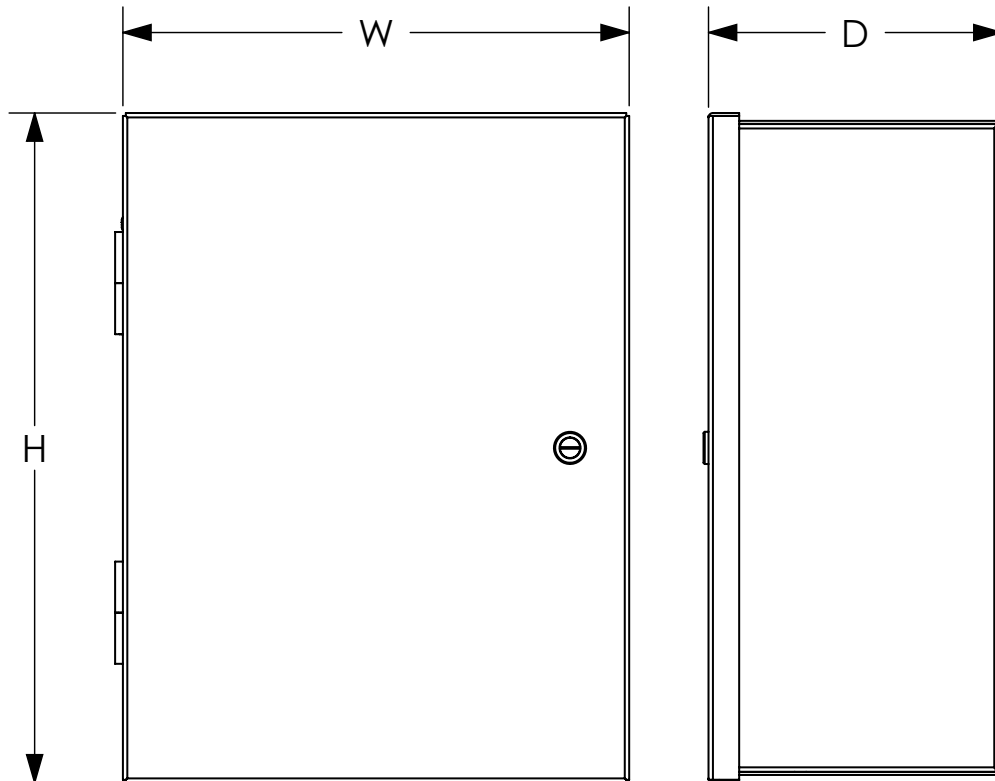

See our website: www.AutomationDirect.com for complete engineering drawings.