


NEMA 3, 3R, 4, 4X, 12 and 13 Stainless Steel Single-Door Wall Mount with 3-Point Handle

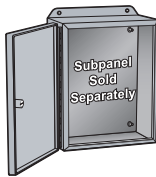

Applications

- Designed to enclose electrical and/or electronic equipment and protect against harsh, industrial environments for Wall Mount applications.
- Provides high level of protection where equipment is hosed down or otherwise be exposed to wet conditions where corrosion is a serious problem.
- Ideal for processing plants, utility, outdoor municipal or petro chemical locations where easy yet secure access is required.

Construction

- Formed 14 gauge 304 or 316 stainless steel.
- Continuously welded seams ground smooth.
- Formed lip on enclosure to exclude flowing liquids and contaminants.
- 316 stainless pad lockable handle with 3-point roller latching system secures door.
- Stainless steel continuous hinge on door may be removed by pulling the stainless steel hinge pin

- Seamless poured-in-place gasket.
- Collar studs provided for mounting subpanel.
- Bonding stud provided on door, and grounding stud installed in enclosure.

Finish

- Cover and enclosure are natural stainless steel with a #4 smooth brushed finish.

Listings

- UL 508A Type 3R, 4, 4X, and 12 [UL File E65324]
- CSA Type 3R, 4, 4X, and 12 [CSA File LR21001]
- Complies with
 - NEMA Type 3R, 4, 4X, 12 and 13
 - IEC 60529, IP66



NEMA 3, 3R, 4, 4X, 12 and 13 Stainless Steel Single-Door Wall Mount with 3-Point Handle



Shipping Schedule	
Same day	1 - 15 days
Color indicates shipping lead time in business days.	

NEMA 3R, 4, 4X, 12 and 13 Stainless Steel Single-Door Wall Mount with 3-Point Handle				
304 Stainless Steel	Price	316 Stainless Steel	Price	Enclosure Size HxWxD
HW24168SSHK	\$880.00	HW24168S16HK	\$1,056.00	24.00 x 16.00 x 9.21 [610 x 406 x 234]
HW24206SSHK	\$893.00	HW24206S16HK	\$1,085.00	24.00 x 20.00 x 7.21 [610 x 508 x 183]
HW24208SSHK	\$959.00	HW24208S16HK	\$1,095.00	24.00 x 20.00 x 9.21 [610 x 508 x 234]
HW242010SSHK	\$1,026.00	HW242010S16HK	\$1,243.00	24.00 x 20.00 x 11.21 [610 x 508 x 285]
HW24246SSHK	\$990.00	HW24246S16HK	\$1,188.00	24.00 x 24.00 x 7.21 [610 x 610 x 183]
HW24248SSHK	\$1,055.00	HW24248S16HK	\$1,203.00	24.00 x 24.00 x 9.21 [610 x 610 x 234]
HW242412SSHK	\$1,198.00	HW242412S16HK	\$1,454.00	24.00 x 24.00 x 13.21 [610 x 610 x 336]
HW24308SSHK	\$1,319.00	HW24308S16HK	\$1,451.00	24.00 x 30.00 x 9.21 [610 x 762 x 234]
HW30208SSHK	\$1,100.00	HW30208S16HK	\$1,318.00	30.00 x 20.00 x 9.21 [762 x 508 x 234]
HW30248SSHK	\$1,198.00	HW30248S16HK	\$1,366.00	30.00 x 24.00 x 9.21 [762 x 610 x 234]
HW302410SSHK	\$1,344.00	HW302410S16HK	\$1,538.00	30.00 x 24.00 x 11.21 [762 x 610 x 285]
HW302412SSHK	\$1,357.00	HW302412S16HK	\$1,547.00	30.00 x 24.00 x 13.21 [762 x 610 x 336]
HW302416SSHK	\$1,583.00	HW302416S16HK	\$1,902.00	30.00 x 24.00 x 17.21 [762 x 610 x 437]
HW30308SSHK	\$1,366.00	HW30308S16HK	\$1,657.00	30.00 x 30.00 x 9.21 [762 x 762 x 234]
HW36248SSHK	\$1,339.00	HW36248S16HK	\$1,621.00	36.00 x 24.00 x 9.21 [914 x 610 x 234]
HW362410SSHK	\$1,461.00	HW362410S16HK	\$1,756.00	36.00 x 24.00 x 11.21 [914 x 610 x 285]
HW363010SSHK	\$1,631.00	HW363010S16HK	\$1,979.00	36.00 x 30.00 x 11.21 [914 x 762 x 285]
HW363012SSHK	\$1,731.00	HW363012S16HK	\$2,099.00	36.00 x 30.00 x 13.21 [914 x 762 x 336]
HW36308SSHK	\$1,535.00	HW36308S16HK	\$1,775.00	36.00 x 30.00 x 9.21 [914 x 762 x 234]
HW363612SSHK	\$1,944.00	HW363612S16HK	\$2,358.00	36.00 x 36.00 x 13.21 [914 x 914 x 336]
HW363016SSHK	\$1,979.00	HW363016S16HK	\$2,408.00	36.00 x 30.00 x 17.21 [914 x 762 x 437]
HW423010SSHK	\$1,781.00	HW423010S16HK	\$2,097.00	42.00 x 30.00 x 11.21 [1067 x 762 x 285]
HW42368SSHK	\$2,217.00	HW42368S16HK	\$2,355.00	42.00 x 36.00 x 9.21 [1067 x 914 x 234]
HW423612SSHK	\$2,156.00	HW423612S16HK	\$2,716.00	42.00 x 36.00 x 13.21 [1067 x 914 x 336]
HW48368SSHK	\$2,118.00	HW48368S16HK	\$2,571.00	48.00 x 36.00 x 9.21 [1219 x 914 x 234]
HW483610SSHK	\$2,362.00	HW483610S16HK	\$2,760.00	48.00 x 36.00 x 11.21 [1219 x 914 x 285]
HW483612SSHK	\$2,369.00	HW483612S16HK	\$2,874.00	48.00 x 36.00 x 13.21 [1219 x 914 x 336]
HW483616SSHK	\$2,617.00	HW483616S16HK	\$2,984.00	48.00 x 36.00 x 17.21 [1219 x 914 x 437]
HW603612SSHK	\$2,795.00	HW603612S16HK	\$3,391.00	60.00 x 36.00 x 13.21 [1524 x 914 x 336]
HW603616SSHK	\$3,224.00	HW603616S16HK	\$3,769.00	60.00 x 36.00 x 17.21 [1524 x 914 x 437]

Note: Dimensions in inches [millimeters].

NEMA 3, 3R, 4, 4X, 12 and 13 Stainless Steel Single-Door Wall Mount with 3-Point Handle




Shipping Schedule	
Same day	1 - 15 days
Color indicates shipping lead time in business days.	

NEMA 3R, 4, 4X, 12 and 13 Stainless Steel Single-Door Wall Mount with 3-Point Handle						
Enclosures		Optional Subpanels				
304 Stainless	316 Stainless	Painted	Perforated	Aluminum	Galvanized	Stainless
HW24168SSHK	HW24168S16HK	18P2113	-	-	18G2113	18P2113S16
HW24206SSHK	HW24206S16HK	18P2117	18P2117PP	18A2117	18G2117	18P2117S16
HW24208SSHK	HW24208S16HK	18P2117	18P2117PP	18A2117	18G2117	18P2117S16
HW242010SSHK	HW242010S16HK	18P2117	18P2117PP	18A2117	18G2117	18P2117S16
HW24246SSHK	HW24246S16HK	18P2121	18P2121PP	18A2121	18G2121	18P2121S16
HW24248SSHK	HW24248S16HK	18P2121	18P2121PP	18A2121	18G2121	18P2121S16
HW242412SSHK	HW242412S16HK	18P2121	18P2121PP	18A2121	18G2121	18P2121S16
HW24308SSHK	HW24308S16HK	18P2721	18P2721PP	18A2721	18G2721	18P2721S16
HW30208SSHK	HW30208S16HK	18P2717	-	-	18G2717	18P2717S16
HW30248SSHK	HW30248S16HK	18P2721	18P2721PP	18A2721	18G2721	18P2721S16
HW302410SSHK	HW302410S16HK	18P2721	18P2721PP	18A2721	18G2721	18P2721S16
HW302412SSHK	HW302412S16HK	18P2721	18P2721PP	18A2721	18G2721	18P2721S16
HW302416SSHK	HW302416S16HK	18P2721	18P2721PP	18A2721	18G2721	18P2721S16
HW30308SSHK	HW30308S16HK	18P2727	18P2727PP	18G2727	18G2727	18P2727S16
HW36248SSHK	HW36248S16HK	18P3321	18P3321PP	18A3321	18G3321	18P3321S16
HW362410SSHK	HW362410S16HK	18P3321	18P3321PP	18A3321	18G3321	18P3321S16
HW36308SSHK	HW36308S16HK	18P3327	18P3327PP	18A3327	18G3327	18P3327S16
HW363010SSHK	HW363010S16HK	18P3327	18P3327PP	18A3327	18G3327	18P3327S16
HW363012SSHK	HW363012S16HK	18P3327	18P3327PP	18A3327	18G3327	18P3327S16
HW363016SSHK	HW363016S16HK	18P3327	18P3327PP	18A3327	18G3327	18P3327S16
HW363612SSHK	HW363612S16HK	18P3333	18P3333PP	-	18G3333	18P3333S16
HW423010SSHK	HW423010S16HK	18P3927	-	-	18G3927	18P3927S16
HW42368SSHK	HW42368S16HK	18P3933	-	-	18G3933	18P3933S16
HW423612SSHK	HW423612S16HK	18P3933	-	-	18G3933	18P3933S16
HW48368SSHK	HW48368S16HK	18P4533	-	18A4533	18G4533	18P4533S16
HW483610SSHK	HW483610S16HK	18P4533	-	18A4533	18G4533	18P4533S16
HW483612SSHK	HW483612S16HK	18P4533	-	18A4533	18G4533	18P4533S16
HW483616SSHK	HW483616S16HK	18P4533	-	18A4533	18G4533	18P4533S16
HW603612SSHK	HW603612S16HK	18P5733	-	18A5733	18G5733	18P5733S16
HW603616SSHK	HW603616S16HK	18P5733	-	18A5733	18G5733	18P5733S16

NEMA 3, 3R, 4, 4X, 12 and 13 Stainless Steel Single-Door Wall Mount with 3-Point Handle



Dimensions

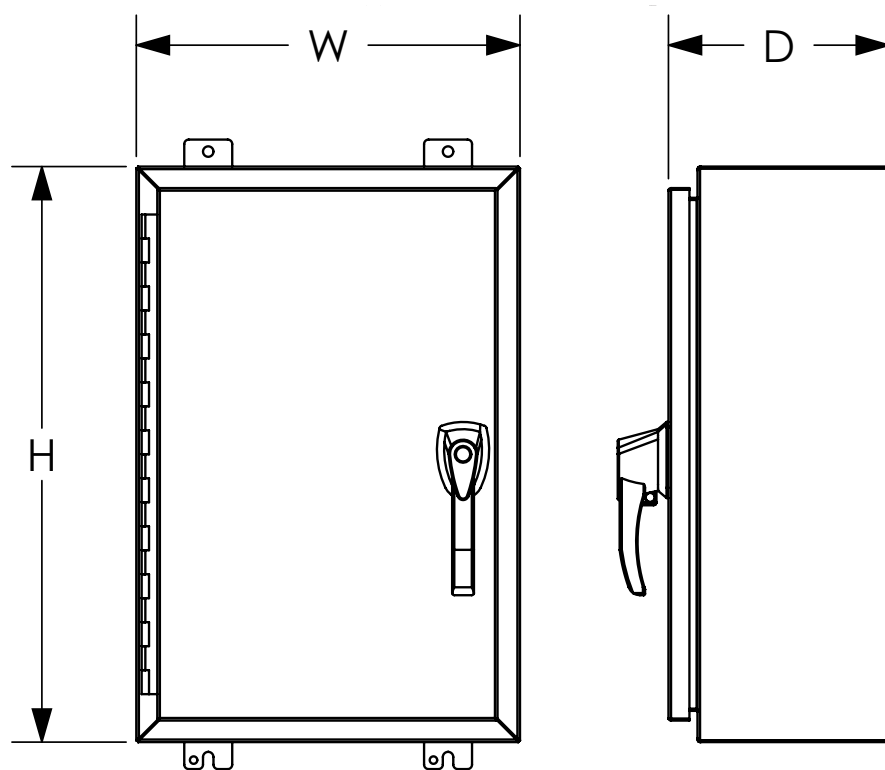

See our website: www.AutomationDirect.com for complete engineering drawings.