


# NEMA 3R, 4, 12 and 13 Single-Door Wall Mount

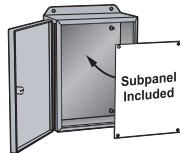

## Applications

- Designed for use as instrument enclosures, electric, hydraulic or pneumatic control housings, electrical junction boxes or terminal wiring enclosures.
- Provides protection where equipment may be hosed down or otherwise be very wet, or in outdoor applications for full weather protection.

- Seamless poured-in-place gasket.
- A removable 12 gauge subpanel is included.
- Collar studs are provided for mounting subpanels.
- A bonding stud is provided on the door, and a grounding stud is provided in the enclosure.
- An adhesive-back literature pocket is included for the inside of the door.

## Construction

- Formed 14 gauge steel bodies and doors.
- Smooth, continuously welded seams without knockouts, cutouts or holes.
- Door and body stiffeners are provided in the larger enclosures for extra rigidity.
- 14 gauge welded mounting brackets
- Formed lip on door and enclosure exclude flowing liquids and contaminants.
- Stainless steel continuous hinge on door may be removed by pulling the stainless steel hinge pin.
- Door is secured with easily operated stainless steel clamps.
- Provision for padlocking.

## Finish

- Cover and enclosure are finished in recoatable smooth ANSI 61 gray powder.
- Removable subpanel is finished in white powder coating.

## Listings

- UL 508A Type 3R,12, 4 [UL File E65324]
- CSA Type 3R,12, 4 CSA File LR21001]
- Complies with
  - NEMA Type 3R, 4, 12 and 13
  - IEC 60529, IP66

Shipping Schedule	
Same day	1 - 15 days
Color indicates shipping lead time in business days.	



NEMA 3R, 4, 12 and 13 Single-Door Wall Mount								
Part Number	Price	Enclosure Size HxWxD	Subpanels					Dimensions
			Painted (included)	Perforated	Aluminum	Galvanized	Stainless	
1418N4B6	\$331.00	16.00 x 12.00 x 7.20 [406 x 305 x 183]	18P1309	18P1309PP	18A1309	18G1309	18P1309S16	13.00 x 9.00in
1418N4B8	\$347.00	16.00 x 12.00 x 9.20 [406 x 305 x 234]	18P1309	18P1309PP	18A1309	18G1309	18P1309S16	13.00 x 9.00in
1418N4G6	\$360.00	16.00 x 16.00 x 7.20 [406 x 406 x 183]	18P1313	18P1313PP	18A1313	18G1313	18P1313S16	13.00 x 13.00in
1418N4CR6	\$399.00	16.00 x 20.00 x 7.20 [406 x 508 x 183]	18P1713	18P1713PP	-	18G1713	18P1713S16	17.00 x 13.00in
1418N4C6	\$389.00	20.00 x 16.00 x 7.20 [508 x 406 x 183]	18P1713	18P1713PP	-	18G1713	18P1713S16	17.00 x 13.00in
1418N4C8	\$408.00	20.00 x 16.00 x 9.20 [508 x 406 x 234]	18P1713	18P1713PP	-	18G1713	18P1713S16	17.00 x 13.00in
1418N4C10	\$428.00	20.00 x 16.00 x 11.20 [508 x 406 x 284]	18P1713	18P1713PP	-	18G1713	18P1713S16	17.00 x 13.00in
1418N4D6	\$424.00	20.00 x 20.00 x 7.20 [508 x 508 x 183]	18P1717	18P1717PP	18A1717	18G1717	18P1717S16	17.00 x 13.00in
1418N4D8	\$446.00	20.00 x 20.00 x 9.20 [508 x 508 x 234]	18P1717	18P1717PP	18A1717	18G1717	18P1717S16	17.00 x 13.00in
1418N4ER8	\$500.00	20.00 x 24.00 x 9.20 [508 x 610 x 234]	18P2117	18P1717PP	18A1717	18G2117	18P2117S16	21.00 x 17.00in
1418N4AR6	\$389.00	24.00 x 12.00 x 7.20 [610 x 305 x 183]	18P2109	-	-	18G2109	-	21.00 x 9.00in
1418N4H6	\$429.00	24.00 x 16.00 x 7.20 [610 x 406 x 183]	18P2113	-	-	18G2113	18P2113S16	21.00 x 13.00in
1418N4E6	\$476.00	24.00 x 20.00 x 7.20 [610 x 508 x 183]	18P2117	18P2117PP	18A2117	18G2117	18P2117S16	21.00 x 13.00in
1418N4E8	\$488.00	24.00 x 20.00 x 9.20 [610 x 508 x 234]	18P2117	18P2117PP	18A2117	18G2117	18P2117S16	21.00 x 13.00in

Note: Dimensions in inches [millimeters].

Continued on next page

# NEMA 3R, 4, 12 and 13 Single-Door Wall Mount



Shipping Schedule	
Same day	1 - 15 days
Color indicates shipping lead time in business days.	

Continued from previous page


NEMA 3R, 4, 12 and 13 Single-Door Wall Mount								
Part Number	Price	Enclosure Size HxWxD	Subpanels					Dimensions
			Painted (included)	Perforated	Aluminum	Galvanized	Stainless	
1418N4E10	\$511.00	24.00 x 20.00 x 11.20 [610 x 508 x 284]	18P2117	18P2117PP	18A2117	18G2117	18P2117S16	21.00 x 13.00in
1418N4E12	\$561.00	24.00 x 20.00 x 13.20 [610 x 508 x 335]	18P2117	18P2117PP	18A2117	18G2117	18P2117S16	21.00 x 17.00in
1418N4J6	\$517.00	24.00 x 24.00 x 7.20 [610 x 610 x 183]	18P2121	18P2121PP	18A2121	18G2121	18P2121S16	21.00 x 21.00in
1418N4J8	\$530.00	24.00 x 24.00 x 9.20 [610 x 610 x 234]	18P2121	18P2121PP	18A2121	18G2121	18P2121S16	21.00 x 21.00in
1418N4KR8	\$610.00	24.00 x 30.00 x 9.20 [610 x 762 x 234]	18P2721	18P2721PP	18A2721	18G2721	18P2721S16	27.00 x 21.00in
1418N4F6	\$529.00	30.00 x 20.00 x 7.20 [762 x 508 x 183]	18P2717	-	-	18G2717	18P2717S16	27.00 x 17.00in
1418N4F8	\$557.00	30.00 x 20.00 x 9.20 [762 x 508 x 234]	18P2717	-	-	18G2717	18P2717S16	27.00 x 17.00in
1418N4K6	\$579.00	30.00 x 24.00 x 7.20 [762 x 610 x 183]	18P2721	18P2721PP	18A2721	18G2721	18P2721S16	27.00 x 21.00in
1418N4K8	\$595.00	30.00 x 24.00 x 9.20 [762 x 610 x 234]	18P2721	18P2721PP	18A2721	18G2721	18P2721S16	27.00 x 21.00in
1418N4K10	\$624.00	30.00 x 24.00 x 11.20 [762 x 610 x 284]	18P2721	18P2721PP	18A2721	18G2721	18P2721S16	27.00 x 21.00in
1418N4K12	\$653.00	30.00 x 24.00 x 13.20 [762 x 610 x 335]	18P2721	18P2721PP	18A2721	18G2721	18P2721S16	27.00 x 21.00in
1418N4K16	\$794.00	30.00 x 24.00 x 17.20 [762 x 610 x 437]	18P2721	18P2721PP	18A2721	18G2721	18P2721S16	27.00 x 21.00in
1418N4KK8	\$688.00	30.00 x 30.00 x 9.20 [762 x 762 x 234]	18P2727	18P2727PP	-	18G2727	18P2727S16	27.00 x 27.00in
1418N4L6	\$645.00	36.00 x 24.00 x 7.20 [914 x 610 x 183]	18P3321	18P3321PP	18A3321	18G3321	18P3321S16	33.00 x 21.00in
1418N4L8	\$661.00	36.00 x 24.00 x 9.20 [914 x 610 x 234]	18P3321	18P3321PP	18A3321	18G3321	18P3321S16	33.00 x 21.00in
1418N4L12	\$756.00	36.00 x 24.00 x 13.20 [914 x 610 x 335]	18P3321	18P3321PP	18A3321	18G3321	18P3321S16	33.00 x 21.00in
1418N4M8	\$763.00	36.00 x 30.00 x 9.20 [914 x 762 x 234]	18P3327	18P3327PP	18A3327	18G3327	18P3327S16	33.00 x 27.00in
1418N4M10	\$799.00	36.00 x 30.00 x 11.20 [914 x 762 x 284]	18P3327	18P3327PP	18A3327	18G3327	18P3327S16	33.00 x 27.00in
1418N4M12	\$835.00	36.00 x 30.00 x 13.20 [914 x 762 x 335]	18P3327	18P3327PP	18A3327	18G3327	18P3327S16	33.00 x 27.00in
1418N4M16	\$907.00	36.00 x 30.00 x 17.20 [914 x 762 x 437]	18P3327	18P3327PP	18A3327	18G3327	18P3327S16	33.00 x 27.00in
1418N4O8	\$862.00	42.00 x 30.00 x 9.20 [1067 x 762 x 234]	18P3927	-	-	18G3927	18P3927S16	39.00 x 27.00in
1418N4P8	\$971.00	42.00 x 36.00 x 9.20 [1067 x 914 x 234]	18P3933	-	-	18G3933	18P3933S16	39.00 x 27.00in
1418N4P12	\$1,060.00	42.00 x 36.00 x 13.20 [1067 x 914 x 335]	18P3933	-	-	18G3933	18P3933S16	39.00 x 27.00in
1418N4R10	\$989.00	48.00 x 30.00 x 11.20 [1219 x 762 x 284]	18P4527	-	-	18G4527	-	45.00 x 27.00
1418N4S8	\$1,067.00	48.00 x 36.00 x 9.20 [1219 x 914 x 234]	18P4533	-	18A4533	18G4533	18P4533S16	45.00 x 33.00in
1418N4S10	\$1,113.00	48.00 x 36.00 x 11.20 [1219 x 914 x 284]	18P4533	-	18A4533	18G4533	18P4533S16	45.00 x 33.00in
1418N4S12	\$1,133.00	48.00 x 36.00 x 13.20 [1219 x 914 x 335]	18P4533	-	18A4533	18G4533	18P4533S16	45.00 x 33.00in
1418N4S16	\$1,224.00	48.00 x 36.00 x 17.20 [1219 x 914 x 437]	18P4533	-	18A4533	18G4533	18P4533S16	45.00 x 33.00in
1418N4T8	\$1,255.00	60.00 x 36.00 x 9.20 [1524 x 914 x 234]	18P5733	-	18A5733	18G5733	18P5733S16	57.00 x 33.00in
1418N4T10	\$1,308.00	60.00 x 36.00 x 11.20 [1524 x 914 x 284]	18P5733	-	18A5733	18G5733	18P5733S16	57.00 x 33.00in
1418N4T16	\$1,434.00	60.00 x 36.00 x 17.20 [1524 x 914 x 437]	18P5733	-	18A5733	18G5733	18P5733S16	57.00 x 33.00in

Note: Dimensions in inches [millimeters].

# NEMA 3R, 4, 12 and 13 Single-Door Wall Mount



## Dimensions

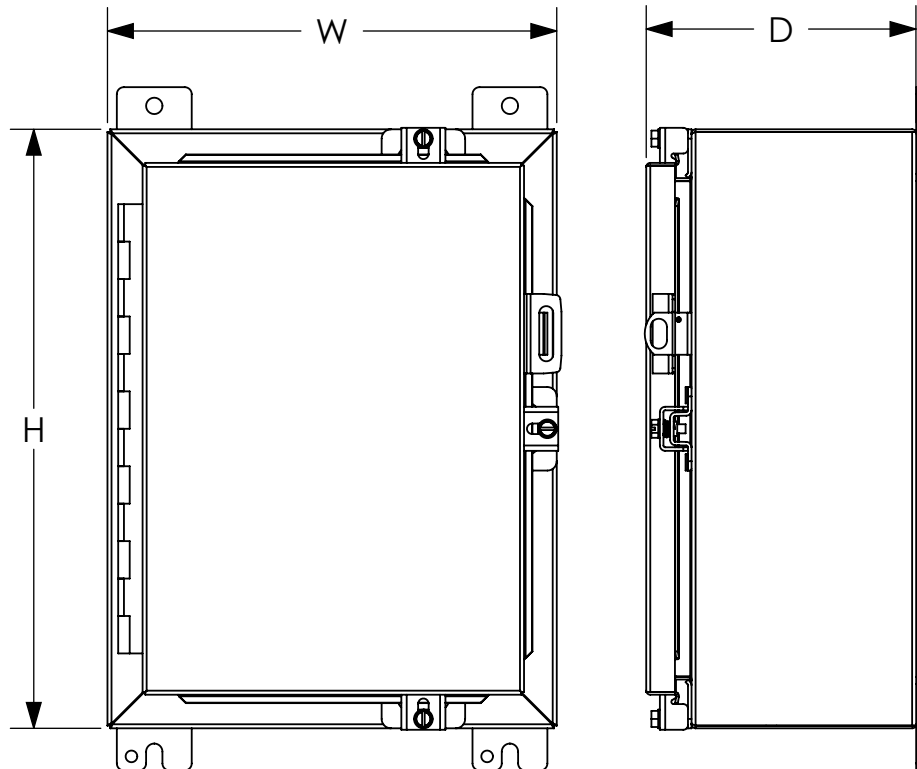

*See our website: [www.AutomationDirect.com](http://www.AutomationDirect.com) for complete engineering drawings.*