


# NEMA 3R, 4, and 12 Freestanding with 3-Point Handle

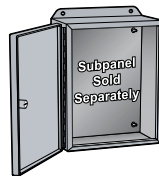

## Applications

- Designed to house electrical, electronic, hydraulic or pneumatic controls with provision for panel mounting or rack mounting of equipment.
- Provides protection where equipment may be hosed down or otherwise be very wet, or in specific applications where corrosion is a serious problem.
- A variety of subpanels, rack mounting rails and swing out frames are available to provide flexibility in mounting arrangements.

## Construction

- Formed 12-gauge steel.
- Smooth, continuously welded seams without knockouts, cutouts, or holes.
- Lifting eyes provide for easy enclosure handling.
- Doors are supported with heavy gauge continuous hinges.
- New 3-point padlocking door handle.
- Uses 1/4 turn latch handles.
- Seamless poured-in-place gasket.
- Provision for light kit mounting.
- Mounting channels are welded on the inside of the enclosure for mounting of optional subpanels or rack equipment rails.
- A grounding stud is provided in the enclosure and a bonding stud is provided on the door.
- Mounting channels are welded on the inside of the enclosure for mounting of optional

subpanels or rack equipment rails.

## Finish

- Cover and enclosure are finished in recoatable smooth ANSI 61 gray powder coating.
- Optional subpanels are available in RAL9003 white powder coating or unpainted galvanized steel.

## Listings

- UL 508A Type 3R, 4, and 12 [UL File E65324]
- CSA Type 3R, 4, and 12 [CSA File LR21001]
- Complies with
  - NEMA Type 3, 3R, 4, and 12
  - IEC 60529, IP66



## NEMA 3R, 4, and 12 Freestanding with 3-Point Handle


Part Number	Price	Enclosure Size HxWxD	Optional Subpanels						Drawing Link
			Painted		Galvanized		Size HxW		
			Full Height	Half Height	Full Height	Half Height	Full Height	Half Height	
<a href="#">HN4FS722518</a>	\$2,533.00	72.06 x 25.06 x 19.27 [1830 x 637 x 489]	<a href="#">72WFW</a>	<a href="#">72WHW</a>	<a href="#">72WFWG</a>	<a href="#">72WHWG</a>	60.00 x 20.00 [1524 x 508]	30.87 x 20.00 [784 x 508]	<a href="#">PDF</a>
<a href="#">HN4FS723124</a>	\$3,086.00	72.06 x 31.06 x 25.27 [1830 x 789 x 642]	<a href="#">72XFW</a>	<a href="#">72XHW</a>	<a href="#">72XFWG</a>	<a href="#">72XHWG</a>	60.00 x 26.00 [1524 x 660]	30.87 x 26.00 [784 x 660]	<a href="#">PDF</a>
<a href="#">HN4FS723724</a>	\$3,362.00	72.06 x 37.06 x 25.27 [1830 x 941 x 642]	<a href="#">72YFW</a>	<a href="#">72YHW</a>	<a href="#">72YFWG</a>	<a href="#">72YHWG</a>	60.00 x 32.00 [1524 x 813]	30.87 x 32.00 [784 x 813]	<a href="#">PDF</a>

Note: Dimensions in inches [millimeters].

# NEMA 3R, 4, and 12 Freestanding with 3-Point Handle



## Dimensions

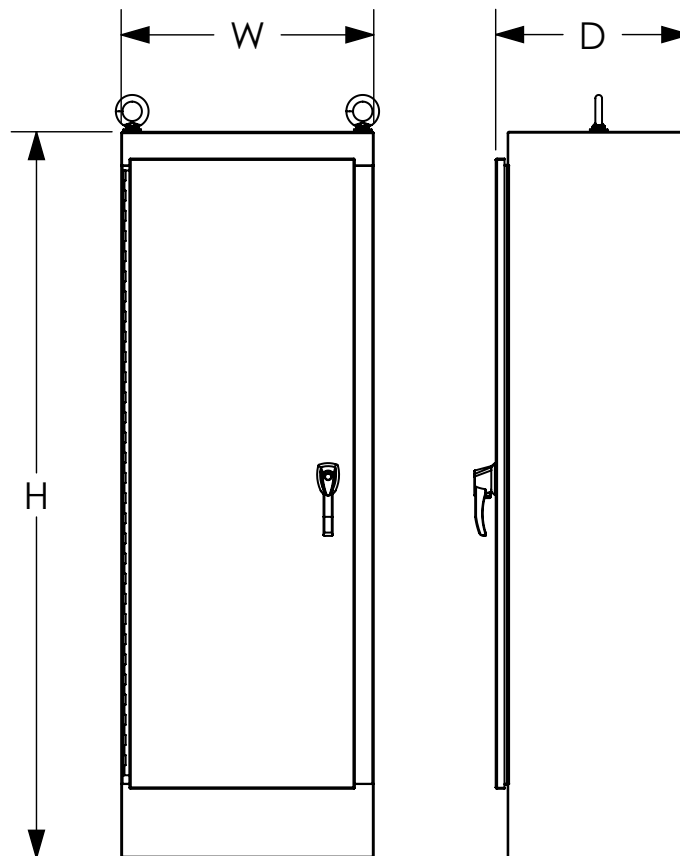

# Enclosure Accessories

## Locks and Latches



### 1/4-Turn Latch Handles



#### Features

- Durable zinc diecast or stainless steel.
- Removable handle stop for clockwise / counter-clockwise operation.
- Textured powder coat Black finish on zinc cast handle.
- Maintains NEMA rating of enclosure.
- Padlock "trigger" design for security requirements.
- Optional key lock or defeater available. Key lock versions include two keys.

1/4-Turn Latch Handles							
Part Number	Price	Security Type	Latch Points	Material	Finish	For Use With These Hammond Enclosures Only	Drawing Link
<a href="#">MHK1</a>	\$127.00	padlocking	1	die-cast zinc	black matte	single-door NEMA 4 and NEMA 12	<a href="#">PDF</a>
<a href="#">MHKD1</a>	\$133.00	padlocking with defeater					<a href="#">PDF</a>
<a href="#">MHKL1</a>	\$144.00	combination keylocking/ padlocking					<a href="#">PDF</a>
<a href="#">MHK2</a>	\$217.00	padlocking	3	die-cast zinc	black matte	less than 60in (H) NEMA 4 and NEMA 12	<a href="#">PDF</a>
<a href="#">MHKD2</a>	\$228.00	padlocking with defeater					<a href="#">PDF</a>
<a href="#">MHKL2</a>	\$246.00	combination keylocking/ padlocking					<a href="#">PDF</a>
<a href="#">MHK3</a>	\$221.00	padlocking	3	die-cast zinc	black matte	60in (H) or greater NEMA 4 and NEMA 12	<a href="#">PDF</a>
<a href="#">MHKD3</a>	\$232.00	padlocking with defeater					<a href="#">PDF</a>
<a href="#">MHKL3</a>	\$251.00	combination keylocking/ padlocking					<a href="#">PDF</a>
<a href="#">MHK1SS</a>	\$234.00	padlocking	1	316 stainless steel	#4 brush	single-door NEMA 4X	<a href="#">PDF</a>
<a href="#">MHKD1SS</a>	\$258.00	padlocking with defeater					<a href="#">PDF</a>
<a href="#">MHKL1SS</a>	\$258.00	combination keylocking/ padlocking					<a href="#">PDF</a>
<a href="#">MHK2SS</a>	\$249.00	padlocking	3	316 stainless steel	#4 brush	less than 60in (H) NEMA 4X	<a href="#">PDF</a>
<a href="#">MHKD2SS</a>	\$274.00	padlocking with defeater					<a href="#">PDF</a>
<a href="#">MHKL2SS</a>	\$274.00	combination keylocking/ padlocking					<a href="#">PDF</a>
<a href="#">MHK3SS</a>	\$362.00	padlocking	3	316 stainless steel	#4 brush	60in (H) or greater NEMA 4X	<a href="#">PDF</a>
<a href="#">MHKD3SS</a>	\$398.00	padlocking with defeater					<a href="#">PDF</a>
<a href="#">MHKL3SS</a>	\$398.00	combination keylocking/ padlocking					<a href="#">PDF</a>