

NEMA 3R, 4 and 12 Single-Door Wall Mount with 3-Point Handle



Applications

- Designed to enclose electrical and/or electronic equipment and protect against harsh, industrial environments for Wall Mount applications.
- Provides protection where equipment may be hosed down or otherwise be very wet, or in outdoor applications for full weather protection.
- Ideal for processing plants, utility, outdoor municipal or petro chemical locations where easy yet secure access is required.

- Seamless poured-in-place gasket.
- Collar studs provided for mounting subpanel.
- Bonding stud provided on door and grounding stud installed in enclosure.

Finish


- Cover and enclosure are finished in recoatable smooth ANSI 61 gray powder coating interior and exterior.

Listings

- UL 508A Type 3R, 4 and 12 [UL File E63524]
- CSA Type 3R, 4 and 12 [CSA File LR21001]
- Complies with
 - NEMA Type 3R, 4, 12 and 13
 - IEC 60529, IP66

Construction

- Formed 14 gauge steel bodies and doors.
- Continuously welded seams ground smooth.
- Formed lip on enclosure to exclude flowing liquids and contaminants.
- Powder coated black zinc diecast padlockable handle with 3-point roller latching system secures door.
- Door may be removed by pulling the stainless steel hinge pin

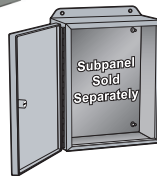

Shipping Schedule	
Same day	1 - 15 days
Color indicates shipping lead time in business days.	




NEMA 3R, 4 and 12 Single-Door Wall Mount with 3-Point Handle							
Part Number	Price	Enclosure Size HxWxD	Optional Subpanels				
			Painted	Perforated	Aluminum	Galvanized	Stainless
HW24168GYHK	\$350.00	24.00 x 16.00 x 9.21 [610 x 406 x 234]	18P2113	-	-	18G2113	18P2113S16
HW24206GYHK	\$359.00	24.00 x 20.00 x 7.21 [610 x 508 x 183]	18P2117	18P2117PP	18A2117	18G2117	18P2117S16
HW24208GYHK	\$377.00	24.00 x 20.00 x 9.21 [610 x 508 x 234]	18P2117	18P2117PP	18A2117	18G2117	18P2117S16
HW242010GYHK	\$395.00	24.00 x 20.00 x 11.21 [610 x 508 x 285]	18P2117	18P2117PP	18A2117	18G2117	18P2117S16
HW24246GYHK	\$388.00	24.00 x 24.00 x 7.21 [610 x 610 x 183]	18P2121	18P2121PP	18A2121	18G2121	18P2121S16
HW24248GYHK	\$407.00	24.00 x 24.00 x 9.21 [610 x 610 x 234]	18P2121	18P2121PP	18A2121	18G2121	18P2121S16
HW242412GYHK	\$446.00	24.00 x 24.00 x 13.21 [610 x 610 x 336]	18P2121	18P2121PP	18A2121	18G2121	18P2121S16
HW24308GYHK	\$455.00	24.00 x 30.00 x 9.21 [610 x 762 x 234]	18P2721	18P2721PP	18A2721	18G2121	18P2721S16
HW30208GYHK	\$432.00	30.00 x 20.00 x 9.21 [762 x 508 x 234]	18P2717	-	-	18G2717	18P2717S16
HW30248GYHK	\$455.00	30.00 x 24.00 x 9.21 [762 x 610 x 234]	18P2721	18P2721PP	18A2721	18G2721	18P2721S16
HW302410GYHK	\$478.00	30.00 x 24.00 x 11.21 [762 x 610 x 285]	18P2721	18P2721PP	18A2721	18G2721	18P2721S16
HW302412GYHK	\$499.00	30.00 x 24.00 x 13.21 [762 x 610 x 336]	18P2721	18P2721PP	18A2721	18G2721	18P2721S16
HW302416GYHK	\$558.00	30.00 x 24.00 x 17.21 [762 x 610 x 437]	18P2721	18P2721PP	18A2721	18G2721	18P2721S16
HW30308GYHK	\$509.00	30.00 x 30.00 x 9.21 [762 x 762 x 234]	18P2727	18P2727PP	-	18G2727	18P2727S16
HW36248GYHK	\$501.00	36.00 x 24.00 x 9.21 [914 x 610 x 234]	18P3321	18P3321PP	18A3321	18G3321	18P3321S16
HW362410GYHK	\$525.00	36.00 x 24.00 x 11.21 [914 x 610 x 285]	18P3321	18P3321PP	18A3321	18G3321	18P3321S16
HW36308GYHK	\$563.00	36.00 x 30.00 x 9.21 [914 x 762 x 234]	18P3327	18P3327PP	18A3327	18G3327	18P3327S16
HW363010GYHK	\$590.00	36.00 x 30.00 x 11.21 [914 x 762 x 285]	18P3327	18P3327PP	18A3327	18G3327	18P3327S16
HW363012GYHK	\$617.00	36.00 x 30.00 x 13.21 [914 x 762 x 336]	18P3327	18P3327PP	18A3327	18G3327	18P3327S16
HW363016GYHK	\$690.00	36.00 x 30.00 x 17.21 [914 x 762 x 437]	18P3327	18P3327PP	18A3327	18G3327	18P3327S16
HW363612GYHK	\$694.00	36.00 x 36.00 x 13.21 [914 x 914 x 336]	18P3333	18P3333PP	-	18G3333	18P3333S16
HW423010GYHK	\$665.00	42.00 x 30.00 x 11.21 [1067 x 762 x 285]	18P3927	-	-	18G3927	18P3927S16
HW42368GYHK	\$634.00	42.00 x 36.00 x 9.21 [1067 x 914 x 234]	18P3933	-	-	18G3933	18P3933S16
HW423612GYHK	\$762.00	42.00 x 36.00 x 13.21 [1067 x 914 x 336]	18P3933	-	-	18G3933	18P3933S16
HW48368GYHK	\$751.00	48.00 x 36.00 x 9.21 [1219 x 914 x 234]	18P4533	-	18A4533	18G4533	18P4533S16
HW483610GYHK	\$785.00	48.00 x 36.00 x 11.21 [1219 x 914 x 285]	18P4533	-	18A4533	18G4533	18P4533S16
HW483612GYHK	\$820.00	48.00 x 36.00 x 13.21 [1219 x 914 x 336]	18P4533	-	18A4533	18G4533	18P4533S16
HW483616GYHK	\$890.00	48.00 x 36.00 x 17.21 [1219 x 914 x 437]	18P4533	-	18A4533	18G4533	18P4533S16
HW603612GYHK	\$966.00	60.00 x 36.00 x 13.21 [1524 x 914 x 336]	18P5733	-	18A5733	18G5733	18P5733S16
HW603616GYHK	\$1,074.00	60.00 x 36.00 x 17.21 [1524 x 914 x 437]	18P5733	-	18A5733	18G5733	18P5733S16

Note: Dimensions in inches [millimeters].

NEMA 3R, 4 and 12 Single-Door Wall Mount with 3-Point Handle



Dimensions

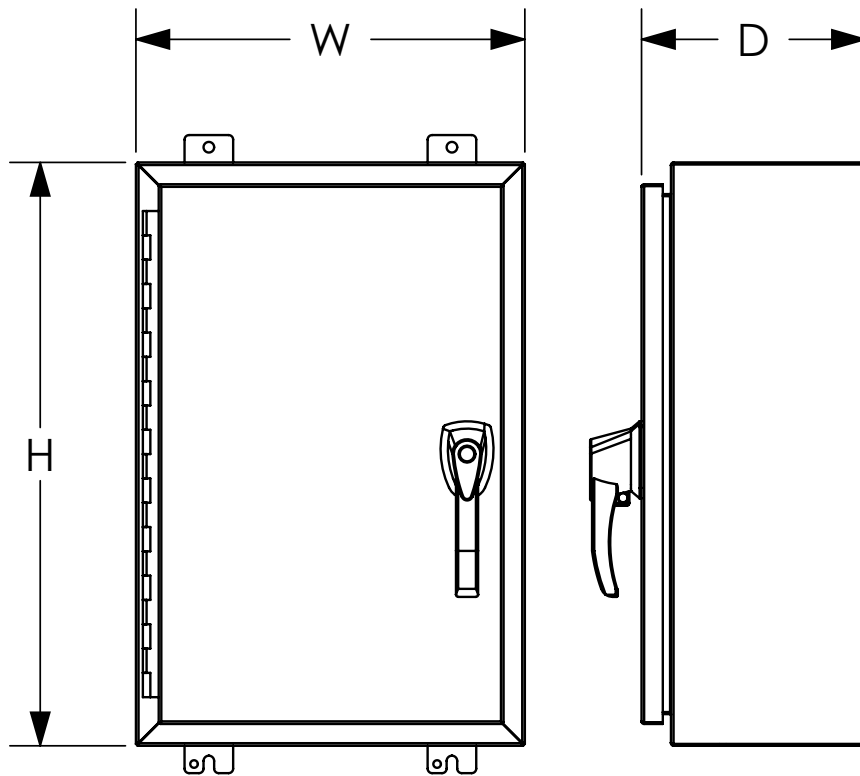

See our website: www.AutomationDirect.com for complete engineering drawings.