


# NEMA 3R, 4, 4X, 12, and 13 Stainless Steel Single-Door Freestanding

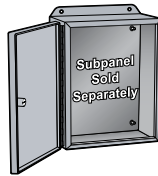

## Applications

- Designed to house electrical, electronic, hydraulic or pneumatic controls with provision for subpanel mounting or rack mounting of equipment.
- Provides protection where equipment may be hosed down or otherwise be very wet, or in specific applications where corrosion is a serious problem.
- A variety of subpanels, rack mounting rails and swing out frames are available to provide flexibility in mounting arrangements.

## Construction

- Formed 12-gauge 304 or 316 stainless steel.
- Smooth, continuously welded seams without knockouts, cutouts, or holes.
- Heavy duty stainless steel lifting eyebolts are provided with reinforcing support angles.
- Doors are supported with heavy gauge continuous hinges.
- Doors are secured with heavy duty stainless steel clamps.
- Seamless poured-in-place gasket.
- Mounting channels are welded on the inside of the enclosure for mounting of optional subpanels or rack equipment rails.
- A grounding stud is provided in the enclosure, and a bonding stud is provided on the door.

## Finish

- Cover and enclosure are natural stainless steel with a #4 smooth brushed finish.
- Optional subpanels are finished in RAL9003 white powder paint.

## Listings

- UL 508A Type 3R, 4, 4X, and 12 [UL File 65324]
- CSA Type 3R, 4, 4X, and 12 [CSA File LR21001]
- Complies with
  - NEMA Type 3R, 4, 4X, 12, and 13
  - IEC 60529, IP66



## Shipping Schedule

Same day	1 - 15 days
----------	-------------

Color indicates shipping lead time in business days.

## NEMA 3R, 4, 4X, 12, and 13 Stainless Steel Single-Door Freestanding

304 Stainless Steel	Price	316 Stainless Steel	Price	Enclosure Size HxWxD	Subpanels			Drawing Link	
					Steel	Galvanized			
						Full Height	Half Height		Subpanel HxW
<b>1418N4SSW18</b>	\$6,427.00	<b>1418N4S16W18</b>	\$8,396.00	72.06 x 24.06 x 19.26 [1830 x 611 x 489]	<b>72WFW</b>	<b>72WFWG</b>	<b>72WHWG</b>	60.00 x 20.00 [1524 x 508]	<a href="#">PDF</a>
<b>1418N4SSX24</b>	\$7,862.00	<b>1418N4S16X24</b>	\$10,265.00	72.06 x 30.06 x 25.26 [1830 x 764 x 642]	<b>72XFW</b>	<b>72XFWG</b>	<b>72XHWG</b>	60.00 x 26.00 [1524 x 660]	<a href="#">PDF</a>
<b>1418N4SSY24</b>	\$8,575.00	<b>1418N4S16Y24</b>	\$11,204.00	72.06 x 36.06 x 25.26 [1830 x 916 x 642]	<b>72YFW</b>	<b>72YFWG</b>	<b>72YHWG</b>	60.00 x 32.00 [1524 x 813]	<a href="#">PDF</a>

Note: Dimensions in inches [millimeters].

# NEMA 3R, 4, 4X, 12, and 13 Stainless Steel Single-Door Freestanding



## Dimensions

