
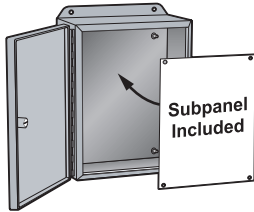


NEMA 3R, 4, 4X, 12 and 13 Stainless Steel Single-Door Wall Mount

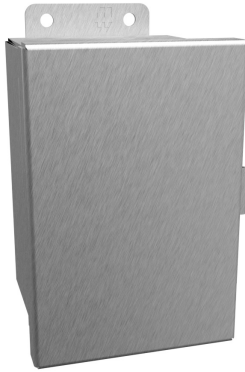

Applications

- Designed for use as instrument enclosures, electric, hydraulic or pneumatic control housings, electrical junction boxes or terminal wiring enclosures.
- Provides protection where equipment may be hosed down or otherwise be very wet, or in specific applications where corrosion may be a problem.

Construction

- Formed from 14 gauge 304 or 316 stainless steel.
- Smooth, continuously welded seams.
- Welded brackets provide for enclosure mounting.
- Continuous stainless steel hinged cover is secured with stainless steel clamps and screws.
- Seamless poured-in-place gasket.
- All models include a removable 14 gauge subpanel.
- Tapped studs are provided for mounting subpanels.
- A bonding stud is provided on the door, and a grounding stud is provided in the enclosure.

Finish

- Cover and enclosure are natural stainless steel with a #4 smooth brushed finish.
- Removable subpanel is finished in RAL 93 white powder coating.

Listings

- UL 508A Type 3R, 4, 4X, 12 and 13 [UL File E65324]
- CSA Type 3R, 4, 14X, 2 and 13 [CSA File LR21001]
- Complies with
 - NEMA Type 3R, 4, 4X, 12 and 13
 - IEC 60529, IP66



Shipping Schedule	
Same day	1 - 15 days
Color indicates shipping lead time in business days.	

NEMA 3R, 4, 4X , 12 and 13 Stainless Steel Single-Door Wall Mount						
304 Stainless Steel	Price	316 Stainless Steel	Price	Enclosure Size HxWxD	Included Subpanel	Subpanel HxW
1414N4PHSSC4	\$160.00	1414N4PHS16C4	\$197.00	6.31 x 4.31 x 4.20 [160 x 109 x 107]	14R0503	4.88 x 2.88in
1414N4PHSSE	\$175.00	1414N4PHS16E	\$221.00	6.31 x 6.31 x 4.20 [160 x 160 x 107]	14R0505	4.88 x 4.88in
1414N4PHSSG	\$197.00	1414N4PHS16G	\$245.00	8.31 x 6.31 x 3.70 [211 x 160 x 94]	14R0705	6.75 x 4.88in
1414N4PHSSG4	\$199.00	1414N4PHS16G4	\$251.00	8.31 x 6.31 x 4.20 [211 x 160 x 107]	14R0705	6.75 x 4.88in
1414N4PHSSI	\$241.00	1414N4PHS16I	\$304.00	10.31 x 8.31 x 4.20 [262 x 211 x 107]	14R0907	8.75 x 6.88in
1414N4PHSSK	\$335.00	1414N4PHS16K	\$425.00	12.31 x 10.31 x 5.20 [313 x 262 x 132]	14R1109	10.75 x 8.88in
1414N4PHSSK6	\$335.00	1414N4PHS16K6	\$425.00	12.31 x 10.31 x 6.20 [313 x 262 x 157]	14R1109	10.75 x 8.88in
1414N4PHSSL6	\$370.00	1414N4PHS16L6	\$470.00	12.31 x 12.31 x 6.20 [313 x 313 x 157]	14R1111	10.75 x 10.88in
1414N4PHSSM6	\$417.00	1414N4PHS16M6	\$515.00	14.31 x 12.31 x 6.20 [363 x 313 x 157]	14R1311	12.75 x 10.88in
1414N4PHSSM8	\$437.00	1414N4PHS16M8	\$527.00	14.31 x 12.31 x 8.20 [363 x 313 x 208]	14R1311	12.75 x 10.88in
1414N4PHSSO6	\$484.00	1414N4PHS16O6	\$615.00	16.31 x 14.31 x 6.20 [414 x 363 x 157]	14R1513	14.75 x 12.88in
1414N4PHSSO10	\$545.00	1414N4PHS16O10	\$670.00	16.31 x 14.31 x 10.20 [414 x 363 x 259]	14R1513	14.75 x 12.88in

Note: Dimensions in inches [millimeters].

NEMA 3R, 4, 4X, 12 and 13 Stainless Steel Single-Door Wall Mount




Shipping Schedule	
Same day	1 - 15 days
Color indicates shipping lead time in business days.	

NEMA 3R, 4, 4X , 12 and 13 Stainless Steel Single-Door Wall Mount				
Enclosures		Optional Subpanels		
304 Stainless Steel	316 Stainless Steel	Aluminum	Galvanized	Stainless
1414N4PHSSC4	1414N4PHS16C4	14A0503	14G0503	14R0503SS
1414N4PHSSE	1414N4PHS16E	14A0505	14G0505	14R0505SS
1414N4PHSSG	1414N4PHS16G	14A0705	14G0705	14R0705SS
1414N4PHSSG4	1414N4PHS16G4	14A0705	14G0705	14R0705SS
1414N4PHSSI	1414N4PHS16I	14A0907	14G0907	14R0907SS
1414N4PHSSK	1414N4PHS16K	14A1109	14G1109	14R1109SS
1414N4PHSSK6	1414N4PHS16K6	14A1109	14G1109	14R1109SS
1414N4PHSSL6	1414N4PHS16L6	14A1111	14G1111	14R1111SS
1414N4PHSSM6	1414N4PHS16M6	14A1311	14G1311	14R1311SS
1414N4PHSSM8	1414N4PHS16M8	14A1311	14G1311	14R1311SS
1414N4PHSSO6	1414N4PHS16O6	14A1513	14G1513	14R1513SS
1414N4PHSSO10	1414N4PHS16O10	14A1513	14G1513	14R1513SS

NEMA 3R, 4, 4X, 12 and 13 Stainless Steel Single-Door Wall Mount



Dimensions

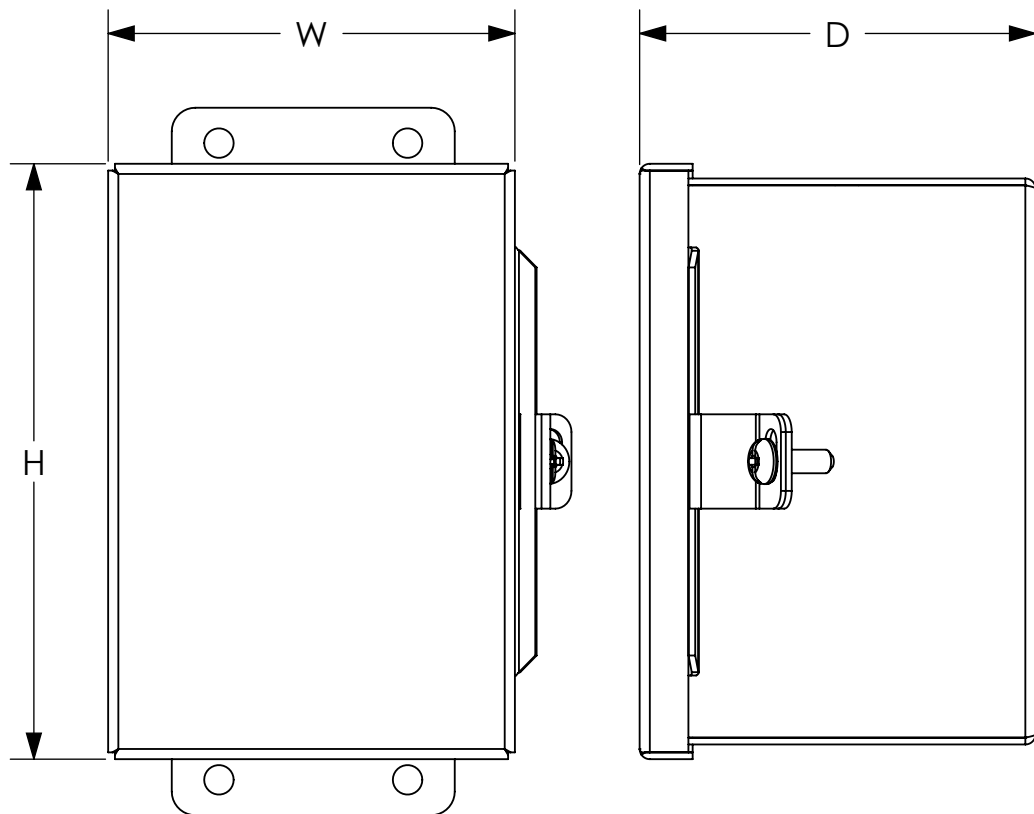

See our website: www.AutomationDirect.com for complete engineering drawings.