

NEMA 3R, 4, 4X, 12, and 13 Stainless Steel Single-Door Freestanding with 3-Point Handle



Applications

- Designed to house electrical, electronic, hydraulic or pneumatic controls with provision for subpanel mounting or rack mounting of equipment.
- Provides protection where equipment may be hosed down or otherwise be very wet, or in specific applications where corrosion is a serious problem.
- A variety of subpanels, rack mounting rails and swing out frames are available to provide flexibility in mounting arrangements.

Construction

- Formed 12-gauge 304 stainless steel.
- Smooth, continuously welded seams without knockouts, cutouts, or holes.
- Heavy duty stainless steel lifting eyebolts are provided with reinforcing support angles.
- Doors are supported with heavy gauge continuous hinges.
- 3-point padlocking door handle.
- Uses 1/4 turn latch handles.
- Seamless poured-in-place gasket.
- A grounding stud is provided in the enclosure, and a bonding stud is provided on the door.
- Mounting channels are welded on the inside of the enclosure for mounting of optional subpanels or rack equipment rails.

Finish

- Cover and enclosure are natural stainless steel with a #4 smooth brushed finish.
- Optional subpanels are finished in RAL9003 white powder paint.

Listings

- UL 508A Type 3R, 4, 4X, and 12 [UL File E65324]
- CSA Type 3R, 4, 4X, and 12 [CSA File LR21001]
- Complies with
 - NEMA Type 3R, 4, 4X, 12, and 13
 - IEC 60529, IP66



NEMA 3R, 4, 4X, 12, and 13 Stainless Steel Single-Door Freestanding with 3-Point Handle Front Access

304 Stainless Steel	Price	316 Stainless Steel	Price	Enclosure Size HxWxD	Optional Subpanels		Drawing Link
					Painted	Galvanized	
HN4FS602418SS	\$3,674.00	HN4FS602418S16	\$4,589.00	60.06 x 24.06 x 19.26 [1526 x 611 x 489]	60TWFW	60TWFWG	PDF
HN4FS603624SS	\$4,900.00	HN4FS603624S16	\$6,118.00	60.06 x 36.06 x 25.26 [1526 x 916 x 642]	60TYFW	60TYFWG	PDF
HN4FS722418SS	\$4,096.00	HN4FS722418S16	\$5,113.00	72.06 x 24.06 x 19.26 [1830 x 611 x 489]	72WFW	72WFWG	PDF
HN4FS722424SS	\$4,548.00	HN4FS722424S16	\$5,678.00	72.06 x 24.06 x 25.26 [1830 x 611 x 642]	72WFW	72WFWG	PDF
HN4FS723018SS	\$4,500.00	HN4FS723018S16	\$5,625.00	72.06 x 30.06 x 19.26 [1830 x 764 x 489]	72XFW	72XFWG	PDF
HN4FS723024SS	\$4,992.00	HN4FS723024S16	\$6,239.00	72.06 x 30.06 x 25.26 [1830 x 764 x 642]	72XFW	72XFWG	PDF
HN4FS723618SS	\$4,930.00	HN4FS723618S16	\$6,162.00	72.06 x 36.06 x 19.26 [1830 x 916 x 489]	72YFW	72YFWG	PDF
HN4FS723624SS	\$5,443.00	HN4FS723624S16	\$6,803.00	72.06 x 36.06 x 25.26 [1830 x 916 x 642]	72YFW	72YFWG	PDF
HN4FS723630SS	\$5,991.00	HN4FS723630S16	\$7,479.00	72.06 x 36.06 x 31.26 [1830 x 916 x 794]	72YFW	72YFWG	PDF
HN4FS723636SS	\$6,514.00	HN4FS723636S16	\$8,123.00	72.06 x 36.06 x 37.26 [1830 x 916 x 946]	72YFW	72YFWG	PDF
HN4FS902420SS	\$4,883.00	HN4FS902420S16	\$6,096.00	90.06 x 24.06 x 21.26 [2288 x 611 x 540]	90YFW	90YFWG	PDF
HN4FS903620SS	\$5,908.00	HN4FS903620S16	\$7,379.00	90.06 x 36.06 x 21.26 [2288 x 916 x 540]	90YFW	90YFWG	PDF
HN4FS903624SS	\$6,316.00	HN4FS903624S16	\$7,886.00	90.06 x 36.06 x 25.26 [2288 x 916 x 642]	90YFW	90YFWG	PDF
HN4FS903636SS	\$7,547.00	HN4FS903636S16	\$9,416.00	90.06 x 36.06 x 37.26 [2288 x 916 x 946]	90YFW	90YFWG	PDF

Note: Dimensions in inches [millimeters].

Table continued on next page

NEMA 3R, 4, 4X, 12, and 13 Stainless Steel Single-Door Freestanding with 3-Point Handle



Table continued from previous page


NEMA 3R, 4, 4X, 12, and 13 Stainless Steel Single-Door Freestanding with 3-Point Handle Dual Access							
304 Stainless	Price	316 Stainless	Price	Enclosure Size HxWxD	Optional Subpanels		Drawing Link
					Painted	Galvanized	
HN4FS722430DASS	\$5,810.00	HN4FS722430DS16	\$7,255.00	72.06 x 24.06 x 32.46 [1830 x 611 x 824]	72WFW	72WFWG	PDF
HN4FS722436DASS	\$6,347.00	HN4FS722436DS16	\$7,928.00	72.06 x 24.06 x 38.46 [1830 x 611 x 977]	72WFW	72WFWG	PDF
HN4FS722424DASS	\$5,277.00	HN4FS722424DS16	\$6,589.00	72.06 x 24.06 x 26.46 [1830 x 611 x 672]	72YFW	72YFWG	PDF
HN4FS723024DASS	\$5,810.00	HN4FS723024DS16	\$7,255.00	72.06 x 30.06 x 26.46 [1830 x 764 x 672]	72YFW	72YFWG	PDF
HN4FS723624DASS	\$6,347.00	HN4FS723624DS16	\$7,928.00	72.06 x 36.06 x 26.46 [1830 x 916 x 672]	72YFW	72YFWG	PDF
HN4FS723636DASS	\$7,543.00	HN4FS723636DS16	\$9,420.00	72.06 x 36.06 x 38.46 [1830 x 916 x 977]	72YFW	72YFWG	PDF
HN4FS903624DASS	\$7,353.00	HN4FS903624DS16	\$9,184.00	90.06 x 36.06 x 26.46 [2288 x 916 x 672]	90YFW	90YFWG	PDF
HN4FS903636DASS	\$8,740.00	HN4FS903636DS16	\$10,916.00	90.06 x 36.06 x 38.46 [2288 x 916 x 977]	90YFW	90YFWG	PDF

Note: Dimensions in inches [millimeters].

NEMA 3R, 4, 4X, 12, and 13 Stainless Steel Single-Door Freestanding with 3-Point Handle



Dimensions

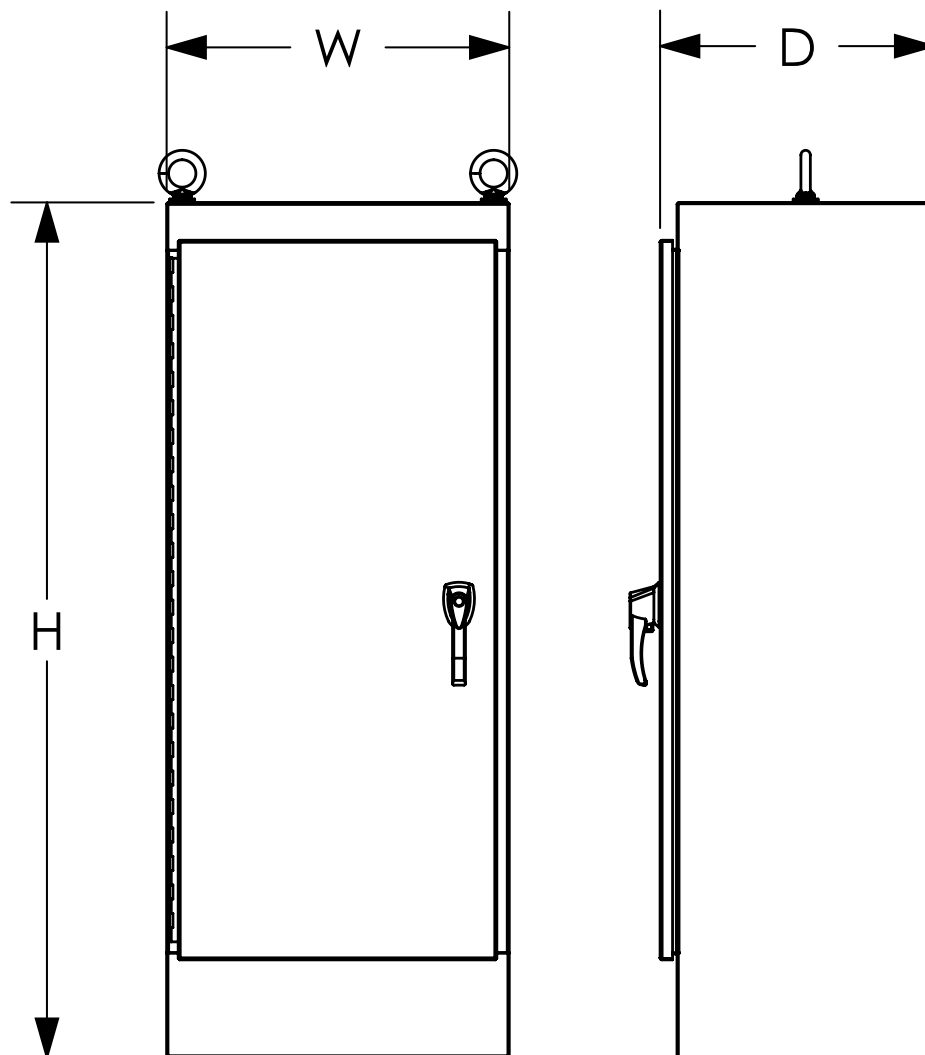

Enclosure Accessories

Locks and Latches



1/4-Turn Latch Handles



Features

- Durable zinc diecast or stainless steel.
- Removable handle stop for clockwise / counter-clockwise operation.
- Textured powder coat Black finish on zinc cast handle.
- Maintains NEMA rating of enclosure.
- Padlock "trigger" design for security requirements.
- Optional key lock or defeater available. Key lock versions include two keys.

1/4-Turn Latch Handles							
Part Number	Price	Security Type	Latch Points	Material	Finish	For Use With These Hammond Enclosures Only	Drawing Link
MHK1	\$127.00	padlocking	1	die-cast zinc	black matte	single-door NEMA 4 and NEMA 12	PDF
MHKD1	\$133.00	padlocking with defeater					PDF
MHKL1	\$144.00	combination keylocking/ padlocking					PDF
MHK2	\$217.00	padlocking	3	die-cast zinc	black matte	less than 60in (H) NEMA 4 and NEMA 12	PDF
MHKD2	\$228.00	padlocking with defeater					PDF
MHKL2	\$246.00	combination keylocking/ padlocking					PDF
MHK3	\$221.00	padlocking	3	die-cast zinc	black matte	60in (H) or greater NEMA 4 and NEMA 12	PDF
MHKD3	\$232.00	padlocking with defeater					PDF
MHKL3	\$251.00	combination keylocking/ padlocking					PDF
MHK1SS	\$234.00	padlocking	1	316 stainless steel	#4 brush	single-door NEMA 4X	PDF
MHKD1SS	\$258.00	padlocking with defeater					PDF
MHKL1SS	\$258.00	combination keylocking/ padlocking					PDF
MHK2SS	\$249.00	padlocking	3	316 stainless steel	#4 brush	less than 60in (H) NEMA 4X	PDF
MHKD2SS	\$274.00	padlocking with defeater					PDF
MHKL2SS	\$274.00	combination keylocking/ padlocking					PDF
MHK3SS	\$362.00	padlocking	3	316 stainless steel	#4 brush	60in (H) or greater NEMA 4X	PDF
MHKD3SS	\$398.00	padlocking with defeater					PDF
MHKL3SS	\$398.00	combination keylocking/ padlocking					PDF