

# Enclosure Subpanels


## Eclipse Series Enclosures



### Construction

- Larger than standard NEMA panel used in same sized enclosure.
- 12-gauge steel construction.
- Larger sizes have 2 or 4 formed flanges for added strength.
- Slotted corner design for easier mounting.
- Finished in RAL9003 white powder coat or unpainted galvanized.

### Dimensions

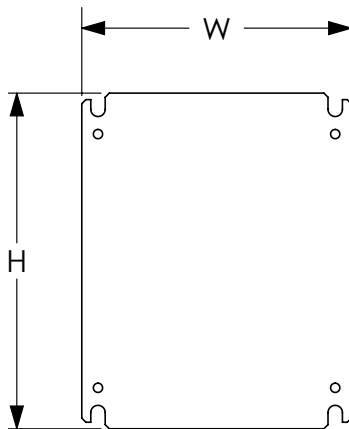

Subpanels for Eclipse Series Hammond Enclosures					
Painted	Price	Galvanized	Price	Dimensions HxW	Drawing Link
<a href="#">EP1210</a>	\$17.25	<a href="#">EPG1210</a>	\$17.75	10.17 x 8.17 [258 x 208]	<a href="#">PDF</a>
<a href="#">EP1212</a>	\$17.25	<a href="#">EPG1212</a>	\$13.25	10.17 x 10.17 [258 x 258]	<a href="#">PDF</a>
<a href="#">EP1224</a>	\$54.00	<a href="#">EPG1224</a>	\$54.00	10.17 x 22.17 [258 x 563]	<a href="#">PDF</a>
<a href="#">EP1612</a>	\$22.50	<a href="#">EPG1612</a>	\$17.00	14.17 x 10.17 [360 x 258]	<a href="#">PDF</a>
<a href="#">EP1616</a>	\$43.00	<a href="#">EPG1616</a>	\$43.00	14.17 x 14.17 [360 x 360]	<a href="#">PDF</a>
<a href="#">EP1620</a>	\$49.50	<a href="#">EPG1620</a>	\$49.50	14.17 x 18.17 [360 x 462]	<a href="#">PDF</a>
<a href="#">EP2012</a>	\$40.00	<a href="#">EPG2012</a>	\$49.50	18.17 x 10.17 [462 x 258]	<a href="#">PDF</a>
<a href="#">EP2016</a>	\$49.50	<a href="#">EPG2016</a>	\$49.50	18.17 x 14.17 [462 x 360]	<a href="#">PDF</a>
<a href="#">EP2020</a>	\$59.00	<a href="#">EPG2020</a>	\$59.00	18.17 x 18.17 [462 x 462]	<a href="#">PDF</a>
<a href="#">EP2024</a>	\$76.00	<a href="#">EPG2024</a>	\$76.00	18.17 x 22.17 [462 x 563]	<a href="#">PDF</a>
<a href="#">EP2412</a>	\$54.00	<a href="#">EPG2412</a>	\$54.00	22.17 x 10.17 [563 x 258]	<a href="#">PDF</a>
<a href="#">EP2416</a>	\$59.00	<a href="#">EPG2416</a>	\$59.00	22.17 x 14.17 [563 x 360]	<a href="#">PDF</a>
<a href="#">EP2420</a>	\$76.00	<a href="#">EPG2420</a>	\$76.00	22.17 x 18.17 [563 x 462]	<a href="#">PDF</a>
<a href="#">EP2424</a>	\$88.00	<a href="#">EPG2424</a>	\$88.00	22.17 x 22.17 [563 x 563]	<a href="#">PDF</a>
<a href="#">EP2430</a>	\$110.00	<a href="#">EPG2430</a>	\$110.00	22.17 x 28.17 [563 x 716]	<a href="#">PDF</a>
<a href="#">EP2442</a>	\$150.00	<a href="#">EPG2442</a>	\$150.00	22.17 x 40.17 [563 x 1020]	<a href="#">PDF</a>
<a href="#">EP2448</a>	\$169.00	<a href="#">EPG2448</a>	\$169.00	22.17 x 46.17 [563 x 1173]	<a href="#">PDF</a>
<a href="#">EP3012</a>	\$67.00	<a href="#">EPG3012</a>	\$67.00	28.17 x 10.17 [716 x 258]	<a href="#">PDF</a>
<a href="#">EP3016</a>	\$81.00	<a href="#">EPG3016</a>	\$81.00	28.17 x 14.17 [716 x 360]	<a href="#">PDF</a>
<a href="#">EP3020</a>	\$95.00	<a href="#">EPG3020</a>	\$95.00	28.17 x 18.17 [716 x 462]	<a href="#">PDF</a>
<a href="#">EP3024</a>	\$110.00	<a href="#">EPG3024</a>	\$110.00	28.17 x 22.17 [716 x 563]	<a href="#">PDF</a>
<a href="#">EP3030</a>	\$144.00	<a href="#">EPG3030</a>	\$144.00	28.17 x 28.17 [716 x 716]	<a href="#">PDF</a>
<a href="#">EP3036</a>	\$167.00	<a href="#">EPG3036</a>	\$167.00	28.17 x 34.17 [716 x 868]	<a href="#">PDF</a>
<a href="#">EP3042</a>	\$195.00	<a href="#">EPG3042</a>	\$195.00	28.17 x 40.17 [716 x 1020]	<a href="#">PDF</a>
<a href="#">EP3048</a>	\$219.00	<a href="#">EPG3048</a>	\$219.00	28.17 x 46.17 [716 x 1173]	<a href="#">PDF</a>
<a href="#">EP3060</a>	\$265.00	<a href="#">EPG3060</a>	\$265.00	28.17 x 58.17 [716 x 1478]	<a href="#">PDF</a>
<a href="#">EP3624</a>	\$128.00	<a href="#">EPG3624</a>	\$128.00	34.17 x 22.17 [868 x 563]	<a href="#">PDF</a>
<a href="#">EP3630</a>	\$167.00	<a href="#">EPG3630</a>	\$167.00	34.17 x 28.17 [868 x 716]	<a href="#">PDF</a>
<a href="#">EP3636</a>	\$195.00	<a href="#">EPG3636</a>	\$195.00	34.17 x 34.17 [868 x 868]	<a href="#">PDF</a>
<a href="#">EP3642</a>	\$227.00	<a href="#">EPG3642</a>	\$227.00	34.17 x 40.17 [868 x 1020]	<a href="#">PDF</a>
<a href="#">EP3648</a>	\$250.00	<a href="#">EPG3648</a>	\$250.00	34.17 x 46.17 [868 x 1173]	<a href="#">PDF</a>
<a href="#">EP3660</a>	\$306.00	<a href="#">EPG3660</a>	\$306.00	34.17 x 58.17 [868 x 1478]	<a href="#">PDF</a>
<a href="#">EP4224</a>	\$148.00	<a href="#">EPG4224</a>	\$147.00	40.17 x 22.17 [1020 x 563]	<a href="#">PDF</a>
<a href="#">EP4230</a>	\$195.00	<a href="#">EPG4230</a>	\$195.00	40.17 x 28.17 [1020 x 716]	<a href="#">PDF</a>
<a href="#">EP4236</a>	\$227.00	<a href="#">EPG4236</a>	\$227.00	40.17 x 34.17 [1020 x 868]	<a href="#">PDF</a>
<a href="#">EP4824</a>	\$169.00	<a href="#">EPG4824</a>	\$169.00	46.17 x 22.17 [1173 x 563]	<a href="#">PDF</a>
<a href="#">EP4830</a>	\$212.00	<a href="#">EPG4830</a>	\$212.00	46.17 x 28.17 [1173 x 716]	<a href="#">PDF</a>
<a href="#">EP4836</a>	\$250.00	<a href="#">EPG4836</a>	\$250.00	46.17 x 34.17 [1173 x 868]	<a href="#">PDF</a>
<a href="#">EP4848</a>	\$302.00	<a href="#">EPG4848</a>	\$302.00	46.17 x 46.17 [1173 x 1173]	<a href="#">PDF</a>
<a href="#">EP6036</a>	\$306.00	<a href="#">EPG6036</a>	\$306.00	58.17 x 34.17 [1478 x 868]	<a href="#">PDF</a>
<a href="#">EP7230</a>	\$332.00	<a href="#">EPG7230</a>	\$332.00	70.17 x 28.17 [1782 x 716]	<a href="#">PDF</a>
<a href="#">EP7236</a>	\$366.00	<a href="#">EPG7236</a>	\$368.00	70.17 x 34.17 [1782 x 868]	<a href="#">PDF</a>

Note: Dimensions in inches [millimeters].

# Eclipse Series Swing Panel Kits



## Construction


- Hinged panel allows access to internally mounted equipment.
- 12-gauge steel panel included.
- Slotted 1/4-turn latches provide closure.
- Adding optional locking 1/4-turn latches (Part Number EQTRL) convert this to a dead front panel.
- Complete with 4- 6 in [102-152 mm] depth adjustment channels.
- Hardware kit maintains UL, CSA and NEMA ratings when field installed.
- Finished in RAL9003 white powder coat.



Swing Panel Kits - Eclipse Series				
Part Number	Price	Dimensions HxW	For Use With	Drawing Link
<a href="#">ESP1212</a>	\$143.00	9.75 x 9.79 [248 x 249]	12x12 (HxW) EN4SD12126xx & ST12126LG	<a href="#">PDF</a>
<a href="#">ESP1612</a>	\$148.00	13.75 x 9.79 [349 x 249]	16x12 (HxW) EN4SD1612xxx & ST1612xxx	<a href="#">PDF</a>
<a href="#">ESP1616</a>	\$156.00	13.75 x 13.79 [349 x 350]	16x16 (HxW) EN4SD1616xxx & ST1616xxx	<a href="#">PDF</a>
<a href="#">ESP1620</a>	\$165.00	13.75 x 17.79 [349 x 452]	16x20 (HxW) EN4SD1620xxx	<a href="#">PDF</a>
<a href="#">ESP2016</a>	\$165.00	17.75 x 13.79 [451 x 350]	20x16 (HxW) EN4SD2016xxx & ST2016xxx	<a href="#">PDF</a>
<a href="#">ESP2020</a>	\$173.00	17.75 x 17.79 [451 x 452]	20x20 (HxW) EN4SD2020xxx & ST2020xxx	<a href="#">PDF</a>
<a href="#">ESP2416</a>	\$172.00	21.75 x 13.79 [552 x 350]	24x16 (HxW) EN4SD2416xxx	<a href="#">PDF</a>
<a href="#">ESP2024</a>	\$184.00	17.75 x 21.79 [451 x 553]	20x24 (HxW) EN4SD2024xxx	<a href="#">PDF</a>
<a href="#">ESP2420</a>	\$184.00	21.75 x 17.79 [552 x 452]	24x20 (HxW) EN4SD2420xxx & ST2420xxx	<a href="#">PDF</a>
<a href="#">ESP2424</a>	\$196.00	21.75 x 21.79 [552 x 553]	24x24 (HxW) EN4SD2424xxx & ST2424xxx	<a href="#">PDF</a>
<a href="#">ESP3020</a>	\$198.00	27.75 x 17.79 [705 x 452]	30x20 (HxW) EN4SD3020xxx	<a href="#">PDF</a>
<a href="#">ESP3024</a>	\$212.00	27.75 x 21.79 [705 x 553]	30x24 (HxW) EN4SD3024xxx & ST3024xxx	<a href="#">PDF</a>
<a href="#">ESP3624</a>	\$232.00	33.75 x 21.79 [857 x 553]	36x24 (HxW) EN4SD3624xxx	<a href="#">PDF</a>
<a href="#">ESP3030</a>	\$235.00	27.75 x 27.79 [705 x 706]	30x30 (HxW) EN4SD3030xxx & ST3030xxx	<a href="#">PDF</a>
<a href="#">ESP4824</a>	\$250.00	45.75 x 21.79 [1162 x 553]	48x24 (HxW) EN4SD4824xxx	<a href="#">PDF</a>
<a href="#">ESP3630</a>	\$257.00	33.75 x 27.79 [857 x 706]	36x30 (HxW) EN4SD3630xxx & ST3630xxx	<a href="#">PDF</a>
<a href="#">ESP3636</a>	\$285.00	33.75 x 33.79 [857 x 858]	36x36 (HxW) EN4SD3636xxx & ST363612xx	<a href="#">PDF</a>
<a href="#">ESP4236</a>	\$313.00	39.75 x 33.79 [1010 x 858]	42x36 (HxW) EN4SD4236xxx	<a href="#">PDF</a>
<a href="#">ESP4836</a>	\$358.00	45.75 x 33.79 [1162 x 858]	48x36 (HxW) EN4SD4836xxx & ST4836xxxx	<a href="#">PDF</a>
<a href="#">ESP6036</a>	\$423.00	57.75 x 33.79 [1467 x 858]	60x36 (HxW) EN4SD6036xxx & ST6036xxxx	<a href="#">PDF</a>

Note: Dimensions in inches [millimeters].

## Dimensions

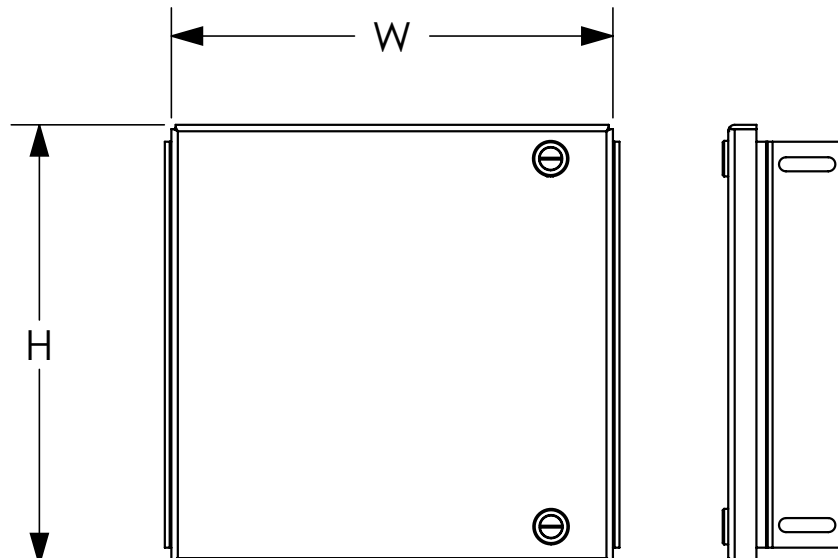

# Eclipse Series Swing Frame



## Construction

- Provides 19 in [483 mm] rack mounting with full EIA spacing (punched holes).
- Hinges allow easy equipment access.
- Slotted 1/4-turn latches provide closure.
- Optional locking 1/4-turn latch available by ordering Part No. EQTRL
- Adding optional locking 1/4-turn latches provides added security.
- Complete with 4- 6 in [102-152 mm] depth adjustment channels.
- Mounting hardware sold separately.
- Hardware kit maintains UL, CSA and NEMA ratings when field installed.
- Finished in black powder coat.

Eclipse Swing Frame					
Part Number	Price	For Use With	Rack Spacing Width	Rack Units	Drawing Link
<b>ESF2424</b>	\$287.00	24x24in	19.00in	11U	<a href="#">PDF</a>
<b>ESF3024</b>	\$371.00	30x24in	19.00in	14U	<a href="#">PDF</a>
<b>ESF3624</b>	\$426.00	36x24in	19.00in	17U	<a href="#">PDF</a>

## Dimensions

