

Enclosure Subpanels


Eclipse Series Enclosures



Construction

- Larger than standard NEMA panel used in same sized enclosure.
- 12-gauge steel construction.
- Larger sizes have 2 or 4 formed flanges for added strength.
- Slotted corner design for easier mounting.
- Finished in RAL9003 white powder coat or unpainted galvanized.

Dimensions

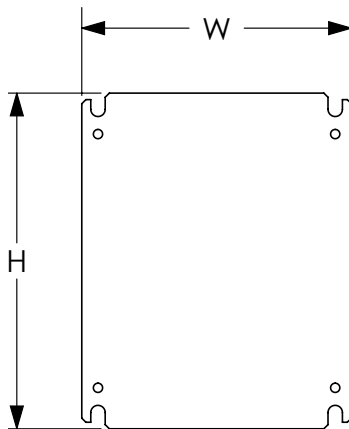

Subpanels for Eclipse Series Hammond Enclosures					
Painted	Price	Galvanized	Price	Dimensions HxW	Drawing Link
EP1210	\$17.25	EPG1210	\$17.75	10.17 x 8.17 [258 x 208]	PDF
EP1212	\$17.25	EPG1212	\$13.25	10.17 x 10.17 [258 x 258]	PDF
EP1224	\$54.00	EPG1224	\$54.00	10.17 x 22.17 [258 x 563]	PDF
EP1612	\$22.50	EPG1612	\$17.00	14.17 x 10.17 [360 x 258]	PDF
EP1616	\$43.00	EPG1616	\$43.00	14.17 x 14.17 [360 x 360]	PDF
EP1620	\$49.50	EPG1620	\$49.50	14.17 x 18.17 [360 x 462]	PDF
EP2012	\$40.00	EPG2012	\$49.50	18.17 x 10.17 [462 x 258]	PDF
EP2016	\$49.50	EPG2016	\$49.50	18.17 x 14.17 [462 x 360]	PDF
EP2020	\$59.00	EPG2020	\$59.00	18.17 x 18.17 [462 x 462]	PDF
EP2024	\$76.00	EPG2024	\$76.00	18.17 x 22.17 [462 x 563]	PDF
EP2412	\$54.00	EPG2412	\$54.00	22.17 x 10.17 [563 x 258]	PDF
EP2416	\$59.00	EPG2416	\$59.00	22.17 x 14.17 [563 x 360]	PDF
EP2420	\$76.00	EPG2420	\$76.00	22.17 x 18.17 [563 x 462]	PDF
EP2424	\$88.00	EPG2424	\$88.00	22.17 x 22.17 [563 x 563]	PDF
EP2430	\$110.00	EPG2430	\$110.00	22.17 x 28.17 [563 x 716]	PDF
EP2442	\$150.00	EPG2442	\$150.00	22.17 x 40.17 [563 x 1020]	PDF
EP2448	\$169.00	EPG2448	\$169.00	22.17 x 46.17 [563 x 1173]	PDF
EP3012	\$67.00	EPG3012	\$67.00	28.17 x 10.17 [716 x 258]	PDF
EP3016	\$81.00	EPG3016	\$81.00	28.17 x 14.17 [716 x 360]	PDF
EP3020	\$95.00	EPG3020	\$95.00	28.17 x 18.17 [716 x 462]	PDF
EP3024	\$110.00	EPG3024	\$110.00	28.17 x 22.17 [716 x 563]	PDF
EP3030	\$144.00	EPG3030	\$144.00	28.17 x 28.17 [716 x 716]	PDF
EP3036	\$167.00	EPG3036	\$167.00	28.17 x 34.17 [716 x 868]	PDF
EP3042	\$195.00	EPG3042	\$195.00	28.17 x 40.17 [716 x 1020]	PDF
EP3048	\$219.00	EPG3048	\$219.00	28.17 x 46.17 [716 x 1173]	PDF
EP3060	\$265.00	EPG3060	\$265.00	28.17 x 58.17 [716 x 1478]	PDF
EP3624	\$128.00	EPG3624	\$128.00	34.17 x 22.17 [868 x 563]	PDF
EP3630	\$167.00	EPG3630	\$167.00	34.17 x 28.17 [868 x 716]	PDF
EP3636	\$195.00	EPG3636	\$195.00	34.17 x 34.17 [868 x 868]	PDF
EP3642	\$227.00	EPG3642	\$227.00	34.17 x 40.17 [868 x 1020]	PDF
EP3648	\$250.00	EPG3648	\$250.00	34.17 x 46.17 [868 x 1173]	PDF
EP3660	\$306.00	EPG3660	\$306.00	34.17 x 58.17 [868 x 1478]	PDF
EP4224	\$148.00	EPG4224	\$147.00	40.17 x 22.17 [1020 x 563]	PDF
EP4230	\$195.00	EPG4230	\$195.00	40.17 x 28.17 [1020 x 716]	PDF
EP4236	\$227.00	EPG4236	\$227.00	40.17 x 34.17 [1020 x 868]	PDF
EP4824	\$169.00	EPG4824	\$169.00	46.17 x 22.17 [1173 x 563]	PDF
EP4830	\$212.00	EPG4830	\$212.00	46.17 x 28.17 [1173 x 716]	PDF
EP4836	\$250.00	EPG4836	\$250.00	46.17 x 34.17 [1173 x 868]	PDF
EP4848	\$302.00	EPG4848	\$302.00	46.17 x 46.17 [1173 x 1173]	PDF
EP6036	\$306.00	EPG6036	\$306.00	58.17 x 34.17 [1478 x 868]	PDF
EP7230	\$332.00	EPG7230	\$332.00	70.17 x 28.17 [1782 x 716]	PDF
EP7236	\$366.00	EPG7236	\$368.00	70.17 x 34.17 [1782 x 868]	PDF

Note: Dimensions in inches [millimeters].

Eclipse Series Swing Panel Kits



Construction


- Hinged panel allows access to internally mounted equipment.
- 12-gauge steel panel included.
- Slotted 1/4-turn latches provide closure.
- Adding optional locking 1/4-turn latches (Part Number EQTRL) convert this to a dead front panel.
- Complete with 4- 6 in [102-152 mm] depth adjustment channels.
- Hardware kit maintains UL, CSA and NEMA ratings when field installed.
- Finished in RAL9003 white powder coat.



Swing Panel Kits - Eclipse Series				
Part Number	Price	Dimensions HxW	For Use With	Drawing Link
ESP1212	\$143.00	9.75 x 9.79 [248 x 249]	12x12 (HxW) EN4SD12126xx & ST12126LG	PDF
ESP1612	\$148.00	13.75 x 9.79 [349 x 249]	16x12 (HxW) EN4SD1612xxx & ST1612xxx	PDF
ESP1616	\$156.00	13.75 x 13.79 [349 x 350]	16x16 (HxW) EN4SD1616xxx & ST1616xxx	PDF
ESP1620	\$165.00	13.75 x 17.79 [349 x 452]	16x20 (HxW) EN4SD1620xxx	PDF
ESP2016	\$165.00	17.75 x 13.79 [451 x 350]	20x16 (HxW) EN4SD2016xxx & ST2016xxx	PDF
ESP2020	\$173.00	17.75 x 17.79 [451 x 452]	20x20 (HxW) EN4SD2020xxx & ST2020xxx	PDF
ESP2416	\$172.00	21.75 x 13.79 [552 x 350]	24x16 (HxW) EN4SD2416xxx	PDF
ESP2024	\$184.00	17.75 x 21.79 [451 x 553]	20x24 (HxW) EN4SD2024xxx	PDF
ESP2420	\$184.00	21.75 x 17.79 [552 x 452]	24x20 (HxW) EN4SD2420xxx & ST2420xxx	PDF
ESP2424	\$196.00	21.75 x 21.79 [552 x 553]	24x24 (HxW) EN4SD2424xxx & ST2424xxx	PDF
ESP3020	\$198.00	27.75 x 17.79 [705 x 452]	30x20 (HxW) EN4SD3020xxx	PDF
ESP3024	\$212.00	27.75 x 21.79 [705 x 553]	30x24 (HxW) EN4SD3024xxx & ST3024xxx	PDF
ESP3624	\$232.00	33.75 x 21.79 [857 x 553]	36x24 (HxW) EN4SD3624xxx	PDF
ESP3030	\$235.00	27.75 x 27.79 [705 x 706]	30x30 (HxW) EN4SD3030xxx & ST3030xxx	PDF
ESP4824	\$250.00	45.75 x 21.79 [1162 x 553]	48x24 (HxW) EN4SD4824xxx	PDF
ESP3630	\$257.00	33.75 x 27.79 [857 x 706]	36x30 (HxW) EN4SD3630xxx & ST3630xxx	PDF
ESP3636	\$285.00	33.75 x 33.79 [857 x 858]	36x36 (HxW) EN4SD3636xxx & ST363612xx	PDF
ESP4236	\$313.00	39.75 x 33.79 [1010 x 858]	42x36 (HxW) EN4SD4236xxx	PDF
ESP4836	\$358.00	45.75 x 33.79 [1162 x 858]	48x36 (HxW) EN4SD4836xxx & ST4836xxxx	PDF
ESP6036	\$423.00	57.75 x 33.79 [1467 x 858]	60x36 (HxW) EN4SD6036xxx & ST6036xxxx	PDF

Note: Dimensions in inches [millimeters].

Dimensions

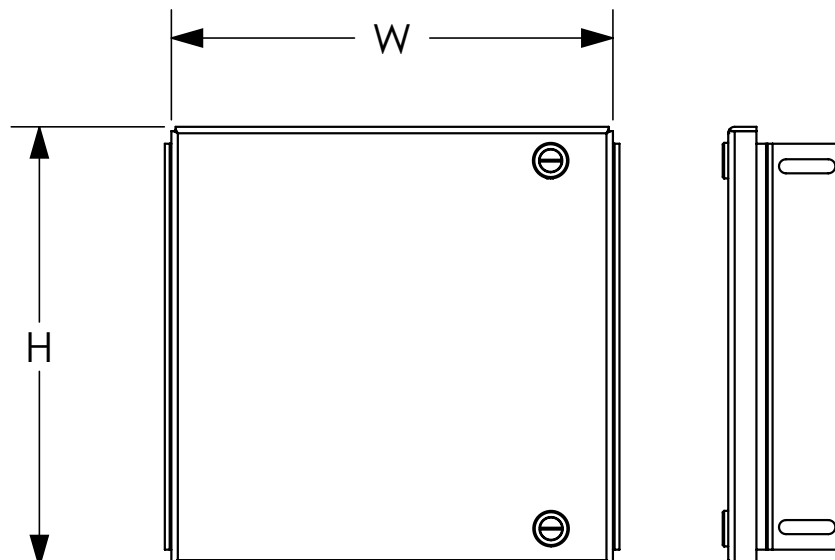

Eclipse Series Swing Frame



Construction

- Provides 19 in [483 mm] rack mounting with full EIA spacing (punched holes).
- Hinges allow easy equipment access.
- Slotted 1/4-turn latches provide closure.
- Optional locking 1/4-turn latch available by ordering Part No. EQTRL
- Adding optional locking 1/4-turn latches provides added security.
- Complete with 4- 6 in [102-152 mm] depth adjustment channels.
- Mounting hardware sold separately.
- Hardware kit maintains UL, CSA and NEMA ratings when field installed.
- Finished in black powder coat.

Eclipse Swing Frame					
Part Number	Price	For Use With	Rack Spacing Width	Rack Units	Drawing Link
ESF2424	\$287.00	24x24in	19.00in	11U	PDF
ESF3024	\$371.00	30x24in	19.00in	14U	PDF
ESF3624	\$426.00	36x24in	19.00in	17U	PDF

Dimensions

