

Fiberglass Enclosures – JIC Series

Screw Cover



HW-J100805SC
Crowned Cover Model Shown

Construction

- Hot compression molded fiberglass reinforced polyester (thermoset)
- Poured polyurethane seamless gasket provides watertight, dust-tight environmental seal
- 304 stainless used on all external hardware
- Rounded edges, minimal protrusions or exposed pocket area for accumulation of dust or debris
- Molded in flange for easy mounting
- Raised bosses with brass inserts accepting 10-32 screws for optional panel mounting
- Stainless steel beaded cover retention chain
- Workable material cuts, drills, punches and saws with ease and accuracy
- Submersible, non-corrosive environmental design
- Lift off cover
- Non-conductive, UV resistant
- High impact resistance - 216 in/lb per UL746C
- Smooth surface, no color variations, swirls or color pockets, no voids
- Color: Gray

Listings

- UL/cUL 50/508, Types 1, 3R, 4X, 6P, 12 [UL File E64791]
- CSA Certified, Types 1, 3R, 4X, 6P, 12 [CSA File 222873]
- NEMA Standard 250, Types 1, 3R, 4x, 6P, 12
- Temperature Range: -76°F to 274°F [-60°C to 134°C]
- Flammability Rating: UL94-5V
- Non-flame propagating
- Flame Spread classification per NFPA No. 101: Class A [1]



Enclosure Shipping Schedule				
Same day	1 - 7 days	1 - 10 days	1 - 15 days	1 - 20 days
Color indicates shipping lead time in business days.				

JIC Series Fiberglass Enclosures - Screw Cover							
Part Number	Price	Enclosure Overall Size HxWxD	Wt. [lb]	Carbon Steel Subpanel	Fiberglass Subpanel	Stainless Steel Subpanel	Aluminum Subpanel
HW-J60404SC	\$43.50	7.47 x 5.45 x 4.70 [190 x 138 x 119]	2.5	HW-MP604CS	HW-MP604FG	HW-MP604SS	HW-MP604A
HW-J60604SC	\$47.00	7.50 x 7.53 x 4.82 [191 x 191 x 122]	2.5	HW-MP606CS	HW-MP606FG	HW-MP606SS	HW-MP606A
HW-J80604SC	\$50.00	9.63 x 7.52 x 4.70 [245 x 191 x 119]	3.2	HW-MP806CS	HW-MP806FG	HW-MP806SS	HW-MP806A
HW-J80804SC	\$66.00	9.56 x 9.38 x 4.87 [243 x 238 x 124]	3.4	HW-MP808CS	HW-MP808FG	HW-MP808SS	-
HW-J100804SC	\$52.00	11.63 x 9.41 x 4.22 [295 x 239 x 107]	4.0	HW-MP1008CS	HW-MP1008FG	HW-MP1008SS	HW-MP1008A
HW-J100805SC [crowned cover]*	\$62.00	11.63 x 9.37 x 5.08 [295 x 238 x 129]	4.1	HW-MP1008CS	HW-MP1008FG	HW-MP1008SS	HW-MP1008A
HW-J100806SC	\$83.00	11.97 x 9.42 x 6.50 [304 x 239 x 165]	4.6	HW-MP1008CS	HW-MP1008FG	HW-MP1008SS	HW-MP1008A
HW-J121005SC	\$70.00	13.56 x 11.43 x 5.22 [344 x 291 x 133]	5.8	HW-MP1210CS	HW-MP1210FG	HW-MP1210SS	HW-MP1210A
HW-J141206SC	\$82.00	15.50 x 13.48 x 6.20 [394 x 342 x 157]	8.4	HW-MP1412CS	HW-MP1412FG	HW-MP1412SS	HW-MP1412A
HW-J161406SC	\$97.00	17.53 x 15.46 x 6.21 [445 x 393 x 157]	10.4	HW-MP1614CS	HW-MP1614FG	HW-MP1614SS	HW-MP1614A
HW-J181608SC	\$127.00	19.63 x 17.61 x 8.81 [499 x 447 x 224]	17.6	HW-MP1816CS	HW-MP1816FG	HW-MP1816SS	HW-MP1816A
HW-J201608SC	\$223.00	22.00 x 17.68 x 8.81 [559 x 449 x 224]	19.9	HW-MP2016CS	HW-MP2016FG	HW-MP2016SS	HW-MP2016A

Notes: Subpanels must be ordered separately.
Dimensions in inches [millimeters].
*In crowned cover units, the center of the cover is raised 3/4 in. Crowned cover is available only in 10x8x5 enclosure.

Fiberglass Enclosures – JIC Series

Hinged Screw Cover



HW-J141206CHSC

Construction

- Hot compression molded fiberglass reinforced polyester (thermoset)
- Poured polyurethane seamless gasket provides watertight, dust-tight environmental seal
- 304 stainless used on all external hardware
- Rounded edges, minimal protrusions or exposed pocket area for accumulation of dust or debris
- Molded in flange for easy mounting
- Raised bosses with brass inserts accepting 10-32 screws for optional panel mounting
- Workable material cuts, drills, punches and saw with ease and accuracy
- Submersible, non-corrosive environmental design
- Full length stainless steel hinged cover with two screws
- Full 180° door opening
- Non-conductive, UV resistant
- High impact resistance - 216 in/lb per UL746C
- Smooth surface, no color variations, swirls or color pockets, no voids
- Color: Gray

Listings

- UL/cUL 50/508, Types 1, 3R, 4X, 6P, 12 [UL File E64791]
- CSA Certified, Types 1, 3R, 4X, 6P, 12 [CSA File 222873]
- NEMA Standard 250, Types 1, 3R, 4X, 6P, 12
- Temperature Range: -76°F to 274°F [-60°C to 134°C]
- Flammability Rating: UL94-5V
- Non-flame propagating
- Flame Spread classification per NFPA No. 101: Class A [1]

Enclosure Shipping Schedule

Same day	1 - 7 days	1 - 10 days	1 - 15 days	1 - 20 days
----------	------------	-------------	-------------	-------------

Color indicates shipping lead time in business days.

JIC Series Fiberglass Enclosures - Hinged Screw Cover

Part Number	Price	Enclosure Overall Size HxWxD	Wt. [lb]	Carbon Steel Subpanel	Fiberglass Subpanel	Stainless Steel Subpanel	Aluminum Subpanel
HW-J60404CHSC	\$46.50	7.47 x 5.45 x 4.70 [191 x 138 x 119]	2.1	HW-MP604CS	HW-MP604FG	HW-MP604SS	HW-MP604A
HW-J60604CHSC	\$53.00	7.50 x 7.53 x 4.82 [191 x 191 x 122]	2.5	HW-MP606CS	HW-MP606FG	HW-MP606SS	HW-MP606A
HW-J80604CHSC	\$55.00	9.63 x 7.52 x 4.70 [245 x 191 x 119]	3.2	HW-MP806CS	HW-MP806FG	HW-MP806SS	HW-MP806A
HW-J80804CHSC	\$78.00	9.56 x 9.38 x 4.87 [243 x 238 x 124]	3.2	HW-MP808CS	HW-MP808FG	HW-MP808SS	-
HW-J100804CHSC	\$64.00	11.63 x 9.41 x 4.22 [295 x 239 x 107]	4.0	HW-MP1008CS	HW-MP1008FG	HW-MP1008SS	HW-MP1008A
HW-J100805CHSC [crowned cover]*	\$67.00	11.62 x 9.37 x 5.06 [295 x 238 x 129]	4.1	HW-MP1008CS	HW-MP1008FG	HW-MP1008SS	HW-MP1008A
HW-J100806CHSC	\$89.00	11.97 x 9.42 x 6.50 [304 x 239 x 165]	4.6	HW-MP1008CS	HW-MP1008FG	HW-MP1008SS	HW-MP1008A
HW-J121005CHSC	\$75.00	13.56 x 11.43 x 5.22 [344 x 291 x 133]	5.8	HW-MP1210CS	HW-MP1210FG	HW-MP1210SS	HW-MP1210A
HW-J141206CHSC	\$87.00	15.50 x 13.48 x 6.20 [394 x 342 x 158]	8.4	HW-MP1412CS	HW-MP1412FG	HW-MP1412SS	HW-MP1412A
HW-J161406CHSC	\$100.00	17.53 x 15.46 x 6.23 [445 x 393 x 157]	10.4	HW-MP1614CS	HW-MP1614FG	HW-MP1614SS	HW-MP1614A
HW-J181608CHSC	\$133.00	19.62 x 17.61 x 8.81 [498 x 447 x 224]	17.6	HW-MP1816CS	HW-MP1816FG	HW-MP1816SS	HW-MP1816A
HW-J201608CHSC	\$230.00	22.00 x 17.68 x 8.81 [559 x 449 x 224]	19.9	HW-MP2016CS	HW-MP2016FG	HW-MP2016SS	HW-MP2016A

Notes: Subpanels must be ordered separately.

Dimensions in inches [millimeters].

**In crowned cover units, the center of the cover is raised 3/4 in. Crowned cover is available only in 10x8x5 enclosure.*

Fiberglass Enclosures – JIC Series

White Hinged Screw Cover



HW-WHJ121005CHSC



Construction

- Hot compression molded fiberglass reinforced polyester (thermostat)
- Poured polyurethane seamless gasket provides watertight, dust-tight environmental seal
- 304 stainless steel used on all external hardware
- Rounded edges, minimal protrusions or exposed pocket areas for accumulation of dust or debris
- Molded in flange for ease of mounting
- Raised bosses with brass inserts accepting 10-32 screws for optional panel mounting
- Workable material cuts, drills, punches, and saws with ease and accuracy
- Submersible, non-corrosive environmental design
- Full length, stainless steel hinged cover with two screws
- Full 180° door opening
- Non-conductive, UV resistant
- High impact resistance - 216 in/lb per UL746C
- Smooth surface, no color variations, swirls or color pockets, no voids
- Color: White

Listings

- UL/cUL 50/508, Types 1, 3R, 4X, 6P, 12 [UL File E64791]
- CSA Certified, Types 1, 3R, 4X, 6P, 12 [CSA File 222873]
- NEMA Standard 250, Types 1, 3R, 4X, 6P, 12
- Temperature Range: -76°F to 274°F [-60°C to 134°C]
- Flammability Rating: UL94-5V
- Non-flame propagating
- Flame Spread classification per NFPA No. 101: Class A [1]



Enclosure Shipping Schedule				
Same day	1 - 7 days	1 - 10 days	1 - 15 days	1 - 20 days
Color indicates shipping lead time in business days.				

JIC Series Fiberglass Enclosures – White Hinged Screw Cover							
Part Number	Price	Enclosure Overall Size HxWxD	Wt. (lb)	Carbon Steel Subpanel	Fiberglass Subpanel	Stainless Steel Subpanel	Aluminum Subpanel
HW-WHJ60404CHSC	\$75.00	7.47 x 5.45 x 4.70 [190 x 138 x 119]	2.1	HW-MP604CS	HW-MP604FG	HW-MP604SS	HW-MP604A
HW-WHJ60604CHSC	\$86.00	7.50 x 7.53 x 4.82 [191 x 191 x 122]	2.4	HW-MP606CS	HW-MP606FG	HW-MP606SS	HW-MP606A
HW-WHJ80604CHSC	\$89.00	9.63 x 7.52 x 4.70 [245 x 191 x 119]	3.0	HW-MP806CS	HW-MP806FG	HW-MP806SS	HW-MP806A
HW-WHJ100804CHSC	\$109.00	11.63 x 9.41 x 4.22 [295 x 239 x 107]	3.8	HW-MP1008CS	HW-MP1008FG	HW-MP1008SS	HW-MP1008A
HW-WHJ121005CHSC	\$128.00	13.56 x 11.43 x 5.22 [344 x 291 x 133]	5.7	HW-MP1210CS	HW-MP1210FG	HW-MP1210SS	HW-MP1210A
HW-WHJ141206CHSC	\$148.00	15.50 x 13.48 x 6.20 [394 x 342 x 158]	8.6	HW-MP1412CS	HW-MP1412FG	HW-MP1412SS	HW-MP1412A
HW-WHJ161406CHSC	\$170.00	17.53 x 15.46 x 6.21 [445 x 393 x 157]	10.0	HW-MP1614CS	HW-MP1614FG	HW-MP1614SS	HW-MP1614A
HW-WHJ181608CHSC	\$225.00	19.63 x 17.61 x 8.81 [499 x 447 x 224]	17.1	HW-MP1816CS	HW-MP1816FG	HW-MP1816SS	HW-MP1816A
HW-WHJ201608CHSC	\$388.00	22.00 x 17.68 x 8.81 [559 x 449 x 224]	19.9	HW-MP2016CS	HW-MP2016FG	HW-MP2016SS	HW-MP2016A

**Notes: Subpanels must be ordered separately.
Dimensions in inches (millimeters).**

Fiberglass Enclosures – JIC Series

Single Door with Twist-Lock Latches



HW-J121005CHTL

Construction

- Hot compression molded fiberglass reinforced polyester (thermoset)
- Poured polyurethane seamless gasket provides watertight, dust-tight environmental seal
- 304 stainless steel used on all external hardware
- Rounded edges, minimal protrusions or exposed pocket area for accumulation of dust or debris
- Molded in flange for easy mounting
- Raised bosses with brass inserts accepting 10-32 screws for optional panel mounting
- Workable material cuts, drills, punches and saws with ease and accuracy
- Full length, stainless steel, hinged cover with twist-lock latches
- Full 180° door opening
- Non-conductive, UV resistant
- High impact resistance - 216 in/lb per UL746C

- Smooth surface, no color variations, swirls or color pockets, no voids
- Submersible, non-corrosive environmental design
- Color: Gray

Listings

- UL/cUL 50/508, Types 1, 3R, 4X, 6P, 12 [UL File E64791]
- CSA Certified, Types 1, 3R, 4X, 6P, 12 [CSA File 222873]
- NEMA Standard 250, Types 1, 3R, 4X, 6P, 12
- Temperature Range: -76°F to 274°F [-60°C to 134°C]
- Flammability Rating: UL94-5V
- Non-flame propagating
- Flame Spread classification per NFPA No. 101: Class A [1]



Enclosure Shipping Schedule				
Same day	1 - 7 days	1 - 10 days	1 - 15 days	1 - 20 days
Color indicates shipping lead time in business days.				

JIC Series Fiberglass Enclosures - Single Door with Twist-Lock Latches								
Part Number	Price	Enclosure Overall Size HxWxD	Wt. [lb]	No. Latches	Carbon Steel Subpanel	Fiberglass Subpanel	Stainless Steel Subpanel	Aluminum Subpanel
HW-J60404CHTL	\$86.00	7.47 x 5.45 x 4.70 [190 x 138 x 119]	2.2	1	HW-MP604CS	HW-MP604FG	HW-MP604SS	HW-MP604A
HW-J60604CHTL	\$89.00	7.50 x 7.53 x 4.82 [191 x 191 x 122]	2.6	1	HW-MP606CS	HW-MP606FG	HW-MP606SS	HW-MP606A
HW-J80604CHTL	\$90.00	9.63 x 7.52 x 4.70 [245 x 191 x 119]	3.1	1	HW-MP680CS	HW-MP680FG	HW-MP680SS	HW-MP680A
HW-J80804CHTL	\$94.00	9.56 x 9.38 x 4.87 [243 x 238 x 124]	3.3	1	HW-MP808CS	HW-MP808FG	HW-MP808SS	-
HW-J100804CHTL	\$98.00	11.63 x 9.41 x 4.22 [295 x 239 x 107]	4.0	2	HW-MP1008CS	HW-MP1008FG	HW-MP1008SS	HW-MP1008A
HW-J100805CHTL [crowned cover]*	\$104.00	11.63 x 9.37 x 5.08 [295 x 238 x 129]	4.3	2	HW-MP1008CS	HW-MP1008FG	HW-MP1008SS	HW-MP1008A
HW-J100806CHTL	\$104.00	11.97 x 9.42 x 6.50 [304 x 239 x 165]	4.6	1	HW-MP1008CS	HW-MP1008FG	HW-MP1008SS	HW-MP1008A
HW-J121005CHTL	\$112.00	13.56 x 11.43 x 5.22 [344 x 291 x 133]	5.8	2	HW-MP1210CS	HW-MP1210FG	HW-MP1210SS	HW-MP1210A
HW-J141206CHTL	\$142.00	15.50 x 13.48 x 6.20 [394 x 342 x 158]	9.2	2	HW-MP1412CS	HW-MP1412FG	HW-MP1412SS	HW-MP1412A
HW-J161406CHTL	\$154.00	17.53 x 15.46 x 6.21 [445 x 393 x 157]	9.5	2	HW-MP1614CS	HW-MP1614FG	HW-MP1615SS	HW-MP1614A
HW-J181608CHTL	\$200.00	19.63 x 17.61 x 8.81 [499 x 447 x 224]	17.3	2	HW-MP1816CS	HW-MP1816FG	HW-MP1816SS	HW-MP1816A
HW-J201608CHTL	\$334.00	22.00 x 17.68 x 8.81 [559 x 449 x 224]	19.0	2	HW-MP2016CS	HW-MP2016FG	HW-MP2016CS	HW-MP2016A

Notes: Subpanels must be ordered separately.
Dimensions in inches [millimeters].
*In crowned cover units, the center of the cover is raised 3/4 in. Crowned cover is available only in 10x8x5 enclosure.

Fiberglass Enclosures – JIC Series

Single Door with Quick-Release Latches



HW-J121005CHQR

Construction

- Hot compression molded fiberglass reinforced polyester (thermoset)
- Poured polyurethane seamless gasket provides watertight, dust-tight environmental seal
- 304 stainless steel used on all external hardware
- Rounded edges, minimal protrusions or exposed pocket areas for accumulation of dust or debris
- Molded in flange for easy mounting
- Raised bosses with brass inserts accepting 10-32 screws for optional panel mounting
- Workable material cuts, drills, punches and saws with ease and accuracy
- Full length, stainless steel, hinged cover with padlockable quick-release latches
- Full 180° door opening
- Non-conductive, UV resistant
- High impact resistance - 216 in/lb per UL746C

- Smooth surface, no color variations, swirls or color pockets, no voids
- Submersible, non-corrosive environmental design
- Color: Gray

Listings

- UL/cUL 50/508, Types 1, 3R, 4X, 6P, 12 [UL File E64791]
- CSA Certified, Types 1, 3R, 4X, 6P, 12 [CSA File 222873]
- NEMA Standard 250, Types 1, 3, 4x, 6P, 12
- Temperature Range: -76°F to 274°F [-60°C to 134°C]
- Flammability Rating: UL94-5V
- Non-flame propagating
- Flame Spread classification per NFPA No. 101: Class A [1]



Enclosure Shipping Schedule

Same day	1 - 7 days	1 - 10 days	1 - 15 days	1 - 20 days
----------	------------	-------------	-------------	-------------

Color indicates shipping lead time in business days.

JIC Series Fiberglass Enclosures - Single Door with Quick-Release Latches

Part Number	Price	Enclosure Overall Size HxWxD	Wt. [lb]	No. Latches	Carbon Steel Subpanel	Fiberglass Subpanel	Stainless Steel Subpanel	Aluminum Subpanel
HW-J60404CHQR	\$65.00	7.47 x 5.45 x 4.70 [190 x 138 x 119]	2.1	1	HW-MP604CS	HW-MP604FG	HW-MP604SS	HW-MP604A
HW-J60604CHQR	\$67.00	7.50 x 7.53 x 4.82 [191 x 191 x 122]	2.5	1	HW-MP606CS	HW-MP606FG	HW-MP606SS	HW-MP606A
HW-J80604CHQR	\$68.00	9.63 x 7.52 x 4.70 [245 x 191 x 119]	3.2	1	HW-MP806CS	HW-MP806FG	HW-MP806SS	HW-MP806A
HW-J80804CHQR	\$92.00	9.56 x 9.38 x 4.87 [243 x 238 x 124]	3.3	1	HW-MP808CS	HW-MP808FG	HW-MP808SS	-
HW-J100804CHQR	\$74.00	11.63 x 9.41 x 4.22 [295 x 239 x 107]	4.1	2	HW-MP1008CS	HW-MP1008FG	HW-MP1008SS	HW-MP1008A
HW-J100805CHQR [crowned cover]*	\$76.00	11.63 x 9.37 x 5.08 [295 x 238 x 129]	4.1	2	HW-MP1008CS	HW-MP1008FG	HW-MP1008SS	HW-MP1008A
HW-J100806CHQR	\$101.00	11.97 x 9.42 x 6.50 [304 x 239 x 165]	4.6	1	HW-MP1008CS	HW-MP1008FG	HW-MP1008SS	HW-MP1008A
HW-J121005CHQR	\$85.00	13.56 x 11.43 x 5.22 [344 x 291 x 133]	5.8	2	HW-MP1210CS	HW-MP1210FG	HW-MP1210SS	HW-MP1210A
HW-J141206CHQR	\$107.00	15.50 x 13.48 x 6.20 [394 x 342 x 158]	8.4	2	HW-MP1412CS	HW-MP1412FG	HW-MP1412SS	HW-MP1412A
HW-J161406CHQR	\$116.00	17.53 x 15.46 x 6.21 [445 x 393 x 157]	10.4	2	HW-MP1614CS	HW-MP1614FG	HW-MP1614SS	HW-MP1614A
HW-J181608CHQR	\$151.00	19.63 x 17.61 x 8.81 [499 x 447 x 224]	17.6	2	HW-MP1816CS	HW-MP1816FG	HW-MP1816SS	HW-MP1816A
HW-J201608CHQR	\$239.00	22.00 x 17.68 x 8.81 [559 x 449 x 224]	19.9	2	HW-MP2016CS	HW-MP2016FG	HW-MP2016SS	HW-MP2016A
HW-J202010CHQR	\$359.00	23.50 x 22.12 x 11.70 [597 x 562 x 297]	26.4	1	HW-MP2020CS	HW-MP2020FG	-	HW-MP2020AL
HW-J242010CHQR	\$517.00	27.50 x 22.12 x 11.70 [699 x 562 x 297]	32.2	1	HW-MP2420CS	HW-MP2420FG	-	HW-MP2420AL
HW-J242410CHQR	\$613.00	27.50 x 26.12 x 11.70 [699 x 663 x 297]	37.0	1	HW-MP2424CS	HW-MP2424FG	-	HW-MP2424AL

Notes: Subpanels must be ordered separately.

Dimensions in inches [millimeters].

*In crowned cover units, the center of the cover is raised 3/4 in. Crowned cover is available only in 10x8x5 enclosure.

Fiberglass Enclosures – JIC Series

White Single Door with Quick-Release Latches



HW-WHJ161406CHQR



Construction

- Hot compression molded fiberglass reinforced polyester (thermoset)
- Poured polyurethane seamless gasket provides watertight, dust-tight environmental seal
- 304 stainless used on all external hardware
- Rounded edges, minimal protrusions or exposed pocket area for accumulation of dust or debris
- Molded in flange for easy mounting
- Raised bosses with brass inserts accepting 10-32 screws for optional panel mounting
- Workable material cuts, drills, punches and saw with ease and accuracy
- Submersible, non-corrosive environmental design
- Full length stainless steel hinged cover with padlockable quick-release latches
- Full 180° door opening
- Non-conductive, UV resistant
- High impact resistance - 216 in/lb per UL746C
- Smooth surface, no color variations, swirls or color pockets, no voids
- Color: White

Listings

- UL/cUL 50/508, Types 1, 3R, 4X, 6P, 12 [File E64791]
- CSA Certified, Types 1, 3, 4X, 6P, 12 [CSA File 222873]
- NEMA Standard 250, Types 1, 3, 4x, 6P, 12
- Temperature Range: -76°F to 274°F [-60°C to 134°C]
- Flammability Rating: UL94-5V
- Non-flame propagating
- Flame Spread classification per NFPA No. 101: Class A [1]



Enclosure Shipping Schedule				
Same day	1 - 7 days	1 - 10 days	1 - 15 days	1 - 20 days
Color indicates shipping lead time in business days.				

JIC Series Fiberglass Enclosures - White Single Door with Quick Release Latches								
Part Number	Price	Enclosure Overall Size HxWxD	Wt. (lb)	No. Latches	Carbon Steel Subpanel	Fiberglass Subpanel	Stainless Steel Subpanel	Aluminum Subpanel
HW-WHJ60404CHQR	\$89.00	7.47 x 5.45 x 4.70 [190 x 138 x 119]	2.1	1	HW-MP604CS	HW-MP604FG	HW-MP604SS	HW-MP604A
HW-WHJ60604CHQR	\$97.00	7.50 x 7.53 x 4.82 [191 x 191 x 122]	2.4	1	HW-MP606CS	HW-MP606FG	HW-MP606SS	HW-MP606A
HW-WHJ80604CHQR	\$98.00	9.63 x 7.52 x 4.70 [245 x 191 x 119]	3.1	1	HW-MP806CS	HW-MP806FG	HW-MP808SS	HW-MP806A
HW-WHJ100804CHQR	\$107.00	11.63 x 9.41 x 4.22 [295 x 239 x 107]	4.1	2	HW-MP1008CS	HW-MP1008FG	HW-MP1008SS	HW-MP1008A
HW-WHJ121005CHQR	\$122.00	13.56 x 11.43 x 5.22 [344 x 291 x 133]	5.9	2	HW-MP1210CS	HW-MP1210FG	HW-MP1210SS	HW-MP1210A
HW-WHJ141206CHQR	\$154.00	15.50 x 13.48 x 6.20 [394 x 342 x 158]	8.7	2	HW-MP1412CS	HW-MP1412FG	HW-MP1412SS	HW-MP1412A
HW-WHJ161406CHQR	\$168.00	17.53 x 15.46 x 6.21 [445 x 393 x 157]	10.7	2	HW-MP1614CS	HW-MP1614FG	HW-MP1614SS	HW-MP1614A
HW-WHJ181608CHQR	\$218.00	19.63 x 17.61 x 8.81 [499 x 447 x 224]	17.5	2	HW-MP1816CS	HW-MP1816FG	HW-MP1816SS	HW-MP1816A
HW-WHJ201608CHQR	\$345.00	22.00 x 17.68 x 8.81 [559 x 449 x 224]	19.8	2	HW-MP2016CS	HW-MP2016FG	HW-MP2016SS	HW-MP2016A

**Notes: Subpanels must be ordered separately.
Dimensions in inches [millimeters].**

Fiberglass Enclosures – JIC Series

Single Door with 3-Point Latch



HW-J2020103PT

Construction

- Hot compression molded fiberglass reinforced polyester (thermoset)
- 3-point single rotating handle system for ease of use and assurance of security
- Overhang cover on smooth-sided base
- Full 180° door opening
- Mounting foot gussets for structural integrity and robustness
- Slotted mounting hole ensures flexibility in mounting
- All stainless steel latches
- Full length stainless steel hinge
- Chemically resistant fiberglass reinforced composite formulation
- UV resistant
- Channel captured gasket assures seal integrity
- 1/2-inch thick integral mounting flange for structural integrity
- Color: Gray

Listings

- UL/cUL 50/508, Types 1, 3, 3R, 4, 4X, 12, 13 [UL File E64791]
- CSA Certified, Types 1, 3, 3R, 4, 4X, 12, 13 [CSA File 222873]
- NEMA Standard 250 Types 1, 3, 3R, 4, 4X, 12, 13
- IEC 60529 IP66
- Temperature Range: -76°F to 274°F [-60°C to 134°C]
- Flammability Rating: UL94-5V
- Non-flame propagating
- Flame Spread classification per NFPA No. 101: Class A [1]



Enclosure Shipping Schedule				
Same day	1 - 7 days	1 - 10 days	1 - 15 days	1 - 20 days

Color indicates shipping lead time in business days.

JIC Series Fiberglass Enclosures - Single Door with 3-Point Latch						
Part Number	Price	Enclosure Overall Size HxWxD	Wt. [lb]	Carbon Steel Subpanel	Fiberglass Subpanel	Aluminum Subpanel
HW-J2020103PT	\$446.00	23.50 x 22.12 x 11.70 [597 x 562 x 297]	26.4	MP-2020CS	MP-2020FG	MP-2020AL
HW-J2420103PT	\$541.00	27.50 x 22.12 x 11.70 [699 x 562 x 297]	32.2	MP-2420CS	MP-2420FG	MP-2420AL
HW-J2424103PT	\$699.00	27.50 x 26.12 x 11.70 [699 x 663 x 297]	27.5	MP-2424CS	MP-2424FG	MP-2424AL

*Notes: Subpanels must be ordered separately.
Dimensions in inches [millimeters].*

Fiberglass Enclosures – JIC Series

Single Door with Acrylic Window and Twist-Lock Latches



HW-J121005CHTLW

Construction

- Hot compression molded fiberglass reinforced polyester (thermoset)
- Poured polyurethane seamless gasket provides watertight, dust-tight environmental seal
- 304 stainless steel used on all external hardware
- Rounded edges, minimal protrusions or exposed pocket area for accumulation of dust or debris
- Molded in flange for easy mounting
- Raised bosses with brass inserts accepting 10-32 screws for optional panel mounting
- Workable material cuts, drills, punches and saws with ease and accuracy
- Scratch- and abrasion-resistant UVA acrylic flush bonded window
- Submersible, non-corrosive environmental design
- Full 180° door opening
- Non-conductive, UV resistant
- High impact resistance - 216 in/lb per UL746C
- Smooth surface, no color variations, swirls or color pockets, no voids
- Full length stainless steel hinged cover with twist-lock latches
- Color: Gray

Listings

- UL/cUL 50/508, Types 1, 3R, 4X, 6P, 12 [UL File E64791]
- CSA Certified, Types 1, 3R, 4X, 6P, 12 [CSA File 222873]
- NEMA Standard 250 Types 1, 3R, 4X, 6P, 12
- Temperature Range: -26°F to 170°F [-32°C to 76°C]
- Temperature Range Window: -26°F to 170°F [-32°C to 76°C]
- Flammability Rating: UL94-5V
- Flammability Rating window: UL94V-HB
- Non-flame propagating
- Flame Spread classification per NFPA No. 101: Class A [1]



Enclosure Shipping Schedule				
Same day	1 - 7 days	1 - 10 days	1 - 15 days	1 - 20 days

Color indicates shipping lead time in business days.

JIC Series Fiberglass Enclosures - Single Door with Acrylic Window and Twist-Lock Latches								
Part Number	Price	Enclosure Overall Size HxWxD	Wt. [lb]	No. Latches	Carbon Steel Subpanel	Fiberglass Subpanel	Stainless Steel Subpanel	Aluminum Subpanel
HW-J60404CHTLW	\$83.00	7.47 x 5.45 x 4.70 [190 x 138 x 119]	2.5	1	HW-MP604CS	HW-MP604FG	HW-MP604SS	HW-MP604A
HW-J80604CHTLW	\$96.00	9.63 x 7.52 x 4.70 [245 x 191 x 119]	3.5	1	HW-MP806CS	HW-MP806FG	HW-MP806SS	HW-MP806A
HW-J100804CHTLW	\$111.00	11.63 x 9.41 x 4.22 [295 x 239 x 107]	5	2	HW-MP1008CS	HW-MP1008FG	HW-MP1008SS	HW-MP1008A
HW-J100806CHTLW	\$188.00	11.97 x 9.42 x 6.50 [304 x 239 x 165]	4.5	2	HW-MP1008CS	HW-MP1008FG	HW-MP1008SS	HW-MP1008A
HW-J121005CHTLW	\$129.00	13.56 x 11.43 x 5.22 [344 x 291 x 133]	6.5	2	HW-MP1210CS	HW-MP1210FG	HW-MP1210SS	HW-MP1210A
HW-J141206CHTLW	\$177.00	15.50 x 13.48 x 6.20 [394 x 342 x 157]	8.5	2	HW-MP1412CS	HW-MP1412FG	HW-MP1412SS	HW-MP1412A
HW-J161406CHTLW	\$195.00	17.53 x 15.46 x 6.21 [445 x 393 x 158]	11.5	2	HW-MP1614CS	HW-MP1614FG	HW-MP1614SS	HW-MP1614A
HW-J181608CHTLW	\$239.00	19.63 x 17.61 x 8.81 [498 x 447 x 224]	19.25	2	HW-MP1816CS	HW-MP1816FG	HW-MP1816SS	HW-MP1816A
HW-J201608CHTLW	\$386.00	22.00 x 17.68 x 8.81 [559 x 449 x 224]	20.25	2	HW-MP2016CS	HW-MP2016FG	HW-MP2016SS	HW-MP2016A

Notes: Subpanels must be ordered separately.
Dimensions in inches [millimeters].

Fiberglass Enclosures – JIC Series

Single Door with Acrylic Window and Quick-Release Latches



HW-J100804CHQRW

Construction

- Hot compression molded fiberglass reinforced polyester (thermoset)
- Poured polyurethane seamless gasket provides watertight, dust-tight environmental seal
- 304 stainless steel used on all external hardware
- Rounded edges, minimal protrusions or exposed pocket area for accumulation of dust or debris
- Molded-in flange for easy mounting
- Raised bosses with brass inserts accepting 10-32 screws for optional panel mounting
- Workable material cuts, drills, punches and saws with ease and accuracy
- Scratch- and abrasion-resistant UVA acrylic flush bonded window
- Submersible, non-corrosive environmental design
- Full 180° door opening
- Non-conductive, UV resistant
- High impact resistance - 216 in/lb per UL746C
- Smooth surface, no color variations, swirls or color pockets, no voids
- Full length stainless steel hinged cover with padlockable quick-release latches
- Color: Gray

Listings

- UL/cUL 50/508, Types 1, 3R, 4X, 6P, 12 [UL File E64791]
- CSA Certified, Types 1, 3R, 4X, 6P, 12 [CSA File 222873]
- NEMA Standard 250 Types 1, 3R, 4X, 6P, 12
- Temperature Range: -26°F to 170°F [-32°C to 76°C]
- Window Temperature Range: -26°F to 170°F [-32°C to 76°C]
- Flammability Rating: UL94-5V
- Flammability Rating window: UL94V-HB
- Non-flame propagating
- Flame Spread classification per NFPA No. 101: Class A [1]




Enclosure Shipping Schedule				
Same day	1 - 7 days	1 -10 days	1 - 15 days	1 - 20 days
Color indicates shipping lead time in business days.				

JIC Series Fiberglass Enclosures - Single Door with Acrylic Window and Quick-Release Latches								
Enclosure Part Number	Price	Enclosure Overall Size HxWxD	Wt. [lb]	No. Latches	Carbon Steel Subpanel	Fiberglass Subpanel	Stainless Steel Subpanel	Aluminum Subpanel
HW-J60404CHQRW	\$82.00	7.47 x 5.45 x 4.70 [191 x 138 x 119]	2.5	1	HW-MP604CS	HW-MP604FG	HW-MP604SS	HW-MP604A
HW-J60604CHQRW	\$90.00	7.50 x 7.53 x 4.82 [191 x 191 x 122]	2.75	1	HW-MP606CS	HW-MP606FG	HW-MP606SS	HW-MP606A
HW-J80604CHQRW	\$94.00	9.63 x 7.52 x 4.70 [245 x 191 x 119]	3.5	1	HW-MP806CS	HW-MP806FG	HW-MP806SS	HW-MP806A
HW-J100804CHQRW	\$109.00	11.62 x 9.41 x 4.22 [295 x 239 x 107]	5	2	HW-MP1008CS	HW-MP1008FG	HW-MP1008SS	HW-MP1008A
HW-J100806CHQRW	\$186.00	11.97 x 9.42 x 6.50 [304 x 239 x 165]	4.5	2	HW-MP1008CS	HW-MP1008FG	HW-MP1008SS	HW-MP1008A
HW-J121005CHQRW	\$126.00	13.56 x 11.43 x 5.22 [344 x 291 x 133]	6.5	2	HW-MP1210CS	HW-MP1210FG	HW-MP1210SS	HW-MP1210A
HW-J141206CHQRW	\$174.00	15.50 x 13.48 x 6.20 [394 x 342 x 157]	8.5	2	HW-MP1412CS	HW-MP1412FG	HW-MP1412SS	HW-MP1412A
HW-J161406CHQRW	\$191.00	17.53 x 15.46 x 6.21 [445 x 393 x 158]	11.5	2	HW-MP1614CS	HW-MP1614FG	HW-MP1614SS	HW-MP1614A
HW-J181608CHQRW*	\$234.00	19.63 x 17.61 x 8.82 [499 x 447 x 224]	19.25	2	HW-MP1816CS	HW-MP1816FG	HW-MP1816SS	HW-MP1816A

Notes: Subpanels must be ordered separately.
Dimensions in inches [millimeters].
*1816 size is not 6P rated.

Fiberglass Enclosures – JIC Series

Dimensions for JIC Series Enclosures

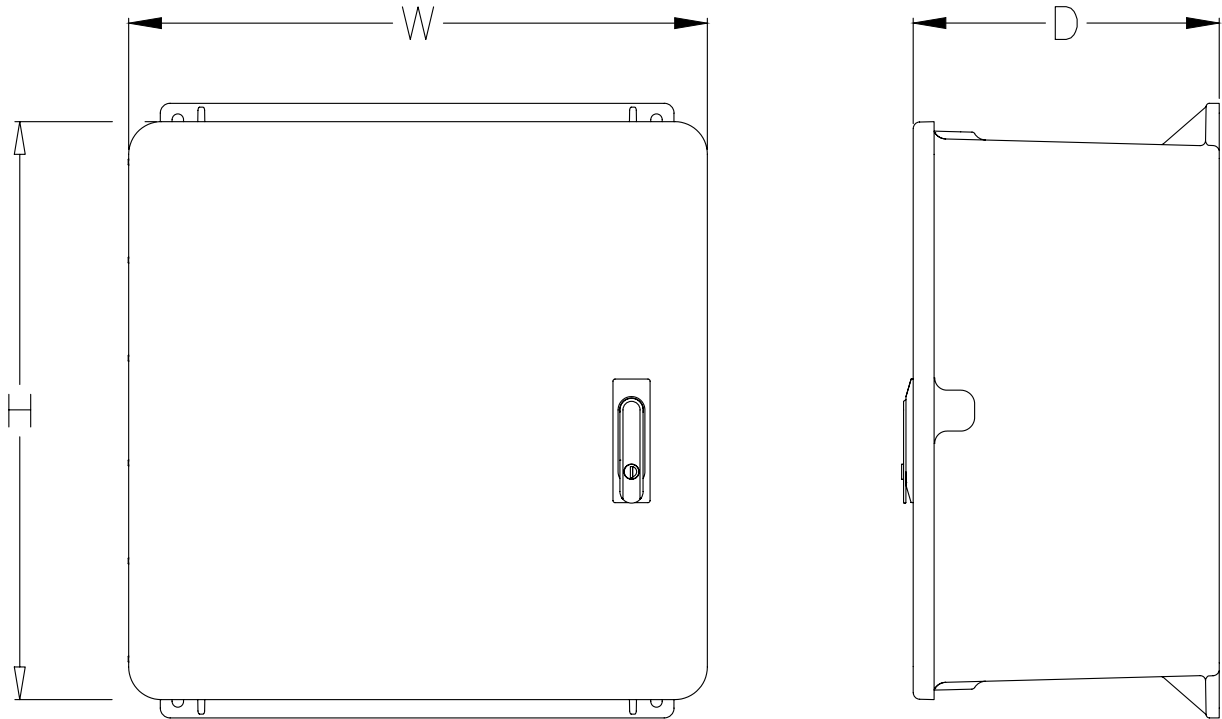

See our website: www.AutomationDirect.com for complete engineering drawings.

Subpanels for Premier, JIC and Classic Series Fiberglass Enclosures



Subpanel Specifications		
Subpanel	Material	Color/Finish
Carbon Steel	Carbon Steel	White polyester powder Finish
Aluminum	3003H14 Aluminum	Mill Finish
Stainless Steel	304 Stainless	Mill Finish
Fiberglass	FRP (Fiberglass reinforced panel)	Gray



Carbon steel subpanels

Fiberglass subpanels

Subpanel Part Number	Price	Subpanel Size HxWxD	Enclosure Nominal Size HxW	Wt (lb)
HW-MP604CS	\$5.75	4.88 x 2.88 x 0.075 [124 x 73 x .19]	6 x 4	0.3
HW-MP606CS	\$5.75	4.88 x 4.88 x 0.075 [124 x 124 x .19]	6 x 6	0.5
HW-MP706CS	\$7.50	6.00 x 4.88 x 0.075 [152 x 124 x .19]	7 x 6	0.6
HW-MP806CS	\$7.75	6.75 x 4.88 x 0.075 [152 x 124 x .19]	8 x 6	0.8
HW-MP808CS	\$10.00	6.88 x 6.88 x 0.075 [175 x 175 x .19]	8 x 8	0.8
HW-MP906CS	\$9.50	8.25 x 4.88 x 0.075 [175 x 124 x .19]	9 x 6	0.9
HW-MP1008CS	\$11.50	8.75 x 6.88 x 0.075 [225 x 175 x .19]	10 x 8	1.3
HW-MP1210CS	\$14.00	10.88 x 8.75 x 0.075 [276 x 225 x .19]	12 x 10	2.1
HW-MP1412CS	\$15.50	12.88 x 10.88 x 0.075 [327 x 276 x .19]	14 x 12	3.0
HW-MP1614CS	\$20.50	14.88 x 12.88 x 0.075 [378 x 327 x .19]	16 x 14	4.1
HW-MP1816CS	\$26.50	16.88 x 14.88 x 0.075 [429 x 378 x .19]	18 x 16	5.4
HW-MP2016CS	\$33.50	18.88 x 14.88 x 0.075 [479 x 378 x .19]	20 x 16	6.1
HW-MP2020CS	\$98.00	18.00 x 18.00 x 0.105 [457 x 457 x 2.7]	20 x 20	9.4
HW-MP2420CS	\$119.00	22.00 x 18.00 x 0.105 [558 x 457 x 2.7]	24 x 20	11
HW-MP2424CS	\$146.00	22.00 x 22.00 x 0.105 [558 x 558 x 2.7]	24 x 24	22

Note: Dimensions in inches [millimeters].

Subpanel Part Number	Price	Subpanel Size HxWxD	Enclosure Nominal Size HxW	Wt. (lb)
HW-MP604FG	\$5.75	4.88 x 2.88 x 0.13 [124 x 73 x 3.2]	6 x 4	0.1
HW-MP606FG	\$5.75	4.88 x 4.88 x 0.13 [124 x 124 x 3.2]	6 x 6	0.2
HW-MP806FG	\$7.75	6.88 x 4.88 x 0.13 [175 x 124 x 3.2]	8 x 6	0.3
HW-MP808FG	\$10.00	6.88 x 6.88 x 0.13 [175 x 175 x 3.2]	8 x 8	0.3
HW-MP1008FG	\$9.50	8.88 x 6.88 x 0.13 [225 x 175 x 3.2]	10 x 8	0.5
HW-MP1210FG	\$13.50	10.88 x 8.88 x 0.13 [276 x 225 x 3.2]	12 x 10	0.9
HW-MP1412FG	\$17.00	12.88 x 10.88 x 0.13 [327 x 276 x 3.2]	14 x 12	1.0
HW-MP1614FG	\$21.00	14.88 x 12.88 x 0.13 [378 x 327 x 3.2]	16 x 14	0.8
HW-MP1816FG	\$27.00	16.88 x 14.88 x 0.13 [429 x 378 x 3.2]	18 x 16	2.0
HW-MP2016FG	\$33.00	18.88 x 14.88 x 0.13 [479 x 378 x 3.2]	20 x 16	2.2
HW-MP2020FG	\$106.00	18.00 x 18.00 x 0.13 [457 x 457 x 3.2]	20 x 20	2.3
HW-MP2420FG	\$128.00	22.00 x 18.00 x 0.13 [558 x 457 x 3.2]	24 x 20	2.8
HW-MP2424FG	\$157.00	22.00 x 22.00 x 0.13 [558 x 558 x 3.2]	24 x 24	3.5

Note: Dimensions in inches [millimeters].

Enclosure Shipping Schedule				
Same day	1 - 7 days	1 -10 days	1 - 15 days	1 - 20 days
Color indicates shipping lead time in business days.				

Subpanels for Premier, JIC and Classic Series Fiberglass Enclosures

Stainless steel subpanels

Subpanel Part Number	Price	Subpanel Size HxWxD	Enclosure Nominal Size HxW	Wt. (lb)
HW-MP604SS	\$7.75	4.88 x 2.88 x 0.064 [124 x 73 x 1.5]	6 x 4	0.3
HW-MP606SS	\$9.75	4.88 x 4.88 x 0.064 [124 x 124 x 1.5]	6 x 6	0.5
HW-MP806SS	\$12.50	6.88 x 4.88 x 0.064 [175 x 124 x 1.5]	8 x 6	0.8
HW-MP808SS	\$15.50	6.88 x 6.88 x 0.064 [175 x 175 x 1.5]	8 x 8	0.8
HW-MP1008SS	\$21.00	8.88 x 6.88 x 0.064 [225 x 175 x 1.5]	10 x 8	1.2
HW-MP1210SS	\$31.50	10.88 x 8.88 x 0.064 [276 x 225 x 1.5]	12 x 10	1.9
HW-MP1412SS	\$46.50	12.88 x 10.88 x 0.064 [327 x 276] x 1.5]	14 x 12	2.9
HW-MP1614SS	\$56.00	14.88 x 12.88 x 0.064 [378 x 327 x 1.5]	16 x 14	3.1
HW-MP1816SS	\$65.00	16.88 x 14.88 x 0.064 [429 x 378 x 1.5]	18 x 16	6.0
HW-MP2016SS	\$77.00	18.88 x 14.88 x 0.064 [479 x 378 x 1.5]	20 x 16	6.1

Note: Dimensions in inches [millimeters].



Enclosure Shipping Schedule				
Same day	1 - 7 days	1 - 10 days	1 - 15 days	1 - 20 days


Color indicates shipping lead time in business days.

Aluminum subpanels

Subpanel Part Number	Price	Subpanel Size HxWxD	Enclosure Nominal Size HxW	Wt. (lb)
HW-MP604A	\$5.75	4.88 x 2.88 x 0.081 [124 x 73 x 2.0]	6 x 4	0.1
HW-MP606A	\$5.75	4.88 x 4.88 x 0.081 [124 x 124 x 2.0]	6 x 6	0.2
HW-MP806A	\$7.75	6.88 x 4.88 x 0.081 [175 x 124] x 2.0]	8 x 6	0.3
HW-MP1008A	\$11.50	8.88 x 6.88 x 0.081 [225 x 175 x 2.0]	10 x 8	0.5
HW-MP1210A	\$14.00	10.88 x 8.88 x 0.081 [276 x 225 x 2.0]	12 x 10	0.8
HW-MP1412A	\$15.50	12.88 x 10.88 x 0.081 [327 x 276 x 2.0]	14 x 12	1.1
HW-MP1614A	\$20.50	14.88 x 12.88 x 0.081 [378 x 327 x 2.0]	16 x 14	1.5
HW-MP1816A	\$26.50	16.88 x 14.88 x 0.081 [429 x 378 x 2.0]	18 x 16	2.5
HW-MP2016A	\$33.50	18.88 x 14.88 x 0.081 [479 x 378 x 2.0]	20 x 16	2.4
HW-MP2020AL	\$94.00	18.0 x 18.0 x 0.129 [457 x 457 x 3.3]	20 x 20	3.7
HW-MP2420AL	\$113.00	22.0 x 18.0 x 0.129 [558 x 457 x 3.3]	24 x 20	4.5
HW-MP2424AL	\$139.00	22.0 x 22.0 x 0.129 [558 x 558 x 3.3]	24 x 24	5.4

Note: Dimensions in inches [millimeters].

Dimensions

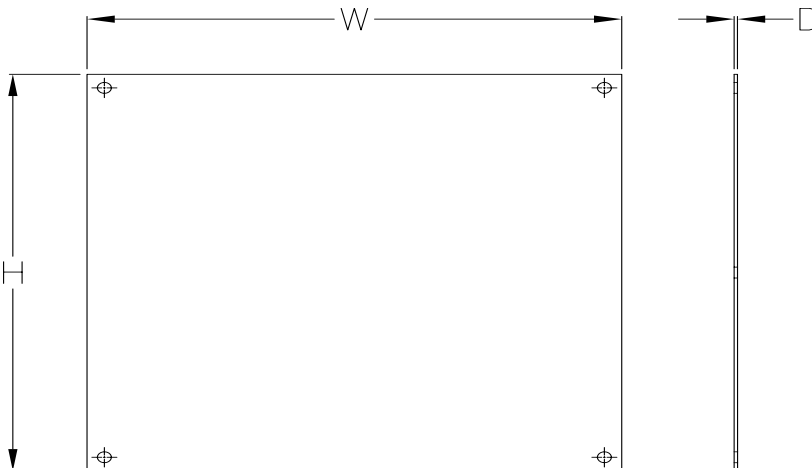

See our website: www.AutomationDirect.com for complete engineering drawings.

Enclosure Accessories - Hole Seals and Plugs



Hole Plugs for Non-Metal Enclosures

Designed to seal extra pushbutton holes, conduit openings, and knockout openings in Hubbell-Wiegman fiberglass enclosures from dirt, dust, oil, and water. Conduit hole sizes are nominal trade sizes, not actual hole sizes. (Example: 1 in. conduit actual diameter = 1.315 in.)



Hole Plugs	Price	Description	Nominal Hole Diameter Range in [mm]	Wt. [oz]
HW-FGHP	\$4.75	Hubbell-Wiegmann hole plug, fiber-reinforced plastic (FRP), closed-cell neoprene gasket, for 1/2 to 3/4-inch hole in non-metallic enclosure	0.50 - 0.81 [12.7 - 20.6]	2
HW-FGHP-PB-000	\$11.50	Hubbell-Wiegmann hole plug, fiberglass-reinforced plastic (FRP), closed-cell neoprene gasket. For use with 1/2in conduit holes in non-metallic enclosures.	0.88 [22.4]	2
HW-FGHP-PB-075	\$5.75	Hubbell-Wiegmann hole plug, fiber-reinforced plastic (FRP), closed-cell neoprene gasket, for 1/2- to 3/4-inch conduit holes and 22 or 30mm pushbutton holes in non-metallic enclosure	0.88 - 1.28 [22.4 - 32.5]	2
HW-FGHP-100-125	\$9.50	Hubbell-Wiegmann hole plug, fiber-reinforced plastic (FRP), closed-cell neoprene gasket, for 1 to 1-1/4 inch conduit holes in non-metallic enclosure	1.38 - 1.75 [35.1 - 44.5]	2
HW-FGHP-150-200*	\$11.50	Hubbell-Wiegmann hole plug, fiber-reinforced plastic (FRP), closed-cell neoprene gasket, for 1-1/2 to 2-inch conduit holes in non-metallic enclosure	2.00 - 2.56 [50.1 - 65.0]	2
HW-FGHP-200-275	\$21.50	Hubbell-Wiegmann hole plug, fiberglass-reinforced plastic (FRP), closed-cell neoprene gasket. For use with 2-1/2in conduit holes in non-metallic enclosures.	3.00 [76.2]	2
HW-FGHP-250-350	\$28.50	Hubbell-Wiegmann hole plug, fiberglass-reinforced plastic (FRP), closed-cell neoprene gasket. For use with 3in conduit holes in non-metallic enclosures.	3.62 [92.0]	2
HW-FGHP-300-425	\$37.00	Hubbell-Wiegmann hole plug, fiberglass-reinforced plastic (FRP), closed-cell neoprene gasket. For use with 3-1/2in conduit holes in non-metallic enclosures.	4.12 [104.7]	2
HW-FGHP-350-500	\$47.50	Hubbell-Wiegmann hole plug, fiberglass-reinforced plastic (FRP), closed-cell neoprene gasket. For use with 4in conduit holes in non-metallic enclosures.	4.62 [117.4]	2

**Note: Will maintain NEMA 4X rating.*

Enclosure Shipping Schedule			
Same day	1-7 days	1-10 days	1 - 15 days

Color indicates shipping lead time in business days.

Vents and Louvers for Non-Metallic Enclosures



Drain/Breather Vents



HW-DVKIT



HW-4XBKIT



HW-4XDVKIT

Part Number	Price	Description	Wt. (oz)
HW-DV	\$9.75	Hubbell-Wiegmann single drain vent, PVC. For use on non-metallic enclosures. Includes drain vent and silicone adhesive/sealant.	2
HW-DVKIT	\$14.00	Hubbell-Wiegmann single drain vent kit, PVC. Includes drain vent and silicone adhesive/sealant.	2
HW-4XBKIT	\$48.00	Hubbell-Wiegmann single breather vent kit allows enclosure to "breathe" while maintaining UL Type 4X enclosure rating.	4.8
HW-4XDVKIT	\$20.00	Hubbell-Wiegmann single drain vent kit properly drains unwanted moisture while maintaining UL Type 4X enclosure rating.	3.2

Enclosure Shipping Schedule				
Same day	1 - 7 days	1 - 10 days	1 - 15 days	1 - 20 days
Color indicates shipping lead time in business days.				

Louver Plate



HW-LPKIT

Part Number	Price	Description	Wt.
HW-LP	\$14.00	Louver plate, for ventilation in non-metallic enclosure, polypropylene, 4.5 inch wide x 4.0 inch high. For 3 inch x 3 inch cutout.	2 oz
HW-LPKIT	\$30.50	Louver plate kit, for ventilation in non-metallic enclosure. Includes 4.5 inch wide x 4.0 inch high polypropylene louver plate, rivets and silicone adhesive/sealant. For 3 inch x 3 inch cutout.	2 oz