

# Fiberglass Enclosures – JIC Series

## Screw Cover



**HW-J100805SC**  
Crowned Cover Model Shown

### Construction

- Hot compression molded fiberglass reinforced polyester (thermoset)
- Poured polyurethane seamless gasket provides watertight, dust-tight environmental seal
- 304 stainless used on all external hardware
- Rounded edges, minimal protrusions or exposed pocket area for accumulation of dust or debris
- Molded in flange for easy mounting
- Raised bosses with brass inserts accepting 10-32 screws for optional panel mounting
- Stainless steel beaded cover retention chain
- Workable material cuts, drills, punches and saws with ease and accuracy
- Submersible, non-corrosive environmental design
- Lift off cover
- Non-conductive, UV resistant
- High impact resistance - 216 in/lb per UL746C
- Smooth surface, no color variations, swirls or color pockets, no voids
- Color: Gray

### Listings

- UL/cUL 50/508, Types 1, 3R, 4X, 6P, 12 [UL File E64791]
- CSA Certified, Types 1, 3R, 4X, 6P, 12 [CSA File 222873]
- NEMA Standard 250, Types 1, 3R, 4x, 6P, 12
- Temperature Range: -76°F to 274°F [-60°C to 134°C]
- Flammability Rating: UL94-5V
- Non-flame propagating
- Flame Spread classification per NFPA No. 101: Class A [1]



#### Enclosure Shipping Schedule

Same day	1 - 10 days	1-15 days
----------	-------------	-----------

Color indicates shipping lead time in business days.

JIC Series Fiberglass Enclosures - Screw Cover							
Part Number	Price	Enclosure Overall Size HxWxD	Wt. [lb]	Carbon Steel Subpanel	Fiberglass Subpanel	Stainless Steel Subpanel	Aluminum Subpanel
HW-J60404SC	\$43.50	7.47 x 5.45 x 4.70 [190 x 138 x 119]	2.5	HW-MP604CS	HW-MP604FG	HW-MP604SS	HW-MP604A
HW-J60604SC	\$47.00	7.50 x 7.53 x 4.82 [191 x 191 x 122]	2.5	HW-MP606CS	HW-MP606FG	HW-MP606SS	HW-MP606A
HW-J80604SC	\$50.00	9.63 x 7.52 x 4.70 [245 x 191 x 119]	3.2	HW-MP806CS	HW-MP806FG	HW-MP806SS	HW-MP806A
HW-J80804SC	\$66.00	9.56 x 9.38 x 4.87 [243 x 238 x 124]	3.4	HW-MP808CS	HW-MP808FG	HW-MP808SS	-
HW-J100804SC	\$52.00	11.63 x 9.41 x 4.22 [295 x 239 x 107]	4.0	HW-MP1008CS	HW-MP1008FG	HW-MP1008SS	HW-MP1008A
HW-J100805SC [crowned cover]*	\$62.00	11.63 x 9.37 x 5.08 [295 x 238 x 129]	4.1	HW-MP1008CS	HW-MP1008FG	HW-MP1008SS	HW-MP1008A
HW-J100806SC	\$83.00	11.97 x 9.42 x 6.50 [304 x 239 x 165]	4.6	HW-MP1008CS	HW-MP1008FG	HW-MP1008SS	HW-MP1008A
HW-J121005SC	\$70.00	13.56 x 11.43 x 5.22 [344 x 291 x 133]	5.8	HW-MP1210CS	HW-MP1210FG	HW-MP1210SS	HW-MP1210A
HW-J141206SC	\$82.00	15.50 x 13.48 x 6.20 [394 x 342 x 157]	8.4	HW-MP1412CS	HW-MP1412FG	HW-MP1412SS	HW-MP1412A
HW-J161406SC	\$97.00	17.53 x 15.46 x 6.21 [445 x 393 x 157]	10.4	HW-MP1614CS	HW-MP1614FG	HW-MP1614SS	HW-MP1614A
HW-J181608SC	\$127.00	19.63 x 17.61 x 8.81 [499 x 447 x 224]	17.6	HW-MP1816CS	HW-MP1816FG	HW-MP1816SS	HW-MP1816A
HW-J201608SC	\$223.00	22.00 x 17.68 x 8.81 [559 x 449 x 224]	19.9	HW-MP2016CS	HW-MP2016FG	HW-MP2016SS	HW-MP2016A

*Notes: Subpanels must be ordered separately.  
Dimensions in inches [millimeters].  
\*In crowned cover units, the center of the cover is raised 3/4 in. Crowned cover is available only in 10x8x5 enclosure.*

# Fiberglass Enclosures – JIC Series

## Hinged Screw Cover



**HW-J141206CHSC**

### Construction

- Hot compression molded fiberglass reinforced polyester (thermoset)
- Poured polyurethane seamless gasket provides watertight, dust-tight environmental seal
- 304 stainless used on all external hardware
- Rounded edges, minimal protrusions or exposed pocket area for accumulation of dust or debris
- Molded in flange for easy mounting
- Raised bosses with brass inserts accepting 10-32 screws for optional panel mounting
- Workable material cuts, drills, punches and saw with ease and accuracy
- Submersible, non-corrosive environmental design
- Full length stainless steel hinged cover with two screws
- Full 180° door opening
- Non-conductive, UV resistant
- High impact resistance - 216 in/lb per UL746C
- Smooth surface, no color variations, swirls or color pockets, no voids
- Color: Gray

### Listings

- UL/cUL 50/508, Types 1, 3R, 4X, 6P, 12 [UL File E64791]
- CSA Certified, Types 1, 3R, 4X, 6P, 12 [CSA File 222873]
- NEMA Standard 250, Types 1, 3R, 4X, 6P, 12
- Temperature Range: -76°F to 274°F [-60°C to 134°C]
- Flammability Rating: UL94-5V
- Non-flame propagating
- Flame Spread classification per NFPA No. 101: Class A [1]

Enclosure Shipping Schedule		
Same day	1 - 10 days	1-15 days
Color indicates shipping lead time in business days.		

JIC Series Fiberglass Enclosures - Hinged Screw Cover							
Part Number	Price	Enclosure Overall Size HxWxD	Wt. [lb]	Carbon Steel Subpanel	Fiberglass Subpanel	Stainless Steel Subpanel	Aluminum Subpanel
<b>HW-J60404CHSC</b>	\$46.50	7.47 x 5.45 x 4.70 [191 x 138 x 119]	2.1	<b>HW-MP604CS</b>	<b>HW-MP604FG</b>	<b>HW-MP604SS</b>	<b>HW-MP604A</b>
<b>HW-J60604CHSC</b>	\$53.00	7.50 x 7.53 x 4.82 [191 x 191 x 122]	2.5	<b>HW-MP606CS</b>	<b>HW-MP606FG</b>	<b>HW-MP606SS</b>	<b>HW-MP606A</b>
<b>HW-J80604CHSC</b>	\$55.00	9.63 x 7.52 x 4.70 [245 x 191 x 119]	3.2	<b>HW-MP806CS</b>	<b>HW-MP806FG</b>	<b>HW-MP806SS</b>	<b>HW-MP806A</b>
<b>HW-J80804CHSC</b>	\$78.00	9.56 x 9.38 x 4.87 [243 x 238 x 124]	3.2	<b>HW-MP808CS</b>	<b>HW-MP808FG</b>	<b>HW-MP808SS</b>	-
<b>HW-J100804CHSC</b>	\$64.00	11.63 x 9.41 x 4.22 [295 x 239 x 107]	4.0	<b>HW-MP1008CS</b>	<b>HW-MP1008FG</b>	<b>HW-MP1008SS</b>	<b>HW-MP1008A</b>
<b>HW-J100805CHSC [crowned cover]*</b>	\$67.00	11.62 x 9.37 x 5.06 [295 x 238 x 129]	4.1	<b>HW-MP1008CS</b>	<b>HW-MP1008FG</b>	<b>HW-MP1008SS</b>	<b>HW-MP1008A</b>
<b>HW-J100806CHSC</b>	\$89.00	11.97 x 9.42 x 6.50 [304 x 239 x 165]	4.6	<b>HW-MP1008CS</b>	<b>HW-MP1008FG</b>	<b>HW-MP1008SS</b>	<b>HW-MP1008A</b>
<b>HW-J121005CHSC</b>	\$75.00	13.56 x 11.43 x 5.22 [344 x 291 x 133]	5.8	<b>HW-MP1210CS</b>	<b>HW-MP1210FG</b>	<b>HW-MP1210SS</b>	<b>HW-MP1210A</b>
<b>HW-J141206CHSC</b>	\$87.00	15.50 x 13.48 x 6.20 [394 x 342 x 158]	8.4	<b>HW-MP1412CS</b>	<b>HW-MP1412FG</b>	<b>HW-MP1412SS</b>	<b>HW-MP1412A</b>
<b>HW-J161406CHSC</b>	\$100.00	17.53 x 15.46 x 6.23 [445 x 393 x 157]	10.4	<b>HW-MP1614CS</b>	<b>HW-MP1614FG</b>	<b>HW-MP1614SS</b>	<b>HW-MP1614A</b>
<b>HW-J181608CHSC</b>	\$133.00	19.62 x 17.61 x 8.81 [498 x 447 x 224]	17.6	<b>HW-MP1816CS</b>	<b>HW-MP1816FG</b>	<b>HW-MP1816SS</b>	<b>HW-MP1816A</b>
<b>HW-J201608CHSC</b>	\$230.00	22.00 x 17.68 x 8.81 [559 x 449 x 224]	19.9	<b>HW-MP2016CS</b>	<b>HW-MP2016FG</b>	<b>HW-MP2016SS</b>	<b>HW-MP2016A</b>

*Notes: Subpanels must be ordered separately.  
Dimensions in inches [millimeters].  
\*In crowned cover units, the center of the cover is raised 3/4 in. Crowned cover is available only in 10x8x5 enclosure.*

# Fiberglass Enclosures – JIC Series

## White Hinged Screw Cover



**HW-WHJ121005CHSC**



### Construction

- Hot compression molded fiberglass reinforced polyester (thermostat)
- Poured polyurethane seamless gasket provides watertight, dust-tight environmental seal
- 304 stainless steel used on all external hardware
- Rounded edges, minimal protrusions or exposed pocket areas for accumulation of dust or debris
- Molded in flange for ease of mounting
- Raised bosses with brass inserts accepting 10-32 screws for optional panel mounting
- Workable material cuts, drills, punches, and saws with ease and accuracy
- Submersible, non-corrosive environmental design
- Full length, stainless steel hinged cover with two screws
- Full 180° door opening
- Non-conductive, UV resistant
- High impact resistance - 216 in/lb per UL746C
- Smooth surface, no color variations, swirls or color pockets, no voids
- Color: White

### Listings

- UL/cUL 50/508, Types 1, 3R, 4X, 6P, 12 [UL File E64791]
- CSA Certified, Types 1, 3R, 4X, 6P, 12 [CSA File 222873]
- NEMA Standard 250, Types 1, 3R, 4X, 6P, 12
- Temperature Range: -76°F to 274°F [-60°C to 134°C]
- Flammability Rating: UL94-5V
- Non-flame propagating
- Flame Spread classification per NFPA No. 101: Class A [1]



Enclosure Shipping Schedule		
Same day	1-10 days	1 - 15 days
Color indicates shipping lead time in business days.		

JIC Series Fiberglass Enclosures – White Hinged Screw Cover							
Part Number	Price	Enclosure Overall Size HxWxD	Wt. (lb)	Carbon Steel Subpanel	Fiberglass Subpanel	Stainless Steel Subpanel	Aluminum Subpanel
<b>HW-WHJ60404CHSC</b>	\$75.00	7.47 x 5.45 x 4.70 [190 x 138 x 119]	2.1	<b>HW-MP604CS</b>	<b>HW-MP604FG</b>	<b>HW-MP604SS</b>	<b>HW-MP604A</b>
<b>HW-WHJ60604CHSC</b>	\$86.00	7.50 x 7.53 x 4.82 [191 x 191 x 122]	2.4	<b>HW-MP606CS</b>	<b>HW-MP606FG</b>	<b>HW-MP606SS</b>	<b>HW-MP606A</b>
<b>HW-WHJ80604CHSC</b>	\$89.00	9.63 x 7.52 x 4.70 [245 x 191 x 119]	3.0	<b>HW-MP806CS</b>	<b>HW-MP806FG</b>	<b>HW-MP806SS</b>	<b>HW-MP806A</b>
<b>HW-WHJ100804CHSC</b>	\$109.00	11.63 x 9.41 x 4.22 [295 x 239 x 107]	3.8	<b>HW-MP1008CS</b>	<b>HW-MP1008FG</b>	<b>HW-MP1008SS</b>	<b>HW-MP1008A</b>
<b>HW-WHJ121005CHSC</b>	\$128.00	13.56 x 11.43 x 5.22 [344 x 291 x 133]	5.7	<b>HW-MP1210CS</b>	<b>HW-MP1210FG</b>	<b>HW-MP1210SS</b>	<b>HW-MP1210A</b>
<b>HW-WHJ141206CHSC</b>	\$148.00	15.50 x 13.48 x 6.20 [394 x 342 x 158]	8.6	<b>HW-MP1412CS</b>	<b>HW-MP1412FG</b>	<b>HW-MP1412SS</b>	<b>HW-MP1412A</b>
<b>HW-WHJ161406CHSC</b>	\$170.00	17.53 x 15.46 x 6.21 [445 x 393 x 157]	10.0	<b>HW-MP1614CS</b>	<b>HW-MP1614FG</b>	<b>HW-MP1614SS</b>	<b>HW-MP1614A</b>
<b>HW-WHJ181608CHSC</b>	\$225.00	19.63 x 17.61 x 8.81 [499 x 447 x 224]	17.1	<b>HW-MP1816CS</b>	<b>HW-MP1816FG</b>	<b>HW-MP1816SS</b>	<b>HW-MP1816A</b>
<b>HW-WHJ201608CHSC</b>	\$388.00	22.00 x 17.68 x 8.81 [559 x 449 x 224]	19.9	<b>HW-MP2016CS</b>	<b>HW-MP2016FG</b>	<b>HW-MP2016SS</b>	<b>HW-MP2016A</b>

*Notes: Subpanels must be ordered separately.  
Dimensions in inches [millimeters].*

# Fiberglass Enclosures – JIC Series

## Single Door with Twist-Lock Latches



**HW-J121005CHTL**

### Construction

- Hot compression molded fiberglass reinforced polyester (thermoset)
- Poured polyurethane seamless gasket provides watertight, dust-tight environmental seal
- 304 stainless steel used on all external hardware
- Rounded edges, minimal protrusions or exposed pocket area for accumulation of dust or debris
- Molded in flange for easy mounting
- Raised bosses with brass inserts accepting 10-32 screws for optional panel mounting
- Workable material cuts, drills, punches and saws with ease and accuracy
- Full length, stainless steel, hinged cover with twist-lock latches
- Full 180° door opening
- Non-conductive, UV resistant
- High impact resistance - 216 in/lb per UL746C
- Smooth surface, no color variations, swirls or color pockets, no voids
- Submersible, non-corrosive environmental design
- Color: Gray

### Listings

- UL/cUL 50/508, Types 1, 3R, 4X, 6P, 12 [UL File E64791]
- CSA Certified, Types 1, 3R, 4X, 6P, 12 [CSA File 222873]
- NEMA Standard 250, Types 1, 3R, 4X, 6P, 12
- Temperature Range: -76°F to 274°F [-60°C to 134°C]
- Flammability Rating: UL94-5V
- Non-flame propagating
- Flame Spread classification per NFPA No. 101: Class A [1]



### Enclosure Shipping Schedule

Same day	1 - 7 days	1-10 days	1 - 15 days
----------	------------	-----------	-------------

Color indicates shipping lead time in business days.

### JIC Series Fiberglass Enclosures - Single Door with Twist-Lock Latches

Part Number	Price	Enclosure Overall Size HxWxD	Wt. [lb]	No. Latches	Carbon Steel Subpanel	Fiberglass Subpanel	Stainless Steel Subpanel	Aluminum Subpanel
<b>HW-J60404CHTL</b>	\$86.00	7.47 x 5.45 x 4.70 [190 x 138 x 119]	2.2	1	HW-MP604CS	HW-MP604FG	HW-MP604SS	HW-MP604A
<b>HW-J60604CHTL</b>	\$89.00	7.50 x 7.53 x 4.82 [191 x 191 x 122]	2.6	1	HW-MP606CS	HW-MP606FG	HW-MP606SS	HW-MP606A
<b>HW-J80604CHTL</b>	\$90.00	9.63 x 7.52 x 4.70 [245 x 191 x 119]	3.1	1	HW-MP680CS	HW-MP680FG	HW-MP680SS	HW-MP680A
<b>HW-J80804CHTL</b>	\$94.00	9.56 x 9.38 x 4.87 [243 x 238 x 124]	3.3	1	HW-MP808CS	HW-MP808FG	HW-MP808SS	-
<b>HW-J100804CHTL</b>	\$98.00	11.63 x 9.41 x 4.22 [295 x 239 x 107]	4.0	2	HW-MP1008CS	HW-MP1008FG	HW-MP1008SS	HW-MP1008A
<b>HW-J100805CHTL [crowned cover]*</b>	\$104.00	11.63 x 9.37 x 5.08 [295 x 238 x 129]	4.3	2	HW-MP1008CS	HW-MP1008FG	HW-MP1008SS	HW-MP1008A
<b>HW-J100806CHTL</b>	\$104.00	11.97 x 9.42 x 6.50 [304 x 239 x 165]	4.6	1	HW-MP1008CS	HW-MP1008FG	HW-MP1008SS	HW-MP1008A
<b>HW-J121005CHTL</b>	\$112.00	13.56 x 11.43 x 5.22 [344 x 291 x 133]	5.8	2	HW-MP1210CS	HW-MP1210FG	HW-MP1210SS	HW-MP1210A
<b>HW-J141206CHTL</b>	\$142.00	15.50 x 13.48 x 6.20 [394 x 342 x 158]	9.2	2	HW-MP1412CS	HW-MP1412FG	HW-MP1412SS	HW-MP1412A
<b>HW-J161406CHTL</b>	\$154.00	17.53 x 15.46 x 6.21 [445 x 393 x 157]	9.5	2	HW-MP1614CS	HW-MP1614FG	HW-MP1615SS	HW-MP1614A
<b>HW-J181608CHTL</b>	\$200.00	19.63 x 17.61 x 8.81 [499 x 447 x 224]	17.3	2	HW-MP1816CS	HW-MP1816FG	HW-MP1816SS	HW-MP1816A
<b>HW-J201608CHTL</b>	\$334.00	22.00 x 17.68 x 8.81 [559 x 449 x 224]	19.0	2	HW-MP2016CS	HW-MP2016FG	HW-MP2016CS	HW-MP2016A

Notes: Subpanels must be ordered separately.

Dimensions in inches [millimeters].

\*In crowned cover units, the center of the cover is raised 3/4 in. Crowned cover is available only in 10x8x5 enclosure.

# Fiberglass Enclosures – JIC Series

## Single Door with Quick-Release Latches



**HW-J121005CHQR**

### Construction

- Hot compression molded fiberglass reinforced polyester (thermoset)
- Poured polyurethane seamless gasket provides watertight, dust-tight environmental seal
- 304 stainless steel used on all external hardware
- Rounded edges, minimal protrusions or exposed pocket areas for accumulation of dust or debris
- Molded in flange for easy mounting
- Raised bosses with brass inserts accepting 10-32 screws for optional panel mounting
- Workable material cuts, drills, punches and saws with ease and accuracy
- Full length, stainless steel, hinged cover with padlockable quick-release latches
- Full 180° door opening
- Non-conductive, UV resistant
- High impact resistance - 216 in/lb per UL746C

- Smooth surface, no color variations, swirls or color pockets, no voids
- Submersible, non-corrosive environmental design
- Color: Gray

### Listings

- UL/cUL 50/508, Types 1, 3R, 4X, 6P, 12 [UL File E64791]
- CSA Certified, Types 1, 3R, 4X, 6P, 12 [CSA File 222873]
- NEMA Standard 250, Types 1, 3, 4x, 6P, 12
- Temperature Range: -76°F to 274°F [-60°C to 134°C]
- Flammability Rating: UL94-5V
- Non-flame propagating
- Flame Spread classification per NFPA No. 101: Class A [1]



Enclosure Shipping Schedule			
Same day	1 - 7 days	1-10 days	1 - 15 days

Color indicates shipping lead time in business days.

JIC Series Fiberglass Enclosures - Single Door with Quick-Release Latches								
Part Number	Price	Enclosure Overall Size HxWxD	Wt. [lb]	No. Latches	Carbon Steel Subpanel	Fiberglass Subpanel	Stainless Steel Subpanel	Aluminum Subpanel
HW-J60404CHQR	\$65.00	7.47 x 5.45 x 4.70 [190 x 138 x 119]	2.1	1	HW-MP604CS	HW-MP604FG	HW-MP604SS	HW-MP604A
HW-J60604CHQR	\$67.00	7.50 x 7.53 x 4.82 [191 x 191 x 122]	2.5	1	HW-MP606CS	HW-MP606FG	HW-MP606SS	HW-MP606A
HW-J80604CHQR	\$68.00	9.63 x 7.52 x 4.70 [245 x 191 x 119]	3.2	1	HW-MP806CS	HW-MP806FG	HW-MP806SS	HW-MP806A
HW-J80804CHQR	\$92.00	9.56 x 9.38 x 4.87 [243 x 238 x 124]	3.3	1	HW-MP808CS	HW-MP808FG	HW-MP808SS	-
HW-J100804CHQR	\$74.00	11.63 x 9.41 x 4.22 [295 x 239 x 107]	4.1	2	HW-MP1008CS	HW-MP1008FG	HW-MP1008SS	HW-MP1008A
HW-J100805CHQR [crowned cover]*	\$76.00	11.63 x 9.37 x 5.08 [295 x 238 x 129]	4.1	2	HW-MP1008CS	HW-MP1008FG	HW-MP1008SS	HW-MP1008A
HW-J100806CHQR	\$101.00	11.97 x 9.42 x 6.50 [304 x 239 x 165]	4.6	1	HW-MP1008CS	HW-MP1008FG	HW-MP1008SS	HW-MP1008A
HW-J121005CHQR	\$85.00	13.56 x 11.43 x 5.22 [344 x 291 x 133]	5.8	2	HW-MP1210CS	HW-MP1210FG	HW-MP1210SS	HW-MP1210A
HW-J141206CHQR	\$107.00	15.50 x 13.48 x 6.20 [394 x 342 x 158]	8.4	2	HW-MP1412CS	HW-MP1412FG	HW-MP1412SS	HW-MP1412A
HW-J161406CHQR	\$116.00	17.53 x 15.46 x 6.21 [445 x 393 x 157]	10.4	2	HW-MP1614CS	HW-MP1614FG	HW-MP1614SS	HW-MP1614A
HW-J181608CHQR	\$151.00	19.63 x 17.61 x 8.81 [499 x 447 x 224]	17.6	2	HW-MP1816CS	HW-MP1816FG	HW-MP1816SS	HW-MP1816A
HW-J201608CHQR	\$239.00	22.00 x 17.68 x 8.81 [559 x 449 x 224]	19.9	2	HW-MP2016CS	HW-MP2016FG	HW-MP2016SS	HW-MP2016A
HW-J202010CHQR	\$359.00	23.50 x 22.12 x 11.70 [597 x 562 x 297]	26.4	1	HW-MP2020CS	HW-MP2020FG	-	HW-MP2020AL
HW-J242010CHQR	\$517.00	27.50 x 22.12 x 11.70 [699 x 562 x 297]	32.2	1	HW-MP2420CS	HW-MP2420FG	-	HW-MP2420AL
HW-J242410CHQR	\$613.00	27.50 x 26.12 x 11.70 [699 x 663 x 297]	37.0	1	HW-MP2424CS	HW-MP2424FG	-	HW-MP2424AL

Notes: Subpanels must be ordered separately.  
 Dimensions in inches [millimeters].  
 \*In crowned cover units, the center of the cover is raised 3/4 in. Crowned cover is available only in 10x8x5 enclosure.



# Fiberglass Enclosures – JIC Series

## White Single Door with Quick-Release Latches



**HW-WHJ161406CHQR**



### Construction

- Hot compression molded fiberglass reinforced polyester (thermoset)
- Poured polyurethane seamless gasket provides watertight, dust-tight environmental seal
- 304 stainless used on all external hardware
- Rounded edges, minimal protrusions or exposed pocket area for accumulation of dust or debris
- Molded in flange for easy mounting
- Raised bosses with brass inserts accepting 10-32 screws for optional panel mounting
- Workable material cuts, drills, punches and saw with ease and accuracy
- Submersible, non-corrosive environmental design
- Full length stainless steel hinged cover with padlockable quick-release latches
- Full 180° door opening
- Non-conductive, UV resistant
- High impact resistance - 216 in/lb per UL746C
- Smooth surface, no color variations, swirls or color pockets, no voids
- Color: White

### Listings

- UL/cUL 50/508, Types 1, 3R, 4X, 6P, 12 [File E64791]
- CSA Certified, Types 1, 3, 4X, 6P, 12 [CSA File 222873]
- NEMA Standard 250, Types 1, 3, 4x, 6P, 12
- Temperature Range: -76°F to 274°F [-60°C to 134°C]
- Flammability Rating: UL94-5V
- Non-flame propagating
- Flame Spread classification per NFPA No. 101: Class A [1]



### Enclosure Shipping Schedule

Same day	1 -10 days
Color indicates shipping lead time in business days.	

### JIC Series Fiberglass Enclosures - White Single Door with Quick Release Latches

Part Number	Price	Enclosure Overall Size HxWxD	Wt. (lb)	No. Latches	Carbon Steel Subpanel	Fiberglass Subpanel	Stainless Steel Subpanel	Aluminum Subpanel
<b>HW-WHJ60404CHQR</b>	\$89.00	7.47 x 5.45 x 4.70 [190 x 138 x 119]	2.1	1	<b>HW-MP604CS</b>	<b>HW-MP604FG</b>	<b>HW-MP604SS</b>	<b>HW-MP604A</b>
<b>HW-WHJ60604CHQR</b>	\$97.00	7.50 x 7.53 x 4.82 [191 x 191 x 122]	2.4	1	<b>HW-MP606CS</b>	<b>HW-MP606FG</b>	<b>HW-MP606SS</b>	<b>HW-MP606A</b>
<b>HW-WHJ80604CHQR</b>	\$98.00	9.63 x 7.52 x 4.70 [245 x 191 x 119]	3.1	1	<b>HW-MP806CS</b>	<b>HW-MP806FG</b>	<b>HW-MP808SS</b>	<b>HW-MP806A</b>
<b>HW-WHJ100804CHQR</b>	\$107.00	11.63 x 9.41 x 4.22 [295 x 239 x 107]	4.1	2	<b>HW-MP1008CS</b>	<b>HW-MP1008FG</b>	<b>HW-MP1008SS</b>	<b>HW-MP1008A</b>
<b>HW-WHJ121005CHQR</b>	\$122.00	13.56 x 11.43 x 5.22 [344 x 291 x 133]	5.9	2	<b>HW-MP1210CS</b>	<b>HW-MP1210FG</b>	<b>HW-MP1210SS</b>	<b>HW-MP1210A</b>
<b>HW-WHJ141206CHQR</b>	\$154.00	15.50 x 13.48 x 6.20 [394 x 342 x 158]	8.7	2	<b>HW-MP1412CS</b>	<b>HW-MP1412FG</b>	<b>HW-MP1412SS</b>	<b>HW-MP1412A</b>
<b>HW-WHJ161406CHQR</b>	\$168.00	17.53 x 15.46 x 6.21 [445 x 393 x 157]	10.7	2	<b>HW-MP1614CS</b>	<b>HW-MP1614FG</b>	<b>HW-MP1614SS</b>	<b>HW-MP1614A</b>
<b>HW-WHJ181608CHQR</b>	\$218.00	19.63 x 17.61 x 8.81 [499 x 447 x 224]	17.5	2	<b>HW-MP1816CS</b>	<b>HW-MP1816FG</b>	<b>HW-MP1816SS</b>	<b>HW-MP1816A</b>
<b>HW-WHJ201608CHQR</b>	\$345.00	22.00 x 17.68 x 8.81 [559 x 449 x 224]	19.8	2	<b>HW-MP2016CS</b>	<b>HW-MP2016FG</b>	<b>HW-MP2016SS</b>	<b>HW-MP2016A</b>

Notes: Subpanels must be ordered separately.  
Dimensions in inches (millimeters).

# Fiberglass Enclosures – JIC Series

## Single Door with 3-Point Latch



**HW-J2020103PT**

### Construction

- Hot compression molded fiberglass reinforced polyester (thermoset)
- 3-point single rotating handle system for ease of use and assurance of security
- Overhang cover on smooth-sided base
- Full 180° door opening
- Mounting foot gussets for structural integrity and robustness
- Slotted mounting hole ensures flexibility in mounting
- All stainless steel latches
- Full length stainless steel hinge
- Chemically resistant fiberglass reinforced composite formulation
- UV resistant
- Channel captured gasket assures seal integrity
- 1/2-inch thick integral mounting flange for structural integrity
- Color: Gray

### Listings

- UL/cUL 50/508, Types 1, 3, 3R, 4, 4X, 12, 13 [UL File E64791]
- CSA Certified, Types 1, 3, 3R, 4, 4X, 12, 13 [CSA File 222873]
- NEMA Standard 250 Types 1, 3, 3R, 4, 4X, 12, 13
- IEC 60529 IP66
- Temperature Range: -76°F to 274°F [-60°C to 134°C]
- Flammability Rating: UL94-5V
- Non-flame propagating
- Flame Spread classification per NFPA No. 101: Class A [1]



### Enclosure Shipping Schedule

1 - 7 days

1 - 10 days

Color indicates shipping lead time in business days.

JIC Series Fiberglass Enclosures - Single Door with 3-Point Latch						
Part Number	Price	Enclosure Overall Size HxWxD	Wt. [lb]	Carbon Steel Subpanel	Fiberglass Subpanel	Aluminum Subpanel
<b>HW-J2020103PT</b>	\$446.00	23.50 x 22.12 x 11.70 [597 x 562 x 297]	26.4	<b>MP-2020CS</b>	<b>MP-2020FG</b>	<b>MP-2020AL</b>
<b>HW-J2420103PT</b>	\$541.00	27.50 x 22.12 x 11.70 [699 x 562 x 297]	32.2	<b>MP-2420CS</b>	<b>MP-2420FG</b>	<b>MP-2420AL</b>
<b>HW-J2424103PT</b>	\$699.00	27.50 x 26.12 x 11.70 [699 x 663 x 297]	27.5	<b>MP-2424CS</b>	<b>MP-2424FG</b>	<b>MP-2424AL</b>

*Notes: Subpanels must be ordered separately.  
Dimensions in inches [millimeters].*

# Fiberglass Enclosures – JIC Series

## Single Door with Acrylic Window and Twist-Lock Latches



HW-J121005CHTLW

### Construction

- Hot compression molded fiberglass reinforced polyester (thermoset)
- Poured polyurethane seamless gasket provides watertight, dust-tight environmental seal
- 304 stainless steel used on all external hardware
- Rounded edges, minimal protrusions or exposed pocket area for accumulation of dust or debris
- Molded in flange for easy mounting
- Raised bosses with brass inserts accepting 10-32 screws for optional panel mounting
- Workable material cuts, drills, punches and saws with ease and accuracy
- Scratch- and abrasion-resistant UVA acrylic flush bonded window
- Submersible, non-corrosive environmental design
- Full 180° door opening
- Non-conductive, UV resistant
- High impact resistance - 216 in/lb per UL746C
- Smooth surface, no color variations, swirls or color pockets, no voids
- Full length stainless steel hinged cover with twist-lock latches
- Color: Gray

### Listings

- UL/cUL 50/508, Types 1, 3R, 4X, 6P, 12 [UL File E64791]
- CSA Certified, Types 1, 3R, 4X, 6P, 12 [CSA File 222873]
- NEMA Standard 250 Types 1, 3R, 4X, 6P, 12
- Temperature Range: -26°F to 170°F [-32°C to 76°C]
- Temperature Range Window: -26°F to 170°F [-32°C to 76°C]
- Flammability Rating: UL94-5V
- Flammability Rating window: UL94V-HB
- Non-flame propagating
- Flame Spread classification per NFPA No. 101: Class A [1]



Enclosure Shipping Schedule		
Same day	1 - 10 days	1-15 days
Color indicates shipping lead time in business days.		

JIC Series Fiberglass Enclosures - Single Door with Acrylic Window and Twist-Lock Latches								
Part Number	Price	Enclosure Overall Size HxWxD	Wt. [lb]	No. Latches	Carbon Steel Subpanel	Fiberglass Subpanel	Stainless Steel Subpanel	Aluminum Subpanel
HW-J60404CHTLW	\$83.00	7.47 x 5.45 x 4.70 [190 x 138 x 119]	2.5	1	HW-MP604CS	HW-MP604FG	HW-MP604SS	HW-MP604A
HW-J80604CHTLW	\$96.00	9.63 x 7.52 x 4.70 [245 x 191 x 119]	3.5	1	HW-MP806CS	HW-MP806FG	HW-MP806SS	HW-MP806A
HW-J100804CHTLW	\$111.00	11.63 x 9.41 x 4.22 [295 x 239 x 107]	5	2	HW-MP1008CS	HW-MP1008FG	HW-MP1008SS	HW-MP1008A
HW-J100806CHTLW	\$188.00	11.97 x 9.42 x 6.50 [304 x 239 x 165]	4.5	2	HW-MP1008CS	HW-MP1008FG	HW-MP1008SS	HW-MP1008A
HW-J121005CHTLW	\$129.00	13.56 x 11.43 x 5.22 [344 x 291 x 133]	6.5	2	HW-MP1210CS	HW-MP1210FG	HW-MP1210SS	HW-MP1210A
HW-J141206CHTLW	\$177.00	15.50 x 13.48 x 6.20 [394 x 342 x 157]	8.5	2	HW-MP1412CS	HW-MP1412FG	HW-MP1412SS	HW-MP1412A
HW-J161406CHTLW	\$195.00	17.53 x 15.46 x 6.21 [445 x 393 x 158]	11.5	2	HW-MP1614CS	HW-MP1614FG	HW-MP1614SS	HW-MP1614A
HW-J181608CHTLW	\$239.00	19.63 x 17.61 x 8.81 [498 x 447 x 224]	19.25	2	HW-MP1816CS	HW-MP1816FG	HW-MP1816SS	HW-MP1816A
HW-J201608CHTLW	\$386.00	22.00 x 17.68 x 8.81 [559 x 449 x 224]	20.25	2	HW-MP2016CS	HW-MP2016FG	HW-MP2016SS	HW-MP2016A

Notes: Subpanels must be ordered separately.  
Dimensions in inches [millimeters].



# Fiberglass Enclosures – JIC Series

## Single Door with Acrylic Window and Quick-Release Latches



**HW-J100804CHQRW**

### Construction

- Hot compression molded fiberglass reinforced polyester (thermoset)
- Poured polyurethane seamless gasket provides watertight, dust-tight environmental seal
- 304 stainless steel used on all external hardware
- Rounded edges, minimal protrusions or exposed pocket area for accumulation of dust or debris
- Molded-in flange for easy mounting
- Raised bosses with brass inserts accepting 10-32 screws for optional panel mounting
- Workable material cuts, drills, punches and saws with ease and accuracy
- Scratch- and abrasion-resistant UVA acrylic flush bonded window
- Submersible, non-corrosive environmental design
- Full 180° door opening
- Non-conductive, UV resistant
- High impact resistance - 216 in/lb per UL746C
- Smooth surface, no color variations, swirls or color pockets, no voids
- Full length stainless steel hinged cover with padlockable quick-release latches
- Color: Gray

### Listings

- UL/cUL 50/508, Types 1, 3R, 4X, 6P, 12 [UL File E64791]
- CSA Certified, Types 1, 3R, 4X, 6P, 12 [CSA File 222873]
- NEMA Standard 250 Types 1, 3R, 4X, 6P, 12
- Temperature Range: -26°F to 170°F [-32°C to 76°C]
- Window Temperature Range: -26°F to 170°F [-32°C to 76°C]
- Flammability Rating: UL94-5V
- Flammability Rating window: UL94V-HB
- Non-flame propagating
- Flame Spread classification per NFPA No. 101: Class A [1]



Enclosure Shipping Schedule		
Same day	1-10 days	1 - 15 days
Color indicates shipping lead time in business days.		


### JIC Series Fiberglass Enclosures - Single Door with Acrylic Window and Quick-Release Latches

Enclosure Part Number	Price	Enclosure Overall Size HxWxD	Wt. [lb]	No. Latches	Carbon Steel Subpanel	Fiberglass Subpanel	Stainless Steel Subpanel	Aluminum Subpanel
<b>HW-J60404CHQRW</b>	\$82.00	7.47 x 5.45 x 4.70 [191 x 138 x 119]	2.5	1	<b>HW-MP604CS</b>	<b>HW-MP604FG</b>	<b>HW-MP604SS</b>	<b>HW-MP604A</b>
<b>HW-J60604CHQRW</b>	\$90.00	7.50 x 7.53 x 4.82 [191 x 191 x 122]	2.75	1	<b>HW-MP606CS</b>	<b>HW-MP606FG</b>	<b>HW-MP606SS</b>	<b>HW-MP606A</b>
<b>HW-J80604CHQRW</b>	\$94.00	9.63 x 7.52 x 4.70 [245 x 191 x 119]	3.5	1	<b>HW-MP806CS</b>	<b>HW-MP806FG</b>	<b>HW-MP806SS</b>	<b>HW-MP806A</b>
<b>HW-J100804CHQRW</b>	\$109.00	11.62 x 9.41 x 4.22 [295 x 239 x 107]	5	2	<b>HW-MP1008CS</b>	<b>HW-MP1008FG</b>	<b>HW-MP1008SS</b>	<b>HW-MP1008A</b>
<b>HW-J100806CHQRW</b>	\$186.00	11.97 x 9.42 x 6.50 [304 x 239 x 165]	4.5	2	<b>HW-MP1008CS</b>	<b>HW-MP1008FG</b>	<b>HW-MP1008SS</b>	<b>HW-MP1008A</b>
<b>HW-J121005CHQRW</b>	\$126.00	13.56 x 11.43 x 5.22 [344 x 291 x 133]	6.5	2	<b>HW-MP1210CS</b>	<b>HW-MP1210FG</b>	<b>HW-MP1210SS</b>	<b>HW-MP1210A</b>
<b>HW-J141206CHQRW</b>	\$174.00	15.50 x 13.48 x 6.20 [394 x 342 x 157]	8.5	2	<b>HW-MP1412CS</b>	<b>HW-MP1412FG</b>	<b>HW-MP1412SS</b>	<b>HW-MP1412A</b>
<b>HW-J161406CHQRW</b>	\$191.00	17.53 x 15.46 x 6.21 [445 x 393 x 158]	11.5	2	<b>HW-MP1614CS</b>	<b>HW-MP1614FG</b>	<b>HW-MP1614SS</b>	<b>HW-MP1614A</b>
<b>HW-J181608CHQRW*</b>	\$234.00	19.63 x 17.61 x 8.82 [499 x 447 x 224]	19.25	2	<b>HW-MP1816CS</b>	<b>HW-MP1816FG</b>	<b>HW-MP1816SS</b>	<b>HW-MP1816A</b>

Notes: Subpanels must be ordered separately.  
Dimensions in inches [millimeters].  
\*1816 size is not 6P rated.

# Fiberglass Enclosures – JIC Series

## Dimensions for JIC Series Enclosures

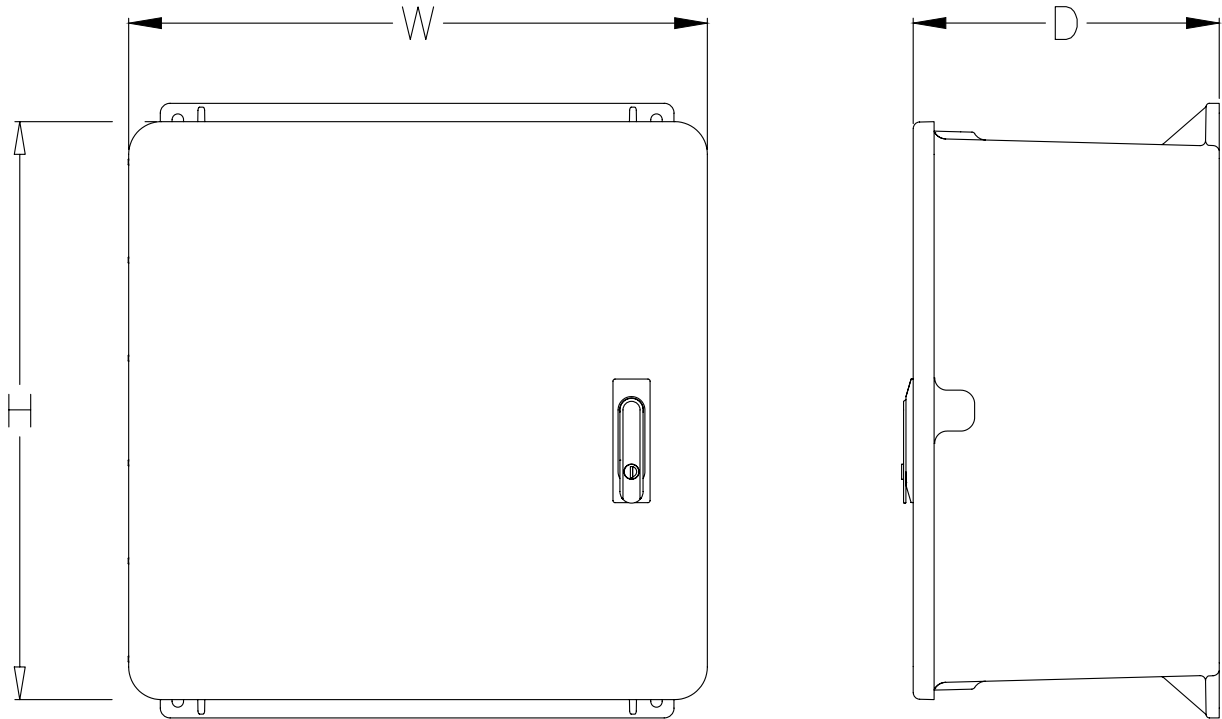

*See our website: [www.AutomationDirect.com](http://www.AutomationDirect.com) for complete engineering drawings.*

# Subpanels for Premier, JIC and Classic Series Fiberglass Enclosures



Subpanel Specifications		
Subpanel	Material	Color/Finish
Carbon Steel	Carbon Steel	White polyester powder Finish
Aluminum	3003H14 Aluminum	Mill Finish
Stainless Steel	304 Stainless	Mill Finish
Fiberglass	FRP (Fiberglass reinforced panel)	Gray



## Carbon steel subpanels

## Fiberglass subpanels

Subpanel Part Number	Price	Subpanel Size HxWxD	Enclosure Nominal Size HxW	Wt (lb)
HW-MP604CS	\$5.75	4.88 x 2.88 x 0.075 [124 x 73 x .19]	6 x 4	0.3
HW-MP606CS	\$5.75	4.88 x 4.88 x 0.075 [124 x 124 x .19]	6 x 6	0.5
HW-MP706CS	\$7.50	6.00 x 4.88 x 0.075 [152 x 124 x .19]	7 x 6	0.6
HW-MP806CS	\$7.75	6.75 x 4.88 x 0.075 [152 x 124 x .19]	8 x 6	0.8
HW-MP808CS	\$10.00	6.88 x 6.88 x 0.075 [175 x 175 x .19]	8 x 8	0.8
HW-MP906CS	\$9.50	8.25 x 4.88 x 0.075 [175 x 124 x .19]	9 x 6	0.9
HW-MP1008CS	\$11.50	8.75 x 6.88 x 0.075 [225 x 175 x .19]	10 x 8	1.3
HW-MP1210CS	\$14.00	10.88 x 8.75 x 0.075 [276 x 225 x .19]	12 x 10	2.1
HW-MP1412CS	\$15.50	12.88 x 10.88 x 0.075 [327 x 276 x .19]	14 x 12	3.0
HW-MP1614CS	\$20.50	14.88 x 12.88 x 0.075 [378 x 327 x .19]	16 x 14	4.1
HW-MP1816CS	\$26.50	16.88 x 14.88 x 0.075 [429 x 378 x .19]	18 x 16	5.4
HW-MP2016CS	\$33.50	18.88 x 14.88 x 0.075 [479 x 378 x .19]	20 x 16	6.1
HW-MP2020CS	\$98.00	18.00 x 18.00 x 0.105 [457 x 457 x 2.7]	20 x 20	9.4
HW-MP2420CS	\$119.00	22.00 x 18.00 x 0.105 [558 x 457 x 2.7]	24 x 20	11
HW-MP2424CS	\$146.00	22.00 x 22.00 x 0.105 [558 x 558 x 2.7]	24 x 24	22

Note: Dimensions in inches [millimeters].

Subpanel Part Number	Price	Subpanel Size HxWxD	Enclosure Nominal Size HxW	Wt. (lb)
HW-MP604FG	\$5.75	4.88 x 2.88 x 0.13 [124 x 73 x 3.2]	6 x 4	0.1
HW-MP606FG	\$5.75	4.88 x 4.88 x 0.13 [124 x 124 x 3.2]	6 x 6	0.2
HW-MP806FG	\$7.75	6.88 x 4.88 x 0.13 [175 x 124 x 3.2]	8 x 6	0.3
HW-MP808FG	\$10.00	6.88 x 6.88 x 0.13 [175 x 175 x 3.2]	8 x 8	0.3
HW-MP1008FG	\$9.50	8.88 x 6.88 x 0.13 [225 x 175 x 3.2]	10 x 8	0.5
HW-MP1210FG	\$13.50	10.88 x 8.88 x 0.13 [276 x 225 x 3.2]	12 x 10	0.9
HW-MP1412FG	\$17.00	12.88 x 10.88 x 0.13 [327 x 276 x 3.2]	14 x 12	1.0
HW-MP1614FG	\$21.00	14.88 x 12.88 x 0.13 [378 x 327 x 3.2]	16 x 14	0.8
HW-MP1816FG	\$27.00	16.88 x 14.88 x 0.13 [429 x 378 x 3.2]	18 x 16	2.0
HW-MP2016FG	\$33.00	18.88 x 14.88 x 0.13 [479 x 378 x 3.2]	20 x 16	2.2
HW-MP2020FG	\$106.00	18.00 x 18.00 x 0.13 [457 x 457 x 3.2]	20 x 20	2.3
HW-MP2420FG	\$128.00	22.00 x 18.00 x 0.13 [558 x 457 x 3.2]	24 x 20	2.8
HW-MP2424FG	\$157.00	22.00 x 22.00 x 0.13 [558 x 558 x 3.2]	24 x 24	3.5

Note: Dimensions in inches [millimeters].

Enclosure Shipping Schedule			
Same day	1-7 days	1 - 10 days	1-15 days

Color indicates shipping lead time in business days.

# Subpanels for Premier, JIC and Classic Series Fiberglass Enclosures

## Stainless steel subpanels

Subpanel Part Number	Price	Subpanel Size HxWxD	Enclosure Nominal Size HxW	Wt. (lb)
<b>HW-MP604SS</b>	\$7.75	4.88 x 2.88 x 0.064 [124 x 73 x 1.5]	6 x 4	0.3
<b>HW-MP606SS</b>	\$9.75	4.88 x 4.88 x 0.064 [124 x 124 x 1.5]	6 x 6	0.5
<b>HW-MP806SS</b>	\$12.50	6.88 x 4.88 x 0.064 [175 x 124 x 1.5]	8 x 6	0.8
<b>HW-MP808SS</b>	\$15.50	6.88 x 6.88 x 0.064 [175 x 175 x 1.5]	8 x 8	0.8
<b>HW-MP1008SS</b>	\$21.00	8.88 x 6.88 x 0.064 [225 x 175 x 1.5]	10 x 8	1.2
<b>HW-MP1210SS</b>	\$31.50	10.88 x 8.88 x 0.064 [276 x 225 x 1.5]	12 x 10	1.9
<b>HW-MP1412SS</b>	\$46.50	12.88 x 10.88 x 0.064 [327 x 276 x 1.5]	14 x 12	2.9
<b>HW-MP1614SS</b>	\$56.00	14.88 x 12.88 x 0.064 [378 x 327 x 1.5]	16 x 14	3.1
<b>HW-MP1816SS</b>	\$65.00	16.88 x 14.88 x 0.064 [429 x 378 x 1.5]	18 x 16	6.0
<b>HW-MP2016SS</b>	\$77.00	18.88 x 14.88 x 0.064 [479 x 378 x 1.5]	20 x 16	6.1

**Note: Dimensions in inches [millimeters].**




## Aluminum subpanels

Subpanel Part Number	Price	Subpanel Size HxWxD	Enclosure Nominal Size HxW	Wt. (lb)
<b>HW-MP604A</b>	\$5.75	4.88 x 2.88 x 0.081 [124 x 73 x 2.0]	6 x 4	0.1
<b>HW-MP606A</b>	\$5.75	4.88 x 4.88 x 0.081 [124 x 124 x 2.0]	6 x 6	0.2
<b>HW-MP806A</b>	\$7.75	6.88 x 4.88 x 0.081 [175 x 124 x 2.0]	8 x 6	0.3
<b>HW-MP1008A</b>	\$11.50	8.88 x 6.88 x 0.081 [225 x 175 x 2.0]	10 x 8	0.5
<b>HW-MP1210A</b>	\$14.00	10.88 x 8.88 x 0.081 [276 x 225 x 2.0]	12 x 10	0.8
<b>HW-MP1412A</b>	\$15.50	12.88 x 10.88 x 0.081 [327 x 276 x 2.0]	14 x 12	1.1
<b>HW-MP1614A</b>	\$20.50	14.88 x 12.88 x 0.081 [378 x 327 x 2.0]	16 x 14	1.5
<b>HW-MP1816A</b>	\$26.50	16.88 x 14.88 x 0.081 [429 x 378 x 2.0]	18 x 16	2.5
<b>HW-MP2016A</b>	\$33.50	18.88 x 14.88 x 0.081 [479 x 378 x 2.0]	20 x 16	2.4
<b>HW-MP2020AL</b>	\$94.00	18.0 x 18.0 x 0.129 [457 x 457 x 3.3]	20 x 20	3.7
<b>HW-MP2420AL</b>	\$113.00	22.0 x 18.0 x 0.129 [558 x 457 x 3.3]	24 x 20	4.5
<b>HW-MP2424AL</b>	\$139.00	22.0 x 22.0 x 0.129 [558 x 558 x 3.3]	24 x 24	5.4

**Note: Dimensions in inches [millimeters].**

Enclosure Shipping Schedule		
Same day	1-7 days	1 - 10 days
Color indicates shipping lead time in business days.		

### Dimensions

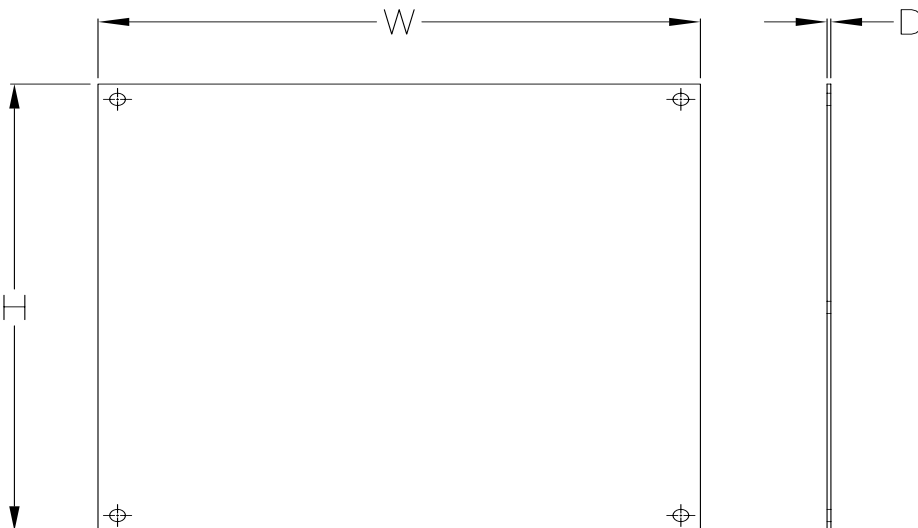

See our website: [www.AutomationDirect.com](http://www.AutomationDirect.com) for complete engineering drawings.

# Enclosure Accessories - Hole Seals and Plugs



## Hole Plugs for Non-Metal Enclosures

Designed to seal extra pushbutton holes, conduit openings, and knockout openings in Hubbell-Wiegman fiberglass enclosures from dirt, dust, oil, and water. Conduit hole sizes are nominal trade sizes, not actual hole sizes. (Example: 1 in. conduit actual diameter = 1.315 in.)



Hole Plugs	Price	Description	Nominal Hole Diameter Range in [mm]	Wt. [oz]
<b>HW-FGHP</b>	\$4.75	Hubbell-Wiegmann hole plug, fiber-reinforced plastic (FRP), closed-cell neoprene gasket, for 1/2 to 3/4-inch hole in non-metallic enclosure	0.50 - 0.81 [12.7 - 20.6]	2
<b>HW-FGHP-PB-000</b>	\$11.50	Hubbell-Wiegmann hole plug, fiberglass-reinforced plastic (FRP), closed-cell neoprene gasket. For use with 1/2in conduit holes in non-metallic enclosures.	0.88 [22.4]	2
<b>HW-FGHP-PB-075</b>	\$5.75	Hubbell-Wiegmann hole plug, fiber-reinforced plastic (FRP), closed-cell neoprene gasket, for 1/2- to 3/4-inch conduit holes and 22 or 30mm pushbutton holes in non-metallic enclosure	0.88 - 1.28 [22.4 - 32.5]	2
<b>HW-FGHP-100-125</b>	\$9.50	Hubbell-Wiegmann hole plug, fiber-reinforced plastic (FRP), closed-cell neoprene gasket, for 1 to 1-1/4 inch conduit holes in non-metallic enclosure	1.38 - 1.75 [35.1 - 44.5]	2
<b>HW-FGHP-150-200*</b>	\$11.50	Hubbell-Wiegmann hole plug, fiber-reinforced plastic (FRP), closed-cell neoprene gasket, for 1-1/2 to 2-inch conduit holes in non-metallic enclosure	2.00 - 2.56 [50.1 - 65.0]	2
<b>HW-FGHP-200-275</b>	\$21.50	Hubbell-Wiegmann hole plug, fiberglass-reinforced plastic (FRP), closed-cell neoprene gasket. For use with 2-1/2in conduit holes in non-metallic enclosures.	3.00 [76.2]	2
<b>HW-FGHP-250-350</b>	\$28.50	Hubbell-Wiegmann hole plug, fiberglass-reinforced plastic (FRP), closed-cell neoprene gasket. For use with 3in conduit holes in non-metallic enclosures.	3.62 [92.0]	2
<b>HW-FGHP-300-425</b>	\$37.00	Hubbell-Wiegmann hole plug, fiberglass-reinforced plastic (FRP), closed-cell neoprene gasket. For use with 3-1/2in conduit holes in non-metallic enclosures.	4.12 [104.7]	2
<b>HW-FGHP-350-500</b>	\$47.50	Hubbell-Wiegmann hole plug, fiberglass-reinforced plastic (FRP), closed-cell neoprene gasket. For use with 4in conduit holes in non-metallic enclosures.	4.62 [117.4]	2

*\*Note: Will maintain NEMA 4X rating.*

Enclosure Shipping Schedule			
Same day	1-7 days	1-10 days	1 - 15 days

Color indicates shipping lead time in business days.



# Vents and Louvers for Non-Metallic Enclosures



## Drain/Breather Vents



**HW-DVKIT**



**HW-4XBKIT**



**HW-4XDVKIT**

Part Number	Price	Description	Wt. (oz)
<b>HW-DV</b>	\$9.75	Hubbell-Wiegmann single drain vent, PVC. For use on non-metallic enclosures. Includes drain vent and silicone adhesive/sealant.	2
<b>HW-DVKIT</b>	\$14.00	Hubbell-Wiegmann single drain vent kit, PVC. Includes drain vent and silicone adhesive/sealant.	2
<b>HW-4XBKIT</b>	\$48.00	Hubbell-Wiegmann single breather vent kit allows enclosure to "breathe" while maintaining UL Type 4X enclosure rating.	4.8
<b>HW-4XDVKIT</b>	\$20.00	Hubbell-Wiegmann single drain vent kit properly drains unwanted moisture while maintaining UL Type 4X enclosure rating.	3.2

Enclosure Shipping Schedule	
1-7 days	1 - 15 days
Color indicates shipping lead time in business days.	

## Louver Plate



**HW-LPKIT**

Part Number	Price	Description	Wt.
<b>HW-LP</b>	\$14.00	Louver plate, for ventilation in non-metallic enclosure, polypropylene, 4.5 inch wide x 4.0 inch high. For 3 inch x 3 inch cutout.	2 oz
<b>HW-LPKIT</b>	\$30.50	Louver plate kit, for ventilation in non-metallic enclosure. Includes 4.5 inch wide x 4.0 inch high polypropylene louver plate, rivets and silicone adhesive/sealant. For 3 inch x 3 inch cutout.	2 oz