
 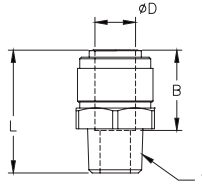




HydroMode™ Potable Water Push-to-Connect Fittings

HydroMode push-to-connect male straight fitting with acetel body and synthetic rubber o-ring. For use with polyethylene and other flexible tubing. Five fittings per package.



| HydroMode™ Male Straight | | | | | | | | | | |
|--|---------|--------------------|-----------|----------|------|------|------------|------|----------------------|---------------|
| Inch Sizes - dimensions in millimeters (mm) unless otherwise noted | | | | | | | | | | |
| Part No. | Price | Size (inch) | ØD (inch) | T (NPTF) | B | ØE | H (inch) | L | Package Weight (lbs) | Qty. per pack |
| MS532-18N-P | \$3.50 | 5/32 in. x 1/8 NPT | 5/32 | 1/8 | 14.7 | 17.8 | 15.8 (5/8) | 22.2 | 0.1 | 5 |
| MS532-14N-P | \$4.00 | 5/32 in. x 1/4 NPT | 5/32 | 1/4 | 14.7 | 17.8 | 15.8 (5/8) | 25.3 | 0.1 | 5 |
| MS14-18N-P | \$4.00 | 1/4 in. x 1/8 NPT | 1/4 | 1/8 | 16.9 | 17.8 | 15.8 (5/8) | 27.0 | 0.1 | 5 |
| MS14-14N-P | \$4.25 | 1/4 in. x 1/4 NPT | 1/4 | 1/4 | 16.9 | 17.8 | 15.8 (5/8) | 27.0 | 0.1 | 5 |
| MS14-38N-P | \$5.75 | 1/4 in. x 3/8 NPT | 1/4 | 1/4 | 16.9 | 21.4 | 19.0 (3/4) | 26.1 | 0.1 | 5 |
| MS516-18N-P | \$4.25 | 5/16 in. x 1/8 NPT | 5/16 | 5/16 | 17.5 | 21.4 | 19.0 (3/4) | 28.4 | 0.1 | 5 |
| MS516-14N-P | \$4.50 | 5/16 in. x 1/4 NPT | 5/16 | 5/16 | 17.5 | 21.4 | 19.0 (3/4) | 27.9 | 0.1 | 5 |
| MS516-38N-P | \$6.25 | 5/16 in. x 3/8 NPT | 5/16 | 5/16 | 17.5 | 21.4 | 19.0 (3/4) | 26.5 | 0.1 | 5 |
| MS516-12N-P | \$4.00 | 5/16 in. x 1/2 NPT | 5/16 | 5/16 | 17.5 | 25.0 | 22.2 (7/8) | 33.5 | 0.1 | 5 |
| MS38-18N-P | \$8.25 | 3/8 in. x 1/8 NPT | 3/8 | 3/8 | 20.2 | 23.0 | 20.6 (3/4) | 30.4 | 0.1 | 5 |
| MS38-14N-P | \$6.25 | 3/8 in. x 1/4 NPT | 3/8 | 3/8 | 20.2 | 23.0 | 20.6 (3/4) | 34.3 | 0.1 | 5 |
| MS38-38N-P | \$7.50 | 3/8 in. x 3/8 NPT | 3/8 | 3/8 | 20.2 | 23.0 | 20.6 (3/4) | 29.6 | 0.1 | 5 |
| MS38-12N-P | \$11.00 | 3/8 in. x 1/2 NPT | 3/8 | 1/2 | 20.2 | 25.0 | 22.2 (7/8) | 33.9 | 0.1 | 5 |
| MS12-38N-P | \$10.00 | 1/2 in. x 3/8 NPT | 1/2 | 3/8 | 25.1 | 27.4 | 25.4 (1.0) | 38.4 | 0.1 | 5 |
| MS12-12N-P | \$10.50 | 1/2 in. x 1/2 NPT | 1/2 | 1/2 | 25.1 | 27.4 | 25.4 (1.0) | 37.9 | 0.1 | 5 |

 HydroMode push-to-connect female straight fitting with acetel body and synthetic rubber o-ring. For use with polyethylene and other flexible tubing. Five fittings per package.

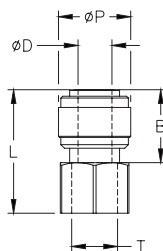


| HydroMode™ Female Straight | | | | | | | | | | | |
|--|--------|-------------------|-----------|------|----------|------|------|---------|------|----------------------|---------------|
| Inch Sizes - dimensions in millimeters (mm) unless otherwise noted | | | | | | | | | | | |
| Part No. | Price | Size (inch) | ØD (inch) | ØP | T (NPTF) | B | ØE | H (Hex) | L | Package Weight (lbs) | Qty. per pack |
| FS14-18N-P | \$6.00 | 1/4 in. x 1/8 NPT | 1/4 | 15.5 | 1/8 | 16.9 | 19.0 | 17.0 | 30.9 | 0.1 | 5 |
| FS14-14N-P | \$6.00 | 1/4 in. x 1/4 NPT | 1/4 | 15.5 | 1/4 | 16.9 | 21.5 | 19.0 | 30.9 | 0.1 | 5 |
| FS38-14N-P | \$6.50 | 3/8 in. x 1/4 NPT | 3/8 | 20.0 | 1/4 | 20.2 | 21.5 | 19.0 | 34.2 | 0.1 | 5 |

HydroMode™ Potable Water Push-to-Connect Fittings

HydroMode push-to-connect fittings are designed to work with potable water and beverages. Installing or removing flexible tubing is quick and easy. All fittings are made of NSF approved materials with NSF-51® and NSF-61® certifications. The body and collet of the fittings are made from polyoxymethylene (POM) also known as acetal, while the o-rings are made from ethylene propylene diene monomer (EPDM) which is a type of synthetic rubber.

Features

- Designed for potable water and beverages
- NSF-51 and NSF-61 certified
- Easy tubing installation and removal
- Optional retaining clips prevent accidental tube removal
- Fittings rated for up to 145psi at 70°C (158°F)

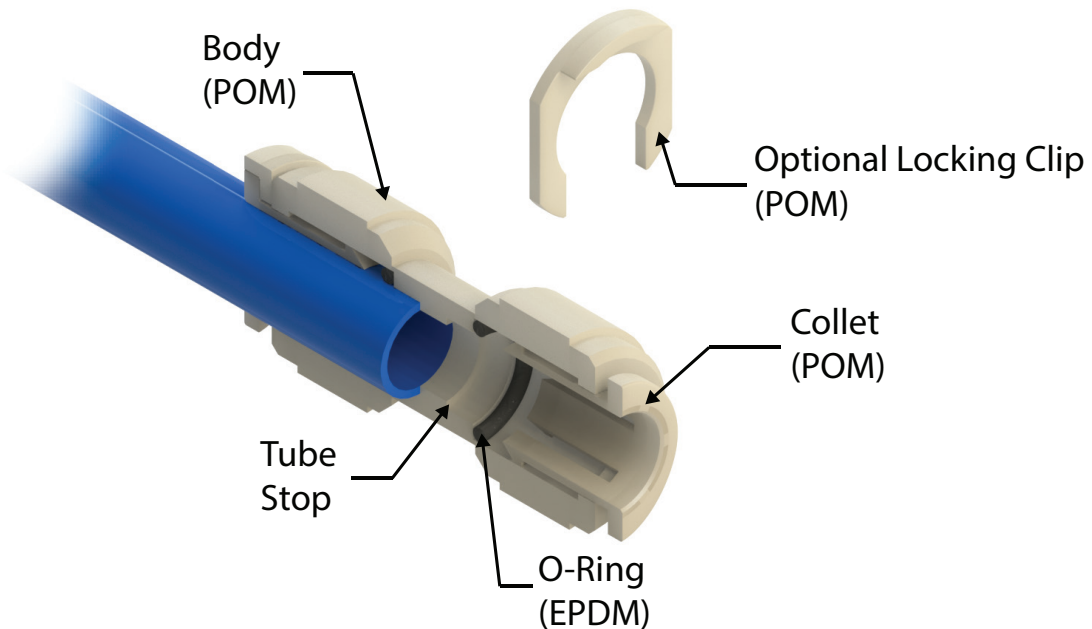

*Push-to-Connect Fitting
Cut-away Diagram*